

Item description/product images



Description

Material:

Steel.

Version:

Electro zinc-plated.

Note:


*A in mm by housing length H=18 mm, H=30 mm and H=50 mm.

Accessory:

Quarter-turn lock zinc, lockable 05564-10.

quarter-turn lock zinc, lockable, long version 05564-14.

Drawings

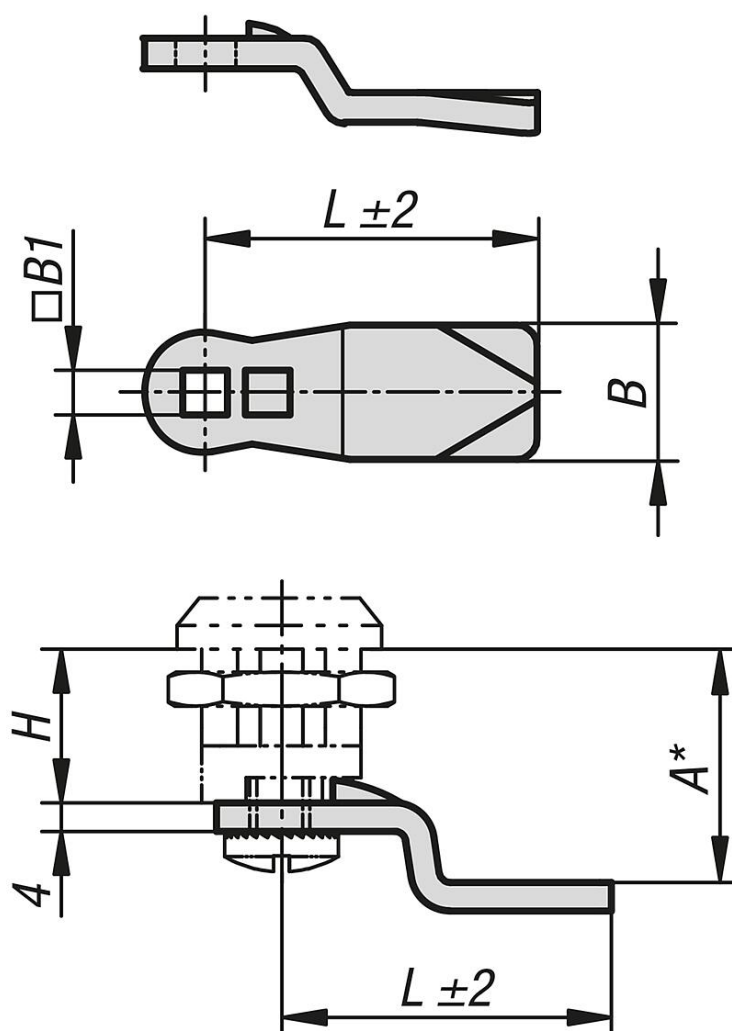

Overview of items

Order No.	Version 2	A for housing length H=18	A for housing length H=30	A for housing length H=50	B	B1	L
05564-15-13506	Size 1	6	18	38	19	8,1	35
05564-15-13508	Size 1	8	20	40	19	8,1	35
05564-15-13510	Size 1	10	22	42	19	8,1	35
05564-15-13513	Size 1	13	25	45	19	8,1	35
05564-15-13514	Size 1	14	26	46	19	8,1	35
05564-15-13516	Size 1	16	28	48	19	8,1	35
05564-15-13518	conus	18	30	50	19	8,1	35
05564-15-13520	Size 1-3	20	32	52	19	8,1	35
05564-15-13522	Size 1-3	22	34	54	19	8,1	35
05564-15-13524	Size 1-3	24	36	56	19	8,1	35
05564-15-13526	Size 1-3	26	38	58	19	8,1	35
05564-15-13528	Size 1-3	28	40	60	19	8,1	35
05564-15-14504	Size 1	4	16	36	19	8,1	45
05564-15-14506	Size 1	6	18	38	19	8,1	45
05564-15-14508	Size 1	8	20	40	19	8,1	45
05564-15-14510	Size 1	10	22	42	19	8,1	45
05564-15-14513	Size 1	13	25	45	19	8,1	45
05564-15-14514	Size 1	14	26	46	19	8,1	45
05564-15-14516	Size 1	16	28	48	19	8,1	45
05564-15-14518	conus	18	30	50	19	8,1	45
05564-15-14520	Size 1-3	20	32	52	19	8,1	45
05564-15-14522	Size 1-3	22	34	54	19	8,1	45
05564-15-14524	Size 1-3	24	36	56	19	8,1	45
05564-15-14526	Size 1-3	26	38	58	19	8,1	45
05564-15-14528	Size 1-3	28	40	60	19	8,1	45
05564-15-14530	Size 1-3	30	42	62	19	8,1	45
05564-15-14532	Size 1-3	32	44	64	19	8,1	45
05564-15-14534	Size 1-3	34	46	66	19	8,1	45
05564-15-14536	Size 1-3	36	48	68	19	8,1	45
05564-15-14538	Size 1-3	38	50	70	19	8,1	45
05564-15-14540	Size 1-3	40	52	72	19	8,1	45
05564-15-14542	Size 1-3	42	54	74	19	8,1	45