



Description

Material:

Slides steel.
Ball cages steel.
Balls, steel.

Version:

Slides electro zinc-plated.
Ball cages, electro zinc-plated.
Balls hardened.

Note for ordering:

Sold in pairs.

Note:

By telescopic slides with full extension, the travel is roughly equal to the installed length, which ensures greater comfort and accessibility. When the release lever is actuated, the drawer can be taken out easily and separated from the guide. The dynamic load capacity of the telescopic slides indicates the maximum load rating of a vertically mounted slide pair when the entire extension length is used.

Not suitable for horizontal mounting.

The head height of the fastening screws should not exceed 2.5 mm otherwise there is a risk of collision with other parts of the slide.

Form A:

When closing, the movement of the telescopic slides is dampened by the soft closing feature and they move automatically into the end position.

The load capacities specified are based on the maximum value by 80,000 cycles.

Form B:

The telescopic slides slide automatically and almost soundlessly out with just a light push. The load capacity specified is calculated with a slide spacing of 450 mm and is based on the maximum value with 80,000 cycles.

Form C:

Latches in open and closed positions. The load capacity specified is calculated with a slide spacing of 450 mm and is based on the maximum value with 10,000 or 80,000 cycles.

Form D:

Latches in closed position.

The load capacity specified is calculated with a slide spacing of 450 mm and is based on the maximum value with 80,000 cycles.

Form E:

The self-retraction function enables the slides to slide automatically into the closed position. The load capacity specified is calculated with a slide spacing of 450 mm and is based on the maximum value with 10,000 or 80,000 cycles.

Temperature range:

Form A:

+10 °C to +40 °C.

Form B:
-20 °C to +70 °C.

Form C:
-20 °C to +70 °C.

Form D:
-20 °C to +70 °C.

Advantages:

Soft close
Push to open
Self-retracting
Latches in open and closed positions
Quick frontal release

Accessory:

Steel mounting bracket for telescopic slides 21335-80


Drawing reference:


Form B:
1) Mounting hole by 21334-15-2040022, 21334-15-2050022,
21334-15-2060022, 21334-15-2040035, 21334-15-2050035 and
21334-15-2060035 not provided

Form C:
1) Mounting hole by 21334-15-30600, 21334-15-30650 and 21334-15-30700
provided
2) Mounting hole by 21334-15-30250 not provided

Form D:
1) Mounting hole by 21334-15-40148, 21334-15-40199
and 21334-15-40250 not provided
2) Mounting hole by 21334-15-40600, 21334-15-40650
and 21334-15-40700 provided
3) Mounting hole by 21334-15-30600 and 21334-15-30650 not provided

Form E:
1) Mounting hole by 21444-15-5040027, 21554-15-5050027, 21447-15-5040041
and 21557-15-5050041 not provided

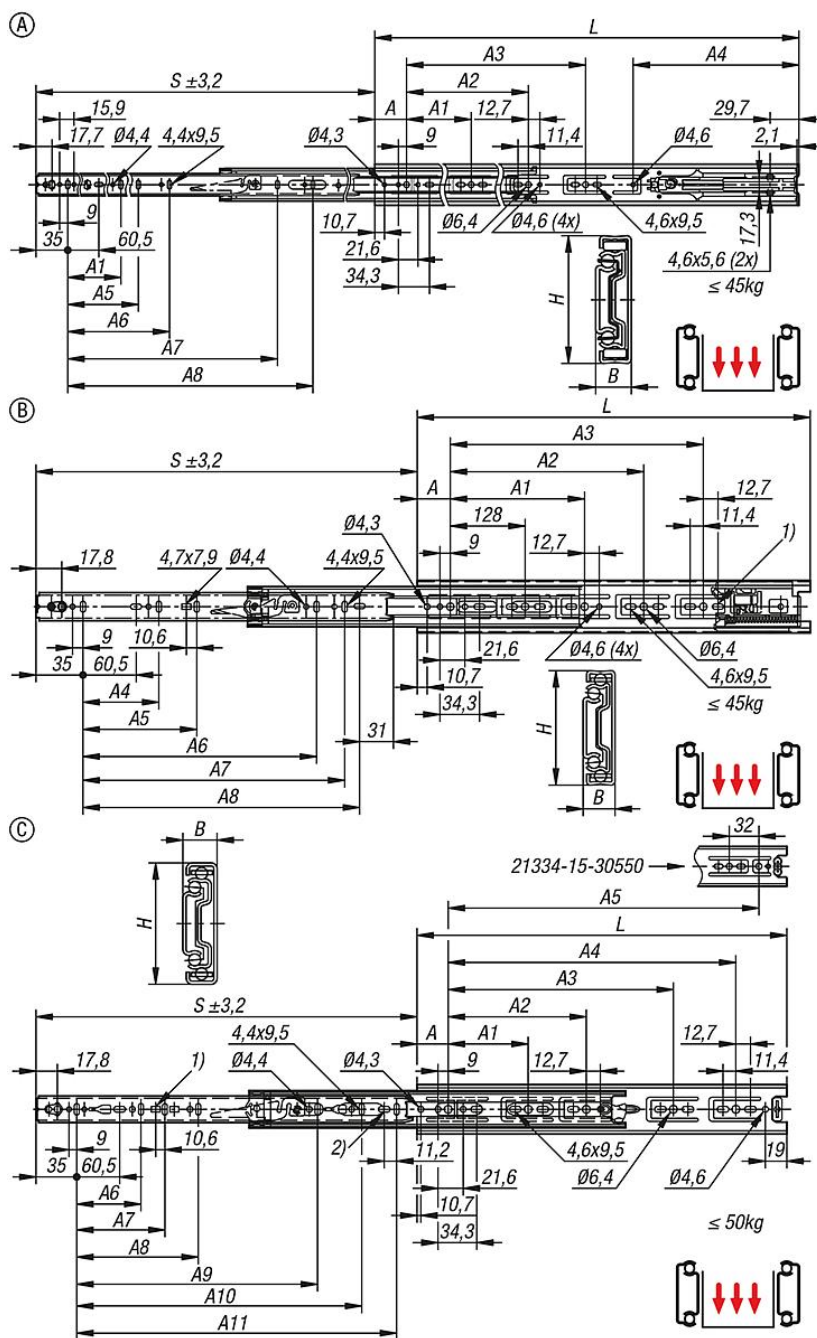

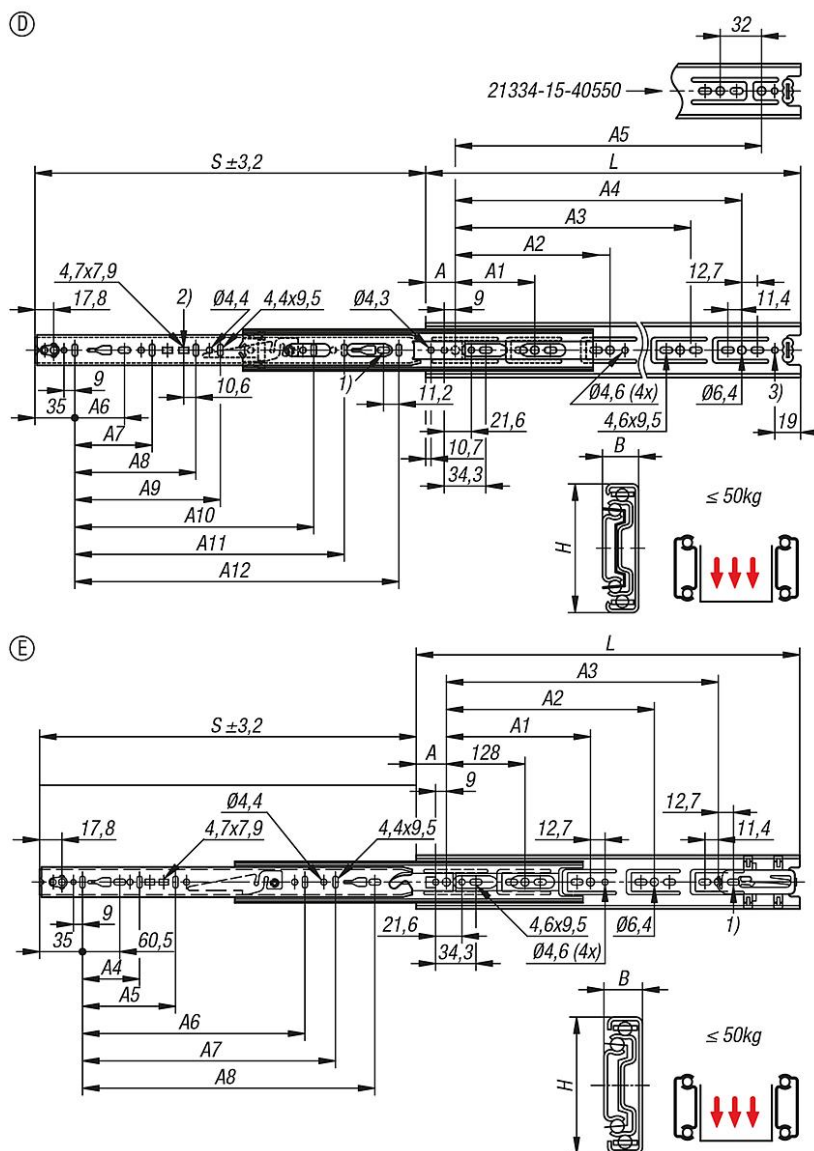

Overview of items

Order No.	Form	Form definition	Assembly	Product type	Load capacity per pair (80,000 cycles) kg	Packaging type
21334-15-10350	DZ3832-0035EC-B	A Soft close	side mounting	standard	43	1 piece = 1 pair
21334-15-10400	DZ3832-0040EC-B	A Soft close	side mounting	standard	44	1 piece = 1 pair
21334-15-10450	DZ3832-0045EC-B	A Soft close	side mounting	standard	45	1 piece = 1 pair
21334-15-10500	DZ3832-0050EC-B	A Soft close	side mounting	standard	45	1 piece = 1 pair
21334-15-10550	DZ3832-0055EC-B	A Soft close	side mounting	standard	45	1 piece = 1 pair
21334-15-10600	DZ3832-0060EC-B	A Soft close	side mounting	standard	45	1 piece = 1 pair
21334-15-10650	DZ3832-0065EC-B	A Soft close	side mounting	standard	44	1 piece = 1 pair
21334-15-10700	DZ3832-0070EC-B	A Soft close	side mounting	standard	43	1 piece = 1 pair

Order No.	A	A1	A2	A3	A4	A5	A6	A7	A8	B	H	Travel S	L
21334-15-10350	35	-	-	-	180,8	-	-	206	-	12,7	45,7	310	350
21334-15-10400	35	128	-	-	180,8	-	-	257	-	12,7	45,7	406	400
21334-15-10450	35	128	224	-	-	-	-	305	-	12,7	45,7	457	450
21334-15-10500	35	128	224	-	180,8	-	-	352	-	12,7	45,7	508	500
21334-15-10550	35	128	224	-	180,8	-	-	407	352	12,7	45,7	559	550
21334-15-10600	35	128	224	352	-	224	-	-	416	12,7	45,7	610	600
21334-15-10650	35	128	224	352	180,8	224	-	-	416	12,7	45,7	660	650

21334-15 Telescopic slides, steel for side mounting, full extension, load capacity up to 50 kg



Overview of items

Order No.	A	A1	A2	A3	A4	A5	A6	A7	A8	B	H	Travel S	L
21334-15-10700	35	128	224	352	180,8	224	288	-	544	12,7	45,7	711	700

Order No.	Form	Form definition	Activating force N	Assembly	Product type	Load capacity per pair (80,000 cycles) kg	Packaging type	
21334-15-2030022	DZ3832-0030TR	B	Push to open	22	side mounting	standard	42	1 piece = 1 pair
21334-15-2035022	DZ3832-0035TR	B	Push to open	22	side mounting	standard	43	1 piece = 1 pair
21334-15-2040022	DZ3832-0040TR	B	Push to open	22	side mounting	standard	44	1 piece = 1 pair
21334-15-2045022	DZ3832-0045TR	B	Push to open	22	side mounting	standard	45	1 piece = 1 pair
21334-15-2050022	DZ3832-0050TR	B	Push to open	22	side mounting	standard	45	1 piece = 1 pair
21334-15-2055022	DZ3832-0055TR	B	Push to open	22	side mounting	standard	45	1 piece = 1 pair
21334-15-2060022	DZ3832-0060TR	B	Push to open	22	side mounting	standard	45	1 piece = 1 pair
21334-15-2065022	DZ3832-0065TR	B	Push to open	22	side mounting	standard	44	1 piece = 1 pair
21334-15-2070022	DZ3832-0070TR	B	Push to open	22	side mounting	standard	43	1 piece = 1 pair
21334-15-2030035	DZ3832-0030HDTR	B	Push to open	35	side mounting	standard	42	1 piece = 1 pair
21334-15-2035035	DZ3832-0035HDTR	B	Push to open	35	side mounting	standard	43	1 piece = 1 pair
21334-15-2040035	DZ3832-0040HDTR	B	Push to open	35	side mounting	standard	44	1 piece = 1 pair
21334-15-2045035	DZ3832-0045HDTR	B	Push to open	35	side mounting	standard	45	1 piece = 1 pair
21334-15-2050035	DZ3832-0050HDTR	B	Push to open	35	side mounting	standard	45	1 piece = 1 pair
21334-15-2055035	DZ3832-0055HDTR	B	Push to open	35	side mounting	standard	45	1 piece = 1 pair
21334-15-2060035	DZ3832-0060HDTR	B	Push to open	35	side mounting	standard	45	1 piece = 1 pair
21334-15-2065035	DZ3832-0065HDTR	B	Push to open	35	side mounting	standard	44	1 piece = 1 pair
21334-15-2070035	DZ3832-0070HDTR	B	Push to open	35	side mounting	standard	43	1 piece = 1 pair

Order No.	A	A1	A2	A3	A4	A5	A6	A7	A8	B	H	Travel S	L
21334-15-2030022	35	-	-	-	-	-	-	-	192	12,7	45,7	305	300
21334-15-2035022	35	224	-	-	128	-	-	-	242	12,7	45,7	356	350
21334-15-2040022	35	224	288	-	128	-	-	-	292	12,7	45,7	406	400
21334-15-2045022	35	224	320	-	128	-	320	-	342	12,7	45,7	457	450
21334-15-2050022	35	224	384	-	128	-	320	-	392	12,7	45,7	508	500
21334-15-2055022	35	224	416	-	128	224	416	-	442	12,7	45,7	559	550
21334-15-2060022	35	224	352	480	128	224	416	-	492	12,7	45,7	610	600
21334-15-2065022	35	224	352	512	128	224	416	512	542	12,7	45,7	660	650
21334-15-2070022	35	224	352	544	128	224	416	512	592	12,7	45,7	711	700
21334-15-2030035	35	-	-	-	-	-	-	-	192	12,7	45,7	305	300
21334-15-2035035	35	224	-	-	128	-	-	-	242	12,7	45,7	356	350
21334-15-2040035	35	224	288	-	128	-	-	-	292	12,7	45,7	406	400
21334-15-2045035	35	224	320	-	128	-	320	-	342	12,7	45,7	457	450
21334-15-2050035	35	224	384	-	128	-	320	-	392	12,7	45,7	508	500
21334-15-2055035	35	224	416	-	128	224	416	-	442	12,7	45,7	559	550
21334-15-2060035	35	224	352	480	128	224	416	-	492	12,7	45,7	610	600
21334-15-2065035	35	224	352	512	128	224	416	512	542	12,7	45,7	660	650
21334-15-2070035	35	224	352	544	128	224	416	512	592	12,7	45,7	711	700

Order No.	Form	Form definition	Assembly	Product type	Load capacity per pair (80,000 cycles) kg	Loading pair (10,000 cycles) kg	Packaging type	
21334-15-30250	DZ3832-0025DO	C	latches in closed and open positions	side mounting	standard	41	47	1 piece = 1 pair
21334-15-30300	DZ3832-0030DO	C	latches in closed and open positions	side mounting	standard	42	48	1 piece = 1 pair
21334-15-30350	DZ3832-0035DO	C	latches in closed and open positions	side mounting	standard	43	49	1 piece = 1 pair
21334-15-30400	DZ3832-0040DO	C	latches in closed and open positions	side mounting	standard	44	50	1 piece = 1 pair
21334-15-30450	DZ3832-0045DO	C	latches in closed and open positions	side mounting	standard	45	50	1 piece = 1 pair
21334-15-30500	DZ3832-0050DO	C	latches in closed and open positions	side mounting	standard	45	50	1 piece = 1 pair
21334-15-30550	DZ3832-0055DO	C	latches in closed and open positions	side mounting	standard	45	50	1 piece = 1 pair
21334-15-30600	DZ3832-0060DO	C	latches in closed and open positions	side mounting	standard	45	50	1 piece = 1 pair
21334-15-30650	DZ3832-0065DO	C	latches in closed and open positions	side mounting	standard	44	49	1 piece = 1 pair
21334-15-30700	DZ3832-0070DO	C	latches in closed and open positions	side mounting	standard	43	48	1 piece = 1 pair

Order No.	A	A1	A2	A3	A4	A5	A6	A7	A8	A9	A10	A11	B	H	Travel S	L
21334-15-30250	35	-	160	-	-	-	96	-	-	-	-	192	12,7	45,7	243	250
21334-15-30300	35	-	224	-	-	-	96	-	-	-	-	242	12,7	45,7	305	300
21334-15-30350	35	128	224	-	-	-	128	-	-	-	-	292	12,7	45,7	356	350

21334-15 Telescopic slides, steel for side mounting, full extension, load capacity up to 50 kg



Overview of items

Order No.	A	A1	A2	A3	A4	A5	A6	A7	A8	A9	A10	A11	B	H	Travel S	L
21334-15-30400	35	128	224	320	-	-	128	-	-	-	-	342	12,7	45,7	406	400
21334-15-30450	35	128	-	352	-	-	128	-	-	320	-	392	12,7	45,7	457	450
21334-15-30500	35	128	-	416	-	-	128	-	-	320	-	442	12,7	45,7	508	500
21334-15-30550	35	128	-	352	-	480	128	-	-	320	416	492	12,7	45,7	559	550
21334-15-30600	35	128	224	352	480	-	128	224	-	416	-	542	12,7	45,7	610	600
21334-15-30650	35	128	224	352	544	-	128	224	-	416	544	592	12,7	45,7	660	650
21334-15-30700	35	128	224	352	544	-	128	224	288	416	544	642	12,7	45,7	711	700

Order No.	Form	Form definition	Assembly	Product type	Load capacity per pair (80,000 cycles) kg	Packaging type
21334-15-40148	D	latches in closed position	side mounting	standard	45	1 piece = 1 pair
21334-15-40199	D	latches in closed position	side mounting	standard	46	1 piece = 1 pair
21334-15-40250	D	latches in closed position	side mounting	standard	47	1 piece = 1 pair
21334-15-40300	D	latches in closed position	side mounting	standard	48	1 piece = 1 pair
21334-15-40350	D	latches in closed position	side mounting	standard	49	1 piece = 1 pair
21334-15-40400	D	latches in closed position	side mounting	standard	50	1 piece = 1 pair
21334-15-40450	D	latches in closed position	side mounting	standard	50	1 piece = 1 pair
21334-15-40500	D	latches in closed position	side mounting	standard	50	1 piece = 1 pair
21334-15-40550	D	latches in closed position	side mounting	standard	50	1 piece = 1 pair
21334-15-40600	D	latches in closed position	side mounting	standard	50	1 piece = 1 pair
21334-15-40650	D	latches in closed position	side mounting	standard	49	1 piece = 1 pair
21334-15-40700	D	latches in closed position	side mounting	standard	49	1 piece = 1 pair

Order No.	A	A1	A2	A3	A4	A5	A6	A7	A8	A9	A10	A11	A12	B	H	Travel S	L
21334-15-40148	35	77,2	-	-	-	-	-	-	-	-	-	-	96	12,7	45,7	138	148
21334-15-40199	35	128	-	-	-	-	60,5	128	-	-	-	-	141	12,7	45,7	203	199
21334-15-40250	35	128	-	-	-	-	60,5	96	-	-	-	-	192	12,7	45,7	354	250
21334-15-40300	35	128	224	-	-	-	60,5	96	-	-	-	-	242	12,7	45,7	305	300
21334-15-40350	35	128	224	-	-	-	60,5	128	-	-	-	-	292	12,7	45,7	356	350
21334-15-40400	35	128	224	320	-	-	60,5	128	-	-	-	-	342	12,7	45,7	406	400
21334-15-40450	35	128	224	352	-	-	60,5	128	-	-	320	-	392	12,7	45,7	457	450
21334-15-40500	35	128	224	416	-	-	60,5	128	-	-	320	-	442	12,7	45,7	508	500
21334-15-40550	35	128	224	352	448	480	60,5	128	-	-	320	416	492	12,7	45,7	559	550
21334-15-40600	35	128	224	352	480	-	60,5	128	224	-	416	-	542	12,7	45,7	610	600
21334-15-40650	35	128	224	352	544	-	60,5	128	224	-	416	544	592	12,7	45,7	660	650
21334-15-40700	35	128	224	352	544	-	60,5	128	224	288	416	544	642	12,7	45,7	711	700