



Description

Material:

Slides steel.
Ball cages steel.
Balls, steel.

Version:

Slides electro zinc-plated.
Ball cages, electro zinc-plated.
Balls hardened.

Note for ordering:

Sold in pairs.

Note:


On telescopic slides with partial extension both sides, the travel is less than the installed length. Latches in open position on both sides. The dynamic load capacity of the telescopic slides indicates the maximum load rating of a vertically mounted slide pair when the entire extension length is used. The load capacity specified is calculated with a slide spacing of 450 mm and is based on the maximum value with 50,000 cycles.

The load capacity is ca. 75% lower by horizontal mounting.

The head height of the fastening screws should not exceed 2.5 mm otherwise there is a risk of collision with other parts of the slide.

Advantages:

Pulls out in both directions
Latches in open position on both sides
Light running

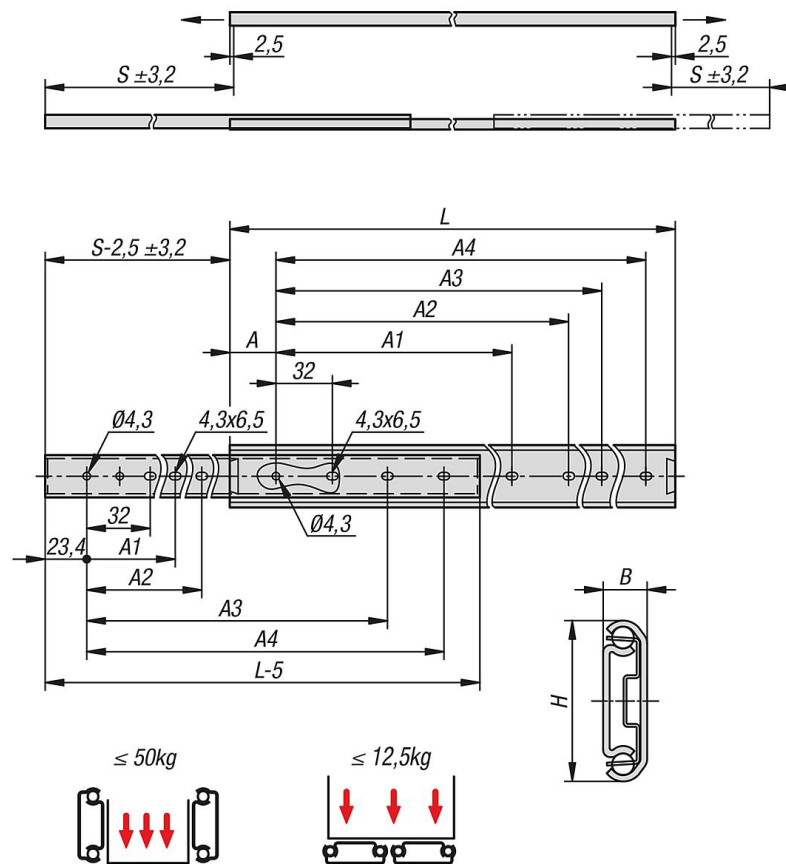

Overview of items

Order No.		Assembly	Product type	Loading per pair kg	Packaging type
21334-25-0300	DZ2026-0030	side mounting	standard	50	1 piece = 1 pair
21334-25-0350	DZ2026-0035	side mounting	standard	50	1 piece = 1 pair
21334-25-0400	DZ2026-0040	side mounting	standard	45	1 piece = 1 pair
21334-25-0450	DZ2026-0045	side mounting	standard	40	1 piece = 1 pair
21334-25-0500	DZ2026-0050	side mounting	standard	40	1 piece = 1 pair
21334-25-0550	DZ2026-0055	side mounting	standard	35	1 piece = 1 pair
21334-25-0600	DZ2026-0060	side mounting	standard	35	1 piece = 1 pair
21334-25-0650	DZ2026-0065	side mounting	standard	30	1 piece = 1 pair
21334-25-0700	DZ2026-0070	side mounting	standard	30	1 piece = 1 pair

Order No.	A	A1	A2	A3	A4	B	H	Travel S	L
21334-25-0300	26	128	160	224	256	9,5	35,3	208,8	300
21334-25-0350	26	160	192	256	288	9,5	35,3	246,1	350
21334-25-0400	26	192	224	320	352	9,5	35,3	283,4	400
21334-25-0450	26	224	256	352	384	9,5	35,3	320,7	450
21334-25-0500	26	256	288	416	448	9,5	35,3	358	500
21334-25-0550	26	256	288	480	512	9,5	35,3	395,3	550
21334-25-0600	26	288	320	512	544	9,5	35,3	432,6	600
21334-25-0650	26	288	320	576	608	9,5	35,3	469,9	650
21334-25-0700	26	320	352	608	640	9,5	35,3	507,2	700

