

Description

Material:

Slides steel.
Ball cages steel.
Balls, steel.

Version:

Slides electro zinc-plated.
Ball cages, electro zinc-plated.
Balls hardened.

Note for ordering:

Sold in pairs.

Note:

On telescopic slides with over-extension, the travel is greater than the installed length.

The dynamic load capacity of the telescopic slides indicates the maximum load rating of a vertically mounted slide pair when the entire extension length is used. The load capacity specified is calculated with a slide spacing of 450 mm and is based on the maximum value with 10,000 cycles.

The load capacity is ca. 75% lower by horizontal mounting.


The head height of the fastening screws should not exceed 2.5 mm otherwise there is a risk of collision with other parts of the slide.

Temperature range:

-20 °C - +70 °C.

Advantages:

Suitable for flat mounting
Light running
Precise guidance for high lateral stability

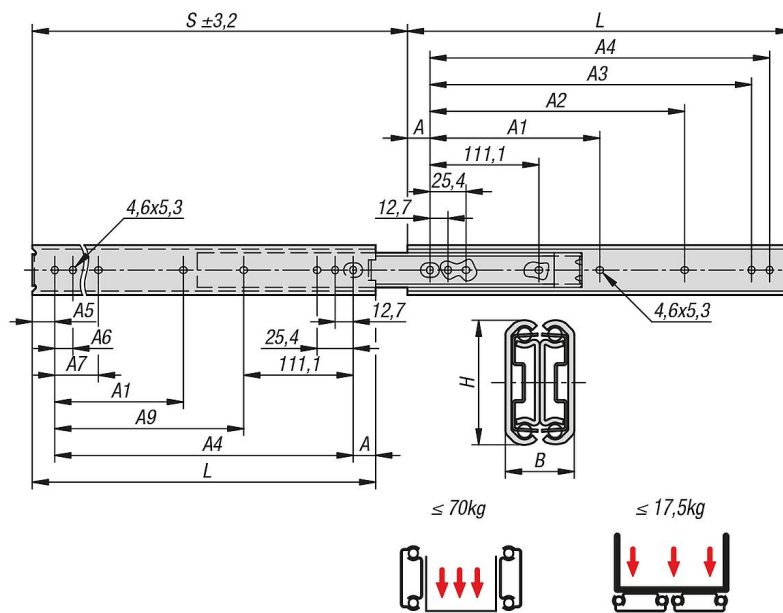

Overview of items

Order No.		Assembly	Product type	Loading per pair kg	Packaging type
21334-70-0305	DZ0301-0012	side mounting	standard	70	1 piece = 1 pair
21334-70-0356	DZ0301-0014	side mounting	standard	67	1 piece = 1 pair
21334-70-0406	DZ0301-0016	side mounting	standard	65	1 piece = 1 pair
21334-70-0457	DZ0301-0018	side mounting	standard	63	1 piece = 1 pair
21334-70-0508	DZ0301-0020	side mounting	standard	60	1 piece = 1 pair
21334-70-0559	DZ0301-0022	side mounting	standard	55	1 piece = 1 pair
21334-70-0610	DZ0301-0024	side mounting	standard	50	1 piece = 1 pair
21334-70-0660	DZ0301-0026	side mounting	standard	45	1 piece = 1 pair
21334-70-0711	DZ0301-0028	side mounting	standard	40	1 piece = 1 pair

Order No.	A	A1	A2	A3	A4	A5	A6	A7	A9	B	H	Travel S	L
21334-70-0305	15,9	-	149,2	260,3	273	16,1	12,7	123,8	161,9	19,1	35,3	327	305
21334-70-0356	15,9	-	200	311,1	323,8	16,3	12,7	123,8	212,7	19,1	35,3	378	356
21334-70-0406	15,9	-	250,8	361,9	374,6	15,5	12,7	123,8	263,5	19,1	35,3	429	406
21334-70-0457	15,9	212,7	301,6	412,7	425,4	15,7	12,7	123,8	314,3	19,1	35,3	480	457
21334-70-0508	15,9	238,1	352,4	463,5	476,2	15,9	12,7	123,8	365,1	19,1	35,3	530	508
21334-70-0559	15,9	263,5	403,2	514,3	527	16,1	12,7	123,8	415,9	19,1	35,3	581	559
21334-70-0610	15,9	288,9	454	565,1	577,8	16,3	12,7	123,8	466,7	19,1	35,3	632	610
21334-70-0660	15,9	314,3	504,8	615,9	628,6	15,5	12,7	123,8	517,5	19,1	35,3	683	660
21334-70-0711	15,9	339,7	555,6	666,7	679,4	15,7	12,7	123,8	568,3	19,1	35,3	734	711