



Description

Material:

Rail stainless steel 1.4301.
Ball cage stainless steel 1.4301.
Balls stainless steel 1.4034.

Version:

Slides bright.
Ball cages bright.
Balls bright.

Note for ordering:

Sold in pairs.

Note:

On telescopic slides with partial extension, the travel is less than the installed length.
Latches in closed position.

The dynamic load capacity of the telescopic slides indicates the maximum load rating of a vertically mounted slide pair when the entire extension length is used.
The load capacity specified is calculated with a slide spacing of 450 mm and is based on the maximum value with 10,000 or 80,000 cycles.


The load capacity is ca. 75% lower by horizontal mounting.

The head height of the fastening screws should not exceed 2.5 mm otherwise there is a risk of collision with other parts of the slide.

Advantages:

Latches in closed position
Suitable for flat mounting
Light running

Drawings

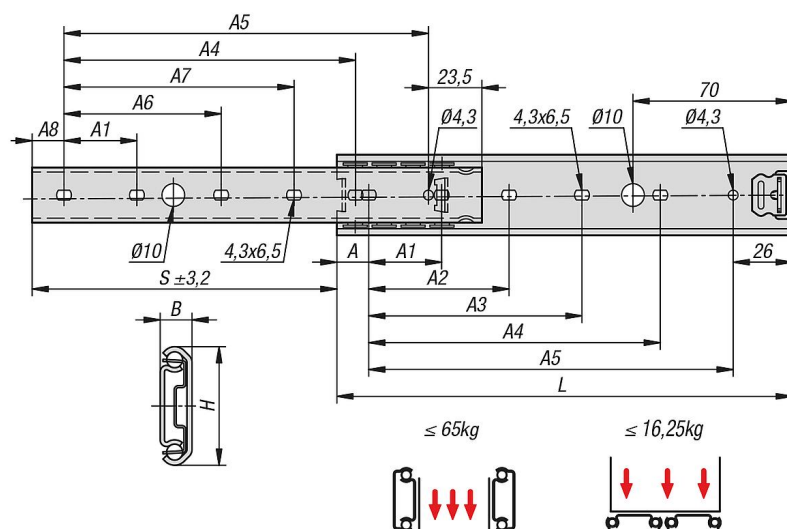

21334-50 Telescopic slides, stainless steel for side mounting, partial extension, load capacity up to 65 kg



Overview of items

Order No.	Manufacturers article number	Assembly	Product type	Load capacity per pair (80,000 cycles) kg	Loading pair (10,000 cycles) kg	Packaging type
21334-50-0300	DS2028-0030	side mounting	standard	60	65	1 piece = 1 pair
21334-50-0350	DS2028-0035	side mounting	standard	57	63	1 piece = 1 pair
21334-50-0400	DS2028-0040	side mounting	standard	54	59	1 piece = 1 pair
21334-50-0450	DS2028-0045	side mounting	standard	50	57	1 piece = 1 pair
21334-50-0500	DS2028-0050	side mounting	standard	47	53	1 piece = 1 pair
21334-50-0550	DS2028-0055	side mounting	standard	45	50	1 piece = 1 pair
21334-50-0600	DS2028-0060	side mounting	standard	43	46	1 piece = 1 pair
21334-50-0650	DS2028-0065	side mounting	standard	41	43	1 piece = 1 pair
21334-50-0700	DS2028-0070	side mounting	standard	40	42	1 piece = 1 pair

Order No.	A	A1	A2	A3	A4	A5	A6	A7	A8	B	H	Travel S	L
21334-50-0300	18	32	-	-	224	256	128	160	17,5	9,5	35,34	209	300
21334-50-0350	36	32	160	192	256	288	160	192	35,5	9,5	35,34	245	350
21334-50-0400	22	32	160	192	320	352	160	192	21,5	9,5	35,34	282	400
21334-50-0450	8	32	224	256	384	416	224	256	7,5	9,5	35,34	320	450
21334-50-0500	26	32	224	256	416	448	224	256	25,5	9,5	35,34	357	500
21334-50-0550	12	32	288	320	480	512	288	320	11,5	9,5	35,34	394	550
21334-50-0600	30	32	288	320	512	544	288	320	29,5	9,5	35,34	432	600
21334-50-0650	16	32	352	384	576	608	352	384	15,5	9,5	35,34	469	650
21334-50-0700	34	32	352	384	608	640	352	384	33,5	9,5	35,34	506	700