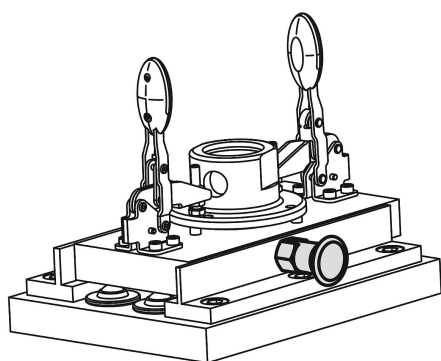


Item description/product images

INCH
Parts

Description

Material:

Steel version
Indexing pin hardened:
grade 5.8

Stainless steel version
Indexing pin not hardened:
Threaded sleeve 1.4305.
Indexing pin 1.4305.

Mushroom knob black-grey thermoplastic.

Version:

Steel version:
Indexing pin hardened, ground, black oxidised.

Stainless steel version:
Indexing pin not hardened, ground, bright.


Note:

Indexing plungers are used to prevent any change in position due to lateral forces. A new locking position can only be set after the pin has been manually disengaged. Form C or D is recommended for applications in which the pin is disengaged over extended periods and should be prevented from springing back.

On request:

Special versions.

Drawings

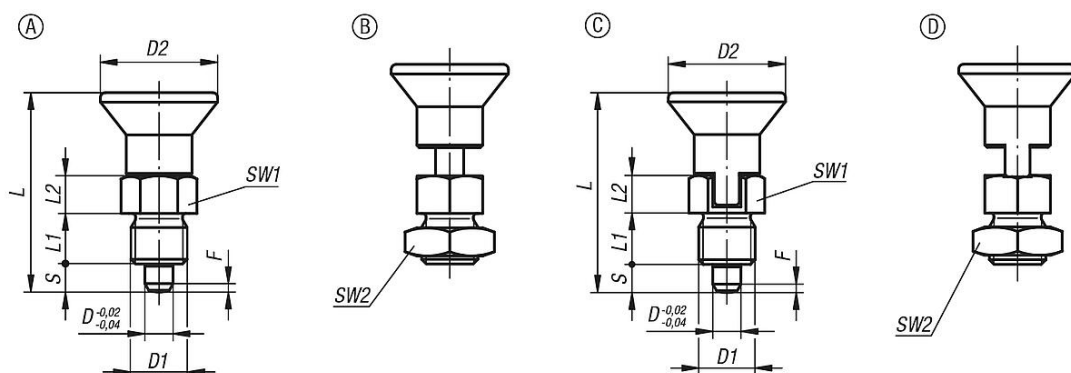

Overview of items

Indexing Plungers short version, pull knob, steel, locking pin hardened, inch

Order No.	Form	Main material	Surface finish body	Component colour	D	D1	D2	L	L1	L2	Travel S	SW1	SW2	Fx30°	Spring force initial pressure F1 approx. N	Spring force final pressure F2 approx. N
03089-5004AK	A	steel	hardened	black grey RAL 7021	4	5/16-24	18	29,5	6	6	4	10	-	1	6	12
03089-5105AL	A	steel	hardened	black grey RAL 7021	5	3/8-24	21	34,5	8	7	5	13	-	1,3	5	12
03089-5206A5	A	steel	hardened	black grey RAL 7021	6	1/2-13	25	41,7	10	8	6	14	-	1,8	6	14
03089-5308A6	A	steel	hardened	black grey RAL 7021	8	5/8-11	33	54	12	10	8	19	-	2,3	14	28
03089-5410A7	A	steel	hardened	black grey RAL 7021	10	3/4-10	33	61	15	12	10	22	-	2,8	15	32
03089-15004AK	A	stainless steel	not hardened	black grey RAL 7021	4	5/16-24	18	29,5	6	6	4	10	-	1	6	12

Overview of items

Order No.	Form	Main material	Surface finish body	Component colour	D	D1	D2	L	L1	L2	Travel S	SW1	SW2	Fx30°	Spring force initial pressure F1 approx. N	Spring force final pressure F2 approx. N
03089-15105AL	A	stainless steel	not hardened	black grey RAL 7021	5	3/8-24	21	34,5	8	7	5	13	-	1,3	5	12
03089-15206A5	A	stainless steel	not hardened	black grey RAL 7021	6	1/2-13	25	41,7	10	8	6	14	-	1,8	6	14
03089-15308A6	A	stainless steel	not hardened	black grey RAL 7021	8	5/8-11	33	54	12	10	8	19	-	2,3	14	28
03089-15410A7	A	stainless steel	not hardened	black grey RAL 7021	10	3/4-10	33	61	15	12	10	22	-	2,8	15	32
03089-6004AK	B	steel	hardened	black grey RAL 7021	4	5/16-24	18	29,5	6	6	4	10	1/2	1	6	12
03089-6105AL	B	steel	hardened	black grey RAL 7021	5	3/8-24	21	34,5	8	7	5	13	9/16	1,3	5	12
03089-6206A5	B	steel	hardened	black grey RAL 7021	6	1/2-13	25	41,7	10	8	6	14	3/4	1,8	6	14
03089-6308A6	B	steel	hardened	black grey RAL 7021	8	5/8-11	33	54	12	10	8	19	15/16	2,3	14	28
03089-6410A7	B	steel	hardened	black grey RAL 7021	10	3/4-10	33	61	15	12	10	22	1-1/8	2,8	15	32
03089-16004AK	B	stainless steel	not hardened	black grey RAL 7021	4	5/16-24	18	29,5	6	6	4	10	1/2	1	6	12
03089-16105AL	B	stainless steel	not hardened	black grey RAL 7021	5	3/8-24	21	34,5	8	7	5	13	9/16	1,3	5	12
03089-16206A5	B	stainless steel	not hardened	black grey RAL 7021	6	1/2-13	25	41,7	10	8	6	14	3/4	1,8	6	14
03089-16308A6	B	stainless steel	not hardened	black grey RAL 7021	8	5/8-11	33	54	12	10	8	19	15/16	2,3	14	28
03089-16410A7	B	stainless steel	not hardened	black grey RAL 7021	10	3/4-10	33	61	15	12	10	22	1-1/8	2,8	15	32
03089-7004AK	C	steel	hardened	black grey RAL 7021	4	5/16-24	18	29,5	6	6	4	10	-	1	6	12
03089-7105AL	C	steel	hardened	black grey RAL 7021	5	3/8-24	21	34,5	8	7	5	13	-	1,3	5	12
03089-7206A5	C	steel	hardened	black grey RAL 7021	6	1/2-13	25	41,7	10	8	6	14	-	1,8	6	14
03089-7308A6	C	steel	hardened	black grey RAL 7021	8	5/8-11	33	54	12	10	8	19	-	2,3	14	28
03089-7410A7	C	steel	hardened	black grey RAL 7021	10	3/4-10	33	61	15	12	10	22	-	2,8	15	32
03089-17004AK	C	stainless steel	not hardened	black grey RAL 7021	4	5/16-24	18	29,5	6	6	4	10	-	1	6	12
03089-17105AL	C	stainless steel	not hardened	black grey RAL 7021	5	3/8-24	21	34,5	8	7	5	13	-	1,3	5	12
03089-17206A5	C	stainless steel	not hardened	black grey RAL 7021	6	1/2-13	25	41,7	10	8	6	14	-	1,8	6	14
03089-17308A6	C	stainless steel	not hardened	black grey RAL 7021	8	5/8-11	33	54	12	10	8	19	-	2,3	14	28
03089-17410A7	C	stainless steel	not hardened	black grey RAL 7021	10	3/4-10	33	61	15	12	10	22	-	2,8	15	32
03089-8004AK	D	steel	hardened	black grey RAL 7021	4	5/16-24	18	29,5	6	6	4	10	1/2	1	6	12
03089-8105AL	D	steel	hardened	black grey RAL 7021	5	3/8-24	21	34,5	8	7	5	13	9/16	1,3	5	12
03089-8206A5	D	steel	hardened	black grey RAL 7021	6	1/2-13	25	41,7	10	8	6	14	3/4	1,8	6	14
03089-8308A6	D	steel	hardened	black grey RAL 7021	8	5/8-11	33	54	12	10	8	19	15/16	2,3	14	28
03089-8410A7	D	steel	hardened	black grey RAL 7021	10	3/4-10	33	61	15	12	10	22	1-1/8	2,8	15	32
03089-18004AK	D	stainless steel	not hardened	black grey RAL 7021	4	5/16-24	18	29,5	6	6	4	10	1/2	1	6	12
03089-18105AL	D	stainless steel	not hardened	black grey RAL 7021	5	3/8-24	21	34,5	8	7	5	13	9/16	1,3	5	12
03089-18206A5	D	stainless steel	not hardened	black grey RAL 7021	6	1/2-13	25	41,7	10	8	6	14	3/4	1,8	6	14
03089-18308A6	D	stainless steel	not hardened	black grey RAL 7021	8	5/8-11	33	54	12	10	8	19	15/16	2,3	14	28
03089-18410A7	D	stainless steel	not hardened	black grey RAL 7021	10	3/4-10	33	61	15	12	10	22	1-1/8	2,8	15	32