

Description de l'article/illustrations du produit



Description


Matière :

Acier 1.1192 ou Inox 1.4571.


Finition :

Naturel.

Exemple d'utilisation :

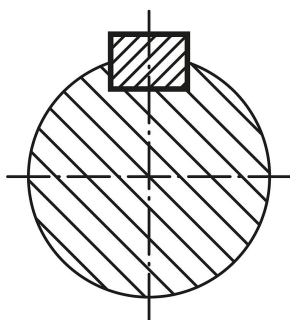

Dessins

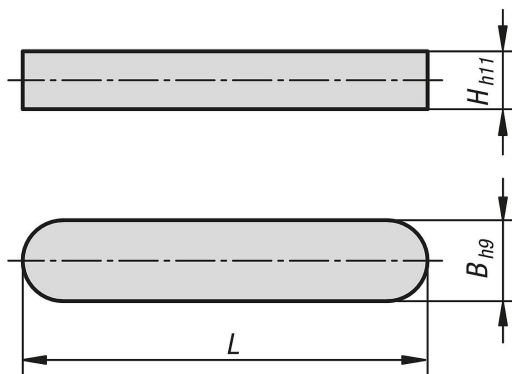

Aperçu des articles

Référence	Matière du corps de base	B	H	L = Longueur
03288-03X8	acier	3	3	8
03288-03X10	acier	3	3	10
03288-03X12	acier	3	3	12
03288-03X14	acier	3	3	14
03288-03X16	acier	3	3	16
03288-03X18	acier	3	3	18
03288-03X20	acier	3	3	20
03288-03X22	acier	3	3	22
03288-03X25	acier	3	3	25
03288-03X28	acier	3	3	28
03288-04X8	acier	4	4	8
03288-04X10	acier	4	4	10
03288-04X12	acier	4	4	12
03288-04X14	acier	4	4	14
03288-04X16	acier	4	4	16

Aperçu des articles

Référence	Matière du corps de base	B	H	L = Longueur
03288-04X18	acier	4	4	18
03288-04X20	acier	4	4	20
03288-04X22	acier	4	4	22
03288-04X25	acier	4	4	25
03288-04X28	acier	4	4	28
03288-05X12	acier	5	5	12
03288-05X14	acier	5	5	14
03288-05X16	acier	5	5	16
03288-05X18	acier	5	5	18
03288-05X20	acier	5	5	20
03288-05X22	acier	5	5	22
03288-05X25	acier	5	5	25
03288-05X28	acier	5	5	28
03288-05X32	acier	5	5	32
03288-05X36	acier	5	5	36
03288-05X40	acier	5	5	40
03288-06X12	acier	6	6	12
03288-06X14	acier	6	6	14
03288-06X16	acier	6	6	16
03288-06X18	acier	6	6	18
03288-06X20	acier	6	6	20
03288-06X22	acier	6	6	22
03288-06X25	acier	6	6	25
03288-06X28	acier	6	6	28
03288-06X32	acier	6	6	32
03288-06X36	acier	6	6	36
03288-06X40	acier	6	6	40
03288-06X45	acier	6	6	45
03288-08X14	acier	8	7	14
03288-08X16	acier	8	7	16
03288-08X18	acier	8	7	18
03288-08X20	acier	8	7	20
03288-08X22	acier	8	7	22
03288-08X25	acier	8	7	25
03288-08X28	acier	8	7	28
03288-08X32	acier	8	7	32
03288-08X36	acier	8	7	36
03288-08X40	acier	8	7	40
03288-08X45	acier	8	7	45
03288-08X50	acier	8	7	50
03288-08X70	acier	8	7	70
03288-10X22	acier	10	8	22
03288-10X25	acier	10	8	25
03288-10X28	acier	10	8	28
03288-10X32	acier	10	8	32
03288-10X36	acier	10	8	36
03288-10X40	acier	10	8	40
03288-10X45	acier	10	8	45
03288-10X50	acier	10	8	50
03288-10X56	acier	10	8	56
03288-10X70	acier	10	8	70
03288-10X80	acier	10	8	80
03288-12X25	acier	12	8	25
03288-12X28	acier	12	8	28
03288-12X32	acier	12	8	32
03288-12X36	acier	12	8	36
03288-12X40	acier	12	8	40
03288-12X45	acier	12	8	45
03288-12X50	acier	12	8	50
03288-12X56	acier	12	8	56
03288-12X70	acier	12	8	70
03288-12X80	acier	12	8	80
03288-14X25	acier	14	9	25
03288-14X28	acier	14	9	28
03288-14X32	acier	14	9	32
03288-14X36	acier	14	9	36

Aperçu des articles

Référence	Matière du corps de base	B	H	L = Longueur
03288-14X40	acier	14	9	40
03288-14X45	acier	14	9	45
03288-14X50	acier	14	9	50
03288-14X56	acier	14	9	56
03288-14X70	acier	14	9	70
03288-14X80	acier	14	9	80
03288-16X50	acier	16	10	50
03288-16X56	acier	16	10	56
03288-16X63	acier	16	10	63
03288-16X70	acier	16	10	70
03288-16X80	acier	16	10	80
03288-16X90	acier	16	10	90
03288-16X100	acier	16	10	100
03288-103X10	acier inoxydable	3	3	10
03288-103X12	acier inoxydable	3	3	12
03288-103X16	acier inoxydable	3	3	16
03288-103X20	acier inoxydable	3	3	20
03288-104X10	acier inoxydable	4	4	10
03288-104X12	acier inoxydable	4	4	12
03288-104X14	acier inoxydable	4	4	14
03288-104X16	acier inoxydable	4	4	16
03288-104X18	acier inoxydable	4	4	18
03288-104X20	acier inoxydable	4	4	20
03288-104X22	acier inoxydable	4	4	22
03288-105X12	acier inoxydable	5	5	12
03288-105X14	acier inoxydable	5	5	14
03288-105X16	acier inoxydable	5	5	16
03288-105X18	acier inoxydable	5	5	18
03288-105X20	acier inoxydable	5	5	20
03288-105X22	acier inoxydable	5	5	22
03288-105X25	acier inoxydable	5	5	25
03288-105X28	acier inoxydable	5	5	28
03288-105X36	acier inoxydable	5	5	36
03288-105X40	acier inoxydable	5	5	40
03288-106X12	acier inoxydable	6	6	12
03288-106X14	acier inoxydable	6	6	14
03288-106X16	acier inoxydable	6	6	16
03288-106X18	acier inoxydable	6	6	18
03288-106X20	acier inoxydable	6	6	20
03288-106X22	acier inoxydable	6	6	22
03288-106X25	acier inoxydable	6	6	25
03288-106X28	acier inoxydable	6	6	28
03288-106X32	acier inoxydable	6	6	32
03288-106X36	acier inoxydable	6	6	36
03288-106X40	acier inoxydable	6	6	40
03288-108X16	acier inoxydable	8	7	16
03288-108X18	acier inoxydable	8	7	18
03288-108X20	acier inoxydable	8	7	20
03288-108X22	acier inoxydable	8	7	22
03288-108X25	acier inoxydable	8	7	25
03288-108X28	acier inoxydable	8	7	28
03288-108X32	acier inoxydable	8	7	32
03288-108X36	acier inoxydable	8	7	36
03288-108X40	acier inoxydable	8	7	40
03288-108X45	acier inoxydable	8	7	45
03288-108X50	acier inoxydable	8	7	50
03288-108X70	acier inoxydable	8	7	70
03288-110X22	acier inoxydable	10	8	22
03288-110X25	acier inoxydable	10	8	25
03288-110X28	acier inoxydable	10	8	28
03288-110X32	acier inoxydable	10	8	32
03288-110X36	acier inoxydable	10	8	36
03288-110X40	acier inoxydable	10	8	40
03288-110X45	acier inoxydable	10	8	45
03288-110X50	acier inoxydable	10	8	50
03288-110X56	acier inoxydable	10	8	56

Aperçu des articles

Référence	Matière du corps de base	B	H	L = Longueur
03288-110X70	acier inoxydable	10	8	70
03288-110X80	acier inoxydable	10	8	80
03288-112X28	acier inoxydable	12	8	28
03288-112X32	acier inoxydable	12	8	32
03288-112X36	acier inoxydable	12	8	36
03288-112X40	acier inoxydable	12	8	40
03288-112X45	acier inoxydable	12	8	45
03288-112X50	acier inoxydable	12	8	50
03288-112X56	acier inoxydable	12	8	56
03288-112X70	acier inoxydable	12	8	70
03288-112X80	acier inoxydable	12	8	80
03288-114X32	acier inoxydable	14	9	32
03288-114X40	acier inoxydable	14	9	40
03288-114X45	acier inoxydable	14	9	45
03288-114X50	acier inoxydable	14	9	50
03288-114X56	acier inoxydable	14	9	56
03288-114X70	acier inoxydable	14	9	70
03288-114X80	acier inoxydable	14	9	80
03288-116X50	acier inoxydable	16	10	50
03288-116X63	acier inoxydable	16	10	63
03288-116X70	acier inoxydable	16	10	70
03288-116X80	acier inoxydable	16	10	80
03288-116X90	acier inoxydable	16	10	90
03288-116X100	acier inoxydable	16	10	100