

Item description/product images



Description

Material:

Steel, stainless steel or stainless steel A4.

Version:


Steel, bright.

Stainless steel bright.

Note:

The dowel pins comply with ISO 2338.

Drawings

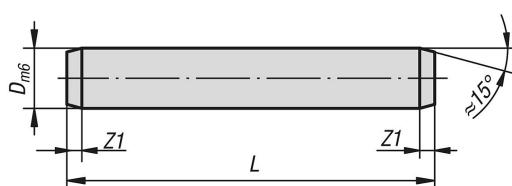

Overview of items

Order No.	Main material	D	L	Z1
03320-10-010X003	0.019	1	3	0,2
03320-10-010X004	0.019	1	4	0,2
03320-10-010X005	0.019	1	5	0,2
03320-10-010X006	0.019	1	6	0,2
03320-10-010X008	0.019	1	8	0,2
03320-10-010X010	0.019	1	10	0,2
03320-10-010X012	0.019	1	12	0,2
03320-10-015X003	0.019	1,5	3	0,3
03320-10-015X004	0.019	1,5	4	0,3
03320-10-015X005	0.019	1,5	5	0,3
03320-10-015X006	0.019	1,5	6	0,3
03320-10-015X008	0.019	1,5	8	0,3
03320-10-015X010	0.019	1,5	10	0,3
03320-10-015X012	0.019	1,5	12	0,3
03320-10-015X014	0.019	1,5	14	0,3
03320-10-015X016	0.019	1,5	16	0,3
03320-10-015X018	0.019	1,5	18	0,3
03320-10-015X020	0.019	1,5	20	0,3
03320-10-020X004	0.019	2	4	0,35
03320-10-020X005	0.019	2	5	0,35
03320-10-020X006	0.019	2	6	0,35
03320-10-020X008	0.019	2	8	0,35
03320-10-020X010	0.019	2	10	0,35
03320-10-020X012	0.019	2	12	0,35
03320-10-020X014	0.019	2	14	0,35
03320-10-020X016	0.019	2	16	0,35
03320-10-020X018	0.019	2	18	0,35
03320-10-020X020	0.019	2	20	0,35
03320-10-020X024	0.019	2	24	0,35
03320-10-020X028	0.019	2	28	0,35
03320-10-020X030	0.019	2	30	0,35
03320-10-025X006	0.019	2,5	6	0,4
03320-10-025X008	0.019	2,5	8	0,4
03320-10-025X010	0.019	2,5	10	0,4
03320-10-025X012	0.019	2,5	12	0,4
03320-10-025X014	0.019	2,5	14	0,4
03320-10-025X016	0.019	2,5	16	0,4

Overview of items

Order No.	Main material	D	L	Z1
03320-10-025X018	0.019	2,5	18	0,4
03320-10-025X020	0.019	2,5	20	0,4
03320-10-025X024	0.019	2,5	24	0,4
03320-10-025X028	0.019	2,5	28	0,4
03320-10-025X032	0.019	2,5	32	0,4
03320-10-030X005	0.019	3	5	0,5
03320-10-030X006	0.019	3	6	0,5
03320-10-030X008	0.019	3	8	0,5
03320-10-030X010	0.019	3	10	0,5
03320-10-030X012	0.019	3	12	0,5
03320-10-030X014	0.019	3	14	0,5
03320-10-030X016	0.019	3	16	0,5
03320-10-030X018	0.019	3	18	0,5
03320-10-030X020	0.019	3	20	0,5
03320-10-030X024	0.019	3	24	0,5
03320-10-030X028	0.019	3	28	0,5
03320-10-030X030	0.019	3	30	0,5
03320-10-030X032	0.019	3	32	0,5
03320-10-030X036	0.019	3	36	0,5
03320-10-030X040	0.019	3	40	0,5
03320-10-030X045	0.019	3	45	0,5
03320-10-030X050	0.019	3	50	0,5
03320-10-040X005	0.019	4	5	0,63
03320-10-040X006	0.019	4	6	0,63
03320-10-040X008	0.019	4	8	0,63
03320-10-040X010	0.019	4	10	0,63
03320-10-040X012	0.019	4	12	0,63
03320-10-040X014	0.019	4	14	0,63
03320-10-040X016	0.019	4	16	0,63
03320-10-040X018	0.019	4	18	0,63
03320-10-040X020	0.019	4	20	0,63
03320-10-040X024	0.019	4	24	0,63
03320-10-040X028	0.019	4	28	0,63
03320-10-040X030	0.019	4	30	0,63
03320-10-040X032	0.019	4	32	0,63
03320-10-040X036	0.019	4	36	0,63
03320-10-040X040	0.019	4	40	0,63
03320-10-040X045	0.019	4	45	0,63
03320-10-040X050	0.019	4	50	0,63
03320-10-050X005	0.019	5	5	0,8
03320-10-050X006	0.019	5	6	0,8
03320-10-050X008	0.019	5	8	0,8
03320-10-050X010	0.019	5	10	0,8
03320-10-050X012	0.019	5	12	0,8
03320-10-050X014	0.019	5	14	0,8
03320-10-050X016	0.019	5	16	0,8
03320-10-050X018	0.019	5	18	0,8
03320-10-050X020	0.019	5	20	0,8
03320-10-050X022	0.019	5	22	0,8
03320-10-050X024	0.019	5	24	0,8
03320-10-050X028	0.019	5	28	0,8
03320-10-050X030	0.019	5	30	0,8
03320-10-050X032	0.019	5	32	0,8
03320-10-050X036	0.019	5	36	0,8
03320-10-050X040	0.019	5	40	0,8
03320-10-050X045	0.019	5	45	0,8
03320-10-050X050	0.019	5	50	0,8
03320-10-050X055	0.019	5	55	0,8
03320-10-050X060	0.019	5	60	0,8
03320-10-060X006	0.019	6	6	1,2
03320-10-060X008	0.019	6	8	1,2
03320-10-060X010	0.019	6	10	1,2
03320-10-060X012	0.019	6	12	1,2
03320-10-060X014	0.019	6	14	1,2
03320-10-060X016	0.019	6	16	1,2

Overview of items

Order No.	Main material	D	L	Z1
03320-10-060X018	0.019	6	18	1,2
03320-10-060X020	0.019	6	20	1,2
03320-10-060X022	0.019	6	22	1,2
03320-10-060X024	0.019	6	24	1,2
03320-10-060X028	0.019	6	28	1,2
03320-10-060X030	0.019	6	30	1,2
03320-10-060X032	0.019	6	32	1,2
03320-10-060X036	0.019	6	36	1,2
03320-10-060X040	0.019	6	40	1,2
03320-10-060X045	0.019	6	45	1,2
03320-10-060X050	0.019	6	50	1,2
03320-10-060X060	0.019	6	60	1,2
03320-10-060X070	0.019	6	70	1,2
03320-10-060X080	0.019	6	80	1,2
03320-10-060X090	0.019	6	90	1,2
03320-10-060X100	0.019	6	100	1,2
03320-10-080X008	0.019	8	8	1,6
03320-10-080X010	0.019	8	10	1,6
03320-10-080X012	0.019	8	12	1,6
03320-10-080X014	0.019	8	14	1,6
03320-10-080X016	0.019	8	16	1,6
03320-10-080X018	0.019	8	18	1,6
03320-10-080X020	0.019	8	20	1,6
03320-10-080X022	0.019	8	22	1,6
03320-10-080X024	0.019	8	24	1,6
03320-10-080X026	0.019	8	26	1,6
03320-10-080X028	0.019	8	28	1,6
03320-10-080X030	0.019	8	30	1,6
03320-10-080X032	0.019	8	32	1,6
03320-10-080X036	0.019	8	36	1,6
03320-10-080X040	0.019	8	40	1,6
03320-10-080X045	0.019	8	45	1,6
03320-10-080X050	0.019	8	50	1,6
03320-10-080X055	0.019	8	55	1,6
03320-10-080X060	0.019	8	60	1,6
03320-10-080X070	0.019	8	70	1,6
03320-10-080X080	0.019	8	80	1,6
03320-10-080X090	0.019	8	90	1,6
03320-10-080X100	0.019	8	100	1,6
03320-10-100X010	0.019	10	10	2
03320-10-100X012	0.019	10	12	2
03320-10-100X014	0.019	10	14	2
03320-10-100X016	0.019	10	16	2
03320-10-100X018	0.019	10	18	2
03320-10-100X020	0.019	10	20	2
03320-10-100X024	0.019	10	24	2
03320-10-100X028	0.019	10	28	2
03320-10-100X030	0.019	10	30	2
03320-10-100X032	0.019	10	32	2
03320-10-100X036	0.019	10	36	2
03320-10-100X040	0.019	10	40	2
03320-10-100X045	0.019	10	45	2
03320-10-100X050	0.019	10	50	2
03320-10-100X055	0.019	10	55	2
03320-10-100X060	0.019	10	60	2
03320-10-100X065	0.019	10	65	2
03320-10-100X070	0.019	10	70	2
03320-10-100X080	0.019	10	80	2
03320-10-100X090	0.019	10	90	2
03320-10-100X100	0.019	10	100	2
03320-10-120X012	0.019	12	12	2,5
03320-10-120X014	0.019	12	14	2,5
03320-10-120X016	0.019	12	16	2,5
03320-10-120X018	0.019	12	18	2,5
03320-10-120X020	0.019	12	20	2,5

Overview of items

Order No.	Main material	D	L	Z1
03320-10-120X024	0.019	12	24	2,5
03320-10-120X028	0.019	12	28	2,5
03320-10-120X030	0.019	12	30	2,5
03320-10-120X032	0.019	12	32	2,5
03320-10-120X036	0.019	12	36	2,5
03320-10-120X040	0.019	12	40	2,5
03320-10-120X045	0.019	12	45	2,5
03320-10-120X050	0.019	12	50	2,5
03320-10-120X055	0.019	12	55	2,5
03320-10-120X060	0.019	12	60	2,5
03320-10-120X070	0.019	12	70	2,5
03320-10-120X080	0.019	12	80	2,5
03320-10-120X090	0.019	12	90	2,5
03320-10-120X100	0.019	12	100	2,5
03320-10-160X020	0.019	16	20	3
03320-10-160X024	0.019	16	24	3
03320-10-160X028	0.019	16	28	3
03320-10-160X030	0.019	16	30	3
03320-10-160X032	0.019	16	32	3
03320-10-160X036	0.019	16	36	3
03320-10-160X040	0.019	16	40	3
03320-10-160X045	0.019	16	45	3
03320-10-160X050	0.019	16	50	3
03320-10-160X055	0.019	16	55	3
03320-10-160X060	0.019	16	60	3
03320-10-160X070	0.019	16	70	3
03320-10-160X080	0.019	16	80	3
03320-10-160X090	0.019	16	90	3
03320-10-160X100	0.019	16	100	3
03320-10-160X120	0.019	16	120	3
03320-10-200X024	0.019	20	24	3,5
03320-10-200X028	0.019	20	28	3,5
03320-10-200X030	0.019	20	30	3,5
03320-10-200X032	0.019	20	32	3,5
03320-10-200X036	0.019	20	36	3,5
03320-10-200X040	0.019	20	40	3,5
03320-10-200X045	0.019	20	45	3,5
03320-10-200X050	0.019	20	50	3,5
03320-10-200X055	0.019	20	55	3,5
03320-10-200X060	0.019	20	60	3,5
03320-10-200X070	0.019	20	70	3,5
03320-10-200X080	0.019	20	80	3,5
03320-10-200X100	0.019	20	100	3,5
03320-10-200X120	0.019	20	120	3,5
03320-10-250X040	0.019	25	40	4
03320-10-250X045	0.019	25	45	4
03320-10-250X050	0.019	25	50	4
03320-10-250X055	0.019	25	55	4
03320-10-250X060	0.019	25	60	4
03320-10-250X070	0.019	25	70	4
03320-10-250X080	0.019	25	80	4
03320-10-250X090	0.019	25	90	4
03320-10-250X100	0.019	25	100	4
03320-10-250X120	0.019	25	120	4
03320-10-300X040	0.019	30	40	5
03320-10-300X045	0.019	30	45	5
03320-10-300X050	0.019	30	50	5
03320-10-300X055	0.019	30	55	5
03320-10-300X060	0.019	30	60	5
03320-10-300X070	0.019	30	70	5
03320-10-300X080	0.019	30	80	5
03320-10-300X090	0.019	30	90	5
03320-10-300X100	0.019	30	100	5
03320-10-300X120	0.019	30	120	5
03320-10-1010X003	3	1	3	0,2

Overview of items

Order No.	Main material	D	L	Z1
03320-10-1010X004	3	1	4	0,2
03320-10-1010X005	3	1	5	0,2
03320-10-1010X006	3	1	6	0,2
03320-10-1010X008	3	1	8	0,2
03320-10-1010X010	3	1	10	0,2
03320-10-1010X012	3	1	12	0,2
03320-10-1015X003	3	1,5	3	0,3
03320-10-1015X004	3	1,5	4	0,3
03320-10-1015X005	3	1,5	5	0,3
03320-10-1015X006	3	1,5	6	0,3
03320-10-1015X008	3	1,5	8	0,3
03320-10-1015X010	3	1,5	10	0,3
03320-10-1015X012	3	1,5	12	0,3
03320-10-1015X014	3	1,5	14	0,3
03320-10-1015X016	3	1,5	16	0,3
03320-10-1015X018	3	1,5	18	0,3
03320-10-1015X020	3	1,5	20	0,3
03320-10-1020X004	3	2	4	0,35
03320-10-1020X005	3	2	5	0,35
03320-10-1020X006	3	2	6	0,35
03320-10-1020X008	3	2	8	0,35
03320-10-1020X010	3	2	10	0,35
03320-10-1020X012	3	2	12	0,35
03320-10-1020X014	3	2	14	0,35
03320-10-1020X016	3	2	16	0,35
03320-10-1020X018	3	2	18	0,35
03320-10-1020X020	3	2	20	0,35
03320-10-1025X006	3	2,5	6	0,4
03320-10-1025X008	3	2,5	8	0,4
03320-10-1025X010	3	2,5	10	0,4
03320-10-1025X012	3	2,5	12	0,4
03320-10-1025X014	3	2,5	14	0,4
03320-10-1025X016	3	2,5	16	0,4
03320-10-1025X018	3	2,5	18	0,4
03320-10-1025X020	3	2,5	20	0,4
03320-10-1025X024	3	2,5	24	0,4
03320-10-1030X005	3	3	5	0,5
03320-10-1030X006	3	3	6	0,5
03320-10-1030X008	3	3	8	0,5
03320-10-1030X010	3	3	10	0,5
03320-10-1030X012	3	3	12	0,5
03320-10-1030X014	3	3	14	0,5
03320-10-1030X016	3	3	16	0,5
03320-10-1030X018	3	3	18	0,5
03320-10-1030X020	3	3	20	0,5
03320-10-1030X024	3	3	24	0,5
03320-10-1030X028	3	3	28	0,5
03320-10-1030X030	3	3	30	0,5
03320-10-1030X032	3	3	32	0,5
03320-10-1030X040	3	3	40	0,5
03320-10-1030X045	3	3	45	0,5
03320-10-1030X050	3	3	50	0,5
03320-10-1030X060	3	3	60	0,5
03320-10-1040X005	3	4	5	0,63
03320-10-1040X006	3	4	6	0,63
03320-10-1040X008	3	4	8	0,63
03320-10-1040X010	3	4	10	0,63
03320-10-1040X012	3	4	12	0,63
03320-10-1040X014	3	4	14	0,63
03320-10-1040X016	3	4	16	0,63
03320-10-1040X018	3	4	18	0,63
03320-10-1040X020	3	4	20	0,63
03320-10-1040X024	3	4	24	0,63
03320-10-1040X026	3	4	26	0,63
03320-10-1040X028	3	4	28	0,63

Overview of items

Order No.	Main material	D	L	Z1
03320-10-1040X032	3	4	32	0,63
03320-10-1040X036	3	4	36	0,63
03320-10-1040X040	3	4	40	0,63
03320-10-1040X050	3	4	50	0,63
03320-10-1040X060	3	4	60	0,63
03320-10-1050X005	3	5	5	0,8
03320-10-1050X006	3	5	6	0,8
03320-10-1050X008	3	5	8	0,8
03320-10-1050X010	3	5	10	0,8
03320-10-1050X012	3	5	12	0,8
03320-10-1050X014	3	5	14	0,8
03320-10-1050X016	3	5	16	0,8
03320-10-1050X018	3	5	18	0,8
03320-10-1050X020	3	5	20	0,8
03320-10-1050X024	3	5	24	0,8
03320-10-1050X028	3	5	28	0,8
03320-10-1050X030	3	5	30	0,8
03320-10-1050X032	3	5	32	0,8
03320-10-1050X036	3	5	36	0,8
03320-10-1050X040	3	5	40	0,8
03320-10-1050X045	3	5	45	0,8
03320-10-1050X050	3	5	50	0,8
03320-10-1060X006	3	6	6	1,2
03320-10-1060X008	3	6	8	1,2
03320-10-1060X010	3	6	10	1,2
03320-10-1060X012	3	6	12	1,2
03320-10-1060X014	3	6	14	1,2
03320-10-1060X016	3	6	16	1,2
03320-10-1060X018	3	6	18	1,2
03320-10-1060X020	3	6	20	1,2
03320-10-1060X024	3	6	24	1,2
03320-10-1060X028	3	6	28	1,2
03320-10-1060X030	3	6	30	1,2
03320-10-1060X032	3	6	32	1,2
03320-10-1060X036	3	6	36	1,2
03320-10-1060X040	3	6	40	1,2
03320-10-1060X045	3	6	45	1,2
03320-10-1060X050	3	6	50	1,2
03320-10-1060X055	3	6	55	1,2
03320-10-1060X060	3	6	60	1,2
03320-10-1080X010	3	8	10	1,6
03320-10-1080X012	3	8	12	1,6
03320-10-1080X014	3	8	14	1,6
03320-10-1080X016	3	8	16	1,6
03320-10-1080X018	3	8	18	1,6
03320-10-1080X020	3	8	20	1,6
03320-10-1080X022	3	8	22	1,6
03320-10-1080X024	3	8	24	1,6
03320-10-1080X028	3	8	28	1,6
03320-10-1080X030	3	8	30	1,6
03320-10-1080X032	3	8	32	1,6
03320-10-1080X036	3	8	36	1,6
03320-10-1080X040	3	8	40	1,6
03320-10-1080X045	3	8	45	1,6
03320-10-1080X050	3	8	50	1,6
03320-10-1080X055	3	8	55	1,6
03320-10-1080X060	3	8	60	1,6
03320-10-1080X070	3	8	70	1,6
03320-10-1080X080	3	8	80	1,6
03320-10-1080X090	3	8	90	1,6
03320-10-1100X010	3	10	10	2
03320-10-1100X012	3	10	12	2
03320-10-1100X014	3	10	14	2
03320-10-1100X016	3	10	16	2
03320-10-1100X018	3	10	18	2

Overview of items

Order No.	Main material	D	L	Z1
03320-10-1100X020	3	10	20	2
03320-10-1100X024	3	10	24	2
03320-10-1100X028	3	10	28	2
03320-10-1100X032	3	10	32	2
03320-10-1100X036	3	10	36	2
03320-10-1100X040	3	10	40	2
03320-10-1100X045	3	10	45	2
03320-10-1100X050	3	10	50	2
03320-10-1100X055	3	10	55	2
03320-10-1100X060	3	10	60	2
03320-10-1100X070	3	10	70	2
03320-10-1100X080	3	10	80	2
03320-10-1100X090	3	10	90	2
03320-10-1100X100	3	10	100	2
03320-10-1120X016	3	12	16	2,5
03320-10-1120X018	3	12	18	2,5
03320-10-1120X020	3	12	20	2,5
03320-10-1120X024	3	12	24	2,5
03320-10-1120X030	3	12	30	2,5
03320-10-1120X032	3	12	32	2,5
03320-10-1120X040	3	12	40	2,5
03320-10-1120X045	3	12	45	2,5
03320-10-1120X050	3	12	50	2,5
03320-10-1120X055	3	12	55	2,5
03320-10-1120X060	3	12	60	2,5
03320-10-1120X070	3	12	70	2,5
03320-10-1120X080	3	12	80	2,5
03320-10-1120X090	3	12	90	2,5
03320-10-1120X100	3	12	100	2,5
03320-10-1160X020	3	16	20	3
03320-10-1160X024	3	16	24	3
03320-10-1160X028	3	16	28	3
03320-10-1160X032	3	16	32	3
03320-10-1160X036	3	16	36	3
03320-10-1160X040	3	16	40	3
03320-10-1160X045	3	16	45	3
03320-10-1160X050	3	16	50	3
03320-10-1160X055	3	16	55	3
03320-10-1160X060	3	16	60	3
03320-10-1160X070	3	16	70	3
03320-10-1160X080	3	16	80	3
03320-10-1160X090	3	16	90	3
03320-10-1160X100	3	16	100	3
03320-10-6010X003	Clamping width 50 mm, width approx. 20 mm	1	3	0,2
03320-10-6010X004	Clamping width 50 mm, width approx. 20 mm	1	4	0,2
03320-10-6010X005	Clamping width 50 mm, width approx. 20 mm	1	5	0,2
03320-10-6010X006	Clamping width 50 mm, width approx. 20 mm	1	6	0,2
03320-10-6010X008	Clamping width 50 mm, width approx. 20 mm	1	8	0,2
03320-10-6010X010	Clamping width 50 mm, width approx. 20 mm	1	10	0,2
03320-10-6010X012	Clamping width 50 mm, width approx. 20 mm	1	12	0,2
03320-10-6015X004	Clamping width 50 mm, width approx. 20 mm	1,5	4	0,3
03320-10-6015X005	Clamping width 50 mm, width approx. 20 mm	1,5	5	0,3
03320-10-6015X006	Clamping width 50 mm, width approx. 20 mm	1,5	6	0,3
03320-10-6015X008	Clamping width 50 mm, width approx. 20 mm	1,5	8	0,3
03320-10-6015X010	Clamping width 50 mm, width approx. 20 mm	1,5	10	0,3
03320-10-6015X012	Clamping width 50 mm, width approx. 20 mm	1,5	12	0,3
03320-10-6015X014	Clamping width 50 mm, width approx. 20 mm	1,5	14	0,3
03320-10-6015X016	Clamping width 50 mm, width approx. 20 mm	1,5	16	0,3
03320-10-6015X018	Clamping width 50 mm, width approx. 20 mm	1,5	18	0,3
03320-10-6015X020	Clamping width 50 mm, width approx. 20 mm	1,5	20	0,3
03320-10-6020X005	Clamping width 50 mm, width approx. 20 mm	2	5	0,35
03320-10-6020X006	Clamping width 50 mm, width approx. 20 mm	2	6	0,35
03320-10-6020X008	Clamping width 50 mm, width approx. 20 mm	2	8	0,35
03320-10-6020X010	Clamping width 50 mm, width approx. 20 mm	2	10	0,35
03320-10-6020X012	Clamping width 50 mm, width approx. 20 mm	2	12	0,35

Overview of items

Order No.	Main material	D	L	Z1
03320-10-6020X014	Clamping width 50 mm, width approx. 20 mm	2	14	0,35
03320-10-6020X016	Clamping width 50 mm, width approx. 20 mm	2	16	0,35
03320-10-6020X018	Clamping width 50 mm, width approx. 20 mm	2	18	0,35
03320-10-6020X020	Clamping width 50 mm, width approx. 20 mm	2	20	0,35
03320-10-6020X024	Clamping width 50 mm, width approx. 20 mm	2	24	0,35
03320-10-6025X006	Clamping width 50 mm, width approx. 20 mm	2,5	6	0,4
03320-10-6025X008	Clamping width 50 mm, width approx. 20 mm	2,5	8	0,4
03320-10-6025X010	Clamping width 50 mm, width approx. 20 mm	2,5	10	0,4
03320-10-6025X012	Clamping width 50 mm, width approx. 20 mm	2,5	12	0,4
03320-10-6025X014	Clamping width 50 mm, width approx. 20 mm	2,5	14	0,4
03320-10-6025X016	Clamping width 50 mm, width approx. 20 mm	2,5	16	0,4
03320-10-6025X018	Clamping width 50 mm, width approx. 20 mm	2,5	18	0,4
03320-10-6025X020	Clamping width 50 mm, width approx. 20 mm	2,5	20	0,4
03320-10-6025X024	Clamping width 50 mm, width approx. 20 mm	2,5	24	0,4
03320-10-6030X005	Clamping width 50 mm, width approx. 20 mm	3	5	0,5
03320-10-6030X006	Clamping width 50 mm, width approx. 20 mm	3	6	0,5
03320-10-6030X008	Clamping width 50 mm, width approx. 20 mm	3	8	0,5
03320-10-6030X010	Clamping width 50 mm, width approx. 20 mm	3	10	0,5
03320-10-6030X012	Clamping width 50 mm, width approx. 20 mm	3	12	0,5
03320-10-6030X014	Clamping width 50 mm, width approx. 20 mm	3	14	0,5
03320-10-6030X016	Clamping width 50 mm, width approx. 20 mm	3	16	0,5
03320-10-6030X018	Clamping width 50 mm, width approx. 20 mm	3	18	0,5
03320-10-6030X020	Clamping width 50 mm, width approx. 20 mm	3	20	0,5
03320-10-6030X024	Clamping width 50 mm, width approx. 20 mm	3	24	0,5
03320-10-6030X028	Clamping width 50 mm, width approx. 20 mm	3	28	0,5
03320-10-6030X030	Clamping width 50 mm, width approx. 20 mm	3	30	0,5
03320-10-6030X032	Clamping width 50 mm, width approx. 20 mm	3	32	0,5
03320-10-6040X006	Clamping width 50 mm, width approx. 20 mm	4	6	0,63
03320-10-6040X008	Clamping width 50 mm, width approx. 20 mm	4	8	0,63
03320-10-6040X010	Clamping width 50 mm, width approx. 20 mm	4	10	0,63
03320-10-6040X012	Clamping width 50 mm, width approx. 20 mm	4	12	0,63
03320-10-6040X014	Clamping width 50 mm, width approx. 20 mm	4	14	0,63
03320-10-6040X016	Clamping width 50 mm, width approx. 20 mm	4	16	0,63
03320-10-6040X018	Clamping width 50 mm, width approx. 20 mm	4	18	0,63
03320-10-6040X020	Clamping width 50 mm, width approx. 20 mm	4	20	0,63
03320-10-6040X024	Clamping width 50 mm, width approx. 20 mm	4	24	0,63
03320-10-6040X028	Clamping width 50 mm, width approx. 20 mm	4	28	0,63
03320-10-6040X030	Clamping width 50 mm, width approx. 20 mm	4	30	0,63
03320-10-6040X032	Clamping width 50 mm, width approx. 20 mm	4	32	0,63
03320-10-6040X036	Clamping width 50 mm, width approx. 20 mm	4	36	0,63
03320-10-6040X040	Clamping width 50 mm, width approx. 20 mm	4	40	0,63
03320-10-6050X006	Clamping width 50 mm, width approx. 20 mm	5	6	0,8
03320-10-6050X008	Clamping width 50 mm, width approx. 20 mm	5	8	0,8
03320-10-6050X010	Clamping width 50 mm, width approx. 20 mm	5	10	0,8
03320-10-6050X012	Clamping width 50 mm, width approx. 20 mm	5	12	0,8
03320-10-6050X014	Clamping width 50 mm, width approx. 20 mm	5	14	0,8
03320-10-6050X016	Clamping width 50 mm, width approx. 20 mm	5	16	0,8
03320-10-6050X018	Clamping width 50 mm, width approx. 20 mm	5	18	0,8
03320-10-6050X020	Clamping width 50 mm, width approx. 20 mm	5	20	0,8
03320-10-6050X024	Clamping width 50 mm, width approx. 20 mm	5	24	0,8
03320-10-6050X028	Clamping width 50 mm, width approx. 20 mm	5	28	0,8
03320-10-6050X030	Clamping width 50 mm, width approx. 20 mm	5	30	0,8
03320-10-6050X032	Clamping width 50 mm, width approx. 20 mm	5	32	0,8
03320-10-6050X036	Clamping width 50 mm, width approx. 20 mm	5	36	0,8
03320-10-6050X040	Clamping width 50 mm, width approx. 20 mm	5	40	0,8
03320-10-6050X045	Clamping width 50 mm, width approx. 20 mm	5	45	0,8
03320-10-6050X050	Clamping width 50 mm, width approx. 20 mm	5	50	0,8
03320-10-6060X008	Clamping width 50 mm, width approx. 20 mm	6	8	1,2
03320-10-6060X010	Clamping width 50 mm, width approx. 20 mm	6	10	1,2
03320-10-6060X012	Clamping width 50 mm, width approx. 20 mm	6	12	1,2
03320-10-6060X014	Clamping width 50 mm, width approx. 20 mm	6	14	1,2
03320-10-6060X016	Clamping width 50 mm, width approx. 20 mm	6	16	1,2
03320-10-6060X018	Clamping width 50 mm, width approx. 20 mm	6	18	1,2
03320-10-6060X020	Clamping width 50 mm, width approx. 20 mm	6	20	1,2
03320-10-6060X024	Clamping width 50 mm, width approx. 20 mm	6	24	1,2

Overview of items

Order No.	Main material	D	L	Z1
03320-10-6060X028	Clamping width 50 mm, width approx. 20 mm	6	28	1,2
03320-10-6060X032	Clamping width 50 mm, width approx. 20 mm	6	32	1,2
03320-10-6060X036	Clamping width 50 mm, width approx. 20 mm	6	36	1,2
03320-10-6060X040	Clamping width 50 mm, width approx. 20 mm	6	40	1,2
03320-10-6060X045	Clamping width 50 mm, width approx. 20 mm	6	45	1,2
03320-10-6060X050	Clamping width 50 mm, width approx. 20 mm	6	50	1,2
03320-10-6060X055	Clamping width 50 mm, width approx. 20 mm	6	55	1,2
03320-10-6060X060	Clamping width 50 mm, width approx. 20 mm	6	60	1,2
03320-10-6080X010	Clamping width 50 mm, width approx. 20 mm	8	10	1,6
03320-10-6080X012	Clamping width 50 mm, width approx. 20 mm	8	12	1,6
03320-10-6080X014	Clamping width 50 mm, width approx. 20 mm	8	14	1,6
03320-10-6080X016	Clamping width 50 mm, width approx. 20 mm	8	16	1,6
03320-10-6080X018	Clamping width 50 mm, width approx. 20 mm	8	18	1,6
03320-10-6080X020	Clamping width 50 mm, width approx. 20 mm	8	20	1,6
03320-10-6080X024	Clamping width 50 mm, width approx. 20 mm	8	24	1,6
03320-10-6080X028	Clamping width 50 mm, width approx. 20 mm	8	28	1,6
03320-10-6080X030	Clamping width 50 mm, width approx. 20 mm	8	30	1,6
03320-10-6080X032	Clamping width 50 mm, width approx. 20 mm	8	32	1,6
03320-10-6080X036	Clamping width 50 mm, width approx. 20 mm	8	36	1,6
03320-10-6080X040	Clamping width 50 mm, width approx. 20 mm	8	40	1,6
03320-10-6080X045	Clamping width 50 mm, width approx. 20 mm	8	45	1,6
03320-10-6080X050	Clamping width 50 mm, width approx. 20 mm	8	50	1,6
03320-10-6080X060	Clamping width 50 mm, width approx. 20 mm	8	60	1,6
03320-10-6080X070	Clamping width 50 mm, width approx. 20 mm	8	70	1,6
03320-10-6080X080	Clamping width 50 mm, width approx. 20 mm	8	80	1,6
03320-10-6100X012	Clamping width 50 mm, width approx. 20 mm	10	12	2
03320-10-6100X014	Clamping width 50 mm, width approx. 20 mm	10	14	2
03320-10-6100X016	Clamping width 50 mm, width approx. 20 mm	10	16	2
03320-10-6100X018	Clamping width 50 mm, width approx. 20 mm	10	18	2
03320-10-6100X020	Clamping width 50 mm, width approx. 20 mm	10	20	2
03320-10-6100X024	Clamping width 50 mm, width approx. 20 mm	10	24	2
03320-10-6100X028	Clamping width 50 mm, width approx. 20 mm	10	28	2
03320-10-6100X030	Clamping width 50 mm, width approx. 20 mm	10	30	2
03320-10-6100X032	Clamping width 50 mm, width approx. 20 mm	10	32	2
03320-10-6100X036	Clamping width 50 mm, width approx. 20 mm	10	36	2
03320-10-6100X040	Clamping width 50 mm, width approx. 20 mm	10	40	2
03320-10-6100X050	Clamping width 50 mm, width approx. 20 mm	10	50	2
03320-10-6100X055	Clamping width 50 mm, width approx. 20 mm	10	55	2
03320-10-6100X060	Clamping width 50 mm, width approx. 20 mm	10	60	2
03320-10-6100X070	Clamping width 50 mm, width approx. 20 mm	10	70	2
03320-10-6100X080	Clamping width 50 mm, width approx. 20 mm	10	80	2
03320-10-6100X090	Clamping width 50 mm, width approx. 20 mm	10	90	2
03320-10-6100X100	Clamping width 50 mm, width approx. 20 mm	10	100	2
03320-10-6120X014	Clamping width 50 mm, width approx. 20 mm	12	14	2,5
03320-10-6120X016	Clamping width 50 mm, width approx. 20 mm	12	16	2,5
03320-10-6120X018	Clamping width 50 mm, width approx. 20 mm	12	18	2,5
03320-10-6120X020	Clamping width 50 mm, width approx. 20 mm	12	20	2,5
03320-10-6120X024	Clamping width 50 mm, width approx. 20 mm	12	24	2,5
03320-10-6120X028	Clamping width 50 mm, width approx. 20 mm	12	28	2,5
03320-10-6120X040	Clamping width 50 mm, width approx. 20 mm	12	40	2,5
03320-10-6120X050	Clamping width 50 mm, width approx. 20 mm	12	50	2,5
03320-10-6120X060	Clamping width 50 mm, width approx. 20 mm	12	60	2,5
03320-10-6120X070	Clamping width 50 mm, width approx. 20 mm	12	70	2,5
03320-10-6120X080	Clamping width 50 mm, width approx. 20 mm	12	80	2,5
03320-10-6120X090	Clamping width 50 mm, width approx. 20 mm	12	90	2,5
03320-10-6120X100	Clamping width 50 mm, width approx. 20 mm	12	100	2,5
03320-10-6160X020	Clamping width 50 mm, width approx. 20 mm	16	20	3
03320-10-6160X024	Clamping width 50 mm, width approx. 20 mm	16	24	3
03320-10-6160X028	Clamping width 50 mm, width approx. 20 mm	16	28	3
03320-10-6160X032	Clamping width 50 mm, width approx. 20 mm	16	32	3
03320-10-6160X036	Clamping width 50 mm, width approx. 20 mm	16	36	3
03320-10-6160X040	Clamping width 50 mm, width approx. 20 mm	16	40	3
03320-10-6160X045	Clamping width 50 mm, width approx. 20 mm	16	45	3
03320-10-6160X050	Clamping width 50 mm, width approx. 20 mm	16	50	3
03320-10-6160X055	Clamping width 50 mm, width approx. 20 mm	16	55	3

Overview of items

Order No.	Main material	D	L	Z1
03320-10-6160X060	Clamping width 50 mm, width approx. 20 mm	16	60	3
03320-10-6160X070	Clamping width 50 mm, width approx. 20 mm	16	70	3
03320-10-6160X080	Clamping width 50 mm, width approx. 20 mm	16	80	3
03320-10-6160X090	Clamping width 50 mm, width approx. 20 mm	16	90	3
03320-10-6160X100	Clamping width 50 mm, width approx. 20 mm	16	100	3