

Item description/product images



Description

Material:

Steel.

Version:

Electro zinc-plated.

Note:

*By housing lengths H=18 mm, H=30 mm, H=40 mm and H=50 mm, dimension A in mm.

Accessory:


Quarter-turn locks polyamide 05567.

Quarter-turn lock, zinc long version 05568.

Quarter-turn locks with T-grip 05572.

Quarter-turn locks with L-grip 05573.

Drawings

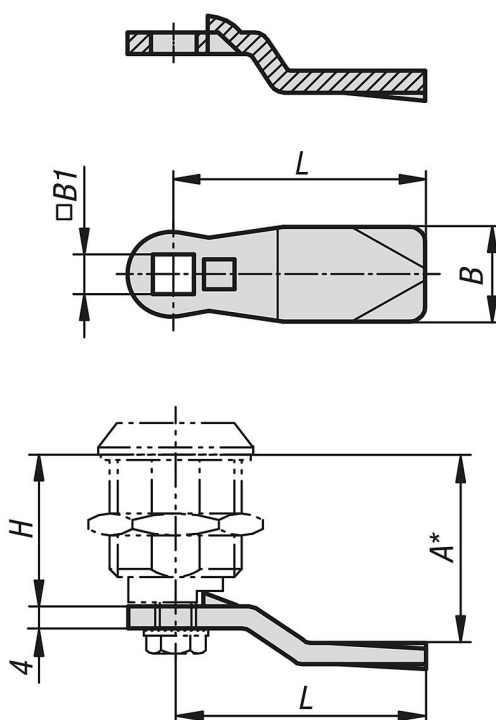

Overview of items

Order No.	Version 1	Version 2	B	B1	A by H=18	A by H=30	A by H=40	A by H=50	L	Suitable for
05569-135X160	with stop	offset upwards	19,5	8,1	16	28	38	48	35	05568, 05567, 05572, 05573
05569-135X180	with stop	straight	19,5	8,1	18	30	40	50	35	05568, 05567, 05572, 05573
05569-135X200	with stop	offset downwards	19,5	8,1	20	32	42	52	35	05568, 05567, 05572, 05573
05569-135X220	with stop	offset downwards	19,5	8,1	22	34	44	54	35	05568, 05567, 05572, 05573
05569-135X240	with stop	offset downwards	19,5	8,1	24	36	46	56	35	05568, 05567, 05572, 05573
05569-145X040	with stop	offset upwards	19,5	8,1	4	16	26	36	45	05568, 05567, 05572, 05573
05569-145X060	with stop	offset upwards	19,5	8,1	6	18	28	38	45	05568, 05567, 05572, 05573
05569-145X080	with stop	offset upwards	19,5	8,1	8	20	30	40	45	05568, 05567, 05572, 05573
05569-145X100	with stop	offset upwards	19,5	8,1	10	22	32	42	45	05568, 05567, 05572, 05573

Overview of items

Order No.	Version 1	Version 2	B	B1	A by H=18	A by H=30	A by H=40	A by H=50	L	Suitable for
05569-145X120	with stop	offset upwards	19,5	8,1	12	24	34	44	45	05568, 05567, 05572, 05573
05569-145X140	with stop	offset upwards	19,5	8,1	14	26	36	46	45	05568, 05567, 05572, 05573
05569-145X160	with stop	offset upwards	19,5	8,1	16	28	38	48	45	05568, 05567, 05572, 05573
05569-145X180	with stop	straight	19,5	8,1	18	30	40	50	45	05568, 05567, 05572, 05573
05569-145X200	with stop	offset downwards	19,5	8,1	20	32	42	52	45	05568, 05567, 05572, 05573
05569-145X220	with stop	offset downwards	19,5	8,1	22	34	44	54	45	05568, 05567, 05572, 05573
05569-145X240	with stop	offset downwards	19,5	8,1	24	36	46	56	45	05568, 05567, 05572, 05573
05569-145X260	with stop	offset downwards	19,5	8,1	26	38	48	58	45	05568, 05567, 05572, 05573
05569-145X280	with stop	offset downwards	19,5	8,1	28	40	50	60	45	05568, 05567, 05572, 05573
05569-145X300	with stop	offset downwards	19,5	8,1	30	42	52	62	45	05568, 05567, 05572, 05573
05569-145X320	with stop	offset downwards	19,5	8,1	32	44	54	64	45	05568, 05567, 05572, 05573
05569-145X340	with stop	offset downwards	19,5	8,1	34	46	56	66	45	05568, 05567, 05572, 05573
05569-145X360	with stop	offset downwards	19,5	8,1	36	48	58	68	45	05568, 05567, 05572, 05573
05569-145X380	with stop	offset downwards	19,5	8,1	38	50	60	70	45	05568, 05567, 05572, 05573
05569-145X400	with stop	offset downwards	19,5	8,1	40	52	62	72	45	05568, 05567, 05572, 05573
05569-145X420	with stop	offset downwards	19,5	8,1	42	54	64	74	45	05568, 05567, 05572, 05573