

Item description/product images



Description

Material:

Steel 1.0503

Version:

Steel, bright.


Steel electro zinc-plated.

Note:

The slotted round nuts are mainly used to fasten bearings to a shaft.

The slotted round nuts can also be used to secure gear wheels, pulleys and other machine components.

Drawings

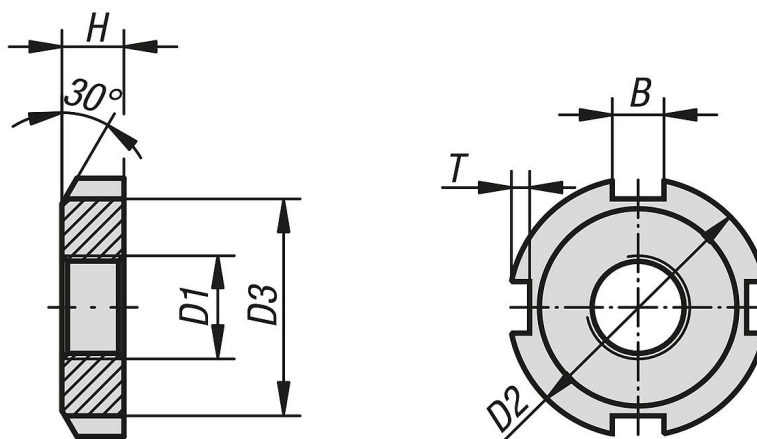

Overview of items

Order No.	Surface finish body	D1	D2	D3	H	B=slot width	T
07590-05-010	Catch plate	M10x1	20	16	5	4,5	1,8
07590-05-012	Catch plate	M12x1,5	22	18	6	4,5	1,8
07590-05-014	Catch plate	M14x1,5	24	20	6	4,5	1,8
07590-05-016	Catch plate	M16x1,5	28	23	6	5,5	2,3
07590-05-018	Catch plate	M18x1,5	30	25	6	5,5	2,3
07590-05-020	Catch plate	M20x1,5	32	27	6	5,5	2,3
07590-05-022	Catch plate	M22x1,5	36	30	7	6,5	2,8
07590-05-024	Catch plate	M24x1,5	38	32	7	6,5	2,8
07590-05-026	Catch plate	M26x1,5	40	34	7	6,5	2,8
07590-05-028	Catch plate	M28x1,5	42	36	7	6,5	2,8
07590-05-030	Catch plate	M30x1,5	44	38	7	6,5	2,8
07590-05-032	Catch plate	M32x1,5	48	41	8	7	3,3
07590-05-035	Catch plate	M35x1,5	50	43	8	7	3,3
07590-05-038	Catch plate	M38x1,5	54	47	8	7	3,3
07590-05-040	Catch plate	M40x1,5	56	49	8	7	3,3
07590-05-042	Catch plate	M42x1,5	60	52	8	8	3,3
07590-05-045	Catch plate	M45x1,5	62	54	8	8	3,3
07590-05-048	Catch plate	M48x1,5	65	57	8	8	3,3
07590-05-050	Catch plate	M50x1,5	68	60	8	8	3,3
07590-05-052	Catch plate	M52x1,5	70	62	8	8	3,3
07590-05-055	Catch plate	M55x1,5	75	67	8	8	3,3
07590-05-060	Catch plate	M60x1,5	80	71	9	11	4,3
07590-05-065	Catch plate	M65x1,5	85	76	9	11	4,3

Overview of items

Order No.	Surface finish body	D1	D2	D3	H	B=slot width	T
07590-05-070	Catch plate	M70X1,5	90	81	9	11	4,3
07590-05-075	Catch plate	M75X1,5	95	86	10	11	4,3
07590-05-080	Catch plate	M80X1,5	100	91	10	11	4,3
07590-05-10	for aluminium profile type I	M10x1,5	20	16	5	4,5	1,8
07590-05-12	for aluminium profile type I	M12x1,5	22	18	6	4,5	1,8
07590-05-14	for aluminium profile type I	M14x1,5	24	20	6	4,5	1,8
07590-05-16	for aluminium profile type I	M16x1,5	28	23	6	5,5	2,3
07590-05-18	for aluminium profile type I	M18x1,5	30	25	6	5,5	2,3
07590-05-20	for aluminium profile type I	M20x1,5	32	27	6	5,5	2,3
07590-05-22	for aluminium profile type I	M22x1,5	36	30	7	6,5	2,8
07590-05-24	for aluminium profile type I	M24x1,5	38	32	7	6,5	2,8
07590-05-26	for aluminium profile type I	M26x1,5	40	34	7	6,5	2,8
07590-05-28	for aluminium profile type I	M28x1,5	42	36	7	6,5	2,8
07590-05-30	for aluminium profile type I	M30x1,5	44	38	7	6,5	2,8
07590-05-32	for aluminium profile type I	M32x1,5	48	41	8	7	3,3
07590-05-35	for aluminium profile type I	M35x1,5	50	43	8	7	3,3
07590-05-38	for aluminium profile type I	M38x1,5	54	47	8	7	3,3
07590-05-40	for aluminium profile type I	M40x1,5	56	49	8	7	3,3
07590-05-42	for aluminium profile type I	M42x1,5	60	52	8	8	3,3
07590-05-45	for aluminium profile type I	M45x1,5	62	54	8	8	3,3
07590-05-48	for aluminium profile type I	M48x1,5	65	57	8	8	3,3
07590-05-50	for aluminium profile type I	M50x1,5	68	60	8	8	3,3
07590-05-52	for aluminium profile type I	M52X1,5	70	62	8	8	3,3
07590-05-55	for aluminium profile type I	M55X1,5	75	67	8	8	3,3
07590-05-60	for aluminium profile type I	M60x1,5	80	71	9	11	4,3
07590-05-65	for aluminium profile type I	M65X1,5	85	76	9	11	4,3
07590-05-70	for aluminium profile type I	M70X1,5	90	81	9	11	4,3
07590-05-75	for aluminium profile type I	M75X1,5	95	86	10	11	4,3
07590-05-80	for aluminium profile type I	M80X1,5	100	91	10	11	4,3