

Item description/product images



Description

Material:

Body soft PVC.

Version:

Body black.

Note:

Hardness Shore 92A.

UV-resistant.

ØD = Tube outside diameter onto which the the respective cap fits.

Application:

The caps serve as protection against sharp edges on pipes.


Temperature range:

Cold tolerant down to approx. -15 °C under load.

Assembly:

Slight heating to ca. 40 °C simplifies the installation, the adhesion is increased and larger pipe tolerances can be compensated for.

Drawings

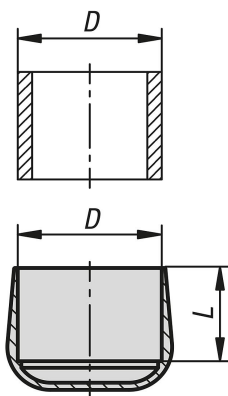

Overview of items

Order No.	D	L
29056-05-06	5,8-6,2	10
29056-05-08	7,9-8,5	11
29056-05-10	9,8-10,2	13
29056-05-12	11,8-12,8	15
29056-05-16	15,5-16,5	22,5
29056-05-18	17,8-18,8	21
29056-05-19	18,8-19,4	22
29056-05-20	19,4-20,8	21,5
29056-05-22	21,8-23	22
29056-05-25	24,5-26	24
29056-05-27	26,5-28	26
29056-05-28	27,5-29	25
29056-05-30	29,5-31,5	26
29056-05-32	31,5-33,5	26

Overview of items

Order No.	D	L
29056-05-34	33-35,5	26
29056-05-38	37-39	27
29056-05-40	39-41	26
29056-05-42	41-43	26
29056-05-43	42-44,5	26
29056-05-45	44-46	26
29056-05-48	47-49,5	27
29056-05-50	48,5-51	27