

## Item description/product images



## Description

**Material:**

Housing, actuator and fastening nut stainless steel 1.4404.

O-rings silicone, red or blue, FDA-compliant.

Locking screw stainless steel 1.4301.

**Version:**

Bright.

**Note:**

The quarter-turn lock fulfils the hygiene requirements of DIN EN ISO 14159 and DIN EN 1672-2.

Particularly suitable for use in the food and beverage industry.

O-rings (FDA-compliant) prevent the ingress of liquid and formation of contamination.

IP65 / IP67 / IP69K in accordance with DIN EN 60529 / DIN 40050.


Please order the tongue in the desired version separately. Every tongue can be combined with every housing.

\*Dimension A results from the combination of the quarter turn lock and the tongue and is specified with the matching tongues.

**Accessory:**

Tongue for stainless steel quarter-turn lock 05566-07.

## Drawings

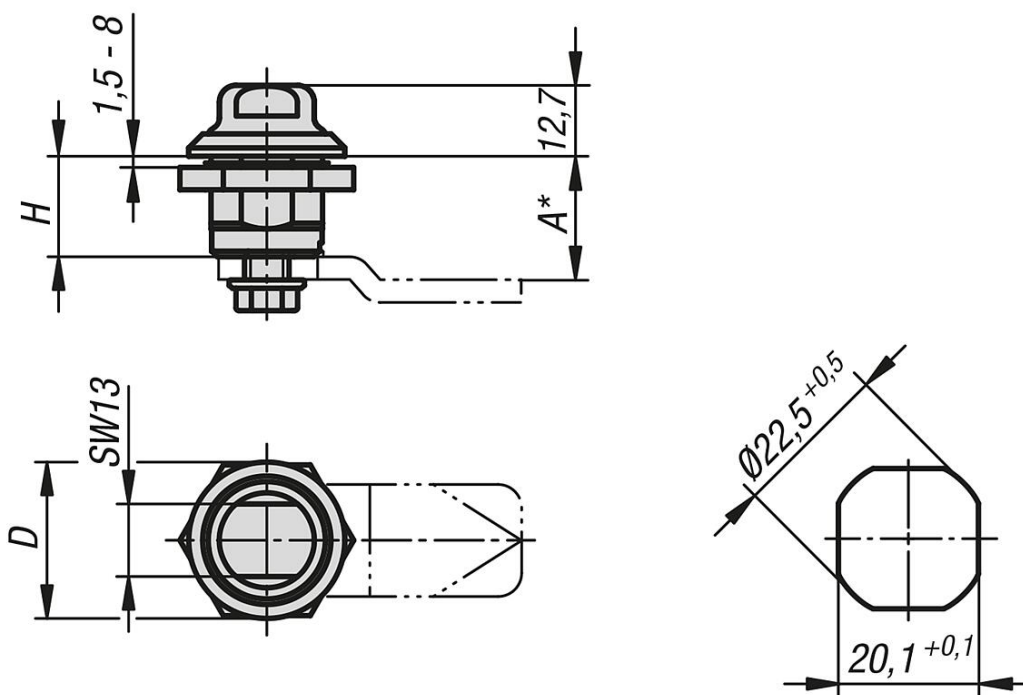

## Overview of items

| Order No.    | Component colour | Actuation   | D  | H  |
|--------------|------------------|-------------|----|----|
| 05595-01-18  | red              | double flat | 28 | 18 |
| 05595-01-181 | blue             | double flat | 28 | 18 |