

Item description/product images



Description

Material:

Polyurethane (PU) with steel cord reinforcement.

Note:

Endless toothed belts with metric pitch ISO 17396 trapezoidal profile. Ideal for drives with high belt flexibility. Permits smallest pulley diameters. The toothed belts are intended for drives where precision is a requirement, safety is important and the effects of chemicals are a concern.

The colour of the toothed belt may differ from the colour shown in the product photo.


Temperature range:

From -10 °C to +80 °C

Features:

- maintenance-free
- high-power transmission
- minimal belt extension
- accurate positioning and angles
- very good chemical resistance, especially to oils, greases and fuels
- extremely high abrasion resistance
- transmits power up to 30 kW
- reliable speed up to 10,000 rpm

Drawings

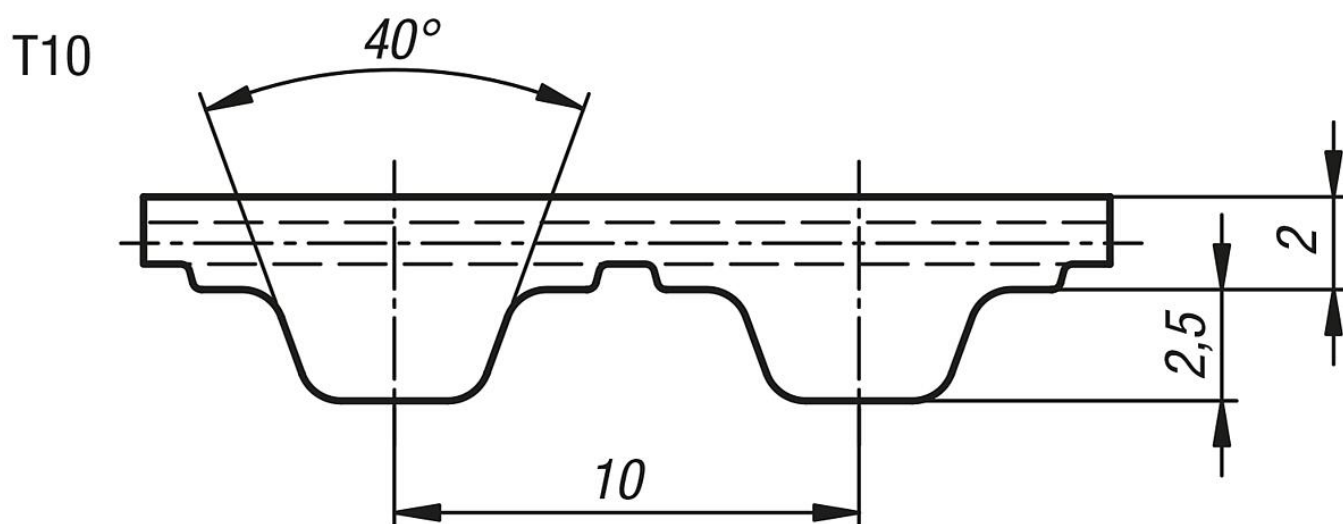

Overview of items

Order No.	belt width	No. of teeth	Effective length
22052-1016X0260	16	26	260
22052-1016X0370	16	37	370
22052-1016X0400	16	40	400
22052-1016X0410	16	41	410
22052-1016X0440	16	44	440
22052-1016X0450	16	45	450
22052-1016X0500	16	50	500

Overview of items

Order No.	belt width	No. of teeth	Effective length
22052-1016X0530	16	53	530
22052-1016X0560	16	56	560
22052-1016X0610	16	61	610
22052-1016X0630	16	63	630
22052-1016X0660	16	66	660
22052-1016X0690	16	69	690
22052-1016X0700	16	70	700
22052-1016X0720	16	72	720
22052-1016X0750	16	75	750
22052-1016X0780	16	78	780
22052-1016X0810	16	81	810
22052-1016X0840	16	84	840
22052-1016X0880	16	88	880
22052-1016X0890	16	89	890
22052-1016X0900	16	90	900
22052-1016X0920	16	92	920
22052-1016X0960	16	96	960
22052-1016X0970	16	97	970
22052-1016X0980	16	98	980
22052-1016X1010	16	101	1010
22052-1016X1080	16	108	1080
22052-1016X1110	16	111	1110
22052-1016X1140	16	114	1140
22052-1016X1150	16	115	1150
22052-1016X1210	16	121	1210
22052-1016X1240	16	124	1240
22052-1016X1250	16	125	1250
22052-1016X1300	16	130	1300
22052-1016X1320	16	132	1320
22052-1016X1350	16	135	1350
22052-1016X1390	16	139	1390
22052-1016X1400	16	140	1400
22052-1016X1420	16	142	1420
22052-1016X1440	16	144	1440
22052-1016X1450	16	145	1450
22052-1016X1460	16	146	1460
22052-1016X1500	16	150	1500
22052-1016X1560	16	156	1560
22052-1016X1610	16	161	1610
22052-1016X1750	16	175	1750
22052-1016X1780	16	178	1780
22052-1016X1880	16	188	1880
22052-1016X1960	16	196	1960
22052-1016X2250	16	225	2250
22052-1025X0260	25	26	260
22052-1025X0370	25	37	370
22052-1025X0400	25	40	400
22052-1025X0410	25	41	410
22052-1025X0440	25	44	440
22052-1025X0450	25	45	450
22052-1025X0500	25	50	500
22052-1025X0530	25	53	530
22052-1025X0560	25	56	560
22052-1025X0610	25	61	610
22052-1025X0630	25	63	630
22052-1025X0660	25	66	660
22052-1025X0690	25	69	690
22052-1025X0700	25	70	700
22052-1025X0720	25	72	720
22052-1025X0750	25	75	750
22052-1025X0780	25	78	780
22052-1025X0810	25	81	810
22052-1025X0840	25	84	840
22052-1025X0880	25	88	880
22052-1025X0890	25	89	890

Overview of items

Order No.	belt width	No. of teeth	Effective length
22052-1025X0900	25	90	900
22052-1025X0920	25	92	920
22052-1025X0960	25	96	960
22052-1025X0970	25	97	970
22052-1025X0980	25	98	980
22052-1025X1010	25	101	1010
22052-1025X1080	25	108	1080
22052-1025X1110	25	111	1110
22052-1025X1140	25	114	1140
22052-1025X1150	25	115	1150
22052-1025X1210	25	121	1210
22052-1025X1240	25	124	1240
22052-1025X1250	25	125	1250
22052-1025X1300	25	130	1300
22052-1025X1320	25	132	1320
22052-1025X1350	25	135	1350
22052-1025X1390	25	139	1390
22052-1025X1400	25	140	1400
22052-1025X1420	25	142	1420
22052-1025X1440	25	144	1440
22052-1025X1450	25	145	1450
22052-1025X1460	25	146	1460
22052-1025X1500	25	150	1500
22052-1025X1560	25	156	1560
22052-1025X1610	25	161	1610
22052-1025X1750	25	175	1750
22052-1025X1780	25	178	1780
22052-1025X1880	25	188	1880
22052-1025X1960	25	196	1960
22052-1025X2250	25	225	2250
22052-1032X0260	32	26	260
22052-1032X0370	32	37	370
22052-1032X0400	32	40	400
22052-1032X0410	32	41	410
22052-1032X0440	32	44	440
22052-1032X0450	32	45	450
22052-1032X0500	32	50	500
22052-1032X0530	32	53	530
22052-1032X0560	32	56	560
22052-1032X0610	32	61	610
22052-1032X0630	32	63	630
22052-1032X0660	32	66	660
22052-1032X0690	32	69	690
22052-1032X0700	32	70	700
22052-1032X0720	32	72	720
22052-1032X0750	32	75	750
22052-1032X0780	32	78	780
22052-1032X0810	32	81	810
22052-1032X0840	32	84	840
22052-1032X0880	32	88	880
22052-1032X0890	32	89	890
22052-1032X0900	32	90	900
22052-1032X0920	32	92	920
22052-1032X0960	32	96	960
22052-1032X0970	32	97	970
22052-1032X0980	32	98	980
22052-1032X1010	32	101	1010
22052-1032X1080	32	108	1080
22052-1032X1110	32	111	1110
22052-1032X1140	32	114	1140
22052-1032X1150	32	115	1150
22052-1032X1210	32	121	1210
22052-1032X1240	32	124	1240
22052-1032X1250	32	125	1250
22052-1032X1300	32	130	1300

Overview of items

Order No.	belt width	No. of teeth	Effective length
22052-1032X1320	32	132	1320
22052-1032X1350	32	135	1350
22052-1032X1390	32	139	1390
22052-1032X1400	32	140	1400
22052-1032X1420	32	142	1420
22052-1032X1440	32	144	1440
22052-1032X1450	32	145	1450
22052-1032X1460	32	146	1460
22052-1032X1500	32	150	1500
22052-1032X1560	32	156	1560
22052-1032X1610	32	161	1610
22052-1032X1750	32	175	1750
22052-1032X1780	32	178	1780
22052-1032X1880	32	188	1880
22052-1032X1960	32	196	1960
22052-1032X2250	32	225	2250