


Item description/product images

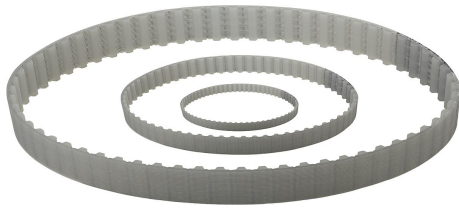

Description

Material:

Polyurethane (PU) with steel cord reinforcement.

Note:

Endless toothed belts with metric pitch ISO 17396 trapezoidal profile. Ideal for drives with high belt flexibility. Permits smallest pulley diameters. The toothed belts are intended for drives where precision is a requirement, safety is important and the effects of chemicals are a concern.

The colour of the toothed belt may differ from the colour shown in the product photo.

Temperature range:

From -10 °C to +80 °C

Features:

- maintenance-free
- high-power transmission
- minimal belt extension
- accurate positioning and angles
- very good chemical resistance, especially to oils, greases and fuels
- extremely high abrasion resistance
- transmits power up to 30 kW
- reliable speed up to 10,000 rpm

Overview of items

Order No.	belt width	No. of teeth	Effective length
22052-2506X0120	6	48	120
22052-2506X0145	6	58	145
22052-2506X0160	6	64	160
22052-2506X0177	6	71	177,5
22052-2506X0180	6	72	180
22052-2506X0200	6	80	200
22052-2506X0230	6	92	230
22052-2506X0245	6	98	245
22052-2506X0265	6	106	265
22052-2506X0285	6	114	285
22052-2506X0290	6	116	290
22052-2506X0305	6	122	305
22052-2506X0317	6	127	317,5
22052-2506X0330	6	132	330
22052-2506X0380	6	152	380
22052-2506X0420	6	168	420
22052-2506X0480	6	192	480
22052-2506X0500	6	200	500
22052-2506X0540	6	216	540
22052-2506X0600	6	240	600
22052-2506X0650	6	260	650
22052-2506X0780	6	312	780
22052-2506X0915	6	366	915
22052-2506X0950	6	380	950

Overview of items
