


Item description/product images

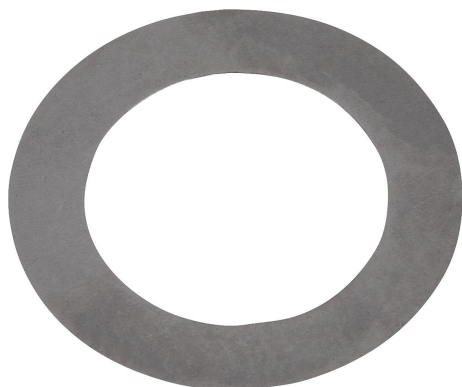

Description

Material:

Steel.

Stainless steel A2.


Version:

Bright.

Note:

With shim washers, an existing axial backlash can be significantly reduced. They are available with a thicknesses from 0.1 mm. Any thicknesses can be made by combining several shim washers.

Drawings

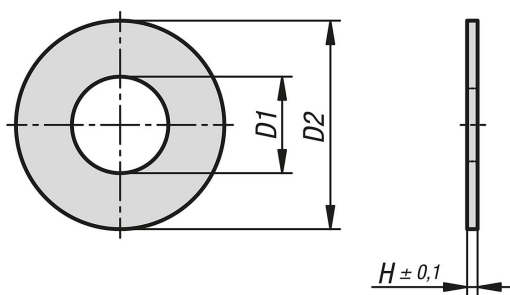

Overview of items

Order No.	Main material	D1	D2	H
07522-0306010	steel	3	6	0,1
07522-0306015	steel	3	6	0,15
07522-0306020	steel	3	6	0,2
07522-0306025	steel	3	6	0,25
07522-0306030	steel	3	6	0,3
07522-0306050	steel	3	6	0,5
07522-0306100	steel	3	6	1
07522-0408010	steel	4	8	0,1
07522-0408015	steel	4	8	0,15
07522-0408020	steel	4	8	0,2
07522-0408030	steel	4	8	0,3
07522-0408050	steel	4	8	0,5
07522-0408100	steel	4	8	1
07522-0510010	steel	5	10	0,1
07522-0510015	steel	5	10	0,15
07522-0510020	steel	5	10	0,2
07522-0510025	steel	5	10	0,25
07522-0510030	steel	5	10	0,3
07522-0510050	steel	5	10	0,5
07522-0510100	steel	5	10	1
07522-0612010	steel	6	12	0,1
07522-0612020	steel	6	12	0,2
07522-0612025	steel	6	12	0,25
07522-0612030	steel	6	12	0,3
07522-0612050	steel	6	12	0,5
07522-0612100	steel	6	12	1
07522-0713010	steel	7	13	0,1
07522-0713020	steel	7	13	0,2
07522-0713030	steel	7	13	0,3
07522-0713050	steel	7	13	0,5

Overview of items

Order No.	Main material	D1	D2	H
07522-0713100	steel	7	13	1
07522-0814010	steel	8	14	0,1
07522-0814015	steel	8	14	0,15
07522-0814020	steel	8	14	0,2
07522-0814025	steel	8	14	0,25
07522-0814030	steel	8	14	0,3
07522-0814050	steel	8	14	0,5
07522-0814100	steel	8	14	1
07522-0915010	steel	9	15	0,1
07522-0915015	steel	9	15	0,15
07522-0915020	steel	9	15	0,2
07522-0915030	steel	9	15	0,3
07522-0915050	steel	9	15	0,5
07522-0915100	steel	9	15	1
07522-1016010	steel	10	16	0,1
07522-1016015	steel	10	16	0,15
07522-1016020	steel	10	16	0,2
07522-1016025	steel	10	16	0,25
07522-1016030	steel	10	16	0,3
07522-1016050	steel	10	16	0,5
07522-1016100	steel	10	16	1
07522-1117010	steel	11	17	0,1
07522-1117020	steel	11	17	0,2
07522-1117025	steel	11	17	0,25
07522-1117030	steel	11	17	0,3
07522-1117050	steel	11	17	0,5
07522-1117100	steel	11	17	1
07522-1218010	steel	12	18	0,1
07522-1218015	steel	12	18	0,15
07522-1218020	steel	12	18	0,2
07522-1218025	steel	12	18	0,25
07522-1218030	steel	12	18	0,3
07522-1218050	steel	12	18	0,5
07522-1218100	steel	12	18	1
07522-1319010	steel	13	19	0,1
07522-1319015	steel	13	19	0,15
07522-1319020	steel	13	19	0,2
07522-1319025	steel	13	19	0,25
07522-1319030	steel	13	19	0,3
07522-1319050	steel	13	19	0,5
07522-1319100	steel	13	19	1
07522-1420010	steel	14	20	0,1
07522-1420015	steel	14	20	0,15
07522-1420020	steel	14	20	0,2
07522-1420025	steel	14	20	0,25
07522-1420030	steel	14	20	0,3
07522-1420050	steel	14	20	0,5
07522-1420100	steel	14	20	1
07522-1521010	steel	15	21	0,1
07522-1521015	steel	15	21	0,15
07522-1521020	steel	15	21	0,2
07522-1521025	steel	15	21	0,25
07522-1521030	steel	15	21	0,3
07522-1521050	steel	15	21	0,5
07522-1521100	steel	15	21	1
07522-1521120	steel	15	21	1,2
07522-1622015	steel	16	22	0,15
07522-1622020	steel	16	22	0,2
07522-1622025	steel	16	22	0,25
07522-1622030	steel	16	22	0,3
07522-1622050	steel	16	22	0,5
07522-1622100	steel	16	22	1
07522-1622120	steel	16	22	1,2
07522-1724010	steel	17	24	0,1
07522-1724015	steel	17	24	0,15

Overview of items

Order No.	Main material	D1	D2	H
07522-1724020	steel	17	24	0,2
07522-1724025	steel	17	24	0,25
07522-1724030	steel	17	24	0,3
07522-1724050	steel	17	24	0,5
07522-1724100	steel	17	24	1
07522-1724120	steel	17	24	1,2
07522-1825010	steel	18	25	0,1
07522-1825015	steel	18	25	0,15
07522-1825020	steel	18	25	0,2
07522-1825025	steel	18	25	0,25
07522-1825030	steel	18	25	0,3
07522-1825050	steel	18	25	0,5
07522-1825100	steel	18	25	1
07522-1825120	steel	18	25	1,2
07522-1926010	steel	19	26	0,1
07522-1926015	steel	19	26	0,15
07522-1926020	steel	19	26	0,2
07522-1926025	steel	19	26	0,25
07522-1926030	steel	19	26	0,3
07522-1926050	steel	19	26	0,5
07522-1926100	steel	19	26	1
07522-1926120	steel	19	26	1,2
07522-2028010	steel	20	28	0,1
07522-2028015	steel	20	28	0,15
07522-2028020	steel	20	28	0,2
07522-2028025	steel	20	28	0,25
07522-2028030	steel	20	28	0,3
07522-2028050	steel	20	28	0,5
07522-2028100	steel	20	28	1
07522-2028120	steel	20	28	1,2
07522-2028150	steel	20	28	1,5
07522-2230010	steel	22	30	0,1
07522-2230015	steel	22	30	0,15
07522-2230020	steel	22	30	0,2
07522-2230025	steel	22	30	0,25
07522-2230030	steel	22	30	0,3
07522-2230050	steel	22	30	0,5
07522-2230100	steel	22	30	1
07522-2230120	steel	22	30	1,2
07522-2230150	steel	22	30	1,5
07522-2535010	steel	25	35	0,1
07522-2535015	steel	25	35	0,15
07522-2535020	steel	25	35	0,2
07522-2535025	steel	25	35	0,25
07522-2535030	steel	25	35	0,3
07522-2535050	steel	25	35	0,5
07522-2535100	steel	25	35	1
07522-2535120	steel	25	35	1,2
07522-2535150	steel	25	35	1,5
07522-2637010	steel	26	37	0,1
07522-2637015	steel	26	37	0,15
07522-2637020	steel	26	37	0,2
07522-2637025	steel	26	37	0,25
07522-2637030	steel	26	37	0,3
07522-2637050	steel	26	37	0,5
07522-2637100	steel	26	37	1
07522-2637120	steel	26	37	1,2
07522-2637150	steel	26	37	1,5
07522-2840010	steel	28	40	0,1
07522-2840015	steel	28	40	0,15
07522-2840020	steel	28	40	0,2
07522-2840025	steel	28	40	0,25
07522-2840030	steel	28	40	0,3
07522-2840050	steel	28	40	0,5
07522-2840100	steel	28	40	1

Overview of items

Order No.	Main material	D1	D2	H
07522-2840120	steel	28	40	1,2
07522-2840150	steel	28	40	1,5
07522-3042010	steel	30	42	0,1
07522-3042015	steel	30	42	0,15
07522-3042020	steel	30	42	0,2
07522-3042025	steel	30	42	0,25
07522-3042030	steel	30	42	0,3
07522-3042050	steel	30	42	0,5
07522-3042100	steel	30	42	1
07522-3042120	steel	30	42	1,2
07522-3042150	steel	30	42	1,5
07522-3042200	steel	30	42	2
07522-3245010	steel	32	45	0,1
07522-3245015	steel	32	45	0,15
07522-3245020	steel	32	45	0,2
07522-3245025	steel	32	45	0,25
07522-3245030	steel	32	45	0,3
07522-3245050	steel	32	45	0,5
07522-3245100	steel	32	45	1
07522-3245120	steel	32	45	1,2
07522-3245150	steel	32	45	1,5
07522-3245200	steel	32	45	2
07522-3545010	steel	35	45	0,1
07522-3545015	steel	35	45	0,15
07522-3545020	steel	35	45	0,2
07522-3545025	steel	35	45	0,25
07522-3545030	steel	35	45	0,3
07522-3545050	steel	35	45	0,5
07522-3545100	steel	35	45	1
07522-3545120	steel	35	45	1,2
07522-3545150	steel	35	45	1,5
07522-3545200	steel	35	45	2
07522-3645010	steel	36	45	0,1
07522-3645015	steel	36	45	0,15
07522-3645020	steel	36	45	0,2
07522-3645025	steel	36	45	0,25
07522-3645030	steel	36	45	0,3
07522-3645050	steel	36	45	0,5
07522-3645100	steel	36	45	1
07522-3645120	steel	36	45	1,2
07522-3645150	steel	36	45	1,5
07522-3645200	steel	36	45	2
07522-3747010	steel	37	47	0,1
07522-3747015	steel	37	47	0,15
07522-3747020	steel	37	47	0,2
07522-3747025	steel	37	47	0,25
07522-3747030	steel	37	47	0,3
07522-3747050	steel	37	47	0,5
07522-3747100	steel	37	47	1
07522-3747120	steel	37	47	1,2
07522-3747150	steel	37	47	1,5
07522-3747200	steel	37	47	2
07522-4050010	steel	40	50	0,1
07522-4050015	steel	40	50	0,15
07522-4050020	steel	40	50	0,2
07522-4050025	steel	40	50	0,25
07522-4050030	steel	40	50	0,3
07522-4050050	steel	40	50	0,5
07522-4050100	steel	40	50	1
07522-4050120	steel	40	50	1,2
07522-4050150	steel	40	50	1,5
07522-4050200	steel	40	50	2
07522-4252010	steel	42	52	0,1
07522-4252015	steel	42	52	0,15
07522-4252020	steel	42	52	0,2

Overview of items

Order No.	Main material	D1	D2	H
07522-4252025	steel	42	52	0,25
07522-4252030	steel	42	52	0,3
07522-4252050	steel	42	52	0,5
07522-4252100	steel	42	52	1
07522-4252120	steel	42	52	1,2
07522-4252150	steel	42	52	1,5
07522-4252200	steel	42	52	2
07522-4555010	steel	45	55	0,1
07522-4555015	steel	45	55	0,15
07522-4555020	steel	45	55	0,2
07522-4555025	steel	45	55	0,25
07522-4555030	steel	45	55	0,3
07522-4555050	steel	45	55	0,5
07522-4555100	steel	45	55	1
07522-4555120	steel	45	55	1,2
07522-4555150	steel	45	55	1,5
07522-4555200	steel	45	55	2
07522-4860010	steel	48	60	0,1
07522-4860015	steel	48	60	0,15
07522-4860020	steel	48	60	0,2
07522-4860025	steel	48	60	0,25
07522-4860030	steel	48	60	0,3
07522-4860050	steel	48	60	0,5
07522-4860100	steel	48	60	1
07522-4860120	steel	48	60	1,2
07522-4860150	steel	48	60	1,5
07522-4860200	steel	48	60	2
07522-5062010	steel	50	62	0,1
07522-5062015	steel	50	62	0,15
07522-5062020	steel	50	62	0,2
07522-5062025	steel	50	62	0,25
07522-5062030	steel	50	62	0,3
07522-5062050	steel	50	62	0,5
07522-5062100	steel	50	62	1
07522-5062120	steel	50	62	1,2
07522-5062150	steel	50	62	1,5
07522-5062200	steel	50	62	2
07522-10408020	stainless steel A2	4	8	0,2
07522-10408030	stainless steel A2	4	8	0,3
07522-10408050	stainless steel A2	4	8	0,5
07522-10408100	stainless steel A2	4	8	1
07522-10510020	stainless steel A2	5	10	0,2
07522-10510030	stainless steel A2	5	10	0,3
07522-10510050	stainless steel A2	5	10	0,5
07522-10510100	stainless steel A2	5	10	1
07522-10612020	stainless steel A2	6	12	0,2
07522-10612100	stainless steel A2	6	12	1
07522-10814050	stainless steel A2	8	14	0,5
07522-10814100	stainless steel A2	8	14	1
07522-10915100	stainless steel A2	9	15	1
07522-11016010	stainless steel A2	10	16	0,1
07522-11016020	stainless steel A2	10	16	0,2
07522-11016050	stainless steel A2	10	16	0,5
07522-11016100	stainless steel A2	10	16	1
07522-11218010	stainless steel A2	12	18	0,1
07522-11218030	stainless steel A2	12	18	0,3
07522-11218050	stainless steel A2	12	18	0,5
07522-11319020	stainless steel A2	13	19	0,2
07522-11420050	stainless steel A2	14	20	0,5
07522-11420100	stainless steel A2	14	20	1
07522-11521050	stainless steel A2	15	21	0,5
07522-11622020	stainless steel A2	16	22	0,2
07522-11622030	stainless steel A2	16	22	0,3
07522-11622100	stainless steel A2	16	22	1
07522-11825100	stainless steel A2	18	25	1

Overview of items

Order No.	Main material	D1	D2	H
07522-12028010	stainless steel A2	20	28	0,1
07522-12028050	stainless steel A2	20	28	0,5
07522-12028100	stainless steel A2	20	28	1
07522-12535100	stainless steel A2	25	35	1
07522-13042050	stainless steel A2	30	42	0,5
07522-13042100	stainless steel A2	30	42	1
07522-13545030	stainless steel A2	35	45	0,3
07522-14050050	stainless steel A2	40	50	0,5
07522-14050100	stainless steel A2	40	50	1