

Item description/product images

**Description****Material:**

Stainless steel 1.4305.

Version:

Bright.

Note:

Rating IP65. This is achieved using an additional O-ring underneath the actuator and a PUR seal foamed onto the housing. The quarter-turn lock can be installed pre-assembled.

Please order the required tongue separately. Every tongue can be combined with this housing.

Accessory:

Key 05586.


Tongue for stainless steel quarter-turn lock 05569.

Drawing reference:

Actuation:

- a) square 8 mm
- b) slit
- c) double lug 5 mm
- d) triangle 7 mm

Drawings

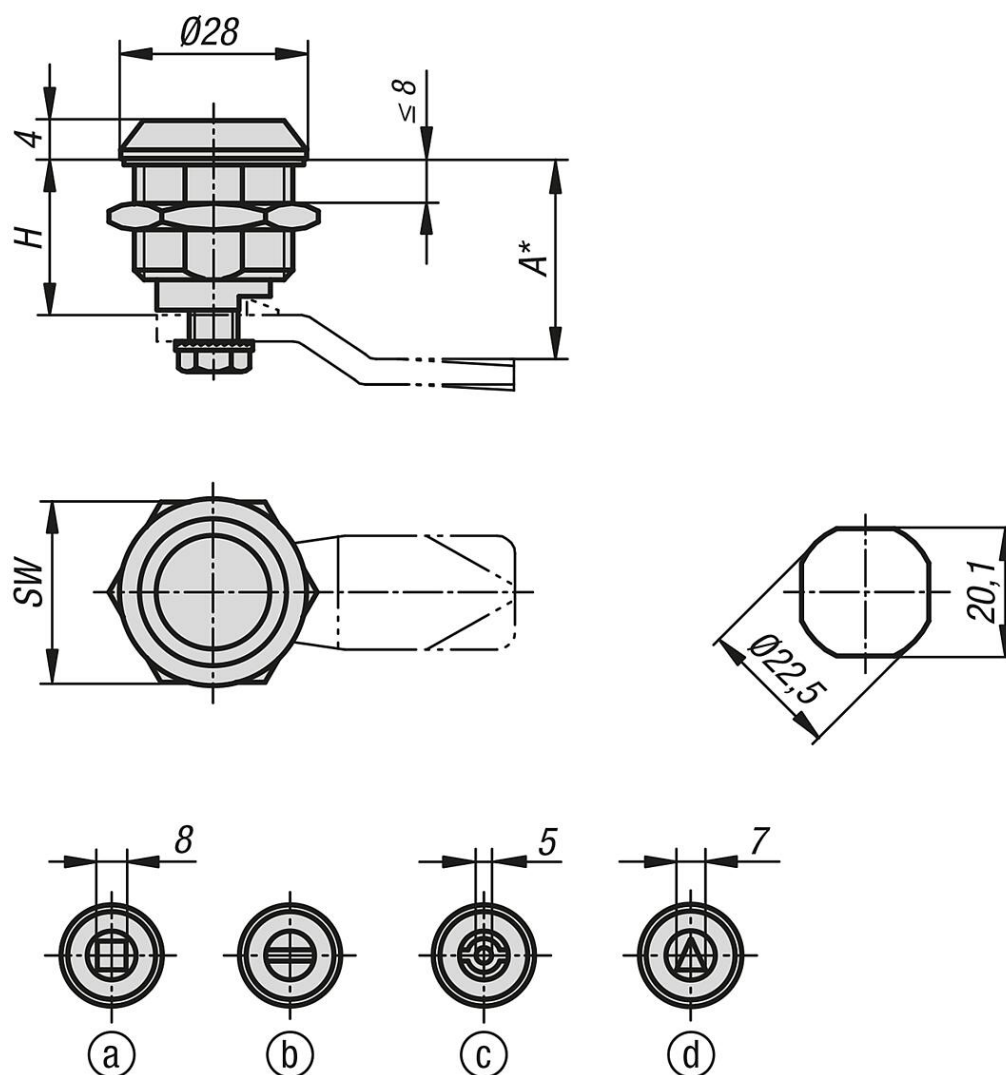

Overview of items

Order No.	Actuation	H	S max.	SW
05587-40186	double lug 5 mm	18	8	27
05587-20186	slot	18	8	27
05587-18186	square 8 mm	18	8	27
05587-87186	Triangle 7 mm	18	8	27