

Item description/product images

**Description****Material:**

Housing, stainless steel 1.4305.

Actuation and fastening nut, stainless steel 1.4404.

Version:

Bright.

Note:

The quarter turn lock can be installed pre-assembled. For right or left use. Water and dust protected acc. to IP65 from DIN EN 60529.

Please order required tongue version separately. Every tongue can be combined with every housing.

*Dimension A results from the combination of the quarter turn lock and the tongue and is specified with the matching tongues.

Accessory:

Key 05586.

Tongue for stainless steel quarter-turn lock 05566-07.

Drawing reference:


Actuation:

- a) square 7 mm
- b) square 8 mm
- c) double lug 3 mm
- d) double lug 5 mm
- e) T-grip
- f) triangle 7 mm

1) O-ring

2) flat seal

Drawings

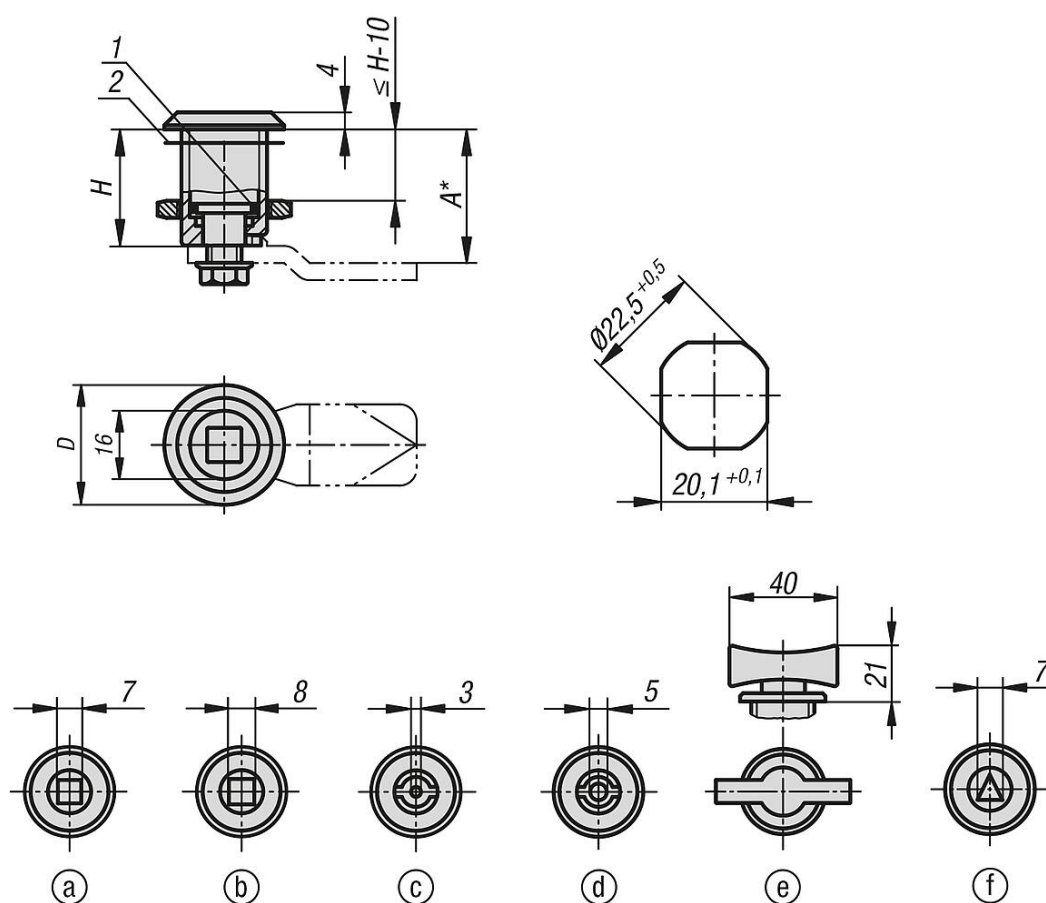

Overview of items

Order No.	Actuation	D	H	S max.
05566-04-1730	square 7 mm	28	30	20
05566-04-1860	square 8 mm	28	60	50
05566-04-4330	double lug 3 mm	28	30	20
05566-04-4336	double lug 3 mm	28	36	26
05566-04-4340	double lug 3 mm	28	40	30
05566-04-4350	double lug 3 mm	28	50	40
05566-04-4360	double lug 3 mm	28	60	50
05566-04-4530	double lug 5 mm	28	30	20
05566-04-4536	double lug 5 mm	28	36	26
05566-04-4540	double lug 5 mm	28	40	30
05566-04-4550	double lug 5 mm	28	50	40
05566-04-1736	square 7 mm	28	36	26
05566-04-4560	double lug 5 mm	28	60	50
05566-04-0030	Wing grip	28	30	20
05566-04-0036	Wing grip	28	36	26
05566-04-0040	Wing grip	28	40	30
05566-04-0050	Wing grip	28	50	40
05566-04-0060	Wing grip	28	60	50
05566-04-1740	square 7 mm	28	40	30
05566-04-1750	square 7 mm	28	50	40
05566-04-1760	square 7 mm	28	60	50
05566-04-1830	square 8 mm	28	30	20
05566-04-1836	square 8 mm	28	36	26
05566-04-1840	square 8 mm	28	40	30
05566-04-1850	square 8 mm	28	50	40
05566-04-8730	triangle 7 mm	28	30	20
05566-04-8736	triangle 7 mm	28	36	26

Overview of items

Order No.	Actuation	D	H	S max.
05566-04-8740	triangle 7 mm	28	40	30
05566-04-8750	triangle 7 mm	28	50	40
05566-04-8760	triangle 7 mm	28	60	50