

Item description/product images



Description

Material:

Knobs thermoset PF 31.


Rod steel or stainless steel 1.4305.

Version:

Thermoset black, high-gloss polished.

Steel black oxidised, blue passivated or bright stainless steel

Drawings

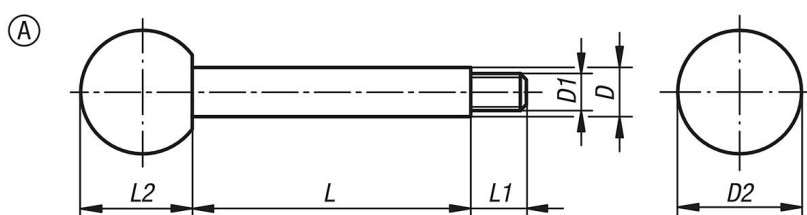

Overview of items

Order No.	Main material	Surface finish body	Form	D	D1	D2	L	L1	L2
06360-208X35	steel	black oxidised	A	8	M6	20	35	9	18
06360-208X50	steel	black oxidised	A	8	M6	20	50	9	18
06360-208X65	steel	black oxidised	A	8	M6	20	65	9	18
06360-210X50	steel	black oxidised	A	10	M8	25	50	13	23
06360-210X65	steel	black oxidised	A	10	M8	25	65	13	23
06360-210X80	steel	black oxidised	A	10	M8	25	80	13	23
06360-210X100	steel	black oxidised	A	10	M8	25	100	13	23
06360-212X65	steel	black oxidised	A	12	M10	32	65	15	29
06360-212X80	steel	black oxidised	A	12	M10	32	80	15	29
06360-212X100	steel	black oxidised	A	12	M10	32	100	15	29
06360-212X125	steel	black oxidised	A	12	M10	32	125	15	29
06360-214X80	steel	black oxidised	A	14	M12	36	80	16	33
06360-214X100	steel	black oxidised	A	14	M12	36	100	16	33
06360-214X125	steel	black oxidised	A	14	M12	36	125	16	33
06360-214X160	steel	black oxidised	A	14	M12	36	160	16	33
06360-2208X35	steel	blue-passivated	A	8	M6	20	35	9	18
06360-2208X50	steel	blue-passivated	A	8	M6	20	50	9	18
06360-2208X65	steel	blue-passivated	A	8	M6	20	65	9	18
06360-2210X50	steel	blue-passivated	A	10	M8	25	50	13	23
06360-2210X65	steel	blue-passivated	A	10	M8	25	65	13	23
06360-2210X80	steel	blue-passivated	A	10	M8	25	80	13	23
06360-2210X100	steel	blue-passivated	A	10	M8	25	100	13	23
06360-2212X65	steel	blue-passivated	A	12	M10	32	65	15	29
06360-2212X80	steel	blue-passivated	A	12	M10	32	80	15	29
06360-2212X100	steel	blue-passivated	A	12	M10	32	100	15	29
06360-2212X125	steel	blue-passivated	A	12	M10	32	125	15	29
06360-2214X80	steel	blue-passivated	A	14	M12	36	80	16	33
06360-2214X100	steel	blue-passivated	A	14	M12	36	100	16	33
06360-2214X125	steel	blue-passivated	A	14	M12	36	125	16	33
06360-2214X160	steel	blue-passivated	A	14	M12	36	160	16	33
06360-1208X35	stainless steel	bright	A	8	M6	20	35	9	18
06360-1208X50	stainless steel	bright	A	8	M6	20	50	9	18
06360-1208X65	stainless steel	bright	A	8	M6	20	65	9	18
06360-1210X50	stainless steel	bright	A	10	M8	25	50	13	23
06360-1210X65	stainless steel	bright	A	10	M8	25	65	13	23
06360-1210X80	stainless steel	bright	A	10	M8	25	80	13	23
06360-1210X100	stainless steel	bright	A	10	M8	25	100	13	23
06360-1212X65	stainless steel	bright	A	12	M10	32	65	15	29

Overview of items

Order No.	Main material	Surface finish body	Form	D	D1	D2	L	L1	L2
06360-1212X80	stainless steel	bright	A	12	M10	32	80	15	29
06360-1212X100	stainless steel	bright	A	12	M10	32	100	15	29
06360-1212X125	stainless steel	bright	A	12	M10	32	125	15	29
06360-1214X80	stainless steel	bright	A	14	M12	36	80	16	33
06360-1214X100	stainless steel	bright	A	14	M12	36	100	16	33
06360-1214X125	stainless steel	bright	A	14	M12	36	125	16	33
06360-1214X160	stainless steel	bright	A	14	M12	36	160	16	33