

Item description/product images



Description

Material:

Knobs thermoset PF 31.


Rod steel or stainless steel 1.4305.

Version:

Thermoset black, high-gloss polished.

Steel black oxidised, blue passivated or bright stainless steel

Drawings

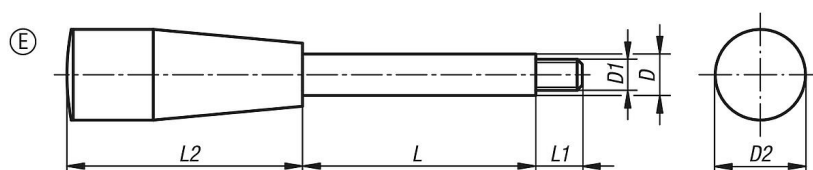

Overview of items

Order No.	Version	Surface finish body	Form	D	D1	D2	L	L1	L2
06360-608X35	steel	black oxidised	E	8	M6	17	35	9	45
06360-608X50	steel	black oxidised	E	8	M6	17	50	9	45
06360-608X65	steel	black oxidised	E	8	M6	17	65	9	45
06360-610X50	steel	black oxidised	E	10	M8	23	50	13	61
06360-610X65	steel	black oxidised	E	10	M8	23	65	13	61
06360-610X80	steel	black oxidised	E	10	M8	23	80	13	61
06360-610X100	steel	black oxidised	E	10	M8	23	100	13	61
06360-612X65	steel	black oxidised	E	12	M10	29	65	15	71
06360-612X80	steel	black oxidised	E	12	M10	29	80	15	71
06360-612X100	steel	black oxidised	E	12	M10	29	100	15	71
06360-612X125	steel	black oxidised	E	12	M10	29	125	15	71
06360-614X80	steel	black oxidised	E	14	M12	29	80	16	71
06360-614X100	steel	black oxidised	E	14	M12	29	100	16	71
06360-614X125	steel	black oxidised	E	14	M12	29	125	16	71
06360-614X160	steel	black oxidised	E	14	M12	29	160	16	71
06360-2608X35	steel	blue-passivated	E	8	M6	17	35	9	45
06360-2608X50	steel	blue-passivated	E	8	M6	17	50	9	45
06360-2608X65	steel	blue-passivated	E	8	M6	17	65	9	45
06360-2610X50	steel	blue-passivated	E	10	M8	23	50	13	61
06360-2610X65	steel	blue-passivated	E	10	M8	23	65	13	61
06360-2610X80	steel	blue-passivated	E	10	M8	23	80	13	61
06360-2610X100	steel	blue-passivated	E	10	M8	23	100	13	61
06360-2612X65	steel	blue-passivated	E	12	M10	29	65	15	71
06360-2612X80	steel	blue-passivated	E	12	M10	29	80	15	71
06360-2612X100	steel	blue-passivated	E	12	M10	29	100	15	71
06360-2612X125	steel	blue-passivated	E	12	M10	29	125	15	71
06360-2614X80	steel	blue-passivated	E	14	M12	29	80	16	71
06360-2614X100	steel	blue-passivated	E	14	M12	29	100	16	71
06360-2614X125	steel	blue-passivated	E	14	M12	29	125	16	71
06360-2614X160	steel	blue-passivated	E	14	M12	29	160	16	71
06360-1608X35	stainless steel	bright	E	8	M6	17	35	9	45
06360-1608X50	stainless steel	bright	E	8	M6	17	50	9	45
06360-1608X65	stainless steel	bright	E	8	M6	17	65	9	45
06360-1610X50	stainless steel	bright	E	10	M8	23	50	13	61
06360-1610X65	stainless steel	bright	E	10	M8	23	65	13	61
06360-1610X80	stainless steel	bright	E	10	M8	23	80	13	61
06360-1610X100	stainless steel	bright	E	10	M8	23	100	13	61
06360-1612X65	stainless steel	bright	E	12	M10	29	65	15	71
06360-1612X80	stainless steel	bright	E	12	M10	29	80	15	71
06360-1612X100	stainless steel	bright	E	12	M10	29	100	15	71

Overview of items

Order No.	Version	Surface finish body	Form	D	D1	D2	L	L1	L2
06360-1612X125	stainless steel	bright	E	12	M10	29	125	15	71
06360-1614X80	stainless steel	bright	E	14	M12	29	80	16	71
06360-1614X100	stainless steel	bright	E	14	M12	29	100	16	71
06360-1614X125	stainless steel	bright	E	14	M12	29	125	16	71
06360-1614X160	stainless steel	bright	E	14	M12	29	160	16	71