

## Item description/product images



lift to  
disengage

**Description****Material:**

Handle die-cast zinc DIN EN 12844.  
Steel parts grade 5.8.

**Version:**

Handle high-gloss chromed.  
Steel parts black oxidised.


**On request:**

Other threads, screw lengths, colours and special versions.  
Dimension "H1" available in other lengths at extra charge.

**Drawing reference:**

1) flat point DIN EN ISO 4753

## Drawings

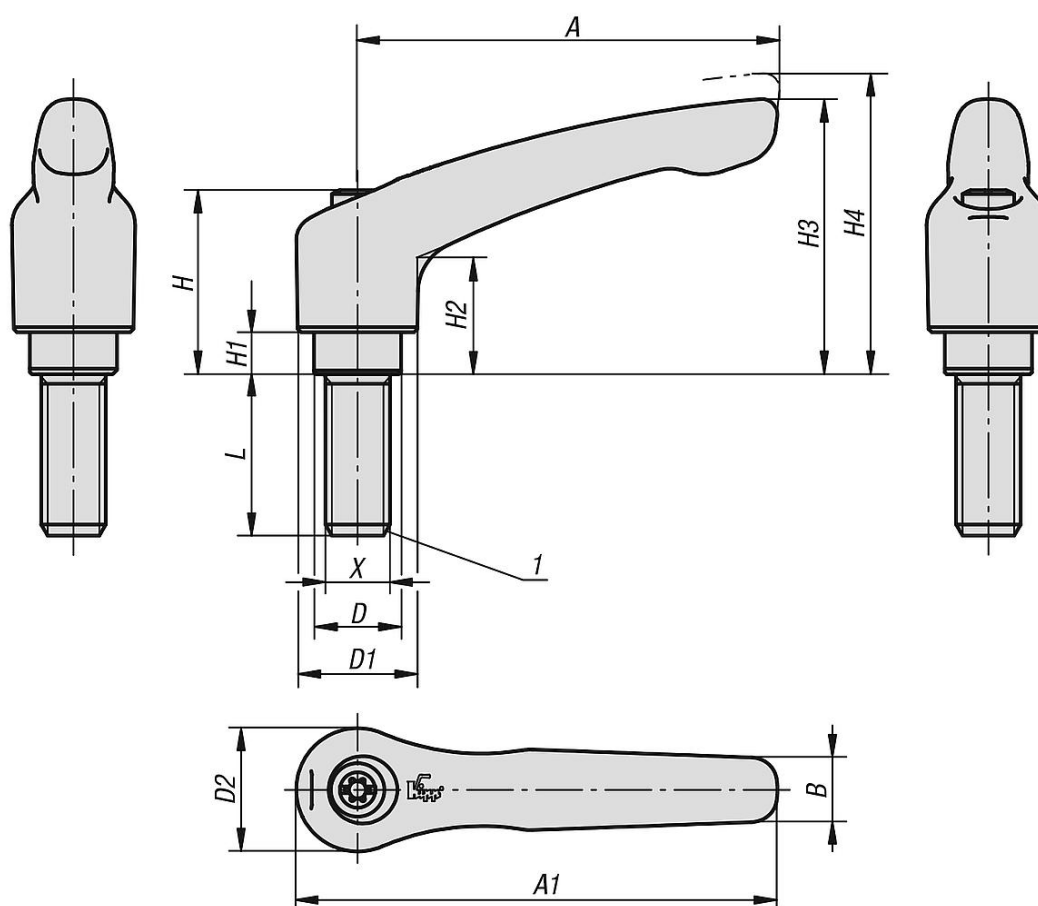

## Overview of items

| Order No.     | Main colour | Surface finish body | Size | X  | D  | D1 | D2   | H    | H1 | H2   | H3 | H4 | A  | A1   | B   | No. of teeth | L  |
|---------------|-------------|---------------------|------|----|----|----|------|------|----|------|----|----|----|------|-----|--------------|----|
| 06460-9036X6  | silver      | high-gloss chromed  | 9    | M3 | 8  | 11 | 11,5 | 21,4 | 4  | 11,9 | 24 | 27 | 22 | 27,7 | 6,4 | 12           | 6  |
| 06460-9036X10 | silver      | high-gloss chromed  | 9    | M3 | 8  | 11 | 11,5 | 21,4 | 4  | 11,9 | 24 | 27 | 22 | 27,7 | 6,4 | 12           | 10 |
| 06460-9036X15 | silver      | high-gloss chromed  | 9    | M3 | 8  | 11 | 11,5 | 21,4 | 4  | 11,9 | 24 | 27 | 22 | 27,7 | 6,4 | 12           | 15 |
| 06460-9036X20 | silver      | high-gloss chromed  | 9    | M3 | 8  | 11 | 11,5 | 21,4 | 4  | 11,9 | 24 | 27 | 22 | 27,7 | 6,4 | 12           | 20 |
| 06460-9046X10 | silver      | high-gloss chromed  | 9    | M4 | 8  | 11 | 11,5 | 21,4 | 4  | 11,9 | 24 | 27 | 22 | 27,7 | 6,4 | 12           | 10 |
| 06460-9046X15 | silver      | high-gloss chromed  | 9    | M4 | 8  | 11 | 11,5 | 21,4 | 4  | 11,9 | 24 | 27 | 22 | 27,7 | 6,4 | 12           | 15 |
| 06460-9046X20 | silver      | high-gloss chromed  | 9    | M4 | 8  | 11 | 11,5 | 21,4 | 4  | 11,9 | 24 | 27 | 22 | 27,7 | 6,4 | 12           | 20 |
| 06460-9046X25 | silver      | high-gloss chromed  | 9    | M4 | 8  | 11 | 11,5 | 21,4 | 4  | 11,9 | 24 | 27 | 22 | 27,7 | 6,4 | 12           | 25 |
| 06460-9046X30 | silver      | high-gloss chromed  | 9    | M4 | 8  | 11 | 11,5 | 21,4 | 4  | 11,9 | 24 | 27 | 22 | 27,7 | 6,4 | 12           | 30 |
| 06460-9046X35 | silver      | high-gloss chromed  | 9    | M4 | 8  | 11 | 11,5 | 21,4 | 4  | 11,9 | 24 | 27 | 22 | 27,7 | 6,4 | 12           | 35 |
| 06460-9056X10 | silver      | high-gloss chromed  | 9    | M5 | 8  | 11 | 11,5 | 21,4 | 4  | 11,9 | 24 | 27 | 22 | 27,7 | 6,4 | 12           | 10 |
| 06460-9056X15 | silver      | high-gloss chromed  | 9    | M5 | 8  | 11 | 11,5 | 21,4 | 4  | 11,9 | 24 | 27 | 22 | 27,7 | 6,4 | 12           | 15 |
| 06460-9056X20 | silver      | high-gloss chromed  | 9    | M5 | 8  | 11 | 11,5 | 21,4 | 4  | 11,9 | 24 | 27 | 22 | 27,7 | 6,4 | 12           | 20 |
| 06460-9056X25 | silver      | high-gloss chromed  | 9    | M5 | 8  | 11 | 11,5 | 21,4 | 4  | 11,9 | 24 | 27 | 22 | 27,7 | 6,4 | 12           | 25 |
| 06460-9056X30 | silver      | high-gloss chromed  | 9    | M5 | 8  | 11 | 11,5 | 21,4 | 4  | 11,9 | 24 | 27 | 22 | 27,7 | 6,4 | 12           | 30 |
| 06460-9056X35 | silver      | high-gloss chromed  | 9    | M5 | 8  | 11 | 11,5 | 21,4 | 4  | 11,9 | 24 | 27 | 22 | 27,7 | 6,4 | 12           | 35 |
| 06460-0036X6  | silver      | high-gloss chromed  | 0    | M3 | 10 | 13 | 14   | 24,5 | 4  | 14,5 | 30 | 33 | 30 | 37   | 7   | 16           | 6  |
| 06460-0036X10 | silver      | high-gloss chromed  | 0    | M3 | 10 | 13 | 14   | 24,5 | 4  | 14,5 | 30 | 33 | 30 | 37   | 7   | 16           | 10 |
| 06460-0036X15 | silver      | high-gloss chromed  | 0    | M3 | 10 | 13 | 14   | 24,5 | 4  | 14,5 | 30 | 33 | 30 | 37   | 7   | 16           | 15 |
| 06460-0036X20 | silver      | high-gloss chromed  | 0    | M3 | 10 | 13 | 14   | 24,5 | 4  | 14,5 | 30 | 33 | 30 | 37   | 7   | 16           | 20 |
| 06460-0046X10 | silver      | high-gloss chromed  | 0    | M4 | 10 | 13 | 14   | 24,5 | 4  | 14,5 | 30 | 33 | 30 | 37   | 7   | 16           | 10 |
| 06460-0046X15 | silver      | high-gloss chromed  | 0    | M4 | 10 | 13 | 14   | 24,5 | 4  | 14,5 | 30 | 33 | 30 | 37   | 7   | 16           | 15 |
| 06460-0046X20 | silver      | high-gloss chromed  | 0    | M4 | 10 | 13 | 14   | 24,5 | 4  | 14,5 | 30 | 33 | 30 | 37   | 7   | 16           | 20 |
| 06460-0046X25 | silver      | high-gloss chromed  | 0    | M4 | 10 | 13 | 14   | 24,5 | 4  | 14,5 | 30 | 33 | 30 | 37   | 7   | 16           | 25 |
| 06460-0046X30 | silver      | high-gloss chromed  | 0    | M4 | 10 | 13 | 14   | 24,5 | 4  | 14,5 | 30 | 33 | 30 | 37   | 7   | 16           | 30 |
| 06460-0046X35 | silver      | high-gloss chromed  | 0    | M4 | 10 | 13 | 14   | 24,5 | 4  | 14,5 | 30 | 33 | 30 | 37   | 7   | 16           | 35 |
| 06460-0046X40 | silver      | high-gloss chromed  | 0    | M4 | 10 | 13 | 14   | 24,5 | 4  | 14,5 | 30 | 33 | 30 | 37   | 7   | 16           | 40 |

| Order No.     | Main colour | Surface finish body | Size | X  | D  | D1 | D2 | H    | H1 | H2   | H3 | H4 | A  | A1 | B | No. of teeth | L  |
|---------------|-------------|---------------------|------|----|----|----|----|------|----|------|----|----|----|----|---|--------------|----|
| 06460-0046X45 | silver      | high-gloss chromed  | 0    | M4 | 10 | 13 | 14 | 24,5 | 4  | 14,5 | 30 | 33 | 30 | 37 | 7 | 16           | 45 |
| 06460-0046X50 | silver      | high-gloss chromed  | 0    | M4 | 10 | 13 | 14 | 24,5 | 4  | 14,5 | 30 | 33 | 30 | 37 | 7 | 16           | 50 |
| 06460-0056X10 | silver      | high-gloss chromed  | 0    | M5 | 10 | 13 | 14 | 24,5 | 4  | 14,5 | 30 | 33 | 30 | 37 | 7 | 16           | 10 |
| 06460-0056X15 | silver      | high-gloss chromed  | 0    | M5 | 10 | 13 | 14 | 24,5 | 4  | 14,5 | 30 | 33 | 30 | 37 | 7 | 16           | 15 |
| 06460-0056X20 | silver      | high-gloss chromed  | 0    | M5 | 10 | 13 | 14 | 24,5 | 4  | 14,5 | 30 | 33 | 30 | 37 | 7 | 16           | 20 |
| 06460-0056X25 | silver      | high-gloss chromed  | 0    | M5 | 10 | 13 | 14 | 24,5 | 4  | 14,5 | 30 | 33 | 30 | 37 | 7 | 16           | 25 |
| 06460-0056X30 | silver      | high-gloss chromed  | 0    | M5 | 10 | 13 | 14 | 24,5 | 4  | 14,5 | 30 | 33 | 30 | 37 | 7 | 16           | 30 |
| 06460-0056X35 | silver      | high-gloss chromed  | 0    | M5 | 10 | 13 | 14 | 24,5 | 4  | 14,5 | 30 | 33 | 30 | 37 | 7 | 16           | 35 |
| 06460-0056X40 | silver      | high-gloss chromed  | 0    | M5 | 10 | 13 | 14 | 24,5 | 4  | 14,5 | 30 | 33 | 30 | 37 | 7 | 16           | 40 |
| 06460-0056X45 | silver      | high-gloss chromed  | 0    | M5 | 10 | 13 | 14 | 24,5 | 4  | 14,5 | 30 | 33 | 30 | 37 | 7 | 16           | 45 |
| 06460-0056X50 | silver      | high-gloss chromed  | 0    | M5 | 10 | 13 | 14 | 24,5 | 4  | 14,5 | 30 | 33 | 30 | 37 | 7 | 16           | 50 |
| 06460-1056X10 | silver      | high-gloss chromed  | 1    | M5 | 10 | 13 | 14 | 24,5 | 4  | 14,5 | 31 | 34 | 40 | 47 | 7 | 16           | 10 |
| 06460-1056X15 | silver      | high-gloss chromed  | 1    | M5 | 10 | 13 | 14 | 24,5 | 4  | 14,5 | 31 | 34 | 40 | 47 | 7 | 16           | 15 |
| 06460-1056X20 | silver      | high-gloss chromed  | 1    | M5 | 10 | 13 | 14 | 24,5 | 4  | 14,5 | 31 | 34 | 40 | 47 | 7 | 16           | 20 |
| 06460-1056X25 | silver      | high-gloss chromed  | 1    | M5 | 10 | 13 | 14 | 24,5 | 4  | 14,5 | 31 | 34 | 40 | 47 | 7 | 16           | 25 |
| 06460-1056X30 | silver      | high-gloss chromed  | 1    | M5 | 10 | 13 | 14 | 24,5 | 4  | 14,5 | 31 | 34 | 40 | 47 | 7 | 16           | 30 |
| 06460-1056X35 | silver      | high-gloss chromed  | 1    | M5 | 10 | 13 | 14 | 24,5 | 4  | 14,5 | 31 | 34 | 40 | 47 | 7 | 16           | 35 |
| 06460-1056X40 | silver      | high-gloss chromed  | 1    | M5 | 10 | 13 | 14 | 24,5 | 4  | 14,5 | 31 | 34 | 40 | 47 | 7 | 16           | 40 |
| 06460-1056X45 | silver      | high-gloss chromed  | 1    | M5 | 10 | 13 | 14 | 24,5 | 4  | 14,5 | 31 | 34 | 40 | 47 | 7 | 16           | 45 |
| 06460-1056X50 | silver      | high-gloss chromed  | 1    | M5 | 10 | 13 | 14 | 24,5 | 4  | 14,5 | 31 | 34 | 40 | 47 | 7 | 16           | 50 |
| 06460-1066X10 | silver      | high-gloss chromed  | 1    | M6 | 10 | 13 | 14 | 24,5 | 4  | 14,5 | 31 | 34 | 40 | 47 | 7 | 16           | 10 |
| 06460-1066X15 | silver      | high-gloss chromed  | 1    | M6 | 10 | 13 | 14 | 24,5 | 4  | 14,5 | 31 | 34 | 40 | 47 | 7 | 16           | 15 |
| 06460-1066X20 | silver      | high-gloss chromed  | 1    | M6 | 10 | 13 | 14 | 24,5 | 4  | 14,5 | 31 | 34 | 40 | 47 | 7 | 16           | 20 |
| 06460-1066X25 | silver      | high-gloss chromed  | 1    | M6 | 10 | 13 | 14 | 24,5 | 4  | 14,5 | 31 | 34 | 40 | 47 | 7 | 16           | 25 |
| 06460-1066X30 | silver      | high-gloss chromed  | 1    | M6 | 10 | 13 | 14 | 24,5 | 4  | 14,5 | 31 | 34 | 40 | 47 | 7 | 16           | 30 |
| 06460-1066X35 | silver      | high-gloss chromed  | 1    | M6 | 10 | 13 | 14 | 24,5 | 4  | 14,5 | 31 | 34 | 40 | 47 | 7 | 16           | 35 |
| 06460-1066X40 | silver      | high-gloss chromed  | 1    | M6 | 10 | 13 | 14 | 24,5 | 4  | 14,5 | 31 | 34 | 40 | 47 | 7 | 16           | 40 |
| 06460-1066X45 | silver      | high-gloss chromed  | 1    | M6 | 10 | 13 | 14 | 24,5 | 4  | 14,5 | 31 | 34 | 40 | 47 |   |              |    |

## Overview of items

| Order No.     | Main colour | Surface finish body | Size | X   | D  | D1 | D2   | H  | H1 | H2   | H3   | H4   | A   | A1  | B  | No. of teeth | L  |
|---------------|-------------|---------------------|------|-----|----|----|------|----|----|------|------|------|-----|-----|----|--------------|----|
| 06460-3086X45 | silver      | high-gloss chromed  | 3    | M8  | 16 | 21 | 22   | 37 | 10 | 24   | 54,5 | 58,5 | 80  | 91  | 11 | 22           | 45 |
| 06460-3086X50 | silver      | high-gloss chromed  | 3    | M8  | 16 | 21 | 22   | 37 | 10 | 24   | 54,5 | 58,5 | 80  | 91  | 11 | 22           | 50 |
| 06460-3086X55 | silver      | high-gloss chromed  | 3    | M8  | 16 | 21 | 22   | 37 | 10 | 24   | 54,5 | 58,5 | 80  | 91  | 11 | 22           | 55 |
| 06460-3086X60 | silver      | high-gloss chromed  | 3    | M8  | 16 | 21 | 22   | 37 | 10 | 24   | 54,5 | 58,5 | 80  | 91  | 11 | 22           | 60 |
| 06460-3106X15 | silver      | high-gloss chromed  | 3    | M10 | 16 | 21 | 22   | 37 | 10 | 24   | 54,5 | 58,5 | 80  | 91  | 11 | 22           | 15 |
| 06460-3106X20 | silver      | high-gloss chromed  | 3    | M10 | 16 | 21 | 22   | 37 | 10 | 24   | 54,5 | 58,5 | 80  | 91  | 11 | 22           | 20 |
| 06460-3106X25 | silver      | high-gloss chromed  | 3    | M10 | 16 | 21 | 22   | 37 | 10 | 24   | 54,5 | 58,5 | 80  | 91  | 11 | 22           | 25 |
| 06460-3106X30 | silver      | high-gloss chromed  | 3    | M10 | 16 | 21 | 22   | 37 | 10 | 24   | 54,5 | 58,5 | 80  | 91  | 11 | 22           | 30 |
| 06460-3106X35 | silver      | high-gloss chromed  | 3    | M10 | 16 | 21 | 22   | 37 | 10 | 24   | 54,5 | 58,5 | 80  | 91  | 11 | 22           | 35 |
| 06460-3106X40 | silver      | high-gloss chromed  | 3    | M10 | 16 | 21 | 22   | 37 | 10 | 24   | 54,5 | 58,5 | 80  | 91  | 11 | 22           | 40 |
| 06460-3106X45 | silver      | high-gloss chromed  | 3    | M10 | 16 | 21 | 22   | 37 | 10 | 24   | 54,5 | 58,5 | 80  | 91  | 11 | 22           | 45 |
| 06460-3106X50 | silver      | high-gloss chromed  | 3    | M10 | 16 | 21 | 22   | 37 | 10 | 24   | 54,5 | 58,5 | 80  | 91  | 11 | 22           | 50 |
| 06460-3106X55 | silver      | high-gloss chromed  | 3    | M10 | 16 | 21 | 22   | 37 | 10 | 24   | 54,5 | 58,5 | 80  | 91  | 11 | 22           | 55 |
| 06460-3106X60 | silver      | high-gloss chromed  | 3    | M10 | 16 | 21 | 22   | 37 | 10 | 24   | 54,5 | 58,5 | 80  | 91  | 11 | 22           | 60 |
| 06460-4106X20 | silver      | high-gloss chromed  | 4    | M10 | 19 | 27 | 27,5 | 43 | 10 | 27   | 63   | 67,5 | 95  | 109 | 13 | 24           | 20 |
| 06460-4106X25 | silver      | high-gloss chromed  | 4    | M10 | 19 | 27 | 27,5 | 43 | 10 | 27   | 63   | 67,5 | 95  | 109 | 13 | 24           | 25 |
| 06460-4106X30 | silver      | high-gloss chromed  | 4    | M10 | 19 | 27 | 27,5 | 43 | 10 | 27   | 63   | 67,5 | 95  | 109 | 13 | 24           | 30 |
| 06460-4106X35 | silver      | high-gloss chromed  | 4    | M10 | 19 | 27 | 27,5 | 43 | 10 | 27   | 63   | 67,5 | 95  | 109 | 13 | 24           | 35 |
| 06460-4106X40 | silver      | high-gloss chromed  | 4    | M10 | 19 | 27 | 27,5 | 43 | 10 | 27   | 63   | 67,5 | 95  | 109 | 13 | 24           | 40 |
| 06460-4106X45 | silver      | high-gloss chromed  | 4    | M10 | 19 | 27 | 27,5 | 43 | 10 | 27   | 63   | 67,5 | 95  | 109 | 13 | 24           | 45 |
| 06460-4106X50 | silver      | high-gloss chromed  | 4    | M10 | 19 | 27 | 27,5 | 43 | 10 | 27   | 63   | 67,5 | 95  | 109 | 13 | 24           | 50 |
| 06460-4106X55 | silver      | high-gloss chromed  | 4    | M10 | 19 | 27 | 27,5 | 43 | 10 | 27   | 63   | 67,5 | 95  | 109 | 13 | 24           | 55 |
| 06460-4106X60 | silver      | high-gloss chromed  | 4    | M10 | 19 | 27 | 27,5 | 43 | 10 | 27   | 63   | 67,5 | 95  | 109 | 13 | 24           | 60 |
| 06460-4106X70 | silver      | high-gloss chromed  | 4    | M10 | 19 | 27 | 27,5 | 43 | 10 | 27   | 63   | 67,5 | 95  | 109 | 13 | 24           | 70 |
| 06460-4106X80 | silver      | high-gloss chromed  | 4    | M10 | 19 | 27 | 27,5 | 43 | 10 | 27   | 63   | 67,5 | 95  | 109 | 13 | 24           | 80 |
| 06460-4106X90 | silver      | high-gloss chromed  | 4    | M10 | 19 | 27 | 27,5 | 43 | 10 | 27   | 63   | 67,5 | 95  | 109 | 13 | 24           | 90 |
| 06460-4126X20 | silver      | high-gloss chromed  | 4    | M12 | 19 | 27 | 27,5 | 43 | 10 | 27   | 63   | 67,5 | 95  | 109 | 13 | 24           | 20 |
| 06460-4126X25 | silver      | high-gloss chromed  | 4    | M12 | 19 | 27 | 27,5 | 43 | 10 | 27   | 63   | 67,5 | 95  | 109 | 13 | 24           | 25 |
| 06460-4126X30 | silver      | high-gloss chromed  | 4    | M12 | 19 | 27 | 27,5 | 43 | 10 | 27   | 63   | 67,5 | 95  | 109 | 13 | 24           | 30 |
| 06460-4126X35 | silver      | high-gloss chromed  | 4    | M12 | 19 | 27 | 27,5 | 43 | 10 | 27   | 63   | 67,5 | 95  | 109 | 13 | 24           | 35 |
| 06460-4126X40 | silver      | high-gloss chromed  | 4    | M12 | 19 | 27 | 27,5 | 43 | 10 | 27   | 63   | 67,5 | 95  | 109 | 13 | 24           | 40 |
| 06460-4126X45 | silver      | high-gloss chromed  | 4    | M12 | 19 | 27 | 27,5 | 43 | 10 | 27   | 63   | 67,5 | 95  | 109 | 13 | 24           | 45 |
| 06460-4126X50 | silver      | high-gloss chromed  | 4    | M12 | 19 | 27 | 27,5 | 43 | 10 | 27   | 63   | 67,5 | 95  | 109 | 13 | 24           | 50 |
| 06460-4126X55 | silver      | high-gloss chromed  | 4    | M12 | 19 | 27 | 27,5 | 43 | 10 | 27   | 63   | 67,5 | 95  | 109 | 13 | 24           | 55 |
| 06460-4126X60 | silver      | high-gloss chromed  | 4    | M12 | 19 | 27 | 27,5 | 43 | 10 | 27   | 63   | 67,5 | 95  | 109 | 13 | 24           | 60 |
| 06460-4126X70 | silver      | high-gloss chromed  | 4    | M12 | 19 | 27 | 27,5 | 43 | 10 | 27   | 63   | 67,5 | 95  | 109 | 13 | 24           | 70 |
| 06460-4126X80 | silver      | high-gloss chromed  | 4    | M12 | 19 | 27 | 27,5 | 43 | 10 | 27   | 63   | 67,5 | 95  | 109 | 13 | 24           | 80 |
| 06460-4126X90 | silver      | high-gloss chromed  | 4    | M12 | 19 | 27 | 27,5 | 43 | 10 | 27   | 63   | 67,5 | 95  | 109 | 13 | 24           | 90 |
| 06460-5126X25 | silver      | high-gloss chromed  | 5    | M12 | 23 | 31 | 32   | 49 | 12 | 31,5 | 73   | 77,5 | 110 | 126 | 15 | 26           | 25 |
| 06460-5126X30 | silver      | high-gloss chromed  | 5    | M12 | 23 | 31 | 32   | 49 | 12 | 31,5 | 73   | 77,5 | 110 | 126 | 15 | 26           | 30 |
| 06460-5126X35 | silver      | high-gloss chromed  | 5    | M12 | 23 | 31 | 32   | 49 | 12 | 31,5 | 73   | 77,5 | 110 | 126 | 15 | 26           | 35 |
| 06460-5126X40 | silver      | high-gloss chromed  | 5    | M12 | 23 | 31 | 32   | 49 | 12 | 31,5 | 73   | 77,5 | 110 | 126 | 15 | 26           | 40 |
| 06460-5126X45 | silver      | high-gloss chromed  | 5    | M12 | 23 | 31 | 32   | 49 | 12 | 31,5 | 73   | 77,5 | 110 | 126 | 15 | 26           | 45 |
| 06460-5126X50 | silver      | high-gloss chromed  | 5    | M12 | 23 | 31 | 32   | 49 | 12 | 31,5 | 73   | 77,5 | 110 | 126 | 15 | 26           | 50 |
| 06460-5126X55 | silver      | high-gloss chromed  | 5    | M12 | 23 | 31 | 32   | 49 | 12 | 31,5 | 73   | 77,5 | 110 | 126 | 15 | 26           | 55 |
| 06460-5126X60 | silver      | high-gloss chromed  | 5    | M12 | 23 | 31 | 32   | 49 | 12 | 31,5 | 73   | 77,5 | 110 | 126 | 15 | 26           | 60 |
| 06460-5126X70 | silver      | high-gloss chromed  | 5    | M12 | 23 | 31 | 32   | 49 | 12 | 31,5 | 73   | 77,5 | 110 | 126 | 15 | 26           | 70 |
| 06460-5126X80 | silver      | high-gloss chromed  | 5    | M12 | 23 | 31 | 32   | 49 | 12 | 31,5 | 73   | 77,5 | 110 | 126 | 15 | 26           | 80 |
| 06460-5126X90 | silver      | high-gloss chromed  | 5    | M12 | 23 | 31 | 32   | 49 | 12 | 31,5 | 73   | 77,5 | 110 | 126 | 15 | 26           | 90 |
| 06460-5166X25 | silver      | high-gloss chromed  | 5    | M16 | 23 | 31 | 32   | 49 | 12 | 31,5 | 73   | 77,5 | 110 | 126 | 15 | 26           | 25 |
| 06460-5166X30 | silver      | high-gloss chromed  | 5    | M16 | 23 | 31 | 32   | 49 | 12 | 31,5 | 73   | 77,5 | 110 | 126 | 15 | 26           | 30 |
| 06460-5166X35 | silver      | high-gloss chromed  | 5    | M16 | 23 | 31 | 32   | 49 | 12 | 31,5 | 73   | 77,5 | 110 | 126 | 15 | 26           | 35 |
| 06460-5166X40 | silver      | high-gloss chromed  | 5    | M16 | 23 | 31 | 32   | 49 | 12 | 31,5 | 73   | 77,5 | 110 | 126 | 15 | 26           | 40 |
| 06460-5166X45 | silver      | high-gloss chromed  | 5    | M16 | 23 | 31 | 32   | 49 | 12 | 31,5 | 73   | 77,5 | 110 | 126 | 15 | 26           | 45 |
| 06460-5166X50 | silver      | high-gloss chromed  | 5    | M16 | 23 | 31 | 32   | 49 | 12 | 31,5 | 73   | 77,5 | 110 | 126 | 15 | 26           | 50 |
| 06460-5166X55 | silver      | high-gloss chromed  | 5    | M16 | 23 | 31 | 32   | 49 | 12 | 31,5 | 73   | 77,5 | 110 | 126 | 15 | 26           | 55 |
| 06460-5166X60 | silver      | high-gloss chromed  | 5    | M16 | 23 | 31 | 32   | 49 | 12 | 31,5 | 73   | 77,5 | 110 | 126 | 15 | 26           | 60 |
| 06460-5166X70 | silver      | high-gloss chromed  | 5    | M16 | 23 | 31 | 32   | 49 | 12 | 31,5 | 73   | 77,5 | 110 | 126 | 15 | 26           | 70 |
| 06460-5166X80 | silver      | high-gloss chromed  | 5    | M16 | 23 | 31 | 32   | 49 | 12 | 31,5 | 73   | 77,5 | 110 | 126 | 15 | 26           | 80 |
| 06460-5166X90 | silver      | high-gloss chromed  | 5    | M16 | 23 | 31 | 32   | 49 | 12 | 31,5 | 73   | 77,5 | 110 | 126 | 15 | 26           | 90 |

