

Item description/product images



Description

Material:

Torque arm stainless steel

Mounting adapter stainless steel.

Note:

The mounting sets are required to connect the actuators 85000-50 to the linear actuators 29105, the double-tube linear actuators 21250 and 21250-01 or the square linear actuator 29104.

Accessory:

Stainless steel or aluminium actuators for linear actuators 85000-50.

Linear actuator 29105.


Stainless steel linear actuators 29105.

Double-tube linear actuators 21250.

Double-tube linear actuator with mounting bracket 21250-01.

Aluminium square linear actuators 29104.

Drawings

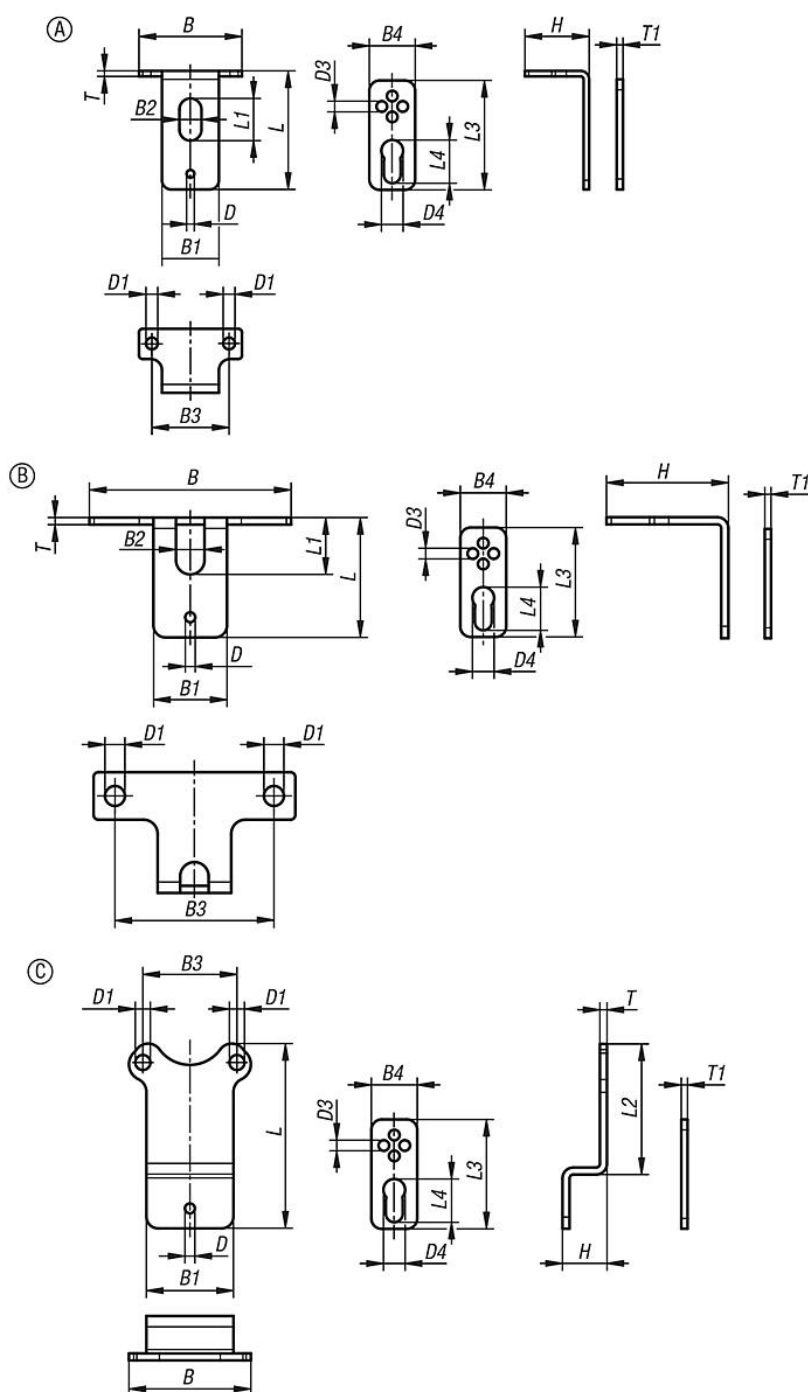

Overview of items

Order No.	Form	Version 1	Type E	Typ EP/EPX	Typ EV	B	B1	B2	B3	B4	D	D1	D2	D3
85000-51-040	A	for linear actuator	40	-	-	68	31	12	54	22	M5	6,4	5	10,4
85000-51-030	A	for linear actuator	30	-	-	56	31	12	42	22	M5	6,4	5	10,4
85000-51-230	A	for square linear actuator	-	-	30	56	31	12	42	22	M5	6,4	5	10,4
85000-51-240	A	for square linear actuator	-	-	40	68	31	12	54	22	M5	6,4	5	10,4
85000-51-050	B	for linear actuator	50	-	-	85	31	12	67	22	M5	8,2	5	10,4
85000-51-250	B	for square linear actuator	-	-	50	85	31	12	67	22	M5	8,2	5	10,4
85000-51-130	C	for double-tube linear actuator	-	30	-	52	37	-	40	22	M5	6,4	5	10,4
85000-51-140	C	for double-tube linear actuator	-	40	-	61	37	-	46	22	M5	8,4	5	10,4

Overview of items

Order No.	Form	Version 1	Type E	Typ EP/EPX	Typ EV	H	L	L1	L2	L3	L4	T1
85000-51-040	A	for linear actuator	40	-	-	47,4	57,6	23	-	52,5	20,9	3
85000-51-030	A	for linear actuator	30	-	-	34,9	64,5	23	-	52,5	20,9	3
85000-51-230	A	for square linear actuator	-	-	30	34,9	64,5	23	-	52,5	20,9	3
85000-51-240	A	for square linear actuator	-	-	40	34,9	57,6	23	-	52,5	20,9	3
85000-51-050	B	for linear actuator	50	-	-	50,9	50,5	24	-	52,5	20,9	3
85000-51-250	B	for square linear actuator	-	-	50	50,9	50,5	24	-	52,5	20,9	3
85000-51-130	C	for double-tube linear actuator	-	30	-	18,9	78,6	-	55,6	52,5	20,9	3
85000-51-140	C	for double-tube linear actuator	-	40	-	31	71	-	48	52,5	20,9	3