


Item description/product images

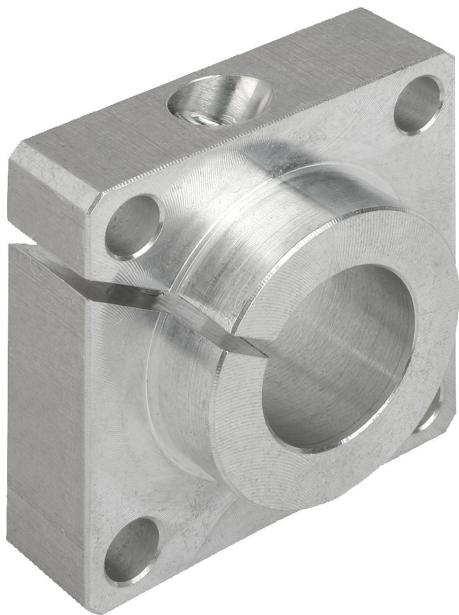

Description



Material:
Aluminium.

Version:
Bright.

Note:
Flanged shaft support with standard bores for easy and secure clamping and fastening the guide shafts.

Accessory:
Precision guide shafts 21595.
Fastening screws 07160 or 07161.

Drawings

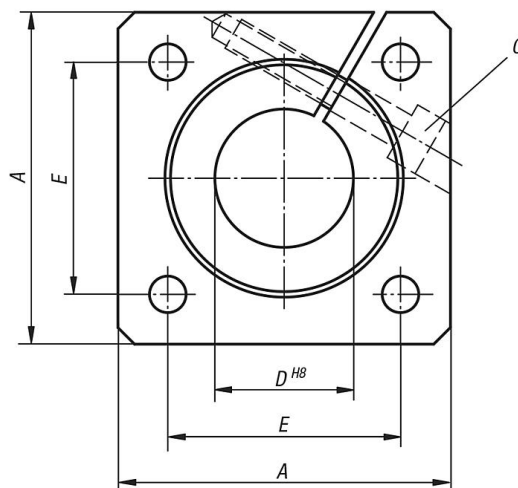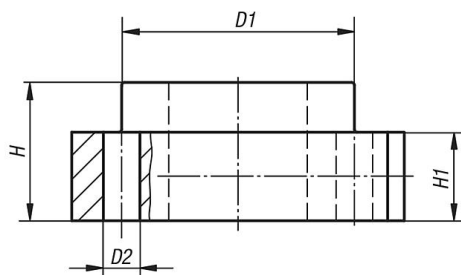

Overview of items

Order No.	A	D	D1	D2	E	H	H1	C (DIN 912)
21585-12	40	12	23,5	5,5	$30 \pm 0,12$	20	12	M4
21585-20	50	20	33,5	6,6	$38 \pm 0,15$	23	14	M5

Overview of items

Order No.	A	D	D1	D2	E	H	H1	C (DIN 912)
21585-25	60	25	42	6,6	42 ±0,15	25	16	M6
21585-16	50	16	27,5	5,5	35 ±0,12	20	12	M4
21585-30	70	30	49,5	9	54 ±0,25	30	19	M8
21585-40	100	40	65	11	68 ±0,25	40	26	M10
21585-50	100	50	75	11	75 ±0,25	50	36	M10