


## Item description/product images

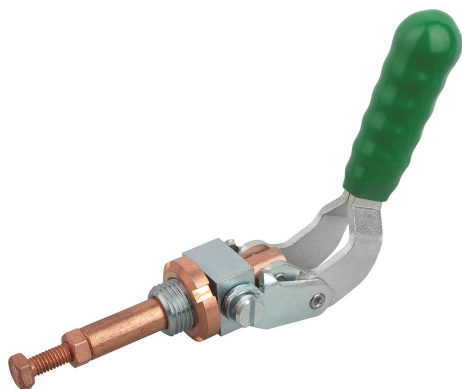

## Description

**Material:**

Body and push-rod 1.0501 carbon steel.

Lever parts steel plate DD11 1.0332.

**Note:**

The clamp can be mounted with a bracket or into fixtures using the front screw.

## Overview of items

| Order No. | L  | L1  | L2 | L3 | L4 | L5 | L6  | L7 | L8 | H   | H1 | H2 | M=clamping spindle | D1 | D2      | S1 | Travel<br>S | F<br>kN | Plastic<br>grips |
|-----------|----|-----|----|----|----|----|-----|----|----|-----|----|----|--------------------|----|---------|----|-------------|---------|------------------|
| 05170-010 | 26 | 52  | 42 | 34 | 13 | 15 | 130 | 18 | 20 | 101 | 20 | 20 | M6x30              | 10 | M16x1,5 | 6  | 26          | 1       | 05200-205        |
| 05170-012 | 32 | 75  | 60 | 50 | 20 | 18 | 170 | 30 | 30 | 139 | 25 | 28 | M8x40              | 12 | M20x1,5 | 8  | 40          | 1,5     | 05200-120        |
| 05170-016 | 40 | 105 | 92 | 78 | 35 | 20 | 213 | 60 | 35 | 155 | 32 | 44 | M10x50             | 16 | M27x1,5 | 8  | 70          | 3,5     | 05200-135        |