

Item description/product images



Description

Material:

Grip 1.4301 stainless steel.

Housing and nut 1.4305 stainless steel.

Version:

Bright.

Note:

Quarter-turn lock with T-grip. For right or left mounting with 90° closing. The quarter-turn lock can be installed pre-assembled. Supplied with standard stainless-steel nut. The lockable quarter-turn lock is supplied with 2 keys. The key can be removed in both the closed and open position. The cylinder locks have a single-key system i.e. the same key works in all locks (lock type 1333).

Rating IP65.

Order the desired tongue separately. Every tongue can be combined with this housing.


*Dimension A results from the combination of the quarter turn lock and the tongue and is specified with the matching tongues.

Accessory:

Tongue for stainless steel quarter-turn lock 05569.

Key for quarter-turn lock 05586.

Drawings

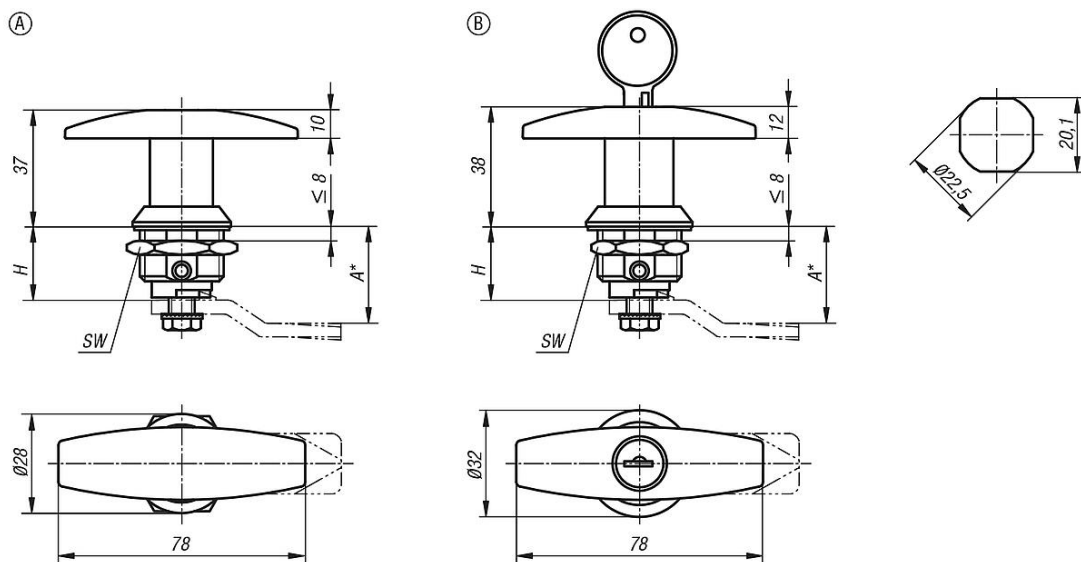

Overview of items

| Order No. | Form | Actuation | H | SW |
|------------|------|-----------------|----|----|
| 05593-1186 | A | T-Grip | 18 | 27 |
| 05593-2186 | B | lockable T-grip | 18 | 27 |

