


## Item description/product images

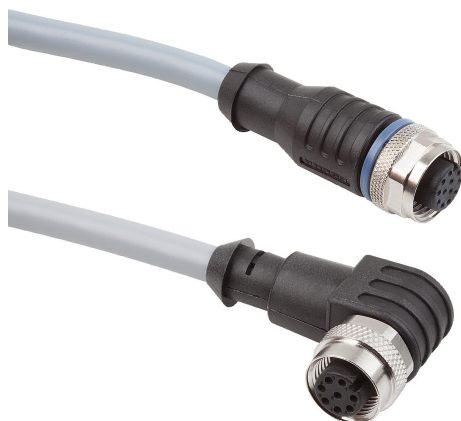

## Description

**Material:**

Cable sheath and housing PVC.

**Version:**

Bush (female)  
 Voltage: Ue 30 V  
 Current: Ie 2 A  
 No. of pins: 8  
 No. of wires: 8  
 Rating: IP 67  
 Grip body: black  
 Cable: grey

**Note:**



Connector with screw lock.  
 Connector moulded to cable.  
 Wires colour coded acc. to DIN 47100.  
 Coding A.  
 Limited dragchain compatibility.  
 Recommended tightening torque: 1.0 Nm.

**Temperature range:**



Moving: 0 °C to +80 °C  
 Fixed: -25 °C to +80 °C

**Drawing reference:**

- 1) White (WH)
- 2) Brown (BN)
- 3) Green (GN)
- 4) Yellow (YE)
- 5) Grey (GY)
- 6) Pink (PK)
- 7) Blue (BU)
- 8) Red (RD)

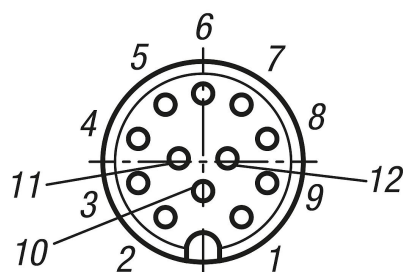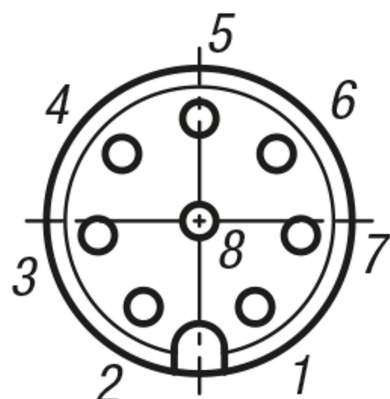

## Drawings

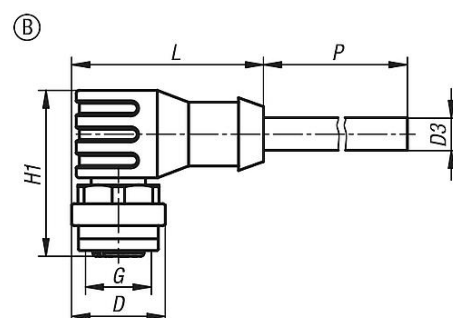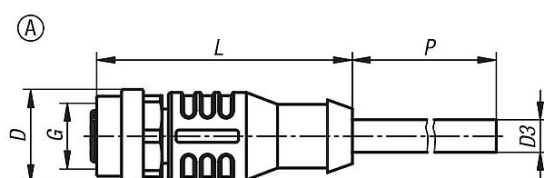

## Overview of items

| Order No.          | Form | Version 2 | D    | D3 | G | H1 | L    | P    |
|--------------------|------|-----------|------|----|---|----|------|------|
| 80150-10-1208X2500 | A    | 8-pin     | 14,5 | 6  | - | -  | 41,5 | 2500 |

## Overview of items

| Order No.            | Form | Version 2 | D    | D3 | G     | H1   | L    | P     |
|----------------------|------|-----------|------|----|-------|------|------|-------|
| 80150-10-1208X5000   | A    | 8-pin     | 14,5 | 6  | -     | -    | 41,5 | 5000  |
| 80150-10-1208X10000  | A    | 8-pin     | 14,5 | 6  | -     | -    | 41,5 | 10000 |
| 80150-10-1212X10000  | A    | 12-pin    | 15   | 6  | M12x1 | -    | 41,9 | 10000 |
| 80150-10-11208X10000 | B    | 8-pin     | 15   | 6  | M12x1 | 26,4 | 39   | 10000 |
| 80150-10-11212X10000 | B    | 12-pin    | 15   | 6  | M12x1 | 26,4 | 39   | 10000 |