


Item description/product images

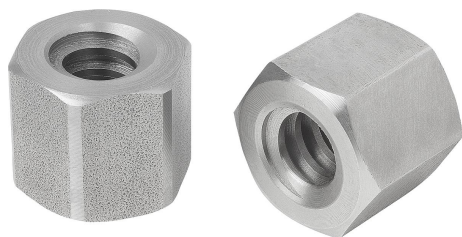

Description

Material:

Steel C35Pb.
Stainless steel 1.4305.

Version:

Bright.


Note:

ISO trapezoidal thread according to DIN 103.

for adjustments during manual operation and as fastening nuts. Not advisable for use with motorised drives due to the steel/steel material pairing.

Tolerance class 7H.

Drawings

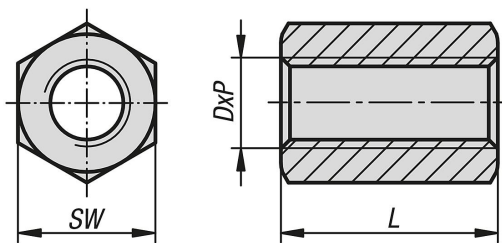

Overview of items

Order No.	Version 1	Main material	DxP	L	SW
24007-100211	RH thread	steel	Tr 10x2	15	17
24007-100311	RH thread	steel	Tr 10x3	15	17
24007-120311	RH thread	steel	Tr 12x3	18	19
24007-140311	RH thread	steel	Tr 14x3	21	22
24007-140411	RH thread	steel	Tr 14x4	21	22
24007-160411	RH thread	steel	Tr 16x4	24	27
24007-180411	RH thread	steel	Tr 18x4	27	27
24007-200411	RH thread	steel	Tr 20x4	30	30
24007-240511	RH thread	steel	Tr 24x5	36	36
24007-260511	RH thread	steel	Tr 26x5	39	36
24007-280511	RH thread	steel	Tr 28x5	42	41
24007-300611	RH thread	steel	Tr 30x6	45	46
24007-320611	RH thread	steel	Tr 32x6	48	46
24007-360611	RH thread	steel	Tr 36x6	54	55
24007-400711	RH thread	steel	Tr 40x7	60	65
24007-440711	RH thread	steel	Tr 44x7	66	65
24007-500811	RH thread	steel	Tr 50x8	75	75
24007-100212	RH thread	stainless steel	Tr 10x2	15	17
24007-100312	RH thread	stainless steel	Tr 10x3	15	17
24007-120312	RH thread	stainless steel	Tr 12x3	18	19
24007-140312	RH thread	stainless steel	Tr 14x3	21	22
24007-140412	RH thread	stainless steel	Tr 14x4	21	22
24007-160412	RH thread	stainless steel	Tr 16x4	24	27
24007-180412	RH thread	stainless steel	Tr 18x4	27	27
24007-200412	RH thread	stainless steel	Tr 20x4	30	30
24007-240512	RH thread	stainless steel	Tr 24x5	36	36
24007-260512	RH thread	stainless steel	Tr 26x5	39	36
24007-280512	RH thread	stainless steel	Tr 28x5	42	46

Overview of items

Order No.	Version 1	Main material	DxP	L	SW
24007-300612	RH thread	stainless steel	Tr 30x6	45	46
24007-320612	RH thread	stainless steel	Tr 32x6	48	46
24007-360612	RH thread	stainless steel	Tr 36x6	54	55
24007-400712	RH thread	stainless steel	Tr 40x7	60	65
24007-440712	RH thread	stainless steel	Tr 44x7	66	65
24007-500812	RH thread	stainless steel	Tr 50x8	75	75
24007-100221	LH thread	steel	Tr 10x2	15	17
24007-100321	LH thread	steel	Tr 10x3	15	17
24007-120321	LH thread	steel	Tr 12x3	18	19
24007-140321	LH thread	steel	Tr 14x3	21	22
24007-140421	LH thread	steel	Tr 14x4	21	22
24007-160421	LH thread	steel	Tr 16x4	24	27
24007-180421	LH thread	steel	Tr 18x4	27	27
24007-200421	LH thread	steel	Tr 20x4	30	30
24007-240521	LH thread	steel	Tr 24x5	36	36
24007-260521	LH thread	steel	Tr 26x5	39	36
24007-280521	LH thread	steel	Tr 28x5	42	41
24007-300621	LH thread	steel	Tr 30x6	45	46
24007-320621	LH thread	steel	Tr 32x6	48	46
24007-360621	LH thread	steel	Tr 36x6	54	55
24007-400721	LH thread	steel	Tr 40x7	60	65
24007-440721	LH thread	steel	Tr 44x7	66	65
24007-500821	LH thread	steel	Tr 50x8	75	75
24007-100222	LH thread	stainless steel	Tr 10x2	15	17
24007-100322	LH thread	stainless steel	Tr 10x3	15	17
24007-120322	LH thread	stainless steel	Tr 12x3	18	19
24007-140322	LH thread	stainless steel	Tr 14x3	21	22
24007-140422	LH thread	stainless steel	Tr 14x4	21	22
24007-160422	LH thread	stainless steel	Tr 16x4	24	27
24007-180422	LH thread	stainless steel	Tr 18x4	27	27
24007-200422	LH thread	stainless steel	Tr 20x4	30	30
24007-240522	LH thread	stainless steel	Tr 24x5	36	36
24007-260522	LH thread	stainless steel	Tr 26x5	39	36
24007-280522	LH thread	stainless steel	Tr 28x5	42	46
24007-300622	LH thread	stainless steel	Tr 30x6	45	46
24007-320622	LH thread	stainless steel	Tr 32x6	48	46
24007-360622	LH thread	stainless steel	Tr 36x6	54	55
24007-400722	LH thread	stainless steel	Tr 40x7	60	65
24007-440722	LH thread	stainless steel	Tr 44x7	66	65
24007-500822	LH thread	stainless steel	Tr 50x8	75	75