

Item description/product images



Description

Material:

Steel.

Version:

Pre-stretched.

Note for ordering:

Packaging unit: 5 metres with odd number of links. Ending with an inner link at both ends. Connecting links must be ordered separately.

Note:

European-type roller chains acc. to DIN ISO 606 with curved link plates (ISO No. 06 with straight links). All chains are pre-stretched. Initial lubrication: anti-corrosion mineral based oil.


$B7$ = maximum value for links.

Pitch = $P \times B1$

Temperature range:

-20°C to +120°C.

Drawings

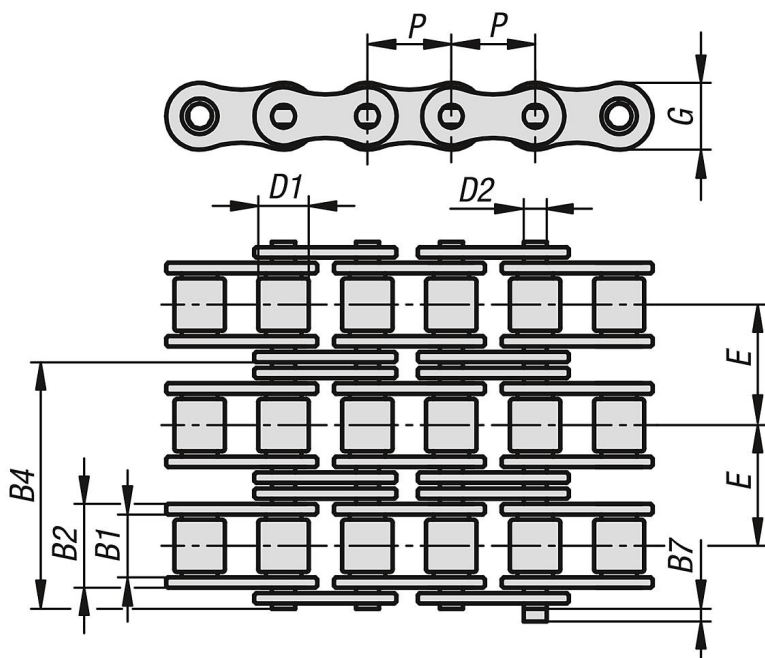

Overview of items

Order No.	ISO No.	Pitch inch	Pitch mm	B2	B4	B7	D1	D2	E	G	~L	No. of links	Break force F min. kN
22202-0380732525	06 B-3	3/8X7/32	9,525 x 5,72	8,53	34	3,3	6,35	3,28	10,24	8,26	~5000	525	24,9
22202-0120516393	08 B-3	1/2X5/16	12,7 x 7,75	11,3	44,9	3,9	8,51	4,45	13,92	11,81	~5000	393	44,5
22202-0580308315	10 B-3	5/8X3/8	15,875 x 9,65	13,28	52,8	4,1	10,16	5,08	16,59	14,73	~5000	315	66,7
22202-0340716263	12 B-3	3/4X7/16	19,05 x 11,68	15,62	61,7	4,6	12,07	5,72	19,46	16,13	~5000	263	86,7
22202-1001702197	16 B-3	1X17,02mm	25,4 x 17,02	25,45	99,9	5,4	15,88	8,28	31,88	21,08	~5000	197	160