

Item description/product images

**Description****Material:**

Adapter plate steel.

Wedges steel 1.0715 or stainless steel 1.4305.

Version:

Adapter plate electro zinc-plated.


Wedges black oxidised or blank.

Note:

The adapter plates enable the toggle clamp to be compatible with hole pattern 3 or 4, for hole grid plates or plates with $\varnothing 16$ mm, $\varnothing 20$ mm or $\varnothing 28$ mm holes.

The clamping pin parts lock in the hole when the cap screw is turned.

Drawings

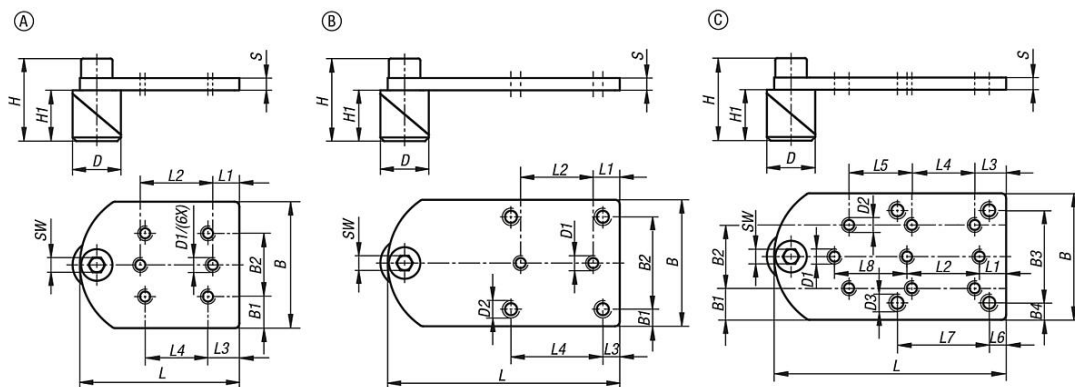

Overview of items

| Order No. | Form | Main material | B | B1 | B2 | B3 | B4 | D | D1 | D2 | D3 | H | H1 | L | L1 | L2 | L3 | L4 | L5 | L6 | L7 | L8 | S | SW |
|------------|------|-----------------|----|----|----|----|----|----|----|----|----|------|------|----|----|----|----|----|----|----|----|----|---|----|
| 04756-0016 | A | steel | 52 | 13 | 26 | - | - | 16 | M5 | - | - | 30,5 | 17,5 | 66 | 11 | 30 | 13 | 26 | - | - | - | - | 5 | 6 |
| 04756-1020 | A | stainless steel | 52 | 13 | 26 | - | - | 20 | M5 | - | - | 34 | 21 | 66 | 11 | 30 | 13 | 26 | - | - | - | - | 5 | 6 |
| 04756-0028 | A | steel | 52 | 13 | 26 | - | - | 28 | M5 | - | - | 41 | 28 | 66 | 11 | 30 | 13 | 26 | - | - | - | - | 5 | 6 |
| 04756-0116 | B | steel | 52 | 7 | 38 | - | - | 16 | M5 | M6 | - | 30,5 | 17,5 | 96 | 11 | 30 | 7 | 38 | - | - | - | - | 5 | 6 |
| 04756-1120 | B | stainless steel | 52 | 7 | 38 | - | - | 20 | M5 | M6 | - | 34 | 21 | 96 | 11 | 30 | 7 | 38 | - | - | - | - | 5 | 6 |
| 04756-0128 | B | steel | 52 | 7 | 38 | - | - | 28 | M5 | M6 | - | 41 | 28 | 96 | 11 | 30 | 7 | 38 | - | - | - | - | 5 | 6 |
| 04756-0216 | C | steel | 52 | 13 | 26 | 7 | 38 | 16 | M5 | M5 | M6 | 30,5 | 17,5 | 96 | 11 | 30 | 13 | 26 | 26 | 7 | 38 | 30 | 5 | 6 |
| 04756-1220 | C | stainless steel | 52 | 13 | 26 | 7 | 38 | 20 | M5 | M5 | M6 | 34 | 21 | 96 | 11 | 30 | 13 | 26 | 26 | 7 | 38 | 30 | 5 | 6 |
| 04756-0228 | C | steel | 52 | 13 | 26 | 7 | 38 | 28 | M5 | M5 | M6 | 41 | 28 | 96 | 11 | 30 | 13 | 26 | 26 | 7 | 38 | 30 | 5 | 6 |