

Item description/product images



**Description**

**Material:**  
Aluminium.

**Version:**  
Natural or black anodised.

**Note for ordering:**  
Order the fastening material and end washers separately.


**Assembly:**  
From the rear.

**Accessory:**  
End washers 06917.

Item description/product images



Drawings

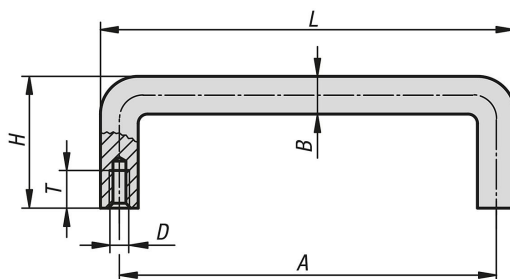

Overview of items

Order No.	Main colour	A	B	D	H	L	T	Load capacity N	Order No. end washer
06917-032041	black	32	8	M4	32	40	10	500	06917-4
06917-055041	black	55	8	M4	32	63	10	500	06917-4
06917-064041	black	64	8	M4	32	72	10	500	06917-4
06917-076041	black	76	8	M4	32	84	10	500	06917-4
06917-088041	black	88	8	M4	32	96	10	500	06917-4
06917-096041	black	96	8	M4	32	104	10	500	06917-4
06917-098041	black	98	8	M4	32	106	10	500	06917-4
06917-100041	black	100	8	M4	32	108	10	500	06917-4
06917-102041	black	102	8	M4	32	110	10	500	06917-4
06917-120041	black	120	8	M4	32	128	10	500	06917-4
06917-136041	black	136	8	M4	32	144	10	500	06917-4
06917-055051	black	55	10	M5	40	65	10	500	06917-1
06917-064051	black	64	10	M5	40	74	10	500	06917-1
06917-076051	black	76	10	M5	40	86	10	500	06917-1
06917-088051	black	88	10	M5	40	98	10	500	06917-1
06917-096051	black	96	10	M5	40	106	10	500	06917-1
06917-098051	black	98	10	M5	40	108	10	500	06917-1
06917-100051	black	100	10	M5	40	110	10	500	06917-1
06917-102051	black	102	10	M5	40	112	10	500	06917-1
06917-120051	black	120	10	M5	40	130	10	500	06917-1
06917-136051	black	136	10	M5	40	146	10	500	06917-1
06917-140051	black	140	10	M5	40	150	10	500	06917-1
06917-160051	black	160	10	M5	40	170	10	500	06917-1
06917-180051	black	180	10	M5	40	190	10	500	06917-1
06917-200051	black	200	10	M5	40	210	10	500	06917-1
06917-235051	black	235	10	M5	40	245	10	500	06917-1
06917-250051	black	250	10	M5	40	260	10	500	06917-1
06917-300051	black	300	10	M5	40	310	10	500	06917-1

## Overview of items

Order No.	Main colour	A	B	D	H	L	T	Load capacity N	Order No. end washer
06917-350051	black	350	10	M5	40	360	10	500	06917-1
06917-120061	black	120	12	M6	42	132	12	500	06917-6
06917-136061	black	136	12	M6	42	148	12	500	06917-6
06917-140061	black	140	12	M6	42	152	12	500	06917-6
06917-160061	black	160	12	M6	42	172	12	500	06917-6
06917-180061	black	180	12	M6	42	192	12	500	06917-6
06917-200061	black	200	12	M6	42	212	12	500	06917-6
06917-235061	black	235	12	M6	42	247	12	500	06917-6
06917-250061	black	250	12	M6	42	262	12	500	06917-6
06917-300061	black	300	12	M6	42	312	12	500	06917-6
06917-350061	black	350	12	M6	42	362	12	500	06917-6
06917-140081	black	140	16	M8	58	156	12	500	-
06917-160081	black	160	16	M8	58	176	12	500	-
06917-180081	black	180	16	M8	58	196	12	500	-
06917-200081	black	200	16	M8	58	216	12	500	-
06917-235081	black	235	16	M8	58	251	12	500	-
06917-250081	black	250	16	M8	58	266	12	500	-
06917-300081	black	300	16	M8	58	316	12	500	-
06917-350081	black	350	16	M8	58	366	12	500	-
06917-200101	black	200	20	M10	70	220	19	500	-
06917-235101	black	235	20	M10	70	255	19	500	-
06917-250101	black	250	20	M10	70	270	19	500	-
06917-300101	black	300	20	M10	70	320	19	500	-
06917-350101	black	350	20	M10	70	370	19	500	-
06917-032043	natural	32	8	M4	32	40	10	500	06917-5
06917-055043	natural	55	8	M4	32	63	10	500	06917-5
06917-064043	natural	64	8	M4	32	72	10	500	06917-5
06917-076043	natural	76	8	M4	32	84	10	500	06917-5
06917-088043	natural	88	8	M4	32	96	10	500	06917-5
06917-096043	natural	96	8	M4	32	104	10	500	06917-5
06917-098043	natural	98	8	M4	32	106	10	500	06917-5
06917-100043	natural	100	8	M4	32	108	10	500	06917-5
06917-102043	natural	102	8	M4	32	110	10	500	06917-5
06917-120043	natural	120	8	M4	32	128	10	500	06917-5
06917-136043	natural	136	8	M4	32	144	10	500	06917-5
06917-055053	natural	55	10	M5	40	65	10	500	06917-3
06917-064053	natural	64	10	M5	40	74	10	500	06917-3
06917-076053	natural	76	10	M5	40	86	10	500	06917-3
06917-088053	natural	88	10	M5	40	98	10	500	06917-3
06917-096053	natural	96	10	M5	40	106	10	500	06917-3
06917-098053	natural	98	10	M5	40	108	10	500	06917-3
06917-100053	natural	100	10	M5	40	110	10	500	06917-3
06917-102053	natural	102	10	M5	40	112	10	500	06917-3
06917-120053	natural	120	10	M5	40	130	10	500	06917-3
06917-136053	natural	136	10	M5	40	146	10	500	06917-3
06917-140053	natural	140	10	M5	40	150	10	500	06917-3
06917-160053	natural	160	10	M5	40	170	10	500	06917-3
06917-180053	natural	180	10	M5	40	190	10	500	06917-3
06917-200053	natural	200	10	M5	40	210	10	500	06917-3
06917-235053	natural	235	10	M5	40	245	10	500	06917-3
06917-250053	natural	250	10	M5	40	260	10	500	06917-3
06917-300053	natural	300	10	M5	40	310	10	500	06917-3
06917-350053	natural	350	10	M5	40	360	10	500	06917-3
06917-120063	natural	120	12	M6	42	132	12	500	06917-7
06917-136063	natural	136	12	M6	42	148	12	500	06917-7
06917-140063	natural	140	12	M6	42	152	12	500	06917-7
06917-160063	natural	160	12	M6	42	172	12	500	06917-7
06917-180063	natural	180	12	M6	42	192	12	500	06917-7
06917-200063	natural	200	12	M6	42	212	12	500	06917-7
06917-235063	natural	235	12	M6	42	247	12	500	06917-7
06917-250063	natural	250	12	M6	42	262	12	500	06917-7
06917-300063	natural	300	12	M6	42	312	12	500	06917-7
06917-350063	natural	350	12	M6	42	362	12	500	06917-7
06917-140083	natural	140	16	M8	58	156	12	500	-

## Overview of items

Order No.	Main colour	A	B	D	H	L	T	Load capacity N	Order No. end washer
06917-160083	natural	160	16	M8	58	176	12	500	-
06917-180083	natural	180	16	M8	58	196	12	500	-
06917-200083	natural	200	16	M8	58	216	12	500	-
06917-235083	natural	235	16	M8	58	251	12	500	-
06917-250083	natural	250	16	M8	58	266	12	500	-
06917-300083	natural	300	16	M8	58	316	12	500	-
06917-350083	natural	350	16	M8	58	366	12	500	-
06917-200103	natural	200	20	M10	70	220	19	500	-
06917-235103	natural	235	20	M10	70	255	19	500	-
06917-250103	natural	250	20	M10	70	270	19	500	-
06917-300103	natural	300	20	M10	70	320	19	500	-
06917-350103	natural	350	20	M10	70	370	19	500	-