
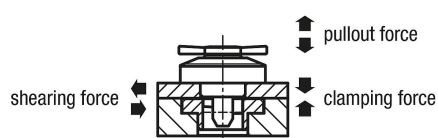


Item description/product images

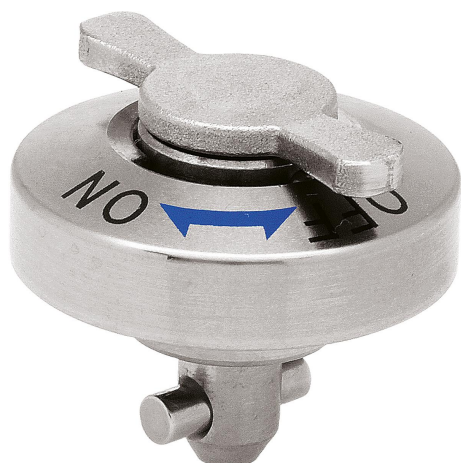

Description

Material:

Housing stainless steel.

Pin stainless steel.

Pin stainless steel.

Knob stainless steel.

Version:

Housing bright.

Pin bright.

Pin bright.

Knob stainless steel, bright.

Note:

M2 or M3 fastening screws are supplied.

Mounting option 1 for plate thickness 6 or 12 mm.

Mounting option 2 for plate thickness 12 to 20 mm.

A gap of more than 0.1 mm appears between the plates if the retaining force is exceeded.


Accessory:

Clamping plates 05592

Drawing reference:

1) plate

Drawings

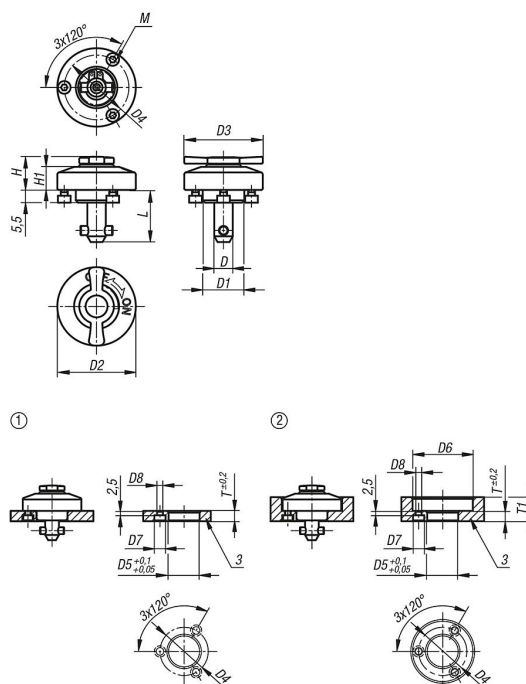

Overview of items

Overview of items

Quarter-turn clamp locks stainless steel, flat

Order No.	D	D1	D2	D3	D4	H	H1	L	M	D5	D6	D7	D8	T	T1	Holding force N	Clamping force N	Shearing force kN	Pullout force F kN	Temperature resistance
05591-15162	15,5	14	25	20	21	11,5	6,5	60	M2x3	14	26	4,4	2,4	6	6-10	1,2	5	60	1,8	≤180 °C
05591-18172	17	18	34	32	28	15,4	10	90	M3x4	18	35	6,5	3,4	6	6-14	2,6	8	90	3,2	≤180 °C
05591-18232	23	18	34	32	28	15,4	10	90	M3x4	18	35	6,5	3,4	12	12-20	2,6	8	90	3,2	≤180 °C