

Item description/product images



Description

Material:
Steel.

Version:
Pre-stretched.

Note for ordering:

Packaging unit: 5 metres with odd number of links. Ending with an inner link at both ends. Connecting links must be ordered separately.

Note:

European-type roller chains acc. to DIN ISO 606 with curved link plates (ISO No. 06 with straight links). All chains are pre-stretched. Initial lubrication: anti-corrosion mineral based oil.


B7 = maximum value for links.

Pitch = PxB1

Temperature range:

-20°C to +120°C.

Drawings

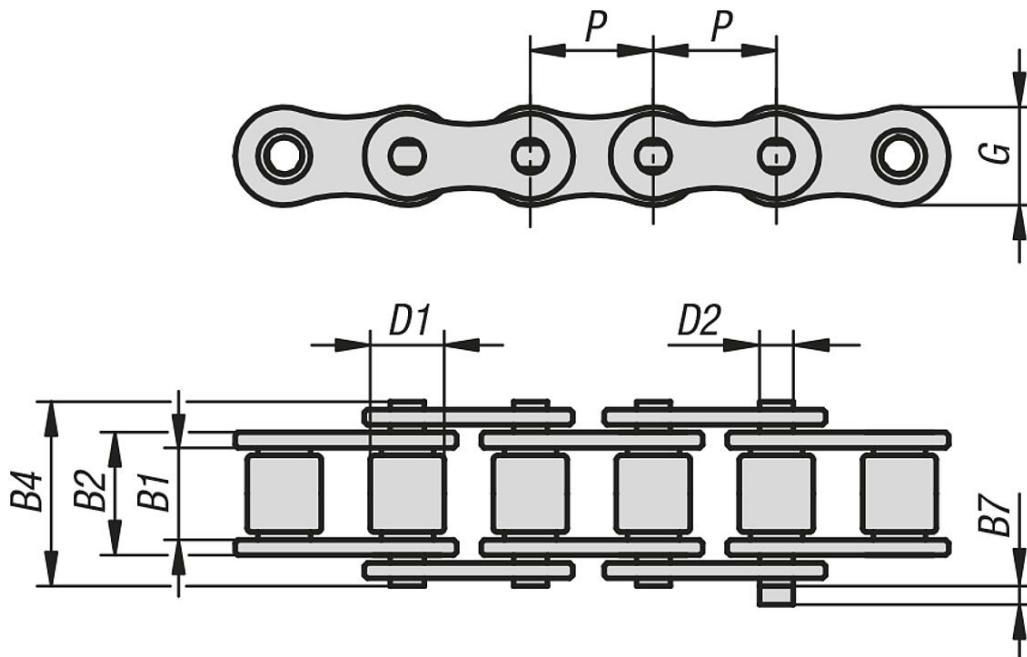

Overview of items

Order No.	ISO No.	Pitch inch	Pitch mm	B2	B4	B7	D1	D2	G	~L	No. of links	Break force F min. kN
22200-0800030625	05 B-1	-	8,0 x 3,0	4,77	8,6	3,1	5	2,31	7,11	~5000	625	4,4
22200-0380732525	06 B-1	3/8X7/32	9,525 x 5,72	8,53	13,5	3,3	6,35	3,28	8,26	~5000	525	6,6
22200-0120516393	08 B-1	1/2X5/16	12,7 x 7,75	11,3	17	3,9	8,51	4,45	11,81	~5000	393	12
22200-0580308315	10 B-1	5/8X3/8	15,875 x 9,65	13,28	19,6	4,1	10,16	5,08	14,73	~5000	315	15
22200-0340716263	12 B-1	3/4X7/16	19,05 x 11,68	15,62	22,7	4,6	12,07	5,72	16,13	~5000	263	17
22200-1001702197	16 B-1	1X17,02mm	25,4 x 17,02	25,45	36,1	5,4	15,88	8,28	21,08	~5000	197	40

Overview of items

Order No.	ISO No.	Pitch inch	Pitch mm	B2	B4	B7	D1	D2	G	~L	No. of links	Break force F min. kN
22200-1140304157	20 B-1	1 1/4X3/4	31,75 x 19,56	29,01	43,2	6,1	19,05	10,19	26,42	~5000	157	95
22200-1121000131	24 B-1	1 1/2X1	38,1 x 25,4	37,92	53,4	6,6	25,4	14,63	33,4	~5000	131	160