

Item description/product images



Description

Material:

Steel.

Version:

Pre-stretched.

Note for ordering:

Packaging unit: 5 metres with odd number of links. Ending with an inner link at both ends. Connecting links must be ordered separately.

Note:

European-type roller chains acc. to DIN ISO 606 with straight link plates. All chains are pre-stretched.

Initial lubrication: anti-corrosion mineral based oil.


B7 = maximum value for links.

Pitch = PxB1

Temperature range:

-20°C to +120°C.

Drawings

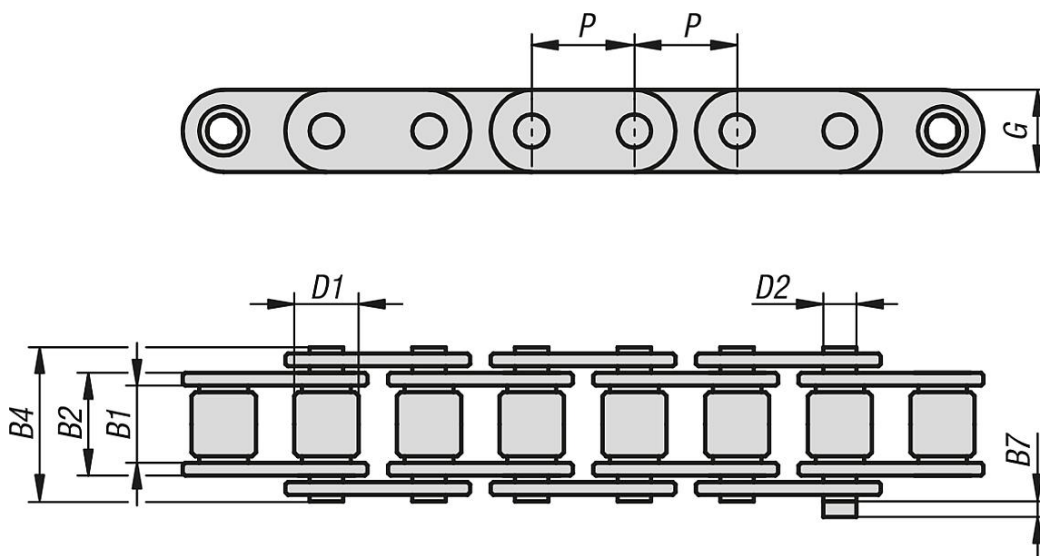

Overview of items

Order No.	ISO No.	Pitch inch	Pitch mm	B2	B4	B7	D1	D2	G	~L	No. of links	Break force F min. kN
22208-0120516393	08 B-1	1/2 x 5/16	12,7 x 7,75	11,3	17	1,5	8,51	4,45	11,8	~5000	393	18
22208-0580308315	10 B-1	5/8 x 3/8	15,875 x 9,65	13,28	19,6	2,4	10,16	5,08	14,7	~5000	315	22,4
22208-0340716263	12 B-1	3/4 x 7/16	19,05 x 11,68	15,62	22,7	2,7	12,07	5,72	16	~5000	263	29
22208-1001702197	16 B-1	1 x 17,02mm	25,4 x 17,02	25,45	36,1	3	15,88	8,28	21	~5000	197	60

