


Item description/product images

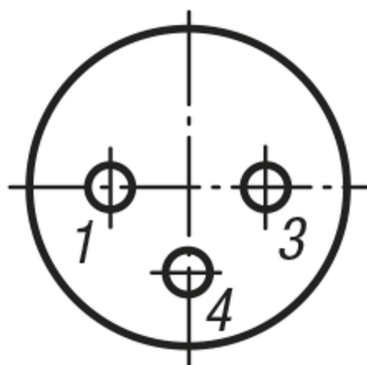

Description

Material:

Cable and housing PUR
Contacts gold-plated bronze.

Version:

Bush (female)
Voltage: U max. 60 V
Current: I max. 4 A
Terminals: 3-pin
Security type: IP 67

Note:

Plug connector with screw fitting.
Plug encapsulated to cable.


Temperature range:

-25 °C to +70 °C.

Drawing reference:

1 = brown (BN)
3 = blue (BU)
4 = black (BK)

Drawings

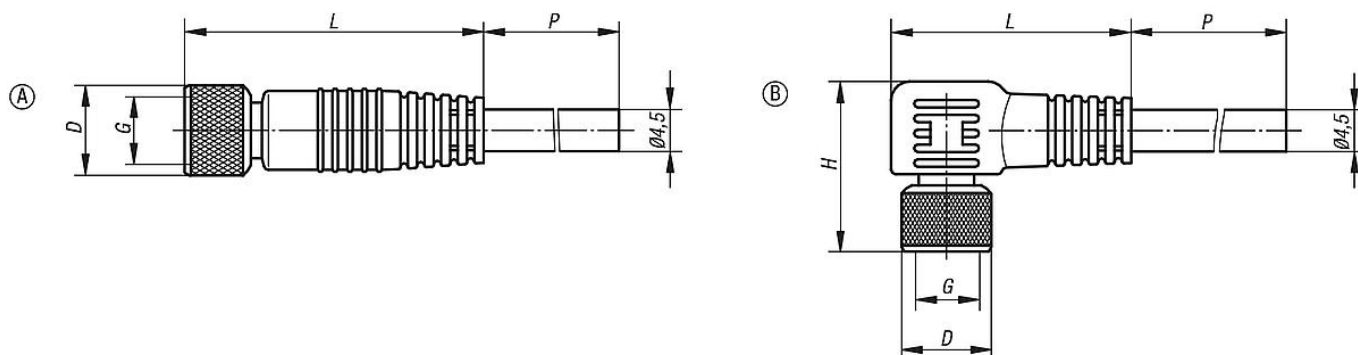

Overview of items

Order No.	Form	D	H	G	L	P	No. of conductors x conductor cross-section
80150-010X2000	A	9,7	-	M8x1	32	2000	3 x 0,25 mm ²
80150-020X2000	A	14,5	-	M12x1	41,5	2000	3 x 0,34 mm ²
80150-030X2000	B	9,7	18,2	M8x1	26	2000	3 x 0,25 mm ²
80150-040X2000	B	14,5	26,5	M12x1	38,5	2000	3 x 0,34 mm ²