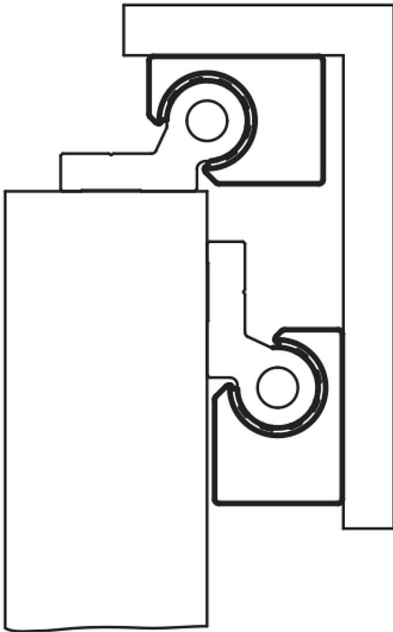


## Item description/product images

**Description****Material:**

Aluminium.

**Version:**

Hard anodised, layer thickness 50 µm.

Hardness 500 HV

**Note:**


Single guide rails enable highest flexibility during construction and easy assembly. Can be used to compensate for height differences in height. Hard anodised aluminium is used as rail material and ensures best friction and wear results. Robust and dirt resistant for transporting heavy loads safely and maintenance-free.

\*\* length L2 = 20 mm and

\* L = 500 mm included

L2 and L only available in full mm.

Drawings

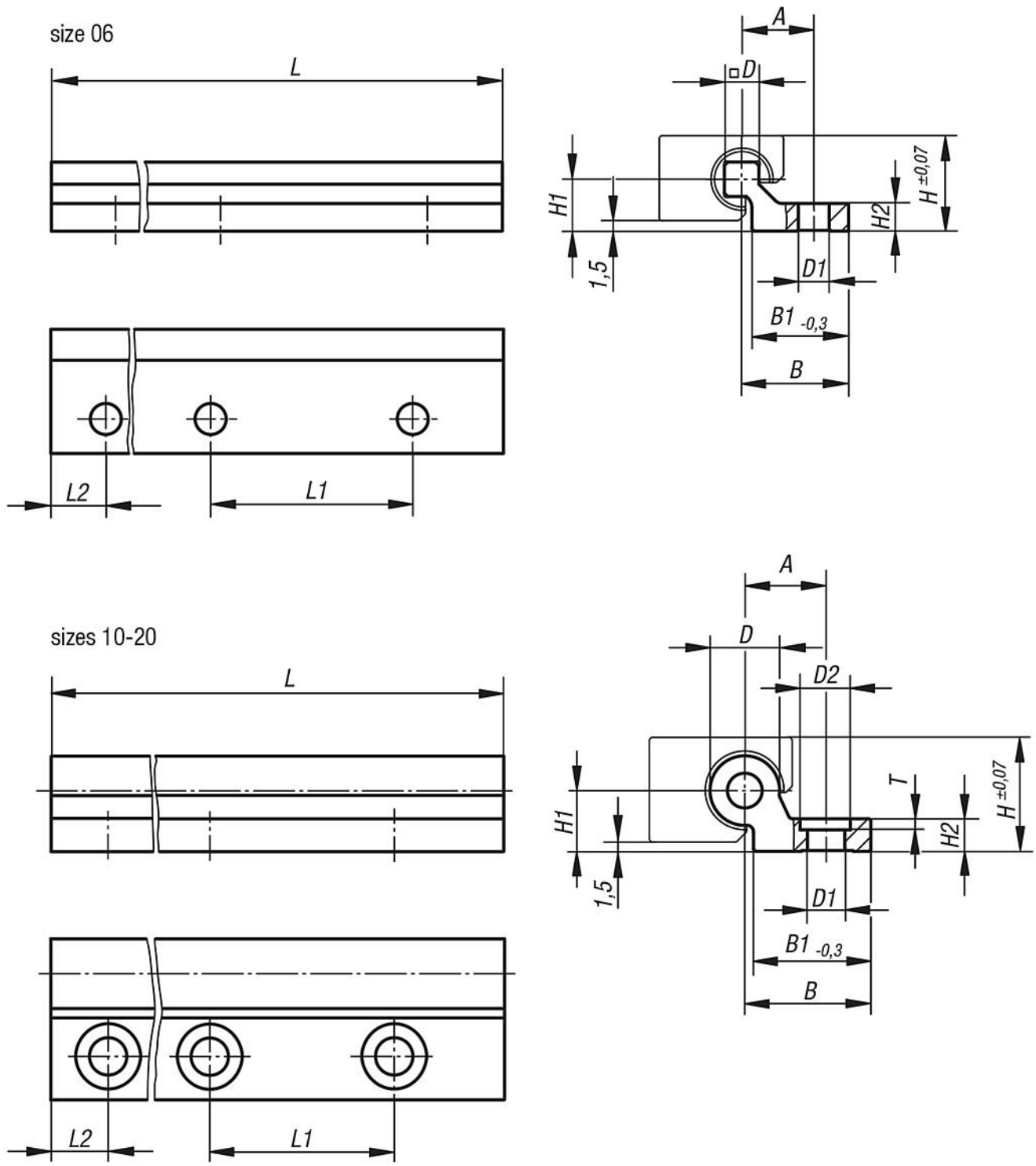

Overview of items

Order No.	Version 1	Size	L max.	L	L2	L2 min.	L2 max.	A	B	B1	D	D1	D2	H	H1	H2	L1	T
21240-10630X3000	-	6	3000	3000	30	-	-	10,5	15,5	14	5	4,5	-	14	7,5	4	60	-
21240-11030X4000	-	10	4000	4000	20	-	-	17	27	27	10	6,6	-	18	9	5,5	120	-
21240-11630X4000	-	16	4000	4000	20	-	-	19	29	27	16	9	15	27	14	7,5	120	4
21240-12030X4000	-	20	4000	4000	20	-	-	21	31	27	20	9	15	36	20	9,5	120	5

## Overview of items

Order No.	Version 1	Size	L max.	L	L2	L2 min.	L2 max.	A	B	B1	D	D1	D2	H	H1	H2	L1	T
21240-106**X*	L2 and L customer specific	6	3000	*	**	20	49,5	10,5	15,5	14	5	4,5	-	14	7,5	4	60	-
21240-110**X*	L2 and L customer specific	10	4000	*	**	20	79,5	17	27	27	10	6,6	-	18	9	5,5	120	-
21240-116**X*	L2 and L customer specific	16	4000	*	**	20	79,5	19	29	27	16	9	15	27	14	7,5	120	4
21240-120**X*	L2 and L customer specific	20	4000	*	**	20	79,5	21	31	27	20	9	15	36	20	9,5	120	5