


Item description/product images

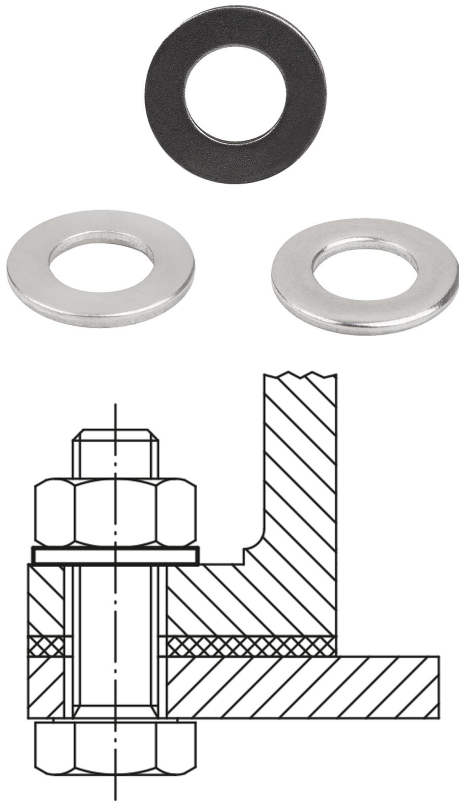

Description

Material:

Steel, stainless steel A2 or stainless steel A4.


Version:

Steel, bright.

Stainless steel A2, bright.

Stainless steel A4, bright.

Drawings

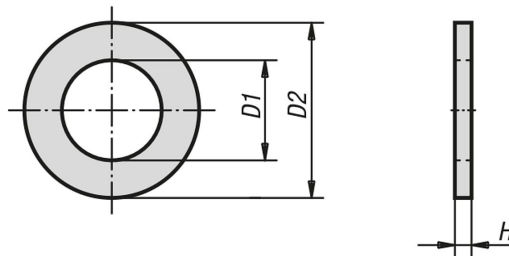

Overview of items

Order No.	Main material	Grade	for screws	D1	D2	H
07300-03	steel	-	M3	3,2	7	0,5
07300-04	steel	-	M4	4,3	9	0,8
07300-05	steel	-	M5	5,3	10	1
07300-06	steel	-	M6	6,4	12	1,6
07300-08	steel	-	M8	8,4	16	1,6
07300-10	steel	-	M10	10,5	20	2
07300-12	steel	-	M12	13	24	2,5
07300-14	steel	-	M14	15	28	2,5
07300-16	steel	-	M16	17	30	3
07300-20	steel	-	M20	21	37	3
07300-24	steel	-	M24	25	44	4
07300-30	steel	-	M30	31	56	4
07300-36	steel	-	M36	37	66	5
07300-103	stainless steel A2	70	M3	3,2	7	0,5
07300-104	stainless steel A2	70	M4	4,3	9	0,8
07300-105	stainless steel A2	70	M5	5,3	10	1

Overview of items

Order No.	Main material	Grade	for screws	D1	D2	H
07300-106	stainless steel A2	70	M6	6,4	12	1,6
07300-108	stainless steel A2	70	M8	8,4	16	1,6
07300-110	stainless steel A2	70	M10	10,5	20	2
07300-112	stainless steel A2	70	M12	13	24	2,5
07300-114	stainless steel A2	70	M14	15	28	2,5
07300-116	stainless steel A2	70	M16	17	30	3
07300-120	stainless steel A2	70	M20	21	37	3
07300-124	stainless steel A2	70	M24	25	44	4
07300-130	stainless steel A2	70	M30	31	56	4
07300-136	stainless steel A2	70	M36	37	66	5
07300-603	stainless steel A4	70	M3	3,2	7	0,5
07300-604	stainless steel A4	70	M4	4,3	9	0,8
07300-605	stainless steel A4	70	M5	5,3	10	1
07300-606	stainless steel A4	70	M6	6,4	12	1,6
07300-608	stainless steel A4	70	M8	8,4	16	1,6
07300-610	stainless steel A4	70	M10	10,5	20	2
07300-612	stainless steel A4	70	M12	13	24	2,5
07300-614	stainless steel A4	70	M14	15	28	2,5
07300-616	stainless steel A4	70	M16	17	30	3
07300-620	stainless steel A4	70	M20	21	37	3
07300-624	stainless steel A4	70	M24	25	44	4
07300-630	stainless steel A4	70	M30	31	56	4
07300-636	stainless steel A4	70	M36	37	66	5