

Item description/product images



Description

Material:

Stainless steel 1.4305.

Version:

Bright.

Note:


Form A: with grub screw DIN 553 (recess)

Form E: with grub screw DIN 914 (hexagon socket)

Drawing reference:

1) Second grub screw from $D1 \geq 75$

Drawings

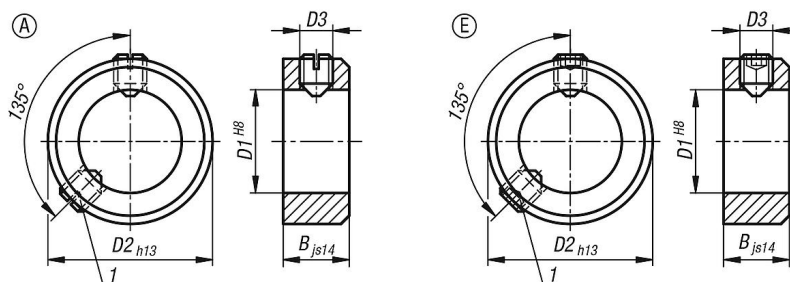

Overview of items

Order No.	Form	Component material	D1	B	D2	D3 grub screw
07800-100302	A	stainless steel	3	5	7	M2x3
07800-100402	A	stainless steel	4	5	8	M2,5x3
07800-100502	A	stainless steel	5	6	10	M3x4
07800-100602	A	stainless steel	6	8	12	M4x5
07800-100702	A	stainless steel	7	8	12	M4x5
07800-100802	A	stainless steel	8	8	16	M4x6
07800-100902	A	stainless steel	9	10	18	M5x8
07800-101002	A	stainless steel	10	10	20	M5x8
07800-101102	A	stainless steel	11	10	20	M5x8
07800-101202	A	stainless steel	12	12	22	M6x8
07800-101402	A	stainless steel	14	12	25	M6x8
07800-101502	A	stainless steel	15	12	25	M6x8
07800-101602	A	stainless steel	16	12	28	M6x8
07800-101802	A	stainless steel	18	14	32	M6x8
07800-102002	A	stainless steel	20	14	32	M6x8
07800-102402	A	stainless steel	24	16	40	M8x12
07800-102502	A	stainless steel	25	16	40	M8x10
07800-102602	A	stainless steel	26	16	40	M8x10
07800-102802	A	stainless steel	28	16	45	M8x12
07800-103002	A	stainless steel	30	16	45	M8x10
07800-103202	A	stainless steel	32	16	50	M8x12
07800-103502	A	stainless steel	35	16	56	M8x12
07800-103602	A	stainless steel	36	16	56	M8x12
07800-103802	A	stainless steel	38	16	56	M8x12
07800-104002	A	stainless steel	40	18	63	M10x16
07800-104202	A	stainless steel	42	18	63	M10x16
07800-104502	A	stainless steel	45	18	70	M10x16

Overview of items

Order No.	Form	Component material	D1	B	D2	D3 grub screw
07800-104802	A	stainless steel	48	18	70	M10x16
07800-105002	A	stainless steel	50	18	80	M10x16
07800-105202	A	stainless steel	52	18	80	M10x16
07800-105502	A	stainless steel	55	18	80	M10x16
07800-105602	A	stainless steel	56	18	80	M10x16
07800-105802	A	stainless steel	58	20	90	M10x16
07800-106002	A	stainless steel	60	20	90	M10x16
07800-106302	A	stainless steel	63	20	90	M10x16
07800-106502	A	stainless steel	65	20	100	M10x20
07800-106802	A	stainless steel	68	20	100	M10x20
07800-107002	A	stainless steel	70	20	100	M10x20
07800-107202	A	stainless steel	72	20	100	M10x20
07800-107502	A	stainless steel	75	22	110	M12x20
07800-108002	A	stainless steel	80	22	110	M12x20
07800-108502	A	stainless steel	85	22	125	M12x25
07800-109002	A	stainless steel	90	22	125	M12x20
07800-110002	A	stainless steel	100	25	140	M12x25
07800-300302	E	stainless steel	3	5	7	M2x3
07800-300402	E	stainless steel	4	5	8	M2,5x3
07800-300502	E	stainless steel	5	6	10	M3x4
07800-300602	E	stainless steel	6	8	12	M4x5
07800-300702	E	stainless steel	7	8	12	M4x5
07800-300802	E	stainless steel	8	8	16	M4x6
07800-300902	E	stainless steel	9	10	18	M5x8
07800-301002	E	stainless steel	10	10	20	M5x8
07800-301102	E	stainless steel	11	10	20	M5x8
07800-301202	E	stainless steel	12	12	22	M6x8
07800-301402	E	stainless steel	14	12	25	M6x8
07800-301502	E	stainless steel	15	12	25	M6x8
07800-301602	E	stainless steel	16	12	28	M6x8
07800-301802	E	stainless steel	18	14	32	M6x8
07800-302002	E	stainless steel	20	14	32	M6x8
07800-302402	E	stainless steel	24	16	40	M8x12
07800-302502	E	stainless steel	25	16	40	M8x10
07800-302602	E	stainless steel	26	16	40	M8x10
07800-302802	E	stainless steel	28	16	45	M8x12
07800-303002	E	stainless steel	30	16	45	M8x10
07800-303202	E	stainless steel	32	16	50	M8x12
07800-303502	E	stainless steel	35	16	56	M8x12
07800-303602	E	stainless steel	36	16	56	M8x12
07800-303802	E	stainless steel	38	16	56	M8x12
07800-304002	E	stainless steel	40	18	63	M10x16
07800-304202	E	stainless steel	42	18	63	M10x16
07800-304502	E	stainless steel	45	18	70	M10x16
07800-304802	E	stainless steel	48	18	70	M10x16
07800-305002	E	stainless steel	50	18	80	M10x16
07800-305202	E	stainless steel	52	18	80	M10x16
07800-305502	E	stainless steel	55	18	80	M10x16
07800-305602	E	stainless steel	56	18	80	M10x16
07800-305802	E	stainless steel	58	20	90	M10x16
07800-306002	E	stainless steel	60	20	90	M10x16
07800-306302	E	stainless steel	63	20	90	M10x16
07800-306502	E	stainless steel	65	20	100	M10x20
07800-306802	E	stainless steel	68	20	100	M10x20
07800-307002	E	stainless steel	70	20	100	M10x20
07800-307202	E	stainless steel	72	20	100	M10x20
07800-307502	E	stainless steel	75	22	110	M12x20
07800-308002	E	stainless steel	80	22	110	M12x20
07800-308502	E	stainless steel	85	22	125	M12x25
07800-309002	E	stainless steel	90	22	125	M12x20
07800-310002	E	stainless steel	100	25	140	M12x25

