



lift to  
disengage



## Description

### Material:

Handle fibreglass reinforced plastic with die-cast zinc toothed ring.  
Steel parts stainless steel 1.4305.

### Version:

Stainless steel bright.


### Note:

Δ Add the desired grip colour here.

### On request:

Other threads and special versions.

Dimension "H1" available in other lengths at extra charge.

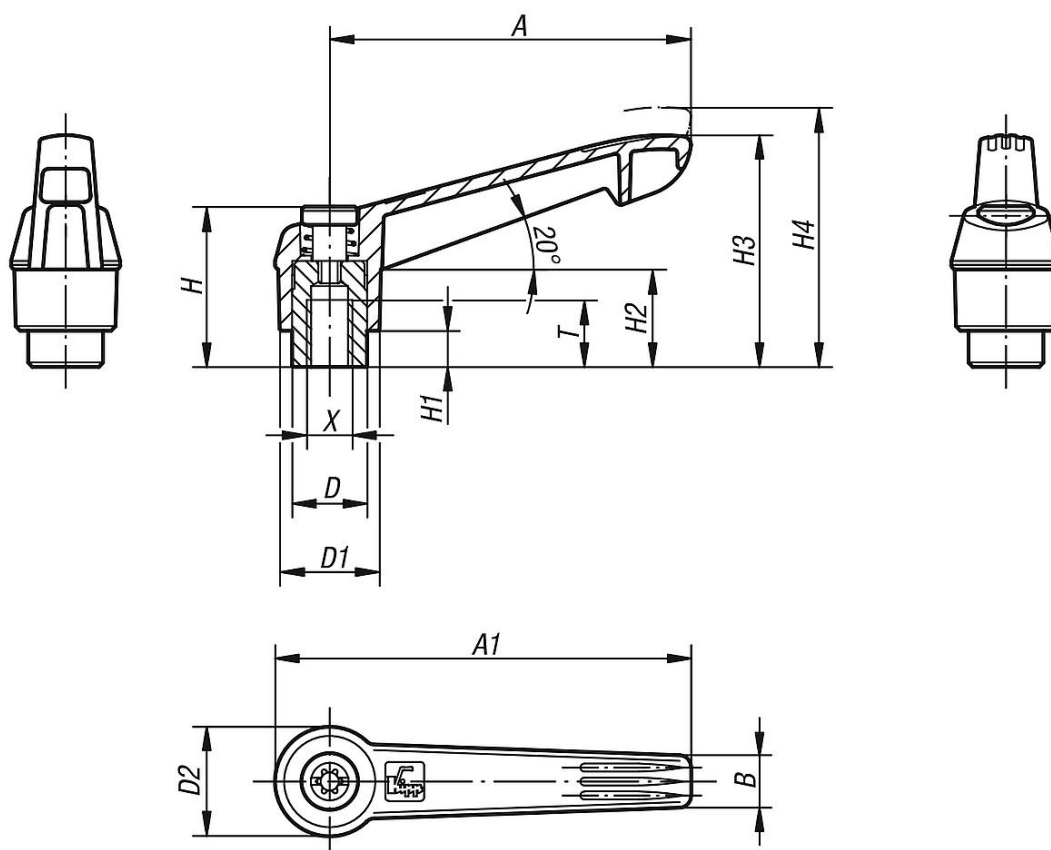

## Overview of items

Order No.	Main colour	Main material	Size	X	T	D	D1	D2	H	H1	H2	H3	H4	A	A1	B	No. of teeth
06601-1041	black grey RAL 7021	plastic	1	M4	9	10	13	14,5	24,5	4	15	30	33,5	40	47	7,5	16
06601-1042	orange RAL 2004	plastic	1	M4	9	10	13	14,5	24,5	4	15	30	33,5	40	47	7,5	16
06601-10416	colza yellow RAL 1021	plastic	1	M4	9	10	13	14,5	24,5	4	15	30	33,5	40	47	7,5	16
06601-10484	traffic red RAL 3020	plastic	1	M4	9	10	13	14,5	24,5	4	15	30	33,5	40	47	7,5	16
06601-10486	signal green RAL 6032	plastic	1	M4	9	10	13	14,5	24,5	4	15	30	33,5	40	47	7,5	16
06601-10487	traffic blue RAL 5017	plastic	1	M4	9	10	13	14,5	24,5	4	15	30	33,5	40	47	7,5	16
06601-10488	light grey RAL 7035	plastic	1	M4	9	10	13	14,5	24,5	4	15	30	33,5	40	47	7,5	16
06601-1051	black grey RAL 7021	plastic	1	M5	9	10	13	14,5	24,5	4	15	30	33,5	40	47	7,5	16
06601-1052	orange RAL 2004	plastic	1	M5	9	10	13	14,5	24,5	4	15	30	33,5	40	47	7,5	16
06601-10516	colza yellow RAL 1021	plastic	1	M5	9	10	13	14,5	24,5	4	15	30	33,5	40	47	7,5	16
06601-10584	traffic red RAL 3020	plastic	1	M5	9	10	13	14,5	24,5	4	15	30	33,5	40	47	7,5	16
06601-10586	signal green RAL 6032	plastic	1	M5	9	10	13	14,5	24,5	4	15	30	33,5	40	47	7,5	16
06601-10587	traffic blue RAL 5017	plastic	1	M5	9	10	13	14,5	24,5	4	15	30	33,5	40	47	7,5	16
06601-10588	light grey RAL 7035	plastic	1	M5	9	10	13	14,5	24,5	4	15	30	33,5	40	47	7,5	16
06601-1061	black grey RAL 7021	plastic	1	M6	9	10	13	14,5	24,5	4	15	30	33,5	40	47	7,5	16
06601-1062	orange RAL 2004	plastic	1	M6	9	10	13	14,5	24,5	4	15	30	33,5	40	47	7,5	16
06601-10616	colza yellow RAL 1021	plastic	1	M6	9	10	13	14,5	24,5	4	15	30	33,5	40	47	7,5	16
06601-10684	traffic red RAL 3020	plastic	1	M6	9	10	13	14,5	24,5	4	15	30	33,5	40	47	7,5	16
06601-10686	signal green RAL 6032	plastic	1	M6	9	10	13	14,5	24,5	4	15	30	33,5	40	47	7,5	16
06601-10687	traffic blue RAL 5017	plastic	1	M6	9	10	13	14,5	24,5	4	15	30	33,5	40	47	7,5	16
06601-10688	light grey RAL 7035	plastic	1	M6	9	10	13	14,5	24,5	4	15	30	33,5	40	47	7,5	16
06601-2061	black grey RAL 7021	plastic	2	M6	12	13,5	18	19,5	28,5	6,5	17,5	41,5	45,5	65	75	9,5	20
06601-2062	orange RAL 2004	plastic	2	M6	12	13,5	18	19,5	28,5	6,5	17,5	41,5	45,5	65	75	9,5	20
06601-20616	colza yellow RAL 1021	plastic	2	M6	12	13,5	18	19,5	28,5	6,5	17,5	41,5	45,5	65	75	9,5	20
06601-20684	traffic red RAL 3020	plastic	2	M6	12	13,5	18	19,5	28,5	6,5	17,5	41,5	45,5	65	75	9,5	20
06601-20686	signal green RAL 6032	plastic	2	M6	12	13,5	18	19,5	28,5	6,5	17,5	41,5	45,5	65	75	9,5	20
06601-20687	traffic blue RAL 5017	plastic	2	M6	12	13,5	18	19,5	28,5	6,5	17,5	41,5	45,5	65	75	9,5	20
06601-20688	light grey RAL 7035	plastic	2	M6	12	13,5	18	19,5	28,5	6,5	17,5	41,5	45,5	65	75	9,5	20
06601-2081	black grey RAL 7021	plastic	2	M8	12	13,5	18	19,5	28,5	6,5	17,5	41,5	45,5	65	75	9,5	20

## Overview of items

Order No.	Main colour	Main material	Size	X	T	D	D1	D2	H	H1	H2	H3	H4	A	A1	B	No. of teeth
06601-2082	orange RAL 2004	plastic	2	M8	12	13,5	18	19,5	28,5	6,5	17,5	41,5	45,5	65	75	9,5	20
06601-20816	colza yellow RAL 1021	plastic	2	M8	12	13,5	18	19,5	28,5	6,5	17,5	41,5	45,5	65	75	9,5	20
06601-20884	traffic red RAL 3020	plastic	2	M8	12	13,5	18	19,5	28,5	6,5	17,5	41,5	45,5	65	75	9,5	20
06601-20886	signal green RAL 6032	plastic	2	M8	12	13,5	18	19,5	28,5	6,5	17,5	41,5	45,5	65	75	9,5	20
06601-20887	traffic blue RAL 5017	plastic	2	M8	12	13,5	18	19,5	28,5	6,5	17,5	41,5	45,5	65	75	9,5	20
06601-20888	light grey RAL 7035	plastic	2	M8	12	13,5	18	19,5	28,5	6,5	17,5	41,5	45,5	65	75	9,5	20
06601-3081	black grey RAL 7021	plastic	3	M8	14	16	21,5	23	37	10	24	53,5	58	80	91,5	11	22
06601-3082	orange RAL 2004	plastic	3	M8	14	16	21,5	23	37	10	24	53,5	58	80	91,5	11	22
06601-30816	colza yellow RAL 1021	plastic	3	M8	14	16	21,5	23	37	10	24	53,5	58	80	91,5	11	22
06601-30884	traffic red RAL 3020	plastic	3	M8	14	16	21,5	23	37	10	24	53,5	58	80	91,5	11	22
06601-30886	signal green RAL 6032	plastic	3	M8	14	16	21,5	23	37	10	24	53,5	58	80	91,5	11	22
06601-30887	traffic blue RAL 5017	plastic	3	M8	14	16	21,5	23	37	10	24	53,5	58	80	91,5	11	22
06601-30888	light grey RAL 7035	plastic	3	M8	14	16	21,5	23	37	10	24	53,5	58	80	91,5	11	22
06601-3101	black grey RAL 7021	plastic	3	M10	14	16	21,5	23	37	10	24	53,5	58	80	91,5	11	22
06601-3102	orange RAL 2004	plastic	3	M10	14	16	21,5	23	37	10	24	53,5	58	80	91,5	11	22
06601-31016	colza yellow RAL 1021	plastic	3	M10	14	16	21,5	23	37	10	24	53,5	58	80	91,5	11	22
06601-31084	traffic red RAL 3020	plastic	3	M10	14	16	21,5	23	37	10	24	53,5	58	80	91,5	11	22
06601-31086	signal green RAL 6032	plastic	3	M10	14	16	21,5	23	37	10	24	53,5	58	80	91,5	11	22
06601-31087	traffic blue RAL 5017	plastic	3	M10	14	16	21,5	23	37	10	24	53,5	58	80	91,5	11	22
06601-31088	light grey RAL 7035	plastic	3	M10	14	16	21,5	23	37	10	24	53,5	58	80	91,5	11	22
06601-4101	black grey RAL 7021	plastic	4	M10	17	19	25,5	27,5	43	10	26	61	66	95	109	13	24
06601-4102	orange RAL 2004	plastic	4	M10	17	19	25,5	27,5	43	10	26	61	66	95	109	13	24
06601-41016	colza yellow RAL 1021	plastic	4	M10	17	19	25,5	27,5	43	10	26	61	66	95	109	13	24
06601-41084	traffic red RAL 3020	plastic	4	M10	17	19	25,5	27,5	43	10	26	61	66	95	109	13	24
06601-41086	signal green RAL 6032	plastic	4	M10	17	19	25,5	27,5	43	10	26	61	66	95	109	13	24
06601-41087	traffic blue RAL 5017	plastic	4	M10	17	19	25,5	27,5	43	10	26	61	66	95	109	13	24
06601-41088	light grey RAL 7035	plastic	4	M10	17	19	25,5	27,5	43	10	26	61	66	95	109	13	24
06601-4121	black grey RAL 7021	plastic	4	M12	17	19	25,5	27,5	43	10	26	61	66	95	109	13	24
06601-4122	orange RAL 2004	plastic	4	M12	17	19	25,5	27,5	43	10	26	61	66	95	109	13	24
06601-41216	colza yellow RAL 1021	plastic	4	M12	17	19	25,5	27,5	43	10	26	61	66	95	109	13	24
06601-41284	traffic red RAL 3020	plastic	4	M12	17	19	25,5	27,5	43	10	26	61	66	95	109	13	24
06601-41286	signal green RAL 6032	plastic	4	M12	17	19	25,5	27,5	43	10	26	61	66	95	109	13	24
06601-41287	traffic blue RAL 5017	plastic	4	M12	17	19	25,5	27,5	43	10	26	61	66	95	109	13	24
06601-41288	light grey RAL 7035	plastic	4	M12	17	19	25,5	27,5	43	10	26	61	66	95	109	13	24
06601-5121	black grey RAL 7021	plastic	5	M12	23	23	30	32,5	49	12	33	72	77	110	126	15,5	26
06601-5122	orange RAL 2004	plastic	5	M12	23	23	30	32,5	49	12	33	72	77	110	126	15,5	26
06601-51216	colza yellow RAL 1021	plastic	5	M12	23	23	30	32,5	49	12	33	72	77	110	126	15,5	26
06601-51284	traffic red RAL 3020	plastic	5	M12	23	23	30	32,5	49	12	33	72	77	110	126	15,5	26
06601-51286	signal green RAL 6032	plastic	5	M12	23	23	30	32,5	49	12	33	72	77	110	126	15,5	26
06601-51287	traffic blue RAL 5017	plastic	5	M12	23	23	30	32,5	49	12	33	72	77	110	126	15,5	26
06601-51288	light grey RAL 7035	plastic	5	M12	23	23	30	32,5	49	12	33	72	77	110	126	15,5	26
06601-5161	black grey RAL 7021	plastic	5	M16	23	23	30	32,5	49	12	33	72	77	110	126	15,5	26
06601-5162	orange RAL 2004	plastic	5	M16	23	23	30	32,5	49	12	33	72	77	110	126	15,5	26
06601-51616	colza yellow RAL 1021	plastic	5	M16	23	23	30	32,5	49	12	33	72	77	110	126	15,5	26
06601-51684	traffic red RAL 3020	plastic	5	M16	23	23	30	32,5	49	12	33	72	77	110	126	15,5	26
06601-51686	signal green RAL 6032	plastic	5	M16	23	23	30	32,5	49	12	33	72	77	110	126	15,5	26
06601-51687	traffic blue RAL 5017	plastic	5	M16	23	23	30	32,5	49	12	33	72	77	110	126	15,5	26
06601-51688	light grey RAL 7035	plastic	5	M16	23	23	30	32,5	49	12	33	72	77	110	126	15,5	26