


Item description/product images

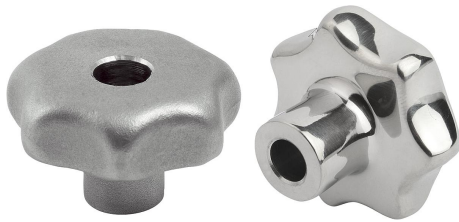

Description

Material:

Stainless steel 1.4308.


Version:

Ground and polished or blasted.

On request:

With external thread.

Drawings

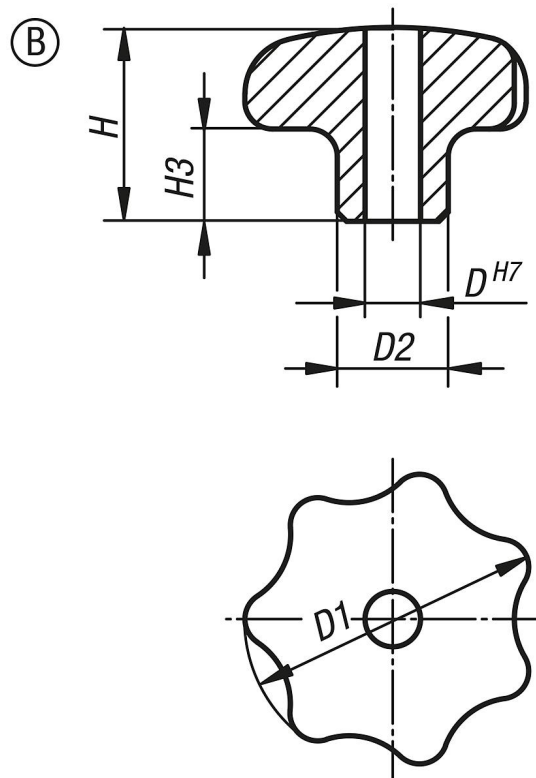

Overview of items

Order No.	Form	Surface finish body	D	D1	D2	H	H3
06194-232062	B	polished	6	32	12	21	10
06194-240082	B	polished	8	40	14	26	13
06194-250102	B	polished	10	50	18	34	17
06194-263122	B	polished	12	63	20	42	21
06194-232063	B	blasted	6	32	12	21	10
06194-240083	B	blasted	8	40	14	26	13
06194-250103	B	blasted	10	50	18	34	17
06194-263123	B	blasted	12	63	20	42	21

