


Item description/product images

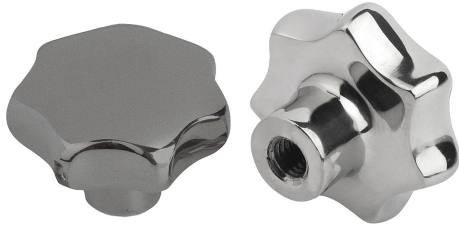

Description

Material:

Stainless steel 1.4308.


Version:

Ground and polished or blasted.

On request:

With external thread.

Drawings

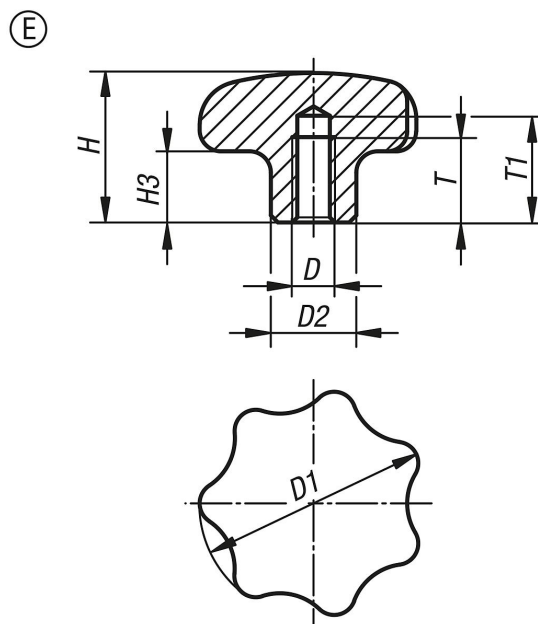

Overview of items

Order No.	Form	Surface finish body	D	D1	D2	H	H3	T	T1
06194-532062	E	polished	M6	32	12	21	10	12	15
06194-540082	E	polished	M8	40	14	26	13	15	18
06194-550102	E	polished	M10	50	18	34	17	18	21
06194-563122	E	polished	M12	63	20	42	21	22	25
06194-532063	E	blasted	M6	32	12	21	10	12	15
06194-540083	E	blasted	M8	40	14	26	13	15	18
06194-550103	E	blasted	M10	50	18	34	17	18	21
06194-563123	E	blasted	M12	63	20	42	21	22	25