

Item description/product images



examples of grip cap designs



Description

Material:

Black thermoplastic.
Bush and screw steel.

Version:

Bush and screw trivalent blue passivated.

Note:

Δ Add the desired cap colour code here. No colour code is required for black caps.


On request:

Other colours or designs, such as company logo.

Drawing reference:

- Form D: tapped bush without cap
- Form G: without bush
- Form H: with reamed bush
- Form K: tapped bush with cap
- Form L: external thread
- Form S: hexagon

Drawings

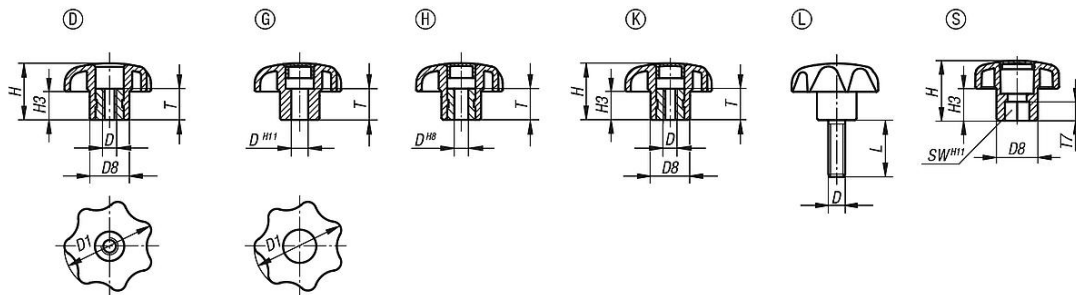

Overview of items

| Order No. | Form | Colour Cap | D | D1 | D8 | H | H3 | L | SW | T | T7 |
|------------|------|-----------------------|-----|----|----|----|----|---|----|----|----|
| 06220-504 | D | - | M4 | 25 | 12 | 16 | 8 | - | - | 10 | - |
| 06220-505 | D | - | M5 | 25 | 12 | 16 | 8 | - | - | 10 | - |
| 06220-5061 | D | - | M6 | 25 | 12 | 16 | 8 | - | - | 10 | - |
| 06220-5051 | D | - | M5 | 32 | 14 | 20 | 10 | - | - | 10 | - |
| 06220-506 | D | - | M6 | 32 | 14 | 20 | 10 | - | - | 10 | - |
| 06220-508 | D | - | M8 | 40 | 18 | 25 | 13 | - | - | 14 | - |
| 06220-5101 | D | - | M10 | 40 | 18 | 25 | 13 | - | - | 14 | - |
| 06220-5081 | D | - | M8 | 50 | 22 | 32 | 17 | - | - | 14 | - |
| 06220-510 | D | - | M10 | 50 | 22 | 32 | 17 | - | - | 14 | - |
| 06220-5121 | D | - | M12 | 50 | 22 | 32 | 17 | - | - | 18 | - |
| 06220-5102 | D | - | M10 | 63 | 26 | 40 | 21 | - | - | 14 | - |
| 06220-512 | D | - | M12 | 63 | 26 | 40 | 21 | - | - | 18 | - |
| 06220-516 | D | - | M16 | 63 | 26 | 40 | 21 | - | - | 18 | - |
| 06220-305 | G | jet black | 5 | 25 | 12 | 16 | 8 | - | - | 10 | - |
| 06220-3055 | G | light grey RAL 7035 | 5 | 25 | 12 | 16 | 8 | - | - | 10 | - |
| 06220-3056 | G | traffic red RAL 3020 | 5 | 25 | 12 | 16 | 8 | - | - | 10 | - |
| 06220-3057 | G | colza yellow RAL 1021 | 5 | 25 | 12 | 16 | 8 | - | - | 10 | - |
| 06220-306 | G | jet black | 6 | 32 | 14 | 20 | 10 | - | - | 10 | - |
| 06220-3065 | G | light grey RAL 7035 | 6 | 32 | 14 | 20 | 10 | - | - | 10 | - |
| 06220-3066 | G | traffic red RAL 3020 | 6 | 32 | 14 | 20 | 10 | - | - | 10 | - |

Overview of items

| Order No. | Form | Colour Cap | D | D1 | D8 | H | H3 | L | SW | T | T7 |
|-------------|------|-----------------------|-----|----|----|----|----|---|----|----|----|
| 06220-3067 | G | colza yellow RAL 1021 | 6 | 32 | 14 | 20 | 10 | - | - | 10 | - |
| 06220-308 | G | jet black | 8 | 40 | 18 | 25 | 13 | - | - | 14 | - |
| 06220-3085 | G | light grey RAL 7035 | 8 | 40 | 18 | 25 | 13 | - | - | 14 | - |
| 06220-3086 | G | traffic red RAL 3020 | 8 | 40 | 18 | 25 | 13 | - | - | 14 | - |
| 06220-3087 | G | colza yellow RAL 1021 | 8 | 40 | 18 | 25 | 13 | - | - | 14 | - |
| 06220-310 | G | jet black | 10 | 50 | 22 | 32 | 17 | - | - | 14 | - |
| 06220-3105 | G | light grey RAL 7035 | 10 | 50 | 22 | 32 | 17 | - | - | 14 | - |
| 06220-3106 | G | traffic red RAL 3020 | 10 | 50 | 22 | 32 | 17 | - | - | 14 | - |
| 06220-3107 | G | colza yellow RAL 1021 | 10 | 50 | 22 | 32 | 17 | - | - | 14 | - |
| 06220-312 | G | jet black | 12 | 63 | 26 | 40 | 21 | - | - | 18 | - |
| 06220-3125 | G | light grey RAL 7035 | 12 | 63 | 26 | 40 | 21 | - | - | 18 | - |
| 06220-3126 | G | traffic red RAL 3020 | 12 | 63 | 26 | 40 | 21 | - | - | 18 | - |
| 06220-3127 | G | colza yellow RAL 1021 | 12 | 63 | 26 | 40 | 21 | - | - | 18 | - |
| 06220-105 | H | jet black | 5 | 25 | 12 | 16 | 8 | - | - | 10 | - |
| 06220-1055 | H | light grey RAL 7035 | 5 | 25 | 12 | 16 | 8 | - | - | 10 | - |
| 06220-1056 | H | traffic red RAL 3020 | 5 | 25 | 12 | 16 | 8 | - | - | 10 | - |
| 06220-1057 | H | colza yellow RAL 1021 | 5 | 25 | 12 | 16 | 8 | - | - | 10 | - |
| 06220-106 | H | jet black | 6 | 32 | 14 | 20 | 10 | - | - | 10 | - |
| 06220-1065 | H | light grey RAL 7035 | 6 | 32 | 14 | 20 | 10 | - | - | 10 | - |
| 06220-1066 | H | traffic red RAL 3020 | 6 | 32 | 14 | 20 | 10 | - | - | 10 | - |
| 06220-1067 | H | colza yellow RAL 1021 | 6 | 32 | 14 | 20 | 10 | - | - | 10 | - |
| 06220-108 | H | jet black | 8 | 40 | 18 | 25 | 13 | - | - | 14 | - |
| 06220-1085 | H | light grey RAL 7035 | 8 | 40 | 18 | 25 | 13 | - | - | 14 | - |
| 06220-1086 | H | traffic red RAL 3020 | 8 | 40 | 18 | 25 | 13 | - | - | 14 | - |
| 06220-1087 | H | colza yellow RAL 1021 | 8 | 40 | 18 | 25 | 13 | - | - | 14 | - |
| 06220-110 | H | jet black | 10 | 50 | 22 | 32 | 17 | - | - | 14 | - |
| 06220-1105 | H | light grey RAL 7035 | 10 | 50 | 22 | 32 | 17 | - | - | 14 | - |
| 06220-1106 | H | traffic red RAL 3020 | 10 | 50 | 22 | 32 | 17 | - | - | 14 | - |
| 06220-1107 | H | colza yellow RAL 1021 | 10 | 50 | 22 | 32 | 17 | - | - | 14 | - |
| 06220-1101 | H | jet black | 10 | 63 | 26 | 40 | 21 | - | - | 14 | - |
| 06220-11015 | H | light grey RAL 7035 | 10 | 63 | 26 | 40 | 21 | - | - | 14 | - |
| 06220-11016 | H | traffic red RAL 3020 | 10 | 63 | 26 | 40 | 21 | - | - | 14 | - |
| 06220-11017 | H | colza yellow RAL 1021 | 10 | 63 | 26 | 40 | 21 | - | - | 14 | - |
| 06220-112 | H | jet black | 12 | 63 | 26 | 40 | 21 | - | - | 18 | - |
| 06220-1125 | H | light grey RAL 7035 | 12 | 63 | 26 | 40 | 21 | - | - | 18 | - |
| 06220-1126 | H | traffic red RAL 3020 | 12 | 63 | 26 | 40 | 21 | - | - | 18 | - |
| 06220-1127 | H | colza yellow RAL 1021 | 12 | 63 | 26 | 40 | 21 | - | - | 18 | - |
| 06220-204 | K | jet black | M4 | 25 | 12 | 16 | 8 | - | - | 10 | - |
| 06220-2045 | K | light grey RAL 7035 | M4 | 25 | 12 | 16 | 8 | - | - | 10 | - |
| 06220-2046 | K | traffic red RAL 3020 | M4 | 25 | 12 | 16 | 8 | - | - | 10 | - |
| 06220-2047 | K | colza yellow RAL 1021 | M4 | 25 | 12 | 16 | 8 | - | - | 10 | - |
| 06220-205 | K | jet black | M5 | 25 | 12 | 16 | 8 | - | - | 10 | - |
| 06220-2055 | K | light grey RAL 7035 | M5 | 25 | 12 | 16 | 8 | - | - | 10 | - |
| 06220-2056 | K | traffic red RAL 3020 | M5 | 25 | 12 | 16 | 8 | - | - | 10 | - |
| 06220-2057 | K | colza yellow RAL 1021 | M5 | 25 | 12 | 16 | 8 | - | - | 10 | - |
| 06220-2061 | K | jet black | M6 | 25 | 12 | 16 | 8 | - | - | 10 | - |
| 06220-20615 | K | light grey RAL 7035 | M6 | 25 | 12 | 16 | 8 | - | - | 10 | - |
| 06220-20616 | K | traffic red RAL 3020 | M6 | 25 | 12 | 16 | 8 | - | - | 10 | - |
| 06220-20617 | K | colza yellow RAL 1021 | M6 | 25 | 12 | 16 | 8 | - | - | 10 | - |
| 06220-2051 | K | jet black | M5 | 32 | 14 | 20 | 10 | - | - | 10 | - |
| 06220-20515 | K | light grey RAL 7035 | M5 | 32 | 14 | 20 | 10 | - | - | 10 | - |
| 06220-20516 | K | traffic red RAL 3020 | M5 | 32 | 14 | 20 | 10 | - | - | 10 | - |
| 06220-20517 | K | colza yellow RAL 1021 | M5 | 32 | 14 | 20 | 10 | - | - | 10 | - |
| 06220-206 | K | jet black | M6 | 32 | 14 | 20 | 10 | - | - | 10 | - |
| 06220-2065 | K | light grey RAL 7035 | M6 | 32 | 14 | 20 | 10 | - | - | 10 | - |
| 06220-2066 | K | traffic red RAL 3020 | M6 | 32 | 14 | 20 | 10 | - | - | 10 | - |
| 06220-2067 | K | colza yellow RAL 1021 | M6 | 32 | 14 | 20 | 10 | - | - | 10 | - |
| 06220-208 | K | jet black | M8 | 40 | 18 | 25 | 13 | - | - | 14 | - |
| 06220-2085 | K | light grey RAL 7035 | M8 | 40 | 18 | 25 | 13 | - | - | 14 | - |
| 06220-2086 | K | traffic red RAL 3020 | M8 | 40 | 18 | 25 | 13 | - | - | 14 | - |
| 06220-2087 | K | colza yellow RAL 1021 | M8 | 40 | 18 | 25 | 13 | - | - | 14 | - |
| 06220-2101 | K | jet black | M10 | 40 | 18 | 25 | 13 | - | - | 14 | - |
| 06220-21015 | K | light grey RAL 7035 | M10 | 40 | 18 | 25 | 13 | - | - | 14 | - |
| 06220-21016 | K | traffic red RAL 3020 | M10 | 40 | 18 | 25 | 13 | - | - | 14 | - |
| 06220-21017 | K | colza yellow RAL 1021 | M10 | 40 | 18 | 25 | 13 | - | - | 14 | - |

Overview of items

| Order No. | Form | Colour Cap | D | D1 | D8 | H | H3 | L | SW | T | T7 |
|---------------|------|-----------------------|-----|----|----|----|----|----|----|----|----|
| 06220-2081 | K | jet black | M8 | 50 | 22 | 32 | 17 | - | - | 14 | - |
| 06220-20815 | K | light grey RAL 7035 | M8 | 50 | 22 | 32 | 17 | - | - | 14 | - |
| 06220-20816 | K | traffic red RAL 3020 | M8 | 50 | 22 | 32 | 17 | - | - | 14 | - |
| 06220-20817 | K | colza yellow RAL 1021 | M8 | 50 | 22 | 32 | 17 | - | - | 14 | - |
| 06220-210 | K | jet black | M10 | 50 | 22 | 32 | 17 | - | - | 14 | - |
| 06220-2105 | K | light grey RAL 7035 | M10 | 50 | 22 | 32 | 17 | - | - | 14 | - |
| 06220-2106 | K | traffic red RAL 3020 | M10 | 50 | 22 | 32 | 17 | - | - | 14 | - |
| 06220-2107 | K | colza yellow RAL 1021 | M10 | 50 | 22 | 32 | 17 | - | - | 14 | - |
| 06220-2121 | K | jet black | M12 | 50 | 22 | 32 | 17 | - | - | 18 | - |
| 06220-21215 | K | light grey RAL 7035 | M12 | 50 | 22 | 32 | 17 | - | - | 18 | - |
| 06220-21216 | K | traffic red RAL 3020 | M12 | 50 | 22 | 32 | 17 | - | - | 18 | - |
| 06220-21217 | K | colza yellow RAL 1021 | M12 | 50 | 22 | 32 | 17 | - | - | 18 | - |
| 06220-2102 | K | jet black | M10 | 63 | 26 | 40 | 21 | - | - | 14 | - |
| 06220-21025 | K | light grey RAL 7035 | M10 | 63 | 26 | 40 | 21 | - | - | 14 | - |
| 06220-21026 | K | traffic red RAL 3020 | M10 | 63 | 26 | 40 | 21 | - | - | 14 | - |
| 06220-21027 | K | colza yellow RAL 1021 | M10 | 63 | 26 | 40 | 21 | - | - | 14 | - |
| 06220-212 | K | jet black | M12 | 63 | 26 | 40 | 21 | - | - | 18 | - |
| 06220-2125 | K | light grey RAL 7035 | M12 | 63 | 26 | 40 | 21 | - | - | 18 | - |
| 06220-2126 | K | traffic red RAL 3020 | M12 | 63 | 26 | 40 | 21 | - | - | 18 | - |
| 06220-2127 | K | colza yellow RAL 1021 | M12 | 63 | 26 | 40 | 21 | - | - | 18 | - |
| 06220-216 | K | jet black | M16 | 63 | 26 | 40 | 21 | - | - | 18 | - |
| 06220-2165 | K | light grey RAL 7035 | M16 | 63 | 26 | 40 | 21 | - | - | 18 | - |
| 06220-2166 | K | traffic red RAL 3020 | M16 | 63 | 26 | 40 | 21 | - | - | 18 | - |
| 06220-2167 | K | colza yellow RAL 1021 | M16 | 63 | 26 | 40 | 21 | - | - | 18 | - |
| 06220-405X10 | L | jet black | M5 | 25 | 12 | 16 | 8 | 10 | - | - | - |
| 06220-4055X10 | L | light grey RAL 7035 | M5 | 25 | 12 | 16 | 8 | 10 | - | - | - |
| 06220-4056X10 | L | traffic red RAL 3020 | M5 | 25 | 12 | 16 | 8 | 10 | - | - | - |
| 06220-4057X10 | L | colza yellow RAL 1021 | M5 | 25 | 12 | 16 | 8 | 10 | - | - | - |
| 06220-405X15 | L | jet black | M5 | 25 | 12 | 16 | 8 | 15 | - | - | - |
| 06220-4055X15 | L | light grey RAL 7035 | M5 | 25 | 12 | 16 | 8 | 15 | - | - | - |
| 06220-4056X15 | L | traffic red RAL 3020 | M5 | 25 | 12 | 16 | 8 | 15 | - | - | - |
| 06220-4057X15 | L | colza yellow RAL 1021 | M5 | 25 | 12 | 16 | 8 | 15 | - | - | - |
| 06220-405X20 | L | jet black | M5 | 25 | 12 | 16 | 8 | 20 | - | - | - |
| 06220-4055X20 | L | light grey RAL 7035 | M5 | 25 | 12 | 16 | 8 | 20 | - | - | - |
| 06220-4056X20 | L | traffic red RAL 3020 | M5 | 25 | 12 | 16 | 8 | 20 | - | - | - |
| 06220-4057X20 | L | colza yellow RAL 1021 | M5 | 25 | 12 | 16 | 8 | 20 | - | - | - |
| 06220-405X25 | L | jet black | M5 | 25 | 12 | 16 | 8 | 25 | - | - | - |
| 06220-4055X25 | L | light grey RAL 7035 | M5 | 25 | 12 | 16 | 8 | 25 | - | - | - |
| 06220-4056X25 | L | traffic red RAL 3020 | M5 | 25 | 12 | 16 | 8 | 25 | - | - | - |
| 06220-4057X25 | L | colza yellow RAL 1021 | M5 | 25 | 12 | 16 | 8 | 25 | - | - | - |
| 06220-405X30 | L | jet black | M5 | 25 | 12 | 16 | 8 | 30 | - | - | - |
| 06220-4055X30 | L | light grey RAL 7035 | M5 | 25 | 12 | 16 | 8 | 30 | - | - | - |
| 06220-4056X30 | L | traffic red RAL 3020 | M5 | 25 | 12 | 16 | 8 | 30 | - | - | - |
| 06220-4057X30 | L | colza yellow RAL 1021 | M5 | 25 | 12 | 16 | 8 | 30 | - | - | - |
| 06220-405X35 | L | jet black | M5 | 25 | 12 | 16 | 8 | 35 | - | - | - |
| 06220-4055X35 | L | light grey RAL 7035 | M5 | 25 | 12 | 16 | 8 | 35 | - | - | - |
| 06220-4056X35 | L | traffic red RAL 3020 | M5 | 25 | 12 | 16 | 8 | 35 | - | - | - |
| 06220-4057X35 | L | colza yellow RAL 1021 | M5 | 25 | 12 | 16 | 8 | 35 | - | - | - |
| 06220-405X40 | L | jet black | M5 | 25 | 12 | 16 | 8 | 40 | - | - | - |
| 06220-4055X40 | L | light grey RAL 7035 | M5 | 25 | 12 | 16 | 8 | 40 | - | - | - |
| 06220-4056X40 | L | traffic red RAL 3020 | M5 | 25 | 12 | 16 | 8 | 40 | - | - | - |
| 06220-4057X40 | L | colza yellow RAL 1021 | M5 | 25 | 12 | 16 | 8 | 40 | - | - | - |
| 06220-405X45 | L | jet black | M5 | 25 | 12 | 16 | 8 | 45 | - | - | - |
| 06220-4055X45 | L | light grey RAL 7035 | M5 | 25 | 12 | 16 | 8 | 45 | - | - | - |
| 06220-4056X45 | L | traffic red RAL 3020 | M5 | 25 | 12 | 16 | 8 | 45 | - | - | - |
| 06220-4057X45 | L | colza yellow RAL 1021 | M5 | 25 | 12 | 16 | 8 | 45 | - | - | - |
| 06220-405X50 | L | jet black | M5 | 25 | 12 | 16 | 8 | 50 | - | - | - |
| 06220-4055X50 | L | light grey RAL 7035 | M5 | 25 | 12 | 16 | 8 | 50 | - | - | - |
| 06220-4056X50 | L | traffic red RAL 3020 | M5 | 25 | 12 | 16 | 8 | 50 | - | - | - |
| 06220-4057X50 | L | colza yellow RAL 1021 | M5 | 25 | 12 | 16 | 8 | 50 | - | - | - |
| 06220-405X60 | L | jet black | M5 | 25 | 12 | 16 | 8 | 60 | - | - | - |
| 06220-4055X60 | L | light grey RAL 7035 | M5 | 25 | 12 | 16 | 8 | 60 | - | - | - |
| 06220-4056X60 | L | traffic red RAL 3020 | M5 | 25 | 12 | 16 | 8 | 60 | - | - | - |
| 06220-4057X60 | L | colza yellow RAL 1021 | M5 | 25 | 12 | 16 | 8 | 60 | - | - | - |
| 06220-406X10 | L | jet black | M6 | 25 | 12 | 16 | 8 | 10 | - | - | - |

Overview of items

| Order No. | Form | Colour Cap | D | D1 | D8 | H | H3 | L | SW | T | T7 |
|----------------|------|-----------------------|----|----|----|----|----|----|----|---|----|
| 06220-4065X10 | L | light grey RAL 7035 | M6 | 25 | 12 | 16 | 8 | 10 | - | - | - |
| 06220-4066X10 | L | traffic red RAL 3020 | M6 | 25 | 12 | 16 | 8 | 10 | - | - | - |
| 06220-4067X10 | L | colza yellow RAL 1021 | M6 | 25 | 12 | 16 | 8 | 10 | - | - | - |
| 06220-406X15 | L | jet black | M6 | 25 | 12 | 16 | 8 | 15 | - | - | - |
| 06220-4065X15 | L | light grey RAL 7035 | M6 | 25 | 12 | 16 | 8 | 15 | - | - | - |
| 06220-4066X15 | L | traffic red RAL 3020 | M6 | 25 | 12 | 16 | 8 | 15 | - | - | - |
| 06220-4067X15 | L | colza yellow RAL 1021 | M6 | 25 | 12 | 16 | 8 | 15 | - | - | - |
| 06220-406X20 | L | jet black | M6 | 25 | 12 | 16 | 8 | 20 | - | - | - |
| 06220-4065X20 | L | light grey RAL 7035 | M6 | 25 | 12 | 16 | 8 | 20 | - | - | - |
| 06220-4066X20 | L | traffic red RAL 3020 | M6 | 25 | 12 | 16 | 8 | 20 | - | - | - |
| 06220-4067X20 | L | colza yellow RAL 1021 | M6 | 25 | 12 | 16 | 8 | 20 | - | - | - |
| 06220-406X25 | L | jet black | M6 | 25 | 12 | 16 | 8 | 25 | - | - | - |
| 06220-4065X25 | L | light grey RAL 7035 | M6 | 25 | 12 | 16 | 8 | 25 | - | - | - |
| 06220-4066X25 | L | traffic red RAL 3020 | M6 | 25 | 12 | 16 | 8 | 25 | - | - | - |
| 06220-4067X25 | L | colza yellow RAL 1021 | M6 | 25 | 12 | 16 | 8 | 25 | - | - | - |
| 06220-406X30 | L | jet black | M6 | 25 | 12 | 16 | 8 | 30 | - | - | - |
| 06220-4065X30 | L | light grey RAL 7035 | M6 | 25 | 12 | 16 | 8 | 30 | - | - | - |
| 06220-4066X30 | L | traffic red RAL 3020 | M6 | 25 | 12 | 16 | 8 | 30 | - | - | - |
| 06220-4067X30 | L | colza yellow RAL 1021 | M6 | 25 | 12 | 16 | 8 | 30 | - | - | - |
| 06220-406X35 | L | jet black | M6 | 25 | 12 | 16 | 8 | 35 | - | - | - |
| 06220-4065X35 | L | light grey RAL 7035 | M6 | 25 | 12 | 16 | 8 | 35 | - | - | - |
| 06220-4066X35 | L | traffic red RAL 3020 | M6 | 25 | 12 | 16 | 8 | 35 | - | - | - |
| 06220-4067X35 | L | colza yellow RAL 1021 | M6 | 25 | 12 | 16 | 8 | 35 | - | - | - |
| 06220-406X40 | L | jet black | M6 | 25 | 12 | 16 | 8 | 40 | - | - | - |
| 06220-4065X40 | L | light grey RAL 7035 | M6 | 25 | 12 | 16 | 8 | 40 | - | - | - |
| 06220-4066X40 | L | traffic red RAL 3020 | M6 | 25 | 12 | 16 | 8 | 40 | - | - | - |
| 06220-4067X40 | L | colza yellow RAL 1021 | M6 | 25 | 12 | 16 | 8 | 40 | - | - | - |
| 06220-406X45 | L | jet black | M6 | 25 | 12 | 16 | 8 | 45 | - | - | - |
| 06220-4065X45 | L | light grey RAL 7035 | M6 | 25 | 12 | 16 | 8 | 45 | - | - | - |
| 06220-4066X45 | L | traffic red RAL 3020 | M6 | 25 | 12 | 16 | 8 | 45 | - | - | - |
| 06220-4067X45 | L | colza yellow RAL 1021 | M6 | 25 | 12 | 16 | 8 | 45 | - | - | - |
| 06220-406X50 | L | jet black | M6 | 25 | 12 | 16 | 8 | 50 | - | - | - |
| 06220-4065X50 | L | light grey RAL 7035 | M6 | 25 | 12 | 16 | 8 | 50 | - | - | - |
| 06220-4066X50 | L | traffic red RAL 3020 | M6 | 25 | 12 | 16 | 8 | 50 | - | - | - |
| 06220-4067X50 | L | colza yellow RAL 1021 | M6 | 25 | 12 | 16 | 8 | 50 | - | - | - |
| 06220-406X60 | L | jet black | M6 | 25 | 12 | 16 | 8 | 60 | - | - | - |
| 06220-4065X60 | L | light grey RAL 7035 | M6 | 25 | 12 | 16 | 8 | 60 | - | - | - |
| 06220-4066X60 | L | traffic red RAL 3020 | M6 | 25 | 12 | 16 | 8 | 60 | - | - | - |
| 06220-4067X60 | L | colza yellow RAL 1021 | M6 | 25 | 12 | 16 | 8 | 60 | - | - | - |
| 06220-4061X10 | L | jet black | M6 | 32 | 14 | 20 | 10 | 10 | - | - | - |
| 06220-40615X10 | L | light grey RAL 7035 | M6 | 32 | 14 | 20 | 10 | 10 | - | - | - |
| 06220-40616X10 | L | traffic red RAL 3020 | M6 | 32 | 14 | 20 | 10 | 10 | - | - | - |
| 06220-40617X10 | L | colza yellow RAL 1021 | M6 | 32 | 14 | 20 | 10 | 10 | - | - | - |
| 06220-4061X15 | L | jet black | M6 | 32 | 14 | 20 | 10 | 15 | - | - | - |
| 06220-40615X15 | L | light grey RAL 7035 | M6 | 32 | 14 | 20 | 10 | 15 | - | - | - |
| 06220-40616X15 | L | traffic red RAL 3020 | M6 | 32 | 14 | 20 | 10 | 15 | - | - | - |
| 06220-40617X15 | L | colza yellow RAL 1021 | M6 | 32 | 14 | 20 | 10 | 15 | - | - | - |
| 06220-4061X20 | L | jet black | M6 | 32 | 14 | 20 | 10 | 20 | - | - | - |
| 06220-40615X20 | L | light grey RAL 7035 | M6 | 32 | 14 | 20 | 10 | 20 | - | - | - |
| 06220-40616X20 | L | traffic red RAL 3020 | M6 | 32 | 14 | 20 | 10 | 20 | - | - | - |
| 06220-40617X20 | L | colza yellow RAL 1021 | M6 | 32 | 14 | 20 | 10 | 20 | - | - | - |
| 06220-4061X25 | L | jet black | M6 | 32 | 14 | 20 | 10 | 25 | - | - | - |
| 06220-40615X25 | L | light grey RAL 7035 | M6 | 32 | 14 | 20 | 10 | 25 | - | - | - |
| 06220-40616X25 | L | traffic red RAL 3020 | M6 | 32 | 14 | 20 | 10 | 25 | - | - | - |
| 06220-40617X25 | L | colza yellow RAL 1021 | M6 | 32 | 14 | 20 | 10 | 25 | - | - | - |
| 06220-4061X30 | L | jet black | M6 | 32 | 14 | 20 | 10 | 30 | - | - | - |
| 06220-40615X30 | L | light grey RAL 7035 | M6 | 32 | 14 | 20 | 10 | 30 | - | - | - |
| 06220-40616X30 | L | traffic red RAL 3020 | M6 | 32 | 14 | 20 | 10 | 30 | - | - | - |
| 06220-40617X30 | L | colza yellow RAL 1021 | M6 | 32 | 14 | 20 | 10 | 30 | - | - | - |
| 06220-4061X35 | L | jet black | M6 | 32 | 14 | 20 | 10 | 35 | - | - | - |
| 06220-40615X35 | L | light grey RAL 7035 | M6 | 32 | 14 | 20 | 10 | 35 | - | - | - |
| 06220-40616X35 | L | traffic red RAL 3020 | M6 | 32 | 14 | 20 | 10 | 35 | - | - | - |
| 06220-40617X35 | L | colza yellow RAL 1021 | M6 | 32 | 14 | 20 | 10 | 35 | - | - | - |
| 06220-4061X40 | L | jet black | M6 | 32 | 14 | 20 | 10 | 40 | - | - | - |
| 06220-40615X40 | L | light grey RAL 7035 | M6 | 32 | 14 | 20 | 10 | 40 | - | - | - |

Overview of items

| Order No. | Form | Colour Cap | D | D1 | D8 | H | H3 | L | SW | T | T7 |
|----------------|------|-----------------------|----|----|----|----|----|----|----|---|----|
| 06220-40616X40 | L | traffic red RAL 3020 | M6 | 32 | 14 | 20 | 10 | 40 | - | - | - |
| 06220-40617X40 | L | colza yellow RAL 1021 | M6 | 32 | 14 | 20 | 10 | 40 | - | - | - |
| 06220-4061X45 | L | jet black | M6 | 32 | 14 | 20 | 10 | 45 | - | - | - |
| 06220-40615X45 | L | light grey RAL 7035 | M6 | 32 | 14 | 20 | 10 | 45 | - | - | - |
| 06220-40616X45 | L | traffic red RAL 3020 | M6 | 32 | 14 | 20 | 10 | 45 | - | - | - |
| 06220-40617X45 | L | colza yellow RAL 1021 | M6 | 32 | 14 | 20 | 10 | 45 | - | - | - |
| 06220-4061X50 | L | jet black | M6 | 32 | 14 | 20 | 10 | 50 | - | - | - |
| 06220-40615X50 | L | light grey RAL 7035 | M6 | 32 | 14 | 20 | 10 | 50 | - | - | - |
| 06220-40616X50 | L | traffic red RAL 3020 | M6 | 32 | 14 | 20 | 10 | 50 | - | - | - |
| 06220-40617X50 | L | colza yellow RAL 1021 | M6 | 32 | 14 | 20 | 10 | 50 | - | - | - |
| 06220-4061X60 | L | jet black | M6 | 32 | 14 | 20 | 10 | 60 | - | - | - |
| 06220-40615X60 | L | light grey RAL 7035 | M6 | 32 | 14 | 20 | 10 | 60 | - | - | - |
| 06220-40616X60 | L | traffic red RAL 3020 | M6 | 32 | 14 | 20 | 10 | 60 | - | - | - |
| 06220-40617X60 | L | colza yellow RAL 1021 | M6 | 32 | 14 | 20 | 10 | 60 | - | - | - |
| 06220-408X15 | L | jet black | M8 | 32 | 14 | 20 | 10 | 15 | - | - | - |
| 06220-4085X15 | L | light grey RAL 7035 | M8 | 32 | 14 | 20 | 10 | 15 | - | - | - |
| 06220-4086X15 | L | traffic red RAL 3020 | M8 | 32 | 14 | 20 | 10 | 15 | - | - | - |
| 06220-4087X15 | L | colza yellow RAL 1021 | M8 | 32 | 14 | 20 | 10 | 15 | - | - | - |
| 06220-408X20 | L | jet black | M8 | 32 | 14 | 20 | 10 | 20 | - | - | - |
| 06220-4085X20 | L | light grey RAL 7035 | M8 | 32 | 14 | 20 | 10 | 20 | - | - | - |
| 06220-4086X20 | L | traffic red RAL 3020 | M8 | 32 | 14 | 20 | 10 | 20 | - | - | - |
| 06220-4087X20 | L | colza yellow RAL 1021 | M8 | 32 | 14 | 20 | 10 | 20 | - | - | - |
| 06220-408X25 | L | jet black | M8 | 32 | 14 | 20 | 10 | 25 | - | - | - |
| 06220-4085X25 | L | light grey RAL 7035 | M8 | 32 | 14 | 20 | 10 | 25 | - | - | - |
| 06220-4086X25 | L | traffic red RAL 3020 | M8 | 32 | 14 | 20 | 10 | 25 | - | - | - |
| 06220-4087X25 | L | colza yellow RAL 1021 | M8 | 32 | 14 | 20 | 10 | 25 | - | - | - |
| 06220-408X30 | L | jet black | M8 | 32 | 14 | 20 | 10 | 30 | - | - | - |
| 06220-4085X30 | L | light grey RAL 7035 | M8 | 32 | 14 | 20 | 10 | 30 | - | - | - |
| 06220-4086X30 | L | traffic red RAL 3020 | M8 | 32 | 14 | 20 | 10 | 30 | - | - | - |
| 06220-4087X30 | L | colza yellow RAL 1021 | M8 | 32 | 14 | 20 | 10 | 30 | - | - | - |
| 06220-408X35 | L | jet black | M8 | 32 | 14 | 20 | 10 | 35 | - | - | - |
| 06220-4085X35 | L | light grey RAL 7035 | M8 | 32 | 14 | 20 | 10 | 35 | - | - | - |
| 06220-4086X35 | L | traffic red RAL 3020 | M8 | 32 | 14 | 20 | 10 | 35 | - | - | - |
| 06220-4087X35 | L | colza yellow RAL 1021 | M8 | 32 | 14 | 20 | 10 | 35 | - | - | - |
| 06220-408X40 | L | jet black | M8 | 32 | 14 | 20 | 10 | 40 | - | - | - |
| 06220-4085X40 | L | light grey RAL 7035 | M8 | 32 | 14 | 20 | 10 | 40 | - | - | - |
| 06220-4086X40 | L | traffic red RAL 3020 | M8 | 32 | 14 | 20 | 10 | 40 | - | - | - |
| 06220-4087X40 | L | colza yellow RAL 1021 | M8 | 32 | 14 | 20 | 10 | 40 | - | - | - |
| 06220-408X45 | L | jet black | M8 | 32 | 14 | 20 | 10 | 45 | - | - | - |
| 06220-4085X45 | L | light grey RAL 7035 | M8 | 32 | 14 | 20 | 10 | 45 | - | - | - |
| 06220-4086X45 | L | traffic red RAL 3020 | M8 | 32 | 14 | 20 | 10 | 45 | - | - | - |
| 06220-4087X45 | L | colza yellow RAL 1021 | M8 | 32 | 14 | 20 | 10 | 45 | - | - | - |
| 06220-408X50 | L | jet black | M8 | 32 | 14 | 20 | 10 | 50 | - | - | - |
| 06220-4085X50 | L | light grey RAL 7035 | M8 | 32 | 14 | 20 | 10 | 50 | - | - | - |
| 06220-4086X50 | L | traffic red RAL 3020 | M8 | 32 | 14 | 20 | 10 | 50 | - | - | - |
| 06220-4087X50 | L | colza yellow RAL 1021 | M8 | 32 | 14 | 20 | 10 | 50 | - | - | - |
| 06220-408X60 | L | jet black | M8 | 32 | 14 | 20 | 10 | 60 | - | - | - |
| 06220-4085X60 | L | light grey RAL 7035 | M8 | 32 | 14 | 20 | 10 | 60 | - | - | - |
| 06220-4086X60 | L | traffic red RAL 3020 | M8 | 32 | 14 | 20 | 10 | 60 | - | - | - |
| 06220-4087X60 | L | colza yellow RAL 1021 | M8 | 32 | 14 | 20 | 10 | 60 | - | - | - |
| 06220-4081X15 | L | jet black | M8 | 40 | 18 | 25 | 13 | 15 | - | - | - |
| 06220-40815X15 | L | light grey RAL 7035 | M8 | 40 | 18 | 25 | 13 | 15 | - | - | - |
| 06220-40816X15 | L | traffic red RAL 3020 | M8 | 40 | 18 | 25 | 13 | 15 | - | - | - |
| 06220-40817X15 | L | colza yellow RAL 1021 | M8 | 40 | 18 | 25 | 13 | 15 | - | - | - |
| 06220-4081X20 | L | jet black | M8 | 40 | 18 | 25 | 13 | 20 | - | - | - |
| 06220-40815X20 | L | light grey RAL 7035 | M8 | 40 | 18 | 25 | 13 | 20 | - | - | - |
| 06220-40816X20 | L | traffic red RAL 3020 | M8 | 40 | 18 | 25 | 13 | 20 | - | - | - |
| 06220-40817X20 | L | colza yellow RAL 1021 | M8 | 40 | 18 | 25 | 13 | 20 | - | - | - |
| 06220-4081X25 | L | jet black | M8 | 40 | 18 | 25 | 13 | 25 | - | - | - |
| 06220-40815X25 | L | light grey RAL 7035 | M8 | 40 | 18 | 25 | 13 | 25 | - | - | - |
| 06220-40816X25 | L | traffic red RAL 3020 | M8 | 40 | 18 | 25 | 13 | 25 | - | - | - |
| 06220-40817X25 | L | colza yellow RAL 1021 | M8 | 40 | 18 | 25 | 13 | 25 | - | - | - |
| 06220-4081X30 | L | jet black | M8 | 40 | 18 | 25 | 13 | 30 | - | - | - |
| 06220-40815X30 | L | light grey RAL 7035 | M8 | 40 | 18 | 25 | 13 | 30 | - | - | - |
| 06220-40816X30 | L | traffic red RAL 3020 | M8 | 40 | 18 | 25 | 13 | 30 | - | - | - |

Overview of items

| Order No. | Form | Colour Cap | D | D1 | D8 | H | H3 | L | SW | T | T7 |
|----------------|------|-----------------------|-----|----|----|----|----|----|----|---|----|
| 06220-40817X30 | L | colza yellow RAL 1021 | M8 | 40 | 18 | 25 | 13 | 30 | - | - | - |
| 06220-4081X35 | L | jet black | M8 | 40 | 18 | 25 | 13 | 35 | - | - | - |
| 06220-40815X35 | L | light grey RAL 7035 | M8 | 40 | 18 | 25 | 13 | 35 | - | - | - |
| 06220-40816X35 | L | traffic red RAL 3020 | M8 | 40 | 18 | 25 | 13 | 35 | - | - | - |
| 06220-40817X35 | L | colza yellow RAL 1021 | M8 | 40 | 18 | 25 | 13 | 35 | - | - | - |
| 06220-4081X40 | L | jet black | M8 | 40 | 18 | 25 | 13 | 40 | - | - | - |
| 06220-40815X40 | L | light grey RAL 7035 | M8 | 40 | 18 | 25 | 13 | 40 | - | - | - |
| 06220-40816X40 | L | traffic red RAL 3020 | M8 | 40 | 18 | 25 | 13 | 40 | - | - | - |
| 06220-40817X40 | L | colza yellow RAL 1021 | M8 | 40 | 18 | 25 | 13 | 40 | - | - | - |
| 06220-4081X45 | L | jet black | M8 | 40 | 18 | 25 | 13 | 45 | - | - | - |
| 06220-40815X45 | L | light grey RAL 7035 | M8 | 40 | 18 | 25 | 13 | 45 | - | - | - |
| 06220-40816X45 | L | traffic red RAL 3020 | M8 | 40 | 18 | 25 | 13 | 45 | - | - | - |
| 06220-40817X45 | L | colza yellow RAL 1021 | M8 | 40 | 18 | 25 | 13 | 45 | - | - | - |
| 06220-4081X50 | L | jet black | M8 | 40 | 18 | 25 | 13 | 50 | - | - | - |
| 06220-40815X50 | L | light grey RAL 7035 | M8 | 40 | 18 | 25 | 13 | 50 | - | - | - |
| 06220-40816X50 | L | traffic red RAL 3020 | M8 | 40 | 18 | 25 | 13 | 50 | - | - | - |
| 06220-40817X50 | L | colza yellow RAL 1021 | M8 | 40 | 18 | 25 | 13 | 50 | - | - | - |
| 06220-4081X60 | L | jet black | M8 | 40 | 18 | 25 | 13 | 60 | - | - | - |
| 06220-40815X60 | L | light grey RAL 7035 | M8 | 40 | 18 | 25 | 13 | 60 | - | - | - |
| 06220-40816X60 | L | traffic red RAL 3020 | M8 | 40 | 18 | 25 | 13 | 60 | - | - | - |
| 06220-40817X60 | L | colza yellow RAL 1021 | M8 | 40 | 18 | 25 | 13 | 60 | - | - | - |
| 06220-410X15 | L | jet black | M10 | 40 | 18 | 25 | 13 | 15 | - | - | - |
| 06220-4105X15 | L | light grey RAL 7035 | M10 | 40 | 18 | 25 | 13 | 15 | - | - | - |
| 06220-4106X15 | L | traffic red RAL 3020 | M10 | 40 | 18 | 25 | 13 | 15 | - | - | - |
| 06220-4107X15 | L | colza yellow RAL 1021 | M10 | 40 | 18 | 25 | 13 | 15 | - | - | - |
| 06220-410X20 | L | jet black | M10 | 40 | 18 | 25 | 13 | 20 | - | - | - |
| 06220-4105X20 | L | light grey RAL 7035 | M10 | 40 | 18 | 25 | 13 | 20 | - | - | - |
| 06220-4106X20 | L | traffic red RAL 3020 | M10 | 40 | 18 | 25 | 13 | 20 | - | - | - |
| 06220-4107X20 | L | colza yellow RAL 1021 | M10 | 40 | 18 | 25 | 13 | 20 | - | - | - |
| 06220-410X25 | L | jet black | M10 | 40 | 18 | 25 | 13 | 25 | - | - | - |
| 06220-4105X25 | L | light grey RAL 7035 | M10 | 40 | 18 | 25 | 13 | 25 | - | - | - |
| 06220-4106X25 | L | traffic red RAL 3020 | M10 | 40 | 18 | 25 | 13 | 25 | - | - | - |
| 06220-4107X25 | L | colza yellow RAL 1021 | M10 | 40 | 18 | 25 | 13 | 25 | - | - | - |
| 06220-410X30 | L | jet black | M10 | 40 | 18 | 25 | 13 | 30 | - | - | - |
| 06220-4105X30 | L | light grey RAL 7035 | M10 | 40 | 18 | 25 | 13 | 30 | - | - | - |
| 06220-4106X30 | L | traffic red RAL 3020 | M10 | 40 | 18 | 25 | 13 | 30 | - | - | - |
| 06220-4107X30 | L | colza yellow RAL 1021 | M10 | 40 | 18 | 25 | 13 | 30 | - | - | - |
| 06220-410X35 | L | jet black | M10 | 40 | 18 | 25 | 13 | 35 | - | - | - |
| 06220-4105X35 | L | light grey RAL 7035 | M10 | 40 | 18 | 25 | 13 | 35 | - | - | - |
| 06220-4106X35 | L | traffic red RAL 3020 | M10 | 40 | 18 | 25 | 13 | 35 | - | - | - |
| 06220-4107X35 | L | colza yellow RAL 1021 | M10 | 40 | 18 | 25 | 13 | 35 | - | - | - |
| 06220-410X40 | L | jet black | M10 | 40 | 18 | 25 | 13 | 40 | - | - | - |
| 06220-4105X40 | L | light grey RAL 7035 | M10 | 40 | 18 | 25 | 13 | 40 | - | - | - |
| 06220-4106X40 | L | traffic red RAL 3020 | M10 | 40 | 18 | 25 | 13 | 40 | - | - | - |
| 06220-4107X40 | L | colza yellow RAL 1021 | M10 | 40 | 18 | 25 | 13 | 40 | - | - | - |
| 06220-410X45 | L | jet black | M10 | 40 | 18 | 25 | 13 | 45 | - | - | - |
| 06220-4105X45 | L | light grey RAL 7035 | M10 | 40 | 18 | 25 | 13 | 45 | - | - | - |
| 06220-4106X45 | L | traffic red RAL 3020 | M10 | 40 | 18 | 25 | 13 | 45 | - | - | - |
| 06220-4107X45 | L | colza yellow RAL 1021 | M10 | 40 | 18 | 25 | 13 | 45 | - | - | - |
| 06220-410X50 | L | jet black | M10 | 40 | 18 | 25 | 13 | 50 | - | - | - |
| 06220-4105X50 | L | light grey RAL 7035 | M10 | 40 | 18 | 25 | 13 | 50 | - | - | - |
| 06220-4106X50 | L | traffic red RAL 3020 | M10 | 40 | 18 | 25 | 13 | 50 | - | - | - |
| 06220-4107X50 | L | colza yellow RAL 1021 | M10 | 40 | 18 | 25 | 13 | 50 | - | - | - |
| 06220-410X60 | L | jet black | M10 | 40 | 18 | 25 | 13 | 60 | - | - | - |
| 06220-4105X60 | L | light grey RAL 7035 | M10 | 40 | 18 | 25 | 13 | 60 | - | - | - |
| 06220-4106X60 | L | traffic red RAL 3020 | M10 | 40 | 18 | 25 | 13 | 60 | - | - | - |
| 06220-4107X60 | L | colza yellow RAL 1021 | M10 | 40 | 18 | 25 | 13 | 60 | - | - | - |
| 06220-4101X15 | L | jet black | M10 | 50 | 22 | 32 | 17 | 15 | - | - | - |
| 06220-41015X15 | L | light grey RAL 7035 | M10 | 50 | 22 | 32 | 17 | 15 | - | - | - |
| 06220-41016X15 | L | traffic red RAL 3020 | M10 | 50 | 22 | 32 | 17 | 15 | - | - | - |
| 06220-41017X15 | L | colza yellow RAL 1021 | M10 | 50 | 22 | 32 | 17 | 15 | - | - | - |
| 06220-4101X20 | L | jet black | M10 | 50 | 22 | 32 | 17 | 20 | - | - | - |
| 06220-41015X20 | L | light grey RAL 7035 | M10 | 50 | 22 | 32 | 17 | 20 | - | - | - |
| 06220-41016X20 | L | traffic red RAL 3020 | M10 | 50 | 22 | 32 | 17 | 20 | - | - | - |
| 06220-41017X20 | L | colza yellow RAL 1021 | M10 | 50 | 22 | 32 | 17 | 20 | - | - | - |

Overview of items

| Order No. | Form | Colour Cap | D | D1 | D8 | H | H3 | L | SW | T | T7 |
|----------------|------|-----------------------|-----|----|----|----|----|----|----|---|----|
| 06220-4101X25 | L | jet black | M10 | 50 | 22 | 32 | 17 | 25 | - | - | - |
| 06220-41015X25 | L | light grey RAL 7035 | M10 | 50 | 22 | 32 | 17 | 25 | - | - | - |
| 06220-41016X25 | L | traffic red RAL 3020 | M10 | 50 | 22 | 32 | 17 | 25 | - | - | - |
| 06220-41017X25 | L | colza yellow RAL 1021 | M10 | 50 | 22 | 32 | 17 | 25 | - | - | - |
| 06220-4101X30 | L | jet black | M10 | 50 | 22 | 32 | 17 | 30 | - | - | - |
| 06220-41015X30 | L | light grey RAL 7035 | M10 | 50 | 22 | 32 | 17 | 30 | - | - | - |
| 06220-41016X30 | L | traffic red RAL 3020 | M10 | 50 | 22 | 32 | 17 | 30 | - | - | - |
| 06220-41017X30 | L | colza yellow RAL 1021 | M10 | 50 | 22 | 32 | 17 | 30 | - | - | - |
| 06220-4101X35 | L | jet black | M10 | 50 | 22 | 32 | 17 | 35 | - | - | - |
| 06220-41015X35 | L | light grey RAL 7035 | M10 | 50 | 22 | 32 | 17 | 35 | - | - | - |
| 06220-41016X35 | L | traffic red RAL 3020 | M10 | 50 | 22 | 32 | 17 | 35 | - | - | - |
| 06220-41017X35 | L | colza yellow RAL 1021 | M10 | 50 | 22 | 32 | 17 | 35 | - | - | - |
| 06220-4101X40 | L | jet black | M10 | 50 | 22 | 32 | 17 | 40 | - | - | - |
| 06220-41015X40 | L | light grey RAL 7035 | M10 | 50 | 22 | 32 | 17 | 40 | - | - | - |
| 06220-41016X40 | L | traffic red RAL 3020 | M10 | 50 | 22 | 32 | 17 | 40 | - | - | - |
| 06220-41017X40 | L | colza yellow RAL 1021 | M10 | 50 | 22 | 32 | 17 | 40 | - | - | - |
| 06220-4101X45 | L | jet black | M10 | 50 | 22 | 32 | 17 | 45 | - | - | - |
| 06220-41015X45 | L | light grey RAL 7035 | M10 | 50 | 22 | 32 | 17 | 45 | - | - | - |
| 06220-41016X45 | L | traffic red RAL 3020 | M10 | 50 | 22 | 32 | 17 | 45 | - | - | - |
| 06220-41017X45 | L | colza yellow RAL 1021 | M10 | 50 | 22 | 32 | 17 | 45 | - | - | - |
| 06220-4101X50 | L | jet black | M10 | 50 | 22 | 32 | 17 | 50 | - | - | - |
| 06220-41015X50 | L | light grey RAL 7035 | M10 | 50 | 22 | 32 | 17 | 50 | - | - | - |
| 06220-41016X50 | L | traffic red RAL 3020 | M10 | 50 | 22 | 32 | 17 | 50 | - | - | - |
| 06220-41017X50 | L | colza yellow RAL 1021 | M10 | 50 | 22 | 32 | 17 | 50 | - | - | - |
| 06220-4101X60 | L | jet black | M10 | 50 | 22 | 32 | 17 | 60 | - | - | - |
| 06220-41015X60 | L | light grey RAL 7035 | M10 | 50 | 22 | 32 | 17 | 60 | - | - | - |
| 06220-41016X60 | L | traffic red RAL 3020 | M10 | 50 | 22 | 32 | 17 | 60 | - | - | - |
| 06220-41017X60 | L | colza yellow RAL 1021 | M10 | 50 | 22 | 32 | 17 | 60 | - | - | - |
| 06220-412X15 | L | jet black | M12 | 50 | 22 | 32 | 17 | 15 | - | - | - |
| 06220-4125X15 | L | light grey RAL 7035 | M12 | 50 | 22 | 32 | 17 | 15 | - | - | - |
| 06220-4126X15 | L | traffic red RAL 3020 | M12 | 50 | 22 | 32 | 17 | 15 | - | - | - |
| 06220-4127X15 | L | colza yellow RAL 1021 | M12 | 50 | 22 | 32 | 17 | 15 | - | - | - |
| 06220-412X20 | L | jet black | M12 | 50 | 22 | 32 | 17 | 20 | - | - | - |
| 06220-4125X20 | L | light grey RAL 7035 | M12 | 50 | 22 | 32 | 17 | 20 | - | - | - |
| 06220-4126X20 | L | traffic red RAL 3020 | M12 | 50 | 22 | 32 | 17 | 20 | - | - | - |
| 06220-4127X20 | L | colza yellow RAL 1021 | M12 | 50 | 22 | 32 | 17 | 20 | - | - | - |
| 06220-412X25 | L | jet black | M12 | 50 | 22 | 32 | 17 | 25 | - | - | - |
| 06220-4125X25 | L | light grey RAL 7035 | M12 | 50 | 22 | 32 | 17 | 25 | - | - | - |
| 06220-4126X25 | L | traffic red RAL 3020 | M12 | 50 | 22 | 32 | 17 | 25 | - | - | - |
| 06220-4127X25 | L | colza yellow RAL 1021 | M12 | 50 | 22 | 32 | 17 | 25 | - | - | - |
| 06220-412X30 | L | jet black | M12 | 50 | 22 | 32 | 17 | 30 | - | - | - |
| 06220-4125X30 | L | light grey RAL 7035 | M12 | 50 | 22 | 32 | 17 | 30 | - | - | - |
| 06220-4126X30 | L | traffic red RAL 3020 | M12 | 50 | 22 | 32 | 17 | 30 | - | - | - |
| 06220-4127X30 | L | colza yellow RAL 1021 | M12 | 50 | 22 | 32 | 17 | 30 | - | - | - |
| 06220-412X35 | L | jet black | M12 | 50 | 22 | 32 | 17 | 35 | - | - | - |
| 06220-4125X35 | L | light grey RAL 7035 | M12 | 50 | 22 | 32 | 17 | 35 | - | - | - |
| 06220-4126X35 | L | traffic red RAL 3020 | M12 | 50 | 22 | 32 | 17 | 35 | - | - | - |
| 06220-4127X35 | L | colza yellow RAL 1021 | M12 | 50 | 22 | 32 | 17 | 35 | - | - | - |
| 06220-412X40 | L | jet black | M12 | 50 | 22 | 32 | 17 | 40 | - | - | - |
| 06220-4125X40 | L | light grey RAL 7035 | M12 | 50 | 22 | 32 | 17 | 40 | - | - | - |
| 06220-4126X40 | L | traffic red RAL 3020 | M12 | 50 | 22 | 32 | 17 | 40 | - | - | - |
| 06220-4127X40 | L | colza yellow RAL 1021 | M12 | 50 | 22 | 32 | 17 | 40 | - | - | - |
| 06220-412X45 | L | jet black | M12 | 50 | 22 | 32 | 17 | 45 | - | - | - |
| 06220-4125X45 | L | light grey RAL 7035 | M12 | 50 | 22 | 32 | 17 | 45 | - | - | - |
| 06220-4126X45 | L | traffic red RAL 3020 | M12 | 50 | 22 | 32 | 17 | 45 | - | - | - |
| 06220-4127X45 | L | colza yellow RAL 1021 | M12 | 50 | 22 | 32 | 17 | 45 | - | - | - |
| 06220-412X50 | L | jet black | M12 | 50 | 22 | 32 | 17 | 50 | - | - | - |
| 06220-4125X50 | L | light grey RAL 7035 | M12 | 50 | 22 | 32 | 17 | 50 | - | - | - |
| 06220-4126X50 | L | traffic red RAL 3020 | M12 | 50 | 22 | 32 | 17 | 50 | - | - | - |
| 06220-4127X50 | L | colza yellow RAL 1021 | M12 | 50 | 22 | 32 | 17 | 50 | - | - | - |
| 06220-412X60 | L | jet black | M12 | 50 | 22 | 32 | 17 | 60 | - | - | - |
| 06220-4125X60 | L | light grey RAL 7035 | M12 | 50 | 22 | 32 | 17 | 60 | - | - | - |
| 06220-4126X60 | L | traffic red RAL 3020 | M12 | 50 | 22 | 32 | 17 | 60 | - | - | - |
| 06220-4127X60 | L | colza yellow RAL 1021 | M12 | 50 | 22 | 32 | 17 | 60 | - | - | - |
| 06220-4102X20 | L | jet black | M10 | 63 | 26 | 40 | 21 | 20 | - | - | - |

Overview of items

| Order No. | Form | Colour Cap | D | D1 | D8 | H | H3 | L | SW | T | T7 |
|----------------|------|-----------------------|-----|----|----|----|----|----|----|---|----|
| 06220-41025X20 | L | light grey RAL 7035 | M10 | 63 | 26 | 40 | 21 | 20 | - | - | - |
| 06220-41026X20 | L | traffic red RAL 3020 | M10 | 63 | 26 | 40 | 21 | 20 | - | - | - |
| 06220-41027X20 | L | colza yellow RAL 1021 | M10 | 63 | 26 | 40 | 21 | 20 | - | - | - |
| 06220-4102X25 | L | jet black | M10 | 63 | 26 | 40 | 21 | 25 | - | - | - |
| 06220-41025X25 | L | light grey RAL 7035 | M10 | 63 | 26 | 40 | 21 | 25 | - | - | - |
| 06220-41026X25 | L | traffic red RAL 3020 | M10 | 63 | 26 | 40 | 21 | 25 | - | - | - |
| 06220-41027X25 | L | colza yellow RAL 1021 | M10 | 63 | 26 | 40 | 21 | 25 | - | - | - |
| 06220-4102X30 | L | jet black | M10 | 63 | 26 | 40 | 21 | 30 | - | - | - |
| 06220-41025X30 | L | light grey RAL 7035 | M10 | 63 | 26 | 40 | 21 | 30 | - | - | - |
| 06220-41026X30 | L | traffic red RAL 3020 | M10 | 63 | 26 | 40 | 21 | 30 | - | - | - |
| 06220-41027X30 | L | colza yellow RAL 1021 | M10 | 63 | 26 | 40 | 21 | 30 | - | - | - |
| 06220-4102X35 | L | jet black | M10 | 63 | 26 | 40 | 21 | 35 | - | - | - |
| 06220-41025X35 | L | light grey RAL 7035 | M10 | 63 | 26 | 40 | 21 | 35 | - | - | - |
| 06220-41026X35 | L | traffic red RAL 3020 | M10 | 63 | 26 | 40 | 21 | 35 | - | - | - |
| 06220-41027X35 | L | colza yellow RAL 1021 | M10 | 63 | 26 | 40 | 21 | 35 | - | - | - |
| 06220-4102X40 | L | jet black | M10 | 63 | 26 | 40 | 21 | 40 | - | - | - |
| 06220-41025X40 | L | light grey RAL 7035 | M10 | 63 | 26 | 40 | 21 | 40 | - | - | - |
| 06220-41026X40 | L | traffic red RAL 3020 | M10 | 63 | 26 | 40 | 21 | 40 | - | - | - |
| 06220-41027X40 | L | colza yellow RAL 1021 | M10 | 63 | 26 | 40 | 21 | 40 | - | - | - |
| 06220-4102X45 | L | jet black | M10 | 63 | 26 | 40 | 21 | 45 | - | - | - |
| 06220-41025X45 | L | light grey RAL 7035 | M10 | 63 | 26 | 40 | 21 | 45 | - | - | - |
| 06220-41026X45 | L | traffic red RAL 3020 | M10 | 63 | 26 | 40 | 21 | 45 | - | - | - |
| 06220-41027X45 | L | colza yellow RAL 1021 | M10 | 63 | 26 | 40 | 21 | 45 | - | - | - |
| 06220-4102X50 | L | jet black | M10 | 63 | 26 | 40 | 21 | 50 | - | - | - |
| 06220-41025X50 | L | light grey RAL 7035 | M10 | 63 | 26 | 40 | 21 | 50 | - | - | - |
| 06220-41026X50 | L | traffic red RAL 3020 | M10 | 63 | 26 | 40 | 21 | 50 | - | - | - |
| 06220-41027X50 | L | colza yellow RAL 1021 | M10 | 63 | 26 | 40 | 21 | 50 | - | - | - |
| 06220-4102X60 | L | jet black | M10 | 63 | 26 | 40 | 21 | 60 | - | - | - |
| 06220-41025X60 | L | light grey RAL 7035 | M10 | 63 | 26 | 40 | 21 | 60 | - | - | - |
| 06220-41026X60 | L | traffic red RAL 3020 | M10 | 63 | 26 | 40 | 21 | 60 | - | - | - |
| 06220-41027X60 | L | colza yellow RAL 1021 | M10 | 63 | 26 | 40 | 21 | 60 | - | - | - |
| 06220-4121X20 | L | jet black | M12 | 63 | 26 | 40 | 21 | 20 | - | - | - |
| 06220-41215X20 | L | light grey RAL 7035 | M12 | 63 | 26 | 40 | 21 | 20 | - | - | - |
| 06220-41216X20 | L | traffic red RAL 3020 | M12 | 63 | 26 | 40 | 21 | 20 | - | - | - |
| 06220-41217X20 | L | colza yellow RAL 1021 | M12 | 63 | 26 | 40 | 21 | 20 | - | - | - |
| 06220-4121X25 | L | jet black | M12 | 63 | 26 | 40 | 21 | 25 | - | - | - |
| 06220-41215X25 | L | light grey RAL 7035 | M12 | 63 | 26 | 40 | 21 | 25 | - | - | - |
| 06220-41216X25 | L | traffic red RAL 3020 | M12 | 63 | 26 | 40 | 21 | 25 | - | - | - |
| 06220-41217X25 | L | colza yellow RAL 1021 | M12 | 63 | 26 | 40 | 21 | 25 | - | - | - |
| 06220-4121X30 | L | jet black | M12 | 63 | 26 | 40 | 21 | 30 | - | - | - |
| 06220-41215X30 | L | light grey RAL 7035 | M12 | 63 | 26 | 40 | 21 | 30 | - | - | - |
| 06220-41216X30 | L | traffic red RAL 3020 | M12 | 63 | 26 | 40 | 21 | 30 | - | - | - |
| 06220-41217X30 | L | colza yellow RAL 1021 | M12 | 63 | 26 | 40 | 21 | 30 | - | - | - |
| 06220-4121X35 | L | jet black | M12 | 63 | 26 | 40 | 21 | 35 | - | - | - |
| 06220-41215X35 | L | light grey RAL 7035 | M12 | 63 | 26 | 40 | 21 | 35 | - | - | - |
| 06220-41216X35 | L | traffic red RAL 3020 | M12 | 63 | 26 | 40 | 21 | 35 | - | - | - |
| 06220-41217X35 | L | colza yellow RAL 1021 | M12 | 63 | 26 | 40 | 21 | 35 | - | - | - |
| 06220-4121X40 | L | jet black | M12 | 63 | 26 | 40 | 21 | 40 | - | - | - |
| 06220-41215X40 | L | light grey RAL 7035 | M12 | 63 | 26 | 40 | 21 | 40 | - | - | - |
| 06220-41216X40 | L | traffic red RAL 3020 | M12 | 63 | 26 | 40 | 21 | 40 | - | - | - |
| 06220-41217X40 | L | colza yellow RAL 1021 | M12 | 63 | 26 | 40 | 21 | 40 | - | - | - |
| 06220-4121X45 | L | jet black | M12 | 63 | 26 | 40 | 21 | 45 | - | - | - |
| 06220-41215X45 | L | light grey RAL 7035 | M12 | 63 | 26 | 40 | 21 | 45 | - | - | - |
| 06220-41216X45 | L | traffic red RAL 3020 | M12 | 63 | 26 | 40 | 21 | 45 | - | - | - |
| 06220-41217X45 | L | colza yellow RAL 1021 | M12 | 63 | 26 | 40 | 21 | 45 | - | - | - |
| 06220-4121X50 | L | jet black | M12 | 63 | 26 | 40 | 21 | 50 | - | - | - |
| 06220-41215X50 | L | light grey RAL 7035 | M12 | 63 | 26 | 40 | 21 | 50 | - | - | - |
| 06220-41216X50 | L | traffic red RAL 3020 | M12 | 63 | 26 | 40 | 21 | 50 | - | - | - |
| 06220-41217X50 | L | colza yellow RAL 1021 | M12 | 63 | 26 | 40 | 21 | 50 | - | - | - |
| 06220-4121X60 | L | jet black | M12 | 63 | 26 | 40 | 21 | 60 | - | - | - |
| 06220-41215X60 | L | light grey RAL 7035 | M12 | 63 | 26 | 40 | 21 | 60 | - | - | - |
| 06220-41216X60 | L | traffic red RAL 3020 | M12 | 63 | 26 | 40 | 21 | 60 | - | - | - |
| 06220-41217X60 | L | colza yellow RAL 1021 | M12 | 63 | 26 | 40 | 21 | 60 | - | - | - |
| 06220-416X30 | L | jet black | M16 | 63 | 26 | 40 | 21 | 30 | - | - | - |
| 06220-4165X30 | L | light grey RAL 7035 | M16 | 63 | 26 | 40 | 21 | 30 | - | - | - |

Overview of items

| Order No. | Form | Colour Cap | D | D1 | D8 | H | H3 | L | SW | T | T7 |
|---------------|------|-----------------------|-----|----|----|----|----|----|----|---|----|
| 06220-4166X30 | L | traffic red RAL 3020 | M16 | 63 | 26 | 40 | 21 | 30 | - | - | - |
| 06220-4167X30 | L | colza yellow RAL 1021 | M16 | 63 | 26 | 40 | 21 | 30 | - | - | - |
| 06220-416X35 | L | jet black | M16 | 63 | 26 | 40 | 21 | 35 | - | - | - |
| 06220-4165X35 | L | light grey RAL 7035 | M16 | 63 | 26 | 40 | 21 | 35 | - | - | - |
| 06220-4166X35 | L | traffic red RAL 3020 | M16 | 63 | 26 | 40 | 21 | 35 | - | - | - |
| 06220-4167X35 | L | colza yellow RAL 1021 | M16 | 63 | 26 | 40 | 21 | 35 | - | - | - |
| 06220-416X40 | L | jet black | M16 | 63 | 26 | 40 | 21 | 40 | - | - | - |
| 06220-4165X40 | L | light grey RAL 7035 | M16 | 63 | 26 | 40 | 21 | 40 | - | - | - |
| 06220-4166X40 | L | traffic red RAL 3020 | M16 | 63 | 26 | 40 | 21 | 40 | - | - | - |
| 06220-4167X40 | L | colza yellow RAL 1021 | M16 | 63 | 26 | 40 | 21 | 40 | - | - | - |
| 06220-416X45 | L | jet black | M16 | 63 | 26 | 40 | 21 | 45 | - | - | - |
| 06220-4165X45 | L | light grey RAL 7035 | M16 | 63 | 26 | 40 | 21 | 45 | - | - | - |
| 06220-4166X45 | L | traffic red RAL 3020 | M16 | 63 | 26 | 40 | 21 | 45 | - | - | - |
| 06220-4167X45 | L | colza yellow RAL 1021 | M16 | 63 | 26 | 40 | 21 | 45 | - | - | - |
| 06220-416X50 | L | jet black | M16 | 63 | 26 | 40 | 21 | 50 | - | - | - |
| 06220-4165X50 | L | light grey RAL 7035 | M16 | 63 | 26 | 40 | 21 | 50 | - | - | - |
| 06220-4166X50 | L | traffic red RAL 3020 | M16 | 63 | 26 | 40 | 21 | 50 | - | - | - |
| 06220-4167X50 | L | colza yellow RAL 1021 | M16 | 63 | 26 | 40 | 21 | 50 | - | - | - |
| 06220-416X60 | L | jet black | M16 | 63 | 26 | 40 | 21 | 60 | - | - | - |
| 06220-4165X60 | L | light grey RAL 7035 | M16 | 63 | 26 | 40 | 21 | 60 | - | - | - |
| 06220-4166X60 | L | traffic red RAL 3020 | M16 | 63 | 26 | 40 | 21 | 60 | - | - | - |
| 06220-4167X60 | L | colza yellow RAL 1021 | M16 | 63 | 26 | 40 | 21 | 60 | - | - | - |
| 06220-808 | S | jet black | - | 32 | 14 | 20 | 10 | - | 8 | - | 5 |
| 06220-810 | S | jet black | - | 40 | 18 | 25 | 13 | - | 10 | - | 10 |
| 06220-813 | S | jet black | - | 50 | 22 | 32 | 17 | - | 13 | - | 10 |
| 06220-816 | S | jet black | - | 63 | 26 | 40 | 21 | - | 16 | - | 15 |