



Item description/product images

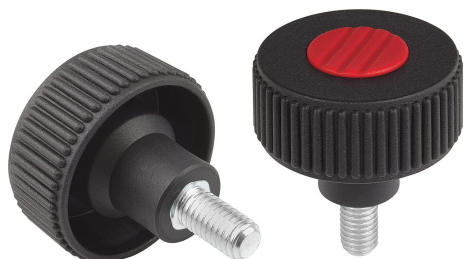


Description

Material:
Black grey thermoplastic.
Threaded pin steel 5.8.

Version:
Steel trivalent blue-passivated.

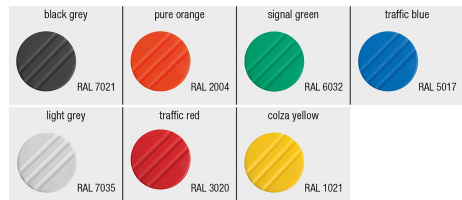

Drawings

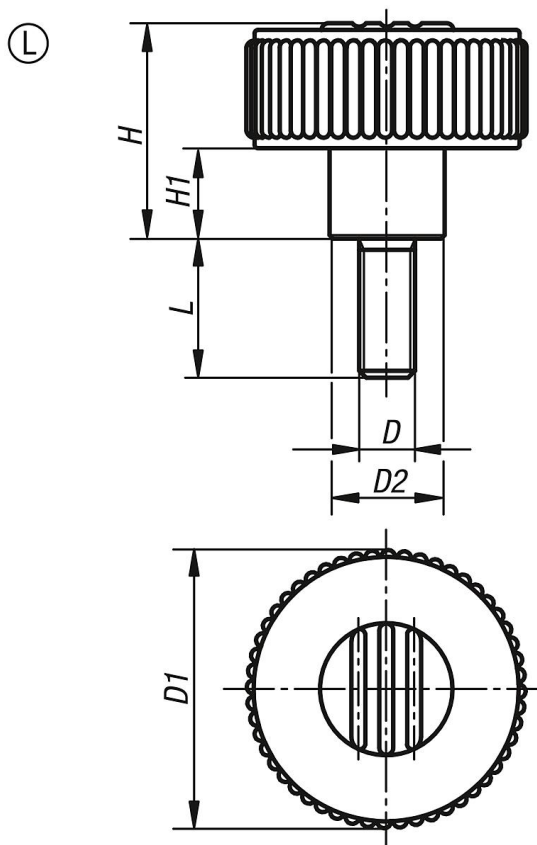

Overview of items

Order No.	Form	Colour Cap	Size	D	D1	D2	H	H1	L
06266-5105X10	L	black grey RAL 7021	1	M5	40	16,5	31	13	10
06266-51051X10	L	orange RAL 2004	1	M5	40	16,5	31	13	10
06266-51052X10	L	signal green RAL6032	1	M5	40	16,5	31	13	10
06266-51053X10	L	blue RAL5017	1	M5	40	16,5	31	13	10
06266-51055X10	L	light grey RAL 7035	1	M5	40	16,5	31	13	10
06266-51056X10	L	traffic red RAL 3020	1	M5	40	16,5	31	13	10
06266-51057X10	L	colza yellow RAL 1021	1	M5	40	16,5	31	13	10
06266-5105X20	L	black grey RAL 7021	1	M5	40	16,5	31	13	20
06266-51051X20	L	orange RAL 2004	1	M5	40	16,5	31	13	20

Overview of items

Order No.	Form	Colour Cap	Size	D	D1	D2	H	H1	L
06266-51052X20	L	signal green RAL6032	1	M5	40	16,5	31	13	20
06266-51053X20	L	blue RAL5017	1	M5	40	16,5	31	13	20
06266-51055X20	L	light grey RAL 7035	1	M5	40	16,5	31	13	20
06266-51056X20	L	traffic red RAL 3020	1	M5	40	16,5	31	13	20
06266-51057X20	L	colza yellow RAL 1021	1	M5	40	16,5	31	13	20
06266-5105X40	L	black grey RAL 7021	1	M5	40	16,5	31	13	40
06266-51051X40	L	orange RAL 2004	1	M5	40	16,5	31	13	40
06266-51052X40	L	signal green RAL6032	1	M5	40	16,5	31	13	40
06266-51053X40	L	blue RAL5017	1	M5	40	16,5	31	13	40
06266-51055X40	L	light grey RAL 7035	1	M5	40	16,5	31	13	40
06266-51056X40	L	traffic red RAL 3020	1	M5	40	16,5	31	13	40
06266-51057X40	L	colza yellow RAL 1021	1	M5	40	16,5	31	13	40
06266-5106X10	L	black grey RAL 7021	1	M6	40	16,5	31	13	10
06266-51061X10	L	orange RAL 2004	1	M6	40	16,5	31	13	10
06266-51062X10	L	signal green RAL6032	1	M6	40	16,5	31	13	10
06266-51063X10	L	blue RAL5017	1	M6	40	16,5	31	13	10
06266-51065X10	L	light grey RAL 7035	1	M6	40	16,5	31	13	10
06266-51066X10	L	traffic red RAL 3020	1	M6	40	16,5	31	13	10
06266-51067X10	L	colza yellow RAL 1021	1	M6	40	16,5	31	13	10
06266-5106X20	L	black grey RAL 7021	1	M6	40	16,5	31	13	20
06266-51061X20	L	orange RAL 2004	1	M6	40	16,5	31	13	20
06266-51062X20	L	signal green RAL6032	1	M6	40	16,5	31	13	20
06266-51063X20	L	blue RAL5017	1	M6	40	16,5	31	13	20
06266-51065X20	L	light grey RAL 7035	1	M6	40	16,5	31	13	20
06266-51066X20	L	traffic red RAL 3020	1	M6	40	16,5	31	13	20
06266-51067X20	L	colza yellow RAL 1021	1	M6	40	16,5	31	13	20
06266-5106X40	L	black grey RAL 7021	1	M6	40	16,5	31	13	40
06266-51061X40	L	orange RAL 2004	1	M6	40	16,5	31	13	40
06266-51062X40	L	signal green RAL6032	1	M6	40	16,5	31	13	40
06266-51063X40	L	blue RAL5017	1	M6	40	16,5	31	13	40
06266-51065X40	L	light grey RAL 7035	1	M6	40	16,5	31	13	40
06266-51066X40	L	traffic red RAL 3020	1	M6	40	16,5	31	13	40
06266-51067X40	L	colza yellow RAL 1021	1	M6	40	16,5	31	13	40
06266-5108X15	L	black grey RAL 7021	1	M8	40	16,5	31	13	15
06266-51081X15	L	orange RAL 2004	1	M8	40	16,5	31	13	15
06266-51082X15	L	signal green RAL6032	1	M8	40	16,5	31	13	15
06266-51083X15	L	blue RAL5017	1	M8	40	16,5	31	13	15
06266-51085X15	L	light grey RAL 7035	1	M8	40	16,5	31	13	15
06266-51086X15	L	traffic red RAL 3020	1	M8	40	16,5	31	13	15
06266-51087X15	L	colza yellow RAL 1021	1	M8	40	16,5	31	13	15
06266-5108X30	L	black grey RAL 7021	1	M8	40	16,5	31	13	30
06266-51081X30	L	orange RAL 2004	1	M8	40	16,5	31	13	30
06266-51082X30	L	signal green RAL6032	1	M8	40	16,5	31	13	30
06266-51083X30	L	blue RAL5017	1	M8	40	16,5	31	13	30
06266-51085X30	L	light grey RAL 7035	1	M8	40	16,5	31	13	30
06266-51086X30	L	traffic red RAL 3020	1	M8	40	16,5	31	13	30
06266-51087X30	L	colza yellow RAL 1021	1	M8	40	16,5	31	13	30
06266-5108X60	L	black grey RAL 7021	1	M8	40	16,5	31	13	60
06266-51081X60	L	orange RAL 2004	1	M8	40	16,5	31	13	60
06266-51082X60	L	signal green RAL6032	1	M8	40	16,5	31	13	60
06266-51083X60	L	blue RAL5017	1	M8	40	16,5	31	13	60
06266-51085X60	L	light grey RAL 7035	1	M8	40	16,5	31	13	60
06266-51086X60	L	traffic red RAL 3020	1	M8	40	16,5	31	13	60
06266-51087X60	L	colza yellow RAL 1021	1	M8	40	16,5	31	13	60
06266-5208X15	L	black grey RAL 7021	2	M8	50	18	36	15	15
06266-52081X15	L	orange RAL 2004	2	M8	50	18	36	15	15
06266-52082X15	L	signal green RAL6032	2	M8	50	18	36	15	15
06266-52083X15	L	blue RAL5017	2	M8	50	18	36	15	15
06266-52085X15	L	light grey RAL 7035	2	M8	50	18	36	15	15
06266-52086X15	L	traffic red RAL 3020	2	M8	50	18	36	15	15
06266-52087X15	L	colza yellow RAL 1021	2	M8	50	18	36	15	15
06266-5208X30	L	black grey RAL 7021	2	M8	50	18	36	15	30
06266-52081X30	L	orange RAL 2004	2	M8	50	18	36	15	30
06266-52082X30	L	signal green RAL6032	2	M8	50	18	36	15	30
06266-52083X30	L	blue RAL5017	2	M8	50	18	36	15	30

Overview of items

Order No.	Form	Colour Cap	Size	D	D1	D2	H	H1	L
06266-52085X30	L	light grey RAL 7035	2	M8	50	18	36	15	30
06266-52086X30	L	traffic red RAL 3020	2	M8	50	18	36	15	30
06266-52087X30	L	colza yellow RAL 1021	2	M8	50	18	36	15	30
06266-5208X60	L	black grey RAL 7021	2	M8	50	18	36	15	60
06266-52081X60	L	orange RAL 2004	2	M8	50	18	36	15	60
06266-52082X60	L	signal green RAL6032	2	M8	50	18	36	15	60
06266-52083X60	L	blue RAL5017	2	M8	50	18	36	15	60
06266-52085X60	L	light grey RAL 7035	2	M8	50	18	36	15	60
06266-52086X60	L	traffic red RAL 3020	2	M8	50	18	36	15	60
06266-52087X60	L	colza yellow RAL 1021	2	M8	50	18	36	15	60
06266-5210X20	L	black grey RAL 7021	2	M10	50	18	36	15	20
06266-52101X20	L	orange RAL 2004	2	M10	50	18	36	15	20
06266-52102X20	L	signal green RAL6032	2	M10	50	18	36	15	20
06266-52103X20	L	blue RAL5017	2	M10	50	18	36	15	20
06266-52105X20	L	light grey RAL 7035	2	M10	50	18	36	15	20
06266-52106X20	L	traffic red RAL 3020	2	M10	50	18	36	15	20
06266-52107X20	L	colza yellow RAL 1021	2	M10	50	18	36	15	20
06266-5210X30	L	black grey RAL 7021	2	M10	50	18	36	15	30
06266-52101X30	L	orange RAL 2004	2	M10	50	18	36	15	30
06266-52102X30	L	signal green RAL6032	2	M10	50	18	36	15	30
06266-52103X30	L	blue RAL5017	2	M10	50	18	36	15	30
06266-52105X30	L	light grey RAL 7035	2	M10	50	18	36	15	30
06266-52106X30	L	traffic red RAL 3020	2	M10	50	18	36	15	30
06266-52107X30	L	colza yellow RAL 1021	2	M10	50	18	36	15	30
06266-5210X60	L	black grey RAL 7021	2	M10	50	18	36	15	60
06266-52101X60	L	orange RAL 2004	2	M10	50	18	36	15	60
06266-52102X60	L	signal green RAL6032	2	M10	50	18	36	15	60
06266-52103X60	L	blue RAL5017	2	M10	50	18	36	15	60
06266-52105X60	L	light grey RAL 7035	2	M10	50	18	36	15	60
06266-52106X60	L	traffic red RAL 3020	2	M10	50	18	36	15	60
06266-52107X60	L	colza yellow RAL 1021	2	M10	50	18	36	15	60
06266-5310X20	L	black grey RAL 7021	3	M10	63	22	41	17	20
06266-53101X20	L	orange RAL 2004	3	M10	63	22	41	17	20
06266-53102X20	L	signal green RAL6032	3	M10	63	22	41	17	20
06266-53103X20	L	blue RAL5017	3	M10	63	22	41	17	20
06266-53105X20	L	light grey RAL 7035	3	M10	63	22	41	17	20
06266-53106X20	L	traffic red RAL 3020	3	M10	63	22	41	17	20
06266-53107X20	L	colza yellow RAL 1021	3	M10	63	22	41	17	20
06266-5310X30	L	black grey RAL 7021	3	M10	63	22	41	17	30
06266-53101X30	L	orange RAL 2004	3	M10	63	22	41	17	30
06266-53102X30	L	signal green RAL6032	3	M10	63	22	41	17	30
06266-53103X30	L	blue RAL5017	3	M10	63	22	41	17	30
06266-53105X30	L	light grey RAL 7035	3	M10	63	22	41	17	30
06266-53106X30	L	traffic red RAL 3020	3	M10	63	22	41	17	30
06266-53107X30	L	colza yellow RAL 1021	3	M10	63	22	41	17	30
06266-5310X60	L	black grey RAL 7021	3	M10	63	22	41	17	60
06266-53101X60	L	orange RAL 2004	3	M10	63	22	41	17	60
06266-53102X60	L	signal green RAL6032	3	M10	63	22	41	17	60
06266-53103X60	L	blue RAL5017	3	M10	63	22	41	17	60
06266-53105X60	L	light grey RAL 7035	3	M10	63	22	41	17	60
06266-53106X60	L	traffic red RAL 3020	3	M10	63	22	41	17	60
06266-53107X60	L	colza yellow RAL 1021	3	M10	63	22	41	17	60
06266-5312X30	L	black grey RAL 7021	3	M12	63	22	41	17	30
06266-53121X30	L	orange RAL 2004	3	M12	63	22	41	17	30
06266-53122X30	L	signal green RAL6032	3	M12	63	22	41	17	30
06266-53123X30	L	blue RAL5017	3	M12	63	22	41	17	30
06266-53125X30	L	light grey RAL 7035	3	M12	63	22	41	17	30
06266-53126X30	L	traffic red RAL 3020	3	M12	63	22	41	17	30
06266-53127X30	L	colza yellow RAL 1021	3	M12	63	22	41	17	30
06266-5312X60	L	black grey RAL 7021	3	M12	63	22	41	17	60
06266-53121X60	L	orange RAL 2004	3	M12	63	22	41	17	60
06266-53122X60	L	signal green RAL6032	3	M12	63	22	41	17	60
06266-53123X60	L	blue RAL5017	3	M12	63	22	41	17	60
06266-53125X60	L	light grey RAL 7035	3	M12	63	22	41	17	60
06266-53126X60	L	traffic red RAL 3020	3	M12	63	22	41	17	60

Overview of items

Order No.	Form	Colour Cap	Size	D	D1	D2	H	H1	L
06266-53127X60	L	colza yellow RAL 1021	3	M12	63	22	41	17	60