

商品描述/产品说明



产品说明


材料：
渗碳钢制 1.7139 或青铜制导向衬套。

规格：
钢表面硬化。

提示：
钢制或青铜制导向衬套是一种可用于工具和模具制造的部件。导向衬套的特点是其精度、耐用性和易于安装。这些轴套的设计无定心轴环，以确保应用中的最大灵活性。

钢制或青铜制导向衬套是一种可用于工具和模具制造的部件，其特点是质量优异、精确可靠。导向衬套的设计无定心环，其配合直径可确保装配简便、安全紧固。

图纸

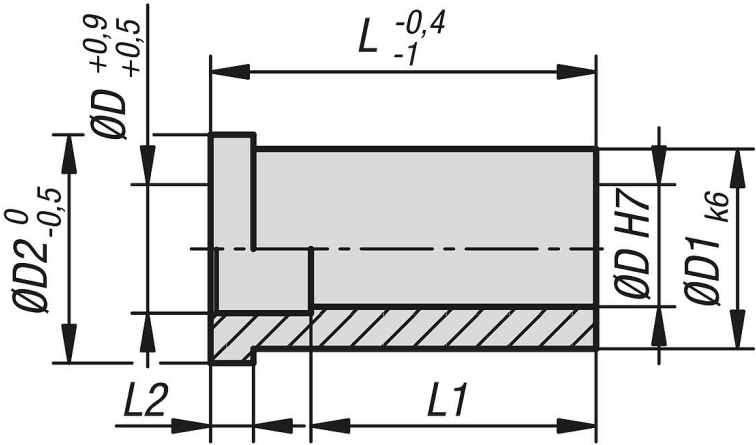

商品概述

订货号	主体材料	D	D1	D2	L	L1	L2
23678-20-009009	渗碳钢	9	14	16	9	-	3
23678-20-009012	渗碳钢	9	14	16	12	-	3
23678-20-009017	渗碳钢	9	14	16	17	-	3
23678-20-009022	渗碳钢	9	14	16	22	-	3
23678-20-009027	渗碳钢	9	14	16	27	-	3
23678-20-009036	渗碳钢	9	14	16	36	27	3

商品概述

订货号	主体材料	D	D1	D2	L	L1	L2
23678-20-009046	渗碳钢	9	14	16	46	36	3
23678-20-009056	渗碳钢	9	14	16	56	36	3
23678-20-009066	渗碳钢	9	14	16	66	36	3
23678-20-010009	渗碳钢	10	14	16	9	-	3
23678-20-010012	渗碳钢	10	14	16	12	-	3
23678-20-010017	渗碳钢	10	14	16	17	-	3
23678-20-010022	渗碳钢	10	14	16	22	-	3
23678-20-010027	渗碳钢	10	14	16	27	-	3
23678-20-010036	渗碳钢	10	14	16	36	27	3
23678-20-010046	渗碳钢	10	14	16	46	36	3
23678-20-010056	渗碳钢	10	14	16	56	36	3
23678-20-010066	渗碳钢	10	14	16	66	36	3
23678-20-012017	渗碳钢	12	18	23	17	-	6
23678-20-012022	渗碳钢	12	18	23	22	-	6
23678-20-012027	渗碳钢	12	18	23	27	-	6
23678-20-012036	渗碳钢	12	18	23	36	-	6
23678-20-012046	渗碳钢	12	18	23	46	36	6
23678-20-012056	渗碳钢	12	18	23	56	36	6
23678-20-014012	渗碳钢	14	20	25	12	-	6
23678-20-014017	渗碳钢	14	20	25	17	-	6
23678-20-014022	渗碳钢	14	20	25	22	-	6
23678-20-014027	渗碳钢	14	20	25	27	-	6
23678-20-014036	渗碳钢	14	20	25	36	-	6
23678-20-014046	渗碳钢	14	20	25	46	-	6
23678-20-014056	渗碳钢	14	20	25	56	46	6
23678-20-014066	渗碳钢	14	20	25	66	46	6
23678-20-014076	渗碳钢	14	20	25	76	46	6
23678-20-014086	渗碳钢	14	20	25	86	46	6
23678-20-014096	渗碳钢	14	20	25	96	46	6
23678-20-015012	渗碳钢	15	20	25	12	-	6
23678-20-015017	渗碳钢	15	20	25	17	-	6
23678-20-015022	渗碳钢	15	20	25	22	-	6
23678-20-015027	渗碳钢	15	20	25	27	-	6
23678-20-015036	渗碳钢	15	20	25	36	-	6
23678-20-015046	渗碳钢	15	20	25	46	-	6
23678-20-015056	渗碳钢	15	20	25	56	46	6
23678-20-015066	渗碳钢	15	20	25	66	46	6
23678-20-015076	渗碳钢	15	20	25	76	46	6
23678-20-015086	渗碳钢	15	20	25	86	46	6
23678-20-015096	渗碳钢	15	20	25	96	46	6
23678-20-016017	渗碳钢	16	22	27	17	-	6
23678-20-016022	渗碳钢	16	22	27	22	-	6
23678-20-016027	渗碳钢	16	22	27	27	-	6
23678-20-016036	渗碳钢	16	22	27	36	-	6
23678-20-016046	渗碳钢	16	22	27	46	-	6
23678-20-016056	渗碳钢	16	22	27	56	-	6
23678-20-018017	渗碳钢	18	26	31	17	-	6
23678-20-018022	渗碳钢	18	26	31	22	-	6
23678-20-018027	渗碳钢	18	26	31	27	-	6
23678-20-018036	渗碳钢	18	26	31	36	-	6
23678-20-018046	渗碳钢	18	26	31	46	-	6
23678-20-018056	渗碳钢	18	26	31	56	-	6
23678-20-018066	渗碳钢	18	26	31	66	56	6
23678-20-018076	渗碳钢	18	26	31	76	56	6
23678-20-018086	渗碳钢	18	26	31	86	56	6
23678-20-018096	渗碳钢	18	26	31	96	56	6
23678-20-018116	渗碳钢	18	26	31	116	56	6
23678-20-020017	渗碳钢	20	26	31	17	-	6
23678-20-020022	渗碳钢	20	26	31	22	-	6
23678-20-020027	渗碳钢	20	26	31	27	-	6
23678-20-020036	渗碳钢	20	26	31	36	-	6
23678-20-020046	渗碳钢	20	26	31	46	-	6
23678-20-020056	渗碳钢	20	26	31	56	-	6
23678-20-020066	渗碳钢	20	26	31	66	56	6
23678-20-020076	渗碳钢	20	26	31	76	56	6

商品概述

订货号	主体材料	D	D1	D2	L	L1	L2
23678-20-020086	渗碳钢	20	26	31	86	56	6
23678-20-020096	渗碳钢	20	26	31	96	56	6
23678-20-020116	渗碳钢	20	26	31	116	56	6
23678-20-022017	渗碳钢	22	30	35	17	-	6
23678-20-022022	渗碳钢	22	30	35	22	-	6
23678-20-022027	渗碳钢	22	30	35	27	-	6
23678-20-022036	渗碳钢	22	30	35	36	-	6
23678-20-022046	渗碳钢	22	30	35	46	-	6
23678-20-022056	渗碳钢	22	30	35	56	-	6
23678-20-022066	渗碳钢	22	30	35	66	-	6
23678-20-022076	渗碳钢	22	30	35	76	-	6
23678-20-022086	渗碳钢	22	30	35	86	76	6
23678-20-022096	渗碳钢	22	30	35	96	76	6
23678-20-022116	渗碳钢	22	30	35	116	76	6
23678-20-022136	渗碳钢	22	30	35	136	76	6
23678-20-022156	渗碳钢	22	30	35	156	76	6
23678-20-024017	渗碳钢	24	30	35	17	-	6
23678-20-024022	渗碳钢	24	30	35	22	-	6
23678-20-024027	渗碳钢	24	30	35	27	-	6
23678-20-024036	渗碳钢	24	30	35	36	-	6
23678-20-024046	渗碳钢	24	30	35	46	-	6
23678-20-024056	渗碳钢	24	30	35	56	-	6
23678-20-024066	渗碳钢	24	30	35	66	-	6
23678-20-024076	渗碳钢	24	30	35	76	-	6
23678-20-024086	渗碳钢	24	30	35	86	76	6
23678-20-024096	渗碳钢	24	30	35	96	76	6
23678-20-024116	渗碳钢	24	30	35	116	76	6
23678-20-024136	渗碳钢	24	30	35	136	76	6
23678-20-024156	渗碳钢	24	30	35	156	76	6
23678-20-030022	渗碳钢	30	42	47	22	-	6
23678-20-030027	渗碳钢	30	42	47	27	-	6
23678-20-030036	渗碳钢	30	42	47	36	-	6
23678-20-030046	渗碳钢	30	42	47	46	-	6
23678-20-030056	渗碳钢	30	42	47	56	-	6
23678-20-030066	渗碳钢	30	42	47	66	-	6
23678-20-030076	渗碳钢	30	42	47	76	-	6
23678-20-030086	渗碳钢	30	42	47	86	-	6
23678-20-030096	渗碳钢	30	42	47	96	-	6
23678-20-030116	渗碳钢	30	42	47	116	96	6
23678-20-030136	渗碳钢	30	42	47	136	96	6
23678-20-030156	渗碳钢	30	42	47	156	96	6
23678-20-030176	渗碳钢	30	42	47	176	96	6
23678-20-030186	渗碳钢	30	42	47	186	96	6
23678-20-030196	渗碳钢	30	42	47	196	96	6
23678-20-030236	渗碳钢	30	42	47	236	96	6
23678-20-032022	渗碳钢	32	42	47	22	-	6
23678-20-032027	渗碳钢	32	42	47	27	-	6
23678-20-032036	渗碳钢	32	42	47	36	-	6
23678-20-032046	渗碳钢	32	42	47	46	-	6
23678-20-032056	渗碳钢	32	42	47	56	-	6
23678-20-032066	渗碳钢	32	42	47	66	-	6
23678-20-032076	渗碳钢	32	42	47	76	-	6
23678-20-032086	渗碳钢	32	42	47	86	-	6
23678-20-032096	渗碳钢	32	42	47	96	-	6
23678-20-032116	渗碳钢	32	42	47	116	96	6
23678-20-032136	渗碳钢	32	42	47	136	96	6
23678-20-032156	渗碳钢	32	42	47	156	96	6
23678-20-032176	渗碳钢	32	42	47	176	96	6
23678-20-032186	渗碳钢	32	42	47	186	96	6
23678-20-032196	渗碳钢	32	42	47	196	96	6
23678-20-032236	渗碳钢	32	42	47	236	96	6
23678-20-040036	渗碳钢	40	54	60	36	-	10
23678-20-040046	渗碳钢	40	54	60	46	-	10
23678-20-040056	渗碳钢	40	54	60	56	-	10
23678-20-040066	渗碳钢	40	54	60	66	-	10

商品概述

订货号	主体材料	D	D1	D2	L	L1	L2
23678-20-040076	渗碳钢	40	54	60	76	-	10
23678-20-040086	渗碳钢	40	54	60	86	-	10
23678-20-040096	渗碳钢	40	54	60	96	-	10
23678-20-040116	渗碳钢	40	54	60	116	-	10
23678-20-040136	渗碳钢	40	54	60	136	116	10
23678-20-040156	渗碳钢	40	54	60	156	116	10
23678-20-040176	渗碳钢	40	54	60	176	116	10
23678-20-040196	渗碳钢	40	54	60	196	116	10
23678-20-040216	渗碳钢	40	54	60	216	116	10
23678-20-040246	渗碳钢	40	54	60	246	116	10
23678-20-042036	渗碳钢	42	54	60	36	-	10
23678-20-042046	渗碳钢	42	54	60	46	-	10
23678-20-042056	渗碳钢	42	54	60	56	-	10
23678-20-042066	渗碳钢	42	54	60	66	-	10
23678-20-042076	渗碳钢	42	54	60	76	-	10
23678-20-042086	渗碳钢	42	54	60	86	-	10
23678-20-042096	渗碳钢	42	54	60	96	-	10
23678-20-042116	渗碳钢	42	54	60	116	-	10
23678-20-042136	渗碳钢	42	54	60	136	116	10
23678-20-042156	渗碳钢	42	54	60	156	116	10
23678-20-042176	渗碳钢	42	54	60	176	116	10
23678-20-042196	渗碳钢	42	54	60	196	116	10
23678-20-042216	渗碳钢	42	54	60	216	116	10
23678-20-042246	渗碳钢	42	54	60	246	116	10
23678-20-050056	渗碳钢	50	66	72	56	-	10
23678-20-050076	渗碳钢	50	66	72	76	-	10
23678-20-050096	渗碳钢	50	66	72	96	-	10
23678-20-050116	渗碳钢	50	66	72	116	-	10
23678-20-050136	渗碳钢	50	66	72	136	116	10
23678-20-050156	渗碳钢	50	66	72	156	116	10
23678-20-050176	渗碳钢	50	66	72	176	116	10
23678-20-050196	渗碳钢	50	66	72	196	116	10
23678-20-052056	渗碳钢	52	66	72	56	-	10
23678-20-052076	渗碳钢	52	66	72	76	-	10
23678-20-052096	渗碳钢	52	66	72	96	-	10
23678-20-052116	渗碳钢	52	66	72	116	-	10
23678-20-052136	渗碳钢	52	66	72	136	116	10
23678-20-052156	渗碳钢	52	66	72	156	116	10
23678-20-052176	渗碳钢	52	66	72	176	116	10
23678-20-052196	渗碳钢	52	66	72	196	116	10
23678-20-060056	渗碳钢	60	80	86	56	-	20
23678-20-060076	渗碳钢	60	80	86	76	-	20
23678-20-060096	渗碳钢	60	80	86	96	-	20
23678-20-060116	渗碳钢	60	80	86	116	-	20
23678-20-060136	渗碳钢	60	80	86	136	-	20
23678-20-060156	渗碳钢	60	80	86	156	136	20
23678-20-060176	渗碳钢	60	80	86	176	136	20
23678-20-060196	渗碳钢	60	80	86	196	136	20
23678-20-060216	渗碳钢	60	80	86	216	136	20
23678-20-060246	渗碳钢	60	80	86	246	136	20
23678-20-062056	渗碳钢	62	80	86	56	-	20
23678-20-062076	渗碳钢	62	80	86	76	-	20
23678-20-062096	渗碳钢	62	80	86	96	-	20
23678-20-062116	渗碳钢	62	80	86	116	-	20
23678-20-062136	渗碳钢	62	80	86	136	-	20
23678-20-062156	渗碳钢	62	80	86	156	136	20
23678-20-062176	渗碳钢	62	80	86	176	136	20
23678-20-062196	渗碳钢	62	80	86	196	136	20
23678-20-062216	渗碳钢	62	80	86	216	136	20
23678-20-062246	渗碳钢	62	80	86	246	136	20
23678-20-109012	青铜	9	14	16	12	-	3
23678-20-109017	青铜	9	14	16	17	-	3
23678-20-109022	青铜	9	14	16	22	-	3
23678-20-109027	青铜	9	14	16	27	18	3
23678-20-109036	青铜	9	14	16	36	18	3

商品概述

订货号	主体材料	D	D1	D2	L	L1	L2
23678-20-109046	青铜	9	14	16	46	18	3
23678-20-109056	青铜	9	14	16	56	18	3
23678-20-110012	青铜	10	14	16	12	-	3
23678-20-110017	青铜	10	14	16	17	-	3
23678-20-110022	青铜	10	14	16	22	-	3
23678-20-110027	青铜	10	14	16	27	20	3
23678-20-110036	青铜	10	14	16	36	20	3
23678-20-110046	青铜	10	14	16	46	20	3
23678-20-110056	青铜	10	14	16	56	20	3
23678-20-112017	青铜	12	18	23	17	-	6
23678-20-112022	青铜	12	18	23	22	-	6
23678-20-112027	青铜	12	18	23	27	-	6
23678-20-112036	青铜	12	18	23	36	24	6
23678-20-112046	青铜	12	18	23	46	24	6
23678-20-112056	青铜	12	18	23	56	24	6
23678-20-114017	青铜	14	20	25	17	-	6
23678-20-114022	青铜	14	20	25	22	-	6
23678-20-114027	青铜	14	20	25	27	-	6
23678-20-114036	青铜	14	20	25	36	28	6
23678-20-114046	青铜	14	20	25	46	28	6
23678-20-114056	青铜	14	20	25	56	28	6
23678-20-115017	青铜	15	20	25	17	-	6
23678-20-115022	青铜	15	20	25	22	-	6
23678-20-115027	青铜	15	20	25	27	-	6
23678-20-115036	青铜	15	20	25	36	30	6
23678-20-115046	青铜	15	20	25	46	30	6
23678-20-115056	青铜	15	20	25	56	30	6
23678-20-116022	青铜	16	22	27	22	-	6
23678-20-116027	青铜	16	22	27	27	-	6
23678-20-116036	青铜	16	22	27	36	32	6
23678-20-116046	青铜	16	22	27	46	32	6
23678-20-116056	青铜	16	22	27	56	32	6
23678-20-118017	青铜	18	26	31	17	-	6
23678-20-118022	青铜	18	26	31	22	-	6
23678-20-118027	青铜	18	26	31	27	-	6
23678-20-118036	青铜	18	26	31	36	-	6
23678-20-118046	青铜	18	26	31	46	36	6
23678-20-118056	青铜	18	26	31	56	36	6
23678-20-118066	青铜	18	26	31	66	36	6
23678-20-118076	青铜	18	26	31	76	36	6
23678-20-120017	青铜	20	26	31	17	-	6
23678-20-120022	青铜	20	26	31	22	-	6
23678-20-120027	青铜	20	26	31	27	-	6
23678-20-120036	青铜	20	26	31	36	-	6
23678-20-120046	青铜	20	26	31	46	40	6
23678-20-120056	青铜	20	26	31	56	40	6
23678-20-120066	青铜	20	26	31	66	40	6
23678-20-120076	青铜	20	26	31	76	40	6
23678-20-122022	青铜	22	30	35	22	-	6
23678-20-122027	青铜	22	30	35	27	-	6
23678-20-122036	青铜	22	30	35	36	-	6
23678-20-122046	青铜	22	30	35	46	44	6
23678-20-122056	青铜	22	30	35	56	44	6
23678-20-122066	青铜	22	30	35	66	44	6
23678-20-122076	青铜	22	30	35	76	44	6
23678-20-122086	青铜	22	30	35	86	44	6
23678-20-122096	青铜	22	30	35	96	44	6
23678-20-124022	青铜	24	30	35	22	-	6
23678-20-124027	青铜	24	30	35	27	-	6
23678-20-124036	青铜	24	30	35	36	-	6
23678-20-124046	青铜	24	30	35	46	-	6
23678-20-124056	青铜	24	30	35	56	48	6
23678-20-124066	青铜	24	30	35	66	48	6
23678-20-124076	青铜	24	30	35	76	48	6
23678-20-124086	青铜	24	30	35	86	48	6

商品概述

订货号	主体材料	D	D1	D2	L	L1	L2
23678-20-124096	青铜	24	30	35	96	48	6
23678-20-130027	青铜	30	42	47	27	-	6
23678-20-130036	青铜	30	42	47	36	-	6
23678-20-130046	青铜	30	42	47	46	-	6
23678-20-130056	青铜	30	42	47	56	-	6
23678-20-130066	青铜	30	42	47	66	60	6
23678-20-130076	青铜	30	42	47	76	60	6
23678-20-130086	青铜	30	42	47	86	60	6
23678-20-130096	青铜	30	42	47	96	60	6
23678-20-130116	青铜	30	42	47	116	60	6
23678-20-132027	青铜	32	42	47	27	-	6
23678-20-132036	青铜	32	42	47	36	-	6
23678-20-132046	青铜	32	42	47	46	-	6
23678-20-132056	青铜	32	42	47	56	-	6
23678-20-132066	青铜	32	42	47	66	64	6
23678-20-132076	青铜	32	42	47	76	64	6
23678-20-132086	青铜	32	42	47	86	64	6
23678-20-132096	青铜	32	42	47	96	64	6
23678-20-132116	青铜	32	42	47	116	64	6
23678-20-140046	青铜	40	54	60	46	-	10
23678-20-140056	青铜	40	54	60	56	-	10
23678-20-140066	青铜	40	54	60	66	-	10
23678-20-140076	青铜	40	54	60	76	-	10
23678-20-140086	青铜	40	54	60	86	80	10
23678-20-140096	青铜	40	54	60	96	80	10
23678-20-140116	青铜	40	54	60	116	80	10
23678-20-140136	青铜	40	54	60	136	80	10
23678-20-142046	青铜	42	54	60	46	-	10
23678-20-142056	青铜	42	54	60	56	-	10
23678-20-142066	青铜	42	54	60	66	-	10
23678-20-142076	青铜	42	54	60	76	-	10
23678-20-142086	青铜	42	54	60	86	84	10
23678-20-142096	青铜	42	54	60	96	84	10
23678-20-142116	青铜	42	54	60	116	84	10
23678-20-142136	青铜	42	54	60	136	84	10