


商品描述/产品说明

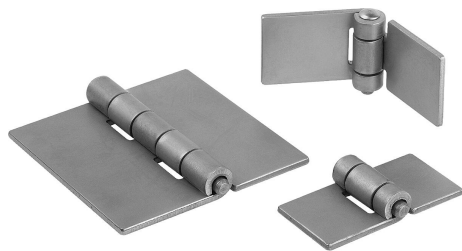

产品说明

材料：
钢或不锈钢

规格：
亮色型钢。
不锈钢 1.4301。

提示：

所示的铰链载荷值是不具约束力的指导值，未考虑安全因素，且不承担任何责任。所有数值仅供参考，并不对财产构成任何相关法律保证。

应力值是在实验室条件下得出。每个用户必须独自确定铰链是否符合各自的使用。


铰链连接的材质、连接方式、天气条件和磨损情况等都会对待确定的值造成影响。

装配：


通过焊接或客户提供的单个钻孔。

图纸

B=30/40/50/60

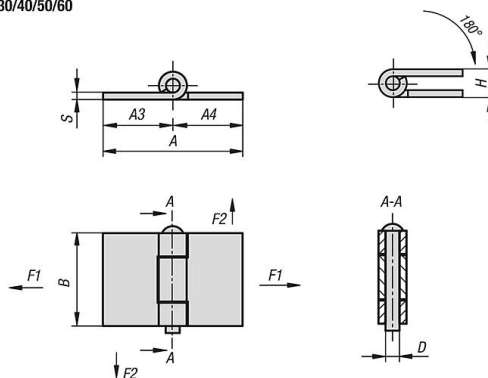

B=80/100

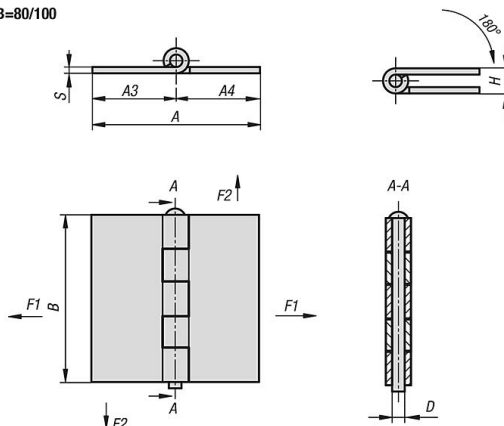

商品概述

订货号	主体材料	A	B	D	A3	A4	H	S	F1 N	F2 N
27888-02-00200200402	钢制	40	40	6	20	20	10	2	850	300
27888-02-00250250502	钢制	50	50	6	25	25	10	2	1050	650
27888-02-00300300302	钢制	60	30	6	30	30	10	2	650	250
27888-02-00300300402	钢制	60	40	6	30	30	10	2	800	500
27888-02-00300300602	钢制	60	60	6	30	30	10	2	1300	800
27888-02-00400400302	钢制	80	30	6	40	40	10	2	600	300
27888-02-00400400402	钢制	80	40	6	40	40	10	2	750	550
27888-02-00400400602	钢制	80	60	6	40	40	10	2	1400	850
27888-02-00400400802	钢制	80	80	6	40	40	10	2	1700	1250
27888-02-00500501002	钢制	100	100	6	50	50	10	2	2350	1600
27888-02-00300300303	钢制	60	30	6	30	30	12	3	800	1200
27888-02-00300300403	钢制	60	40	6	30	30	12	3	800	1200
27888-02-00300300603	钢制	60	60	6	30	30	12	3	1200	1800
27888-02-00400400303	钢制	80	30	6	40	40	12	3	800	800
27888-02-00400400403	钢制	80	40	6	40	40	12	3	800	1000
27888-02-00400400803	钢制	80	80	6	40	40	12	3	1200	1800
27888-02-00500501003	钢制	100	100	6	50	50	12	3	1200	1800
27888-02-00300300305	钢制	60	30	6	30	30	16	5	2600	850
27888-02-00300300405	钢制	60	40	6	30	30	16	5	3650	1300
27888-02-00300300605	钢制	60	60	6	30	30	16	5	5050	1950
27888-02-00600600305	钢制	120	30	6	60	60	16	5	2750	1350
27888-02-00600600405	钢制	120	40	6	60	60	16	5	3700	1400
27888-02-00600600505	钢制	120	50	6	60	60	16	5	4850	2200
27888-02-00600600605	钢制	120	60	6	60	60	16	5	5100	3000
27888-02-00600600805	钢制	120	80	6	60	60	16	5	6800	4300
27888-02-00800800805	钢制	160	80	6	80	80	16	5	6850	4200
27888-02-00800800606	钢制	160	60	8	80	80	20	6	6100	2800
27888-02-00800800806	钢制	160	80	8	80	80	20	6	9200	2800
27888-02-01001000806	钢制	200	80	8	100	100	20	6	9250	4400
27888-02-00800801008	钢制	160	100	8	80	80	24	8	9500	6000
27888-02-01001001008	钢制	200	100	8	100	100	24	8	11100	5950
27888-02-010010010010	钢制	200	100	13	100	100	33	10	14900	5300
27888-02-10200200402	不锈钢 A2	40	40	6	20	20	10	2	750	250
27888-02-10250250502	不锈钢 A2	50	50	6	25	25	10	2	900	550
27888-02-10300300302	不锈钢 A2	60	30	6	30	30	10	2	550	200
27888-02-10300300402	不锈钢 A2	60	40	6	30	30	10	2	700	400
27888-02-10300300602	不锈钢 A2	60	60	6	30	30	10	2	1100	650
27888-02-10400400302	不锈钢 A2	80	30	6	40	40	10	2	500	250
27888-02-10400400402	不锈钢 A2	80	40	6	40	40	10	2	650	450
27888-02-10400400602	不锈钢 A2	80	60	6	40	40	10	2	1200	700
27888-02-10400400802	不锈钢 A2	80	80	6	40	40	10	2	1450	1050
27888-02-10500501002	不锈钢 A2	100	100	6	50	50	10	2	2000	1300
27888-02-10300300303	不锈钢 A2	60	30	6	30	30	12	3	700	1000
27888-02-10300300403	不锈钢 A2	60	40	6	30	30	12	3	700	1000
27888-02-10300300603	不锈钢 A2	60	60	6	30	30	12	3	1000	1500
27888-02-10400400303	不锈钢 A2	80	30	6	40	40	12	3	700	600
27888-02-10400400403	不锈钢 A2	80	40	6	40	40	12	3	700	800
27888-02-10400400803	不锈钢 A2	80	80	6	40	40	12	3	1000	1500
27888-02-10500501003	不锈钢 A2	100	100	6	50	50	12	3	1000	1500
27888-02-10300300305	不锈钢 A2	60	30	6	30	30	16	5	2250	700
27888-02-10300300405	不锈钢 A2	60	40	6	30	30	16	5	3150	1050
27888-02-10300300605	不锈钢 A2	60	60	6	30	30	16	5	4350	1600
27888-02-10600600305	不锈钢 A2	120	30	6	60	60	16	5	2350	1100
27888-02-10600600405	不锈钢 A2	120	40	6	60	60	16	5	3200	1150
27888-02-10600600505	不锈钢 A2	120	50	6	60	60	16	5	4150	1800
27888-02-10600600605	不锈钢 A2	120	60	6	60	60	16	5	4400	2450
27888-02-10600600805	不锈钢 A2	120	80	6	60	60	16	5	5850	3550
27888-02-10800800805	不锈钢 A2	160	80	6	80	80	16	5	5900	3450
27888-02-10800800606	不锈钢 A2	160	60	8	80	80	20	6	5250	2300
27888-02-10800800806	不锈钢 A2	160	80	8	80	80	20	6	7900	2300
27888-02-11001000806	不锈钢 A2	200	80	8	100	100	20	6	7950	3600
27888-02-10800801008	不锈钢 A2	160	100	8	80	80	24	8	8150	4900
27888-02-11001001008	不锈钢 A2	200	100	8	100	100	24	8	9550	4900
27888-02-110010010010	不锈钢 A2	200	100	13	100	100	33	10	12800	4350

商品概述
