

商品描述/产品说明



产品说明

材料：
聚氨酯 (PU) 和钢帘线。

提示：
具有米制节距的符合 ISO 17396 的梯形型材的连续齿带。非常适合具有高皮带挠性的驱动。可实现最小垫圈直径。齿带适用于高精度的驱动传动，安全可靠且很好化学效应。

齿带颜色可能与产品图片中的颜色有所不同。


温度范围：
从 -10 °C 至 +80 °C

特征：


- 免维护
- 高功率传输
- 低皮带伸长度
- 定位精确和角度
- 非常良好的耐化学性，尤其是针对油、油脂和燃料
- 最高耐磨强度
- 最高 30 kW 的可传输功率
- 最高 10000 rpm 的允许转速

图纸


T2,5

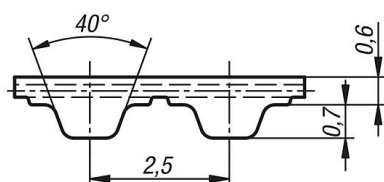

T5

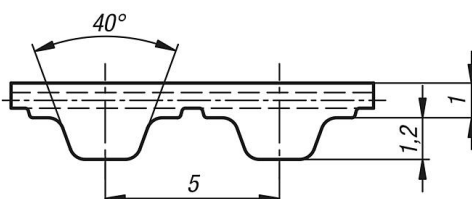

T10

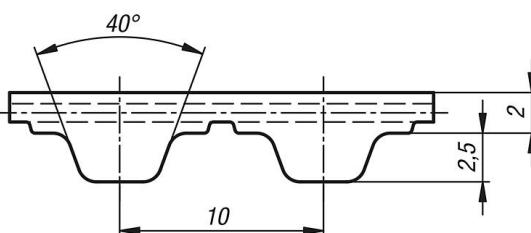

商品概述

订货号	型材	皮带宽度	齿数	有效长度
22052-2506X0120	T2,5	6	48	120
22052-2506X0145	T2,5	6	58	145
22052-2506X0160	T2,5	6	64	160
22052-2506X0177	T2,5	6	71	177,5
22052-2506X0180	T2,5	6	72	180
22052-2506X0200	T2,5	6	80	200
22052-2506X0230	T2,5	6	92	230
22052-2506X0245	T2,5	6	98	245
22052-2506X0265	T2,5	6	106	265
22052-2506X0285	T2,5	6	114	285
22052-2506X0290	T2,5	6	116	290
22052-2506X0305	T2,5	6	122	305
22052-2506X0317	T2,5	6	127	317,5
22052-2506X0330	T2,5	6	132	330
22052-2506X0380	T2,5	6	152	380
22052-2506X0420	T2,5	6	168	420
22052-2506X0480	T2,5	6	192	480
22052-2506X0500	T2,5	6	200	500
22052-2506X0540	T2,5	6	216	540
22052-2506X0600	T2,5	6	240	600
22052-2506X0650	T2,5	6	260	650
22052-2506X0780	T2,5	6	312	780
22052-2506X0915	T2,5	6	366	915
22052-2506X0950	T2,5	6	380	950
22052-0510X0165	T5	10	33	165
22052-0510X0185	T5	10	37	185
22052-0510X0200	T5	10	40	200
22052-0510X0215	T5	10	43	215
22052-0510X0220	T5	10	44	220
22052-0510X0225	T5	10	45	225
22052-0510X0245	T5	10	49	245
22052-0510X0250	T5	10	50	250
22052-0510X0255	T5	10	51	255
22052-0510X0260	T5	10	52	260
22052-0510X0270	T5	10	54	270
22052-0510X0275	T5	10	55	275
22052-0510X0280	T5	10	56	280
22052-0510X0295	T5	10	59	295
22052-0510X0300	T5	10	60	300
22052-0510X0305	T5	10	61	305
22052-0510X0325	T5	10	65	325
22052-0510X0330	T5	10	66	330
22052-0510X0340	T5	10	68	340
22052-0510X0350	T5	10	70	350
22052-0510X0355	T5	10	71	355
22052-0510X0365	T5	10	73	365
22052-0510X0375	T5	10	75	375
22052-0510X0390	T5	10	78	390
22052-0510X0400	T5	10	80	400
22052-0510X0410	T5	10	82	410
22052-0510X0420	T5	10	84	420
22052-0510X0425	T5	10	85	425
22052-0510X0450	T5	10	90	450
22052-0510X0455	T5	10	91	455
22052-0510X0475	T5	10	95	475
22052-0510X0480	T5	10	96	480
22052-0510X0500	T5	10	100	500
22052-0510X0510	T5	10	102	510
22052-0510X0525	T5	10	105	525
22052-0510X0545	T5	10	109	545
22052-0510X0550	T5	10	110	550
22052-0510X0560	T5	10	112	560
22052-0510X0575	T5	10	115	575
22052-0510X0600	T5	10	120	600
22052-0510X0610	T5	10	122	610

商品概述

订货号	型材	皮带宽度	齿数	有效长度
22052-0510X0620	T5	10	124	620
22052-0510X0630	T5	10	126	630
22052-0510X0640	T5	10	128	640
22052-0510X0650	T5	10	130	650
22052-0510X0660	T5	10	132	660
22052-0510X0690	T5	10	138	690
22052-0510X0700	T5	10	140	700
22052-0510X0720	T5	10	144	720
22052-0510X0750	T5	10	150	750
22052-0510X0780	T5	10	156	780
22052-0510X0815	T5	10	163	815
22052-0510X0840	T5	10	168	840
22052-0510X0850	T5	10	170	850
22052-0510X0900	T5	10	180	900
22052-0510X0990	T5	10	198	990
22052-0510X1000	T5	10	200	1000
22052-0510X1075	T5	10	215	1075
22052-0510X1100	T5	10	220	1100
22052-0510X1215	T5	10	243	1215
22052-0510X1380	T5	10	276	1380
22052-0510X1440	T5	10	288	1440
22052-0516X0165	T5	16	33	165
22052-0516X0185	T5	16	37	185
22052-0516X0200	T5	16	40	200
22052-0516X0215	T5	16	43	215
22052-0516X0220	T5	16	44	220
22052-0516X0225	T5	16	45	225
22052-0516X0245	T5	16	49	245
22052-0516X0250	T5	16	50	250
22052-0516X0255	T5	16	51	255
22052-0516X0260	T5	16	52	260
22052-0516X0270	T5	16	54	270
22052-0516X0275	T5	16	55	275
22052-0516X0280	T5	16	56	280
22052-0516X0295	T5	16	59	295
22052-0516X0300	T5	16	60	300
22052-0516X0305	T5	16	61	305
22052-0516X0325	T5	16	65	325
22052-0516X0330	T5	16	66	330
22052-0516X0340	T5	16	68	340
22052-0516X0350	T5	16	70	350
22052-0516X0355	T5	16	71	355
22052-0516X0365	T5	16	73	365
22052-0516X0375	T5	16	75	375
22052-0516X0390	T5	16	78	390
22052-0516X0400	T5	16	80	400
22052-0516X0410	T5	16	82	410
22052-0516X0420	T5	16	84	420
22052-0516X0425	T5	16	85	425
22052-0516X0450	T5	16	90	450
22052-0516X0455	T5	16	91	455
22052-0516X0475	T5	16	95	475
22052-0516X0480	T5	16	96	480
22052-0516X0500	T5	16	100	500
22052-0516X0510	T5	16	102	510
22052-0516X0525	T5	16	105	525
22052-0516X0545	T5	16	109	545
22052-0516X0550	T5	16	110	550
22052-0516X0560	T5	16	112	560
22052-0516X0575	T5	16	115	575
22052-0516X0600	T5	16	120	600
22052-0516X0610	T5	16	122	610
22052-0516X0620	T5	16	124	620
22052-0516X0630	T5	16	126	630
22052-0516X0640	T5	16	128	640

商品概述

订货号	型材	皮带宽度	齿数	有效长度
22052-0516X0650	T5	16	130	650
22052-0516X0660	T5	16	132	660
22052-0516X0690	T5	16	138	690
22052-0516X0700	T5	16	140	700
22052-0516X0720	T5	16	144	720
22052-0516X0750	T5	16	150	750
22052-0516X0780	T5	16	156	780
22052-0516X0815	T5	16	163	815
22052-0516X0840	T5	16	168	840
22052-0516X0850	T5	16	170	850
22052-0516X0900	T5	16	180	900
22052-0516X0990	T5	16	198	990
22052-0516X1000	T5	16	200	1000
22052-0516X1075	T5	16	215	1075
22052-0516X1100	T5	16	220	1100
22052-0516X1215	T5	16	243	1215
22052-0516X1380	T5	16	276	1380
22052-0516X1440	T5	16	288	1440
22052-0525X0185	T5	25	37	185
22052-0525X0215	T5	25	43	215
22052-0525X0220	T5	25	44	220
22052-0525X0225	T5	25	45	225
22052-0525X0245	T5	25	49	245
22052-0525X0250	T5	25	50	250
22052-0525X0255	T5	25	51	255
22052-0525X0260	T5	25	52	260
22052-0525X0270	T5	25	54	270
22052-0525X0275	T5	25	55	275
22052-0525X0280	T5	25	56	280
22052-0525X0295	T5	25	59	295
22052-0525X0300	T5	25	60	300
22052-0525X0305	T5	25	61	305
22052-0525X0325	T5	25	65	325
22052-0525X0330	T5	25	66	330
22052-0525X0340	T5	25	68	340
22052-0525X0350	T5	25	70	350
22052-0525X0355	T5	25	71	355
22052-0525X0365	T5	25	73	365
22052-0525X0375	T5	25	75	375
22052-0525X0390	T5	25	78	390
22052-0525X0400	T5	25	80	400
22052-0525X0410	T5	25	82	410
22052-0525X0420	T5	25	84	420
22052-0525X0425	T5	25	85	425
22052-0525X0450	T5	25	90	450
22052-0525X0455	T5	25	91	455
22052-0525X0475	T5	25	95	475
22052-0525X0480	T5	25	96	480
22052-0525X0500	T5	25	100	500
22052-0525X0510	T5	25	102	510
22052-0525X0525	T5	25	105	525
22052-0525X0545	T5	25	109	545
22052-0525X0550	T5	25	110	550
22052-0525X0560	T5	25	112	560
22052-0525X0575	T5	25	115	575
22052-0525X0600	T5	25	120	600
22052-0525X0610	T5	25	122	610
22052-0525X0620	T5	25	124	620
22052-0525X0630	T5	25	126	630
22052-0525X0650	T5	25	130	650
22052-0525X0660	T5	25	132	660
22052-0525X0690	T5	25	138	690
22052-0525X0700	T5	25	140	700
22052-0525X0720	T5	25	144	720
22052-0525X0750	T5	25	150	750

商品概述

订货号	型材	皮带宽度	齿数	有效长度
22052-0525X0780	T5	25	156	780
22052-0525X0815	T5	25	163	815
22052-0525X0840	T5	25	168	840
22052-0525X0850	T5	25	170	850
22052-0525X0900	T5	25	180	900
22052-0525X0990	T5	25	198	990
22052-0525X1000	T5	25	200	1000
22052-0525X1075	T5	25	215	1075
22052-0525X1100	T5	25	220	1100
22052-0525X1215	T5	25	243	1215
22052-0525X1380	T5	25	276	1380
22052-0525X1440	T5	25	288	1440
22052-1016X0260	T10	16	26	260
22052-1016X0370	T10	16	37	370
22052-1016X0400	T10	16	40	400
22052-1016X0410	T10	16	41	410
22052-1016X0440	T10	16	44	440
22052-1016X0450	T10	16	45	450
22052-1016X0500	T10	16	50	500
22052-1016X0530	T10	16	53	530
22052-1016X0560	T10	16	56	560
22052-1016X0610	T10	16	61	610
22052-1016X0630	T10	16	63	630
22052-1016X0660	T10	16	66	660
22052-1016X0690	T10	16	69	690
22052-1016X0700	T10	16	70	700
22052-1016X0720	T10	16	72	720
22052-1016X0750	T10	16	75	750
22052-1016X0780	T10	16	78	780
22052-1016X0810	T10	16	81	810
22052-1016X0840	T10	16	84	840
22052-1016X0880	T10	16	88	880
22052-1016X0890	T10	16	89	890
22052-1016X0900	T10	16	90	900
22052-1016X0920	T10	16	92	920
22052-1016X0960	T10	16	96	960
22052-1016X0970	T10	16	97	970
22052-1016X0980	T10	16	98	980
22052-1016X1010	T10	16	101	1010
22052-1016X1080	T10	16	108	1080
22052-1016X1110	T10	16	111	1110
22052-1016X1140	T10	16	114	1140
22052-1016X1150	T10	16	115	1150
22052-1016X1210	T10	16	121	1210
22052-1016X1240	T10	16	124	1240
22052-1016X1250	T10	16	125	1250
22052-1016X1300	T10	16	130	1300
22052-1016X1320	T10	16	132	1320
22052-1016X1350	T10	16	135	1350
22052-1016X1390	T10	16	139	1390
22052-1016X1400	T10	16	140	1400
22052-1016X1420	T10	16	142	1420
22052-1016X1440	T10	16	144	1440
22052-1016X1450	T10	16	145	1450
22052-1016X1460	T10	16	146	1460
22052-1016X1500	T10	16	150	1500
22052-1016X1560	T10	16	156	1560
22052-1016X1610	T10	16	161	1610
22052-1016X1750	T10	16	175	1750
22052-1016X1780	T10	16	178	1780
22052-1016X1880	T10	16	188	1880
22052-1016X1960	T10	16	196	1960
22052-1016X2250	T10	16	225	2250
22052-1025X0260	T10	25	26	260
22052-1025X0370	T10	25	37	370

商品概述

订货号	型材	皮带宽度	齿数	有效长度
22052-1025X0400	T10	25	40	400
22052-1025X0410	T10	25	41	410
22052-1025X0440	T10	25	44	440
22052-1025X0450	T10	25	45	450
22052-1025X0500	T10	25	50	500
22052-1025X0530	T10	25	53	530
22052-1025X0560	T10	25	56	560
22052-1025X0610	T10	25	61	610
22052-1025X0630	T10	25	63	630
22052-1025X0660	T10	25	66	660
22052-1025X0690	T10	25	69	690
22052-1025X0700	T10	25	70	700
22052-1025X0720	T10	25	72	720
22052-1025X0750	T10	25	75	750
22052-1025X0780	T10	25	78	780
22052-1025X0810	T10	25	81	810
22052-1025X0840	T10	25	84	840
22052-1025X0880	T10	25	88	880
22052-1025X0890	T10	25	89	890
22052-1025X0900	T10	25	90	900
22052-1025X0920	T10	25	92	920
22052-1025X0960	T10	25	96	960
22052-1025X0970	T10	25	97	970
22052-1025X0980	T10	25	98	980
22052-1025X1010	T10	25	101	1010
22052-1025X1080	T10	25	108	1080
22052-1025X1110	T10	25	111	1110
22052-1025X1140	T10	25	114	1140
22052-1025X1150	T10	25	115	1150
22052-1025X1210	T10	25	121	1210
22052-1025X1240	T10	25	124	1240
22052-1025X1250	T10	25	125	1250
22052-1025X1300	T10	25	130	1300
22052-1025X1320	T10	25	132	1320
22052-1025X1350	T10	25	135	1350
22052-1025X1390	T10	25	139	1390
22052-1025X1400	T10	25	140	1400
22052-1025X1420	T10	25	142	1420
22052-1025X1440	T10	25	144	1440
22052-1025X1450	T10	25	145	1450
22052-1025X1460	T10	25	146	1460
22052-1025X1500	T10	25	150	1500
22052-1025X1560	T10	25	156	1560
22052-1025X1610	T10	25	161	1610
22052-1025X1750	T10	25	175	1750
22052-1025X1780	T10	25	178	1780
22052-1025X1880	T10	25	188	1880
22052-1025X1960	T10	25	196	1960
22052-1025X2250	T10	25	225	2250
22052-1032X0260	T10	32	26	260
22052-1032X0370	T10	32	37	370
22052-1032X0400	T10	32	40	400
22052-1032X0410	T10	32	41	410
22052-1032X0440	T10	32	44	440
22052-1032X0500	T10	32	50	500
22052-1032X0530	T10	32	53	530
22052-1032X0560	T10	32	56	560
22052-1032X0610	T10	32	61	610
22052-1032X0630	T10	32	63	630
22052-1032X0660	T10	32	66	660
22052-1032X0690	T10	32	69	690
22052-1032X0720	T10	32	72	720
22052-1032X0750	T10	32	75	750
22052-1032X0780	T10	32	78	780
22052-1032X0810	T10	32	81	810

商品概述

订货号	型材	皮带宽度	齿数	有效长度
22052-1032X0840	T10	32	84	840
22052-1032X0890	T10	32	89	890
22052-1032X0920	T10	32	92	920
22052-1032X0960	T10	32	96	960
22052-1032X0980	T10	32	98	980
22052-1032X1010	T10	32	101	1010
22052-1032X1080	T10	32	108	1080
22052-1032X1110	T10	32	111	1110
22052-1032X1140	T10	32	114	1140
22052-1032X1150	T10	32	115	1150
22052-1032X1210	T10	32	121	1210
22052-1032X1240	T10	32	124	1240
22052-1032X1250	T10	32	125	1250
22052-1032X1300	T10	32	130	1300
22052-1032X1320	T10	32	132	1320
22052-1032X1350	T10	32	135	1350
22052-1032X1400	T10	32	140	1400
22052-1032X1460	T10	32	146	1460
22052-1032X1500	T10	32	150	1500
22052-1032X1610	T10	32	161	1610
22052-1032X1750	T10	32	175	1750
22052-1032X1880	T10	32	188	1880
22052-1032X1960	T10	32	196	1960
22052-1032X2250	T10	32	225	2250