

## Item description/product images

**Description****Material:**

Steel or stainless steel.

**Version:**

Electro zinc-plated steel.

Bright stainless steel.


Plastic handle, oil-resistant.

**Note:**

Latch toggle clamps are especially suitable for quickly closing and locking covers and hatches.

The travel can be set by altering the hasp length.

## Drawings

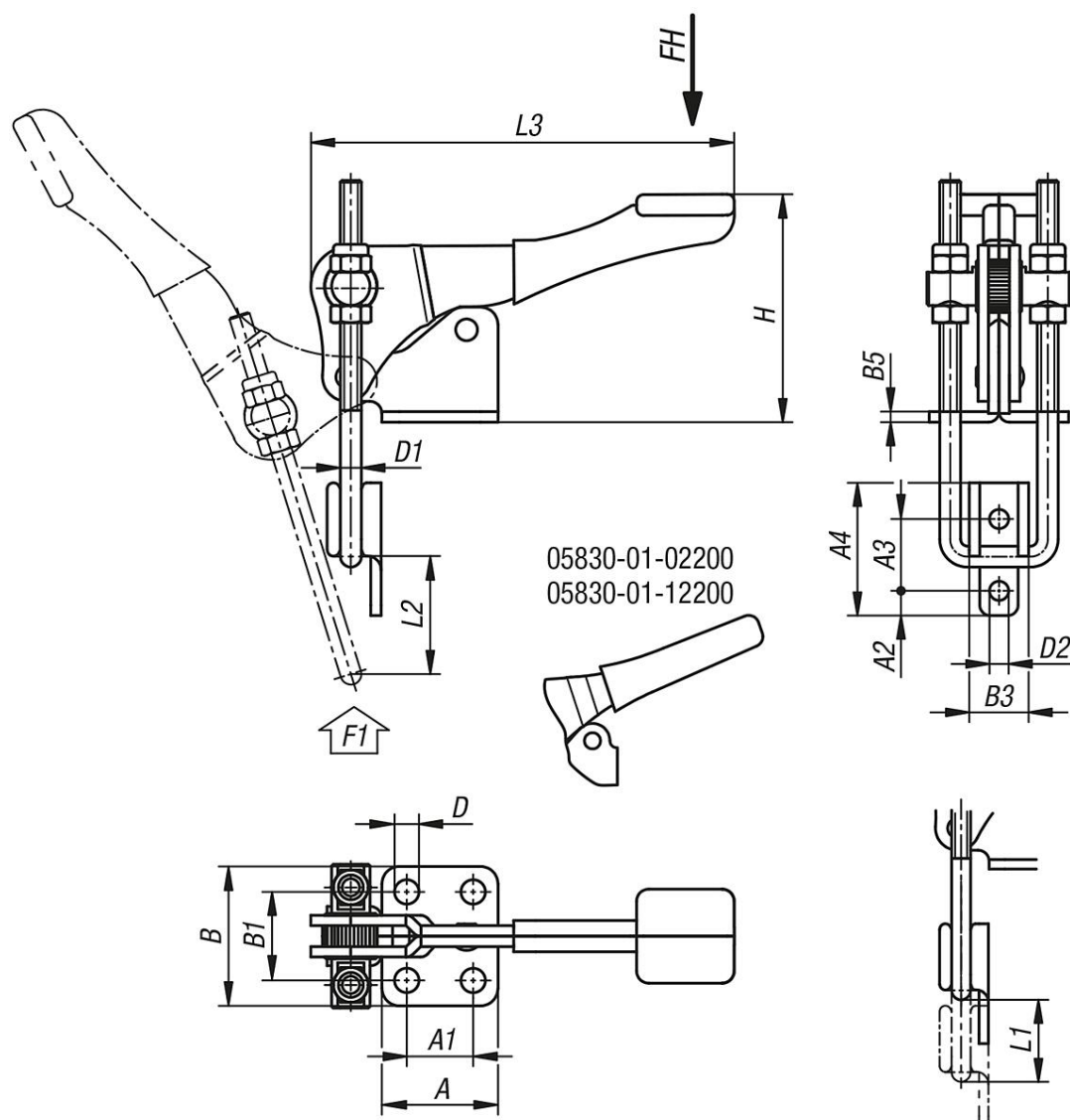

## Overview of items

| Order No.      | Main material | Hand force FH N | Traction force F1 N | A    | A1   | A2  | A3   | A4   | B  | B1   | B3   | B5 | D   | D1 | D2  | H    | L1   | Clamping travel L2 | L3    |
|----------------|---------------|-----------------|---------------------|------|------|-----|------|------|----|------|------|----|-----|----|-----|------|------|--------------------|-------|
| 05830-01-02200 | 0.0062        | 100             | 2200                | 26   | 13   | 4   | 14,3 | 25,4 | 35 | 22   | 13,5 | 2  | 5,3 | 4  | 4,4 | 55   | 12,2 | 38                 | 81    |
| 05830-01-04500 | 0.0062        | 150             | 4500                | 33,3 | 19,1 | 7,1 | 20,6 | 38,1 | 40 | 25,4 | 17   | 3  | 7,1 | 6  | 5,6 | 65,4 | 20,3 | 50                 | 121,5 |
| 05830-01-07000 | 0.0062        | 200             | 9000                | 47,6 | 31,8 | 9,5 | 27   | 54   | 53 | 36,5 | 30   | 4  | 8,7 | 8  | 8,7 | 85,5 | 29,4 | 63                 | 132,4 |
| 05830-01-12200 | 2500          | 100             | 2200                | 26   | 13   | 4   | 14,3 | 25,4 | 35 | 22   | 13,5 | 2  | 5,3 | 4  | 4,4 | 55   | 12,2 | 38                 | 81    |
| 05830-01-14500 | 2500          | 150             | 4500                | 33,3 | 19,1 | 7,1 | 20,6 | 38,1 | 40 | 25,4 | 17   | 3  | 7,1 | 6  | 5,6 | 65,4 | 20,3 | 50                 | 121,5 |
| 05830-01-17000 | 2500          | 200             | 9000                | 47,6 | 31,8 | 9,5 | 27   | 54   | 53 | 36,5 | 30   | 4  | 8,7 | 8  | 8,7 | 92   | 29,4 | 63                 | 132,4 |