

Item description/product images

**Description****Material:**

Crank and grip thermoplastic.

Hub and grip axle steel, strength class 5.8, or stainless steel 1.4404.

Version:

Thermoplastic black grey.

Steel parts black oxidised.

Stainless steel bright.

Note:

The hub cover and the revolving cylinder grip are supplied unassembled.

To assemble, screw the grip into the tapped hole provided.

The crank handles can be secured to the shaft by cross-pinning or by parallel key together with a DIN 6912 cap screw and DIN 7349 washer.

Versions with transverse bore are secured using the ISO 4027 (DIN 914) grub screw.


Accessory:

07161 Cap screws with low head DIN 6912

Drawing reference:

1) Position of the transverse bore to the keyway is offset by 90°.

Drawings

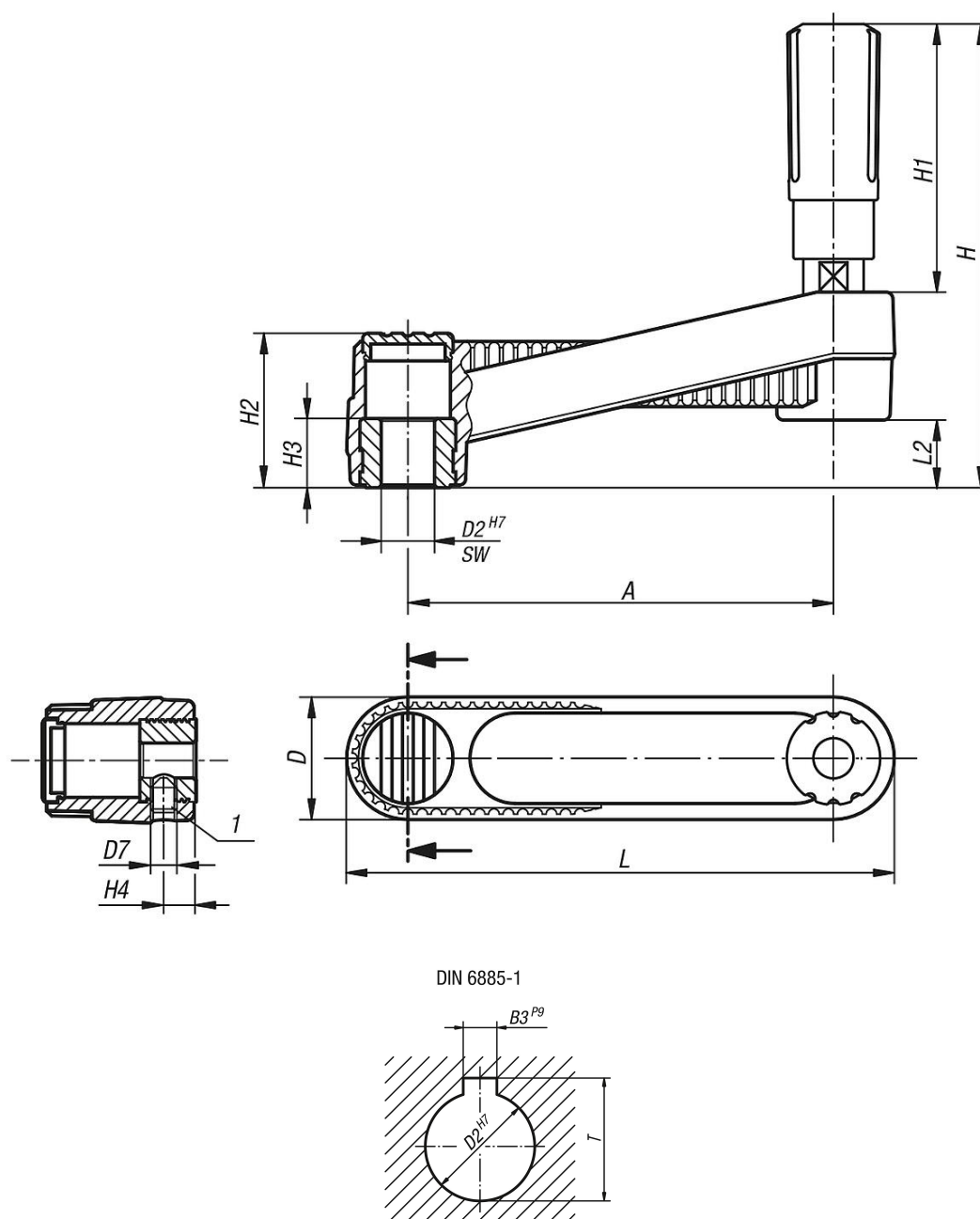

Overview of items

Order No.	Version 1	Version 2	Component material	A	D	D2	D7	H	H1	H2	H3	H4	L	L2	B3	SW	T
06500-3108	Cam screw	DIN 39	0.0029	80	24	8	-	85,8	49,1	28,5	13	-	104	12,7	-	-	-
06500-3110	Cam screw	DIN 39	0.0029	80	24	10	-	85,8	49,1	28,5	13	-	104	12,7	-	-	-
06500-3210	Cam screw	DIN 39	0.0029	100	29	10	-	107,1	61,4	35,5	13	-	129	15,7	-	-	-
06500-3212	Cam screw	DIN 39	0.0029	100	29	12	-	107,1	61,4	35,5	13	-	129	15,7	-	-	-
06500-3312	Cam screw	DIN 39	0.0029	125	36	12	-	139,5	82,5	44	18,5	-	161	19,5	-	-	-
06500-3314	Cam screw	DIN 39	0.0029	125	36	14	-	139,5	82,5	44	18,5	-	161	19,5	-	-	-
06500-31086	Cam-action indexing plungers	ChromLine clamping joints	0.011	80	24	8	M6	85,8	49,1	28,5	13	7,5	104	12,7	-	-	-
06500-31106	Cam-action indexing plungers	ChromLine clamping joints	0.011	80	24	10	M6	85,8	49,1	28,5	13	7,5	104	12,7	-	-	-
06500-32106	Cam-action indexing plungers	ChromLine clamping joints	0.011	100	29	10	M6	107,1	61,4	35,5	13	7,5	129	15,7	-	-	-
06500-32126	Cam-action indexing plungers	ChromLine clamping joints	0.011	100	29	12	M6	107,1	61,4	35,5	13	7,5	129	15,7	-	-	-
06500-33126	Cam-action indexing plungers	ChromLine clamping joints	0.011	125	36	12	M6	139,5	82,5	44	18,5	7,5	161	19,5	-	-	-
06500-33146	Cam-action indexing plungers	ChromLine clamping joints	0.011	125	36	14	M6	139,5	82,5	44	18,5	7,5	161	19,5	-	-	-
06500-03108	Cam-action indexing plungers	DIN 39	3	80	24	8	-	85,8	49,1	28,5	13	-	104	12,7	-	-	-

Overview of items

Order No.	Version 1	Version 2	Component material	A	D	D2	D7	H	H1	H2	H3	H4	L	L2	B3	SW	T
06500-03110	Cam-action indexing plungers	DIN 39	3	80	24	10	-	85,8	49,1	28,5	13	-	104	12,7	-	-	-
06500-03210	Cam-action indexing plungers	DIN 39	3	100	29	10	-	107,1	61,4	35,5	13	-	129	15,7	-	-	-
06500-03212	Cam-action indexing plungers	DIN 39	3	100	29	12	-	107,1	61,4	35,5	13	-	129	15,7	-	-	-
06500-03312	Cam-action indexing plungers	DIN 39	3	125	36	12	-	139,5	82,5	44	18,5	-	161	19,5	-	-	-
06500-03314	Cam-action indexing plungers	DIN 39	3	125	36	14	-	139,5	82,5	44	18,5	-	161	19,5	-	-	-
06500-031086	Cam-action indexing plungers	ChromLine clamping joints	3	80	24	8	M6	85,8	49,1	28,5	13	7,5	104	12,7	-	-	-
06500-031106	Cam-action indexing plungers	ChromLine clamping joints	3	80	24	10	M6	85,8	49,1	28,5	13	7,5	104	12,7	-	-	-
06500-032106	Cam-action indexing plungers	ChromLine clamping joints	3	100	29	10	M6	107,1	61,4	35,5	13	7,5	129	15,7	-	-	-
06500-032126	Cam-action indexing plungers	ChromLine clamping joints	3	100	29	12	M6	107,1	61,4	35,5	13	7,5	129	15,7	-	-	-
06500-033126	Cam-action indexing plungers	ChromLine clamping joints	3	125	36	12	M6	139,5	82,5	44	18,5	7,5	161	19,5	-	-	-
06500-033146	Cam-action indexing plungers	ChromLine clamping joints	3	125	36	14	M6	139,5	82,5	44	18,5	7,5	161	19,5	-	-	-
06500-310802	1 kg can	DIN 39	0.0029	80	24	8	-	85,8	49,1	28,5	13	-	104	12,7	2	-	9
06500-311003	1 kg can	DIN 39	0.0029	80	24	10	-	85,8	49,1	28,5	13	-	104	12,7	3	-	11,4
06500-321003	1 kg can	DIN 39	0.0029	100	29	10	-	107,1	61,4	35,5	13	-	129	15,7	3	-	11,4
06500-321204	1 kg can	DIN 39	0.0029	100	29	12	-	107,1	61,4	35,5	13	-	129	15,7	4	-	13,8
06500-331204	1 kg can	DIN 39	0.0068	125	36	12	-	139,5	82,5	44	18,5	-	161	19,5	4	-	13,8
06500-331405	1 kg can	DIN 39	0.0068	125	36	14	-	139,5	82,5	44	18,5	-	161	19,5	5	-	16,3
06500-3210036	1 kg can	ChromLine clamping joints	0.011	100	29	10	M6	107,1	61,4	35,5	13	7,5	129	15,7	3	-	11,4
06500-3212046	1 kg can	ChromLine clamping joints	0.011	100	29	12	M6	107,1	61,4	35,5	13	7,5	129	15,7	4	-	13,8
06500-3312046	1 kg can	ChromLine clamping joints	0.011	125	36	12	M6	139,5	82,5	44	18,5	7,5	161	19,5	4	-	13,8
06500-3314056	1 kg can	ChromLine clamping joints	0.011	125	36	14	M6	139,5	82,5	44	18,5	7,5	161	19,5	5	-	16,3
06500-3108026	1 kg can	ChromLine clamping joints	0.011	80	24	8	M6	85,8	49,1	28,5	13	7,5	104	12,7	2	-	9
06500-3110036	1 kg can	ChromLine clamping joints	0.011	80	24	10	M6	85,8	49,1	28,5	13	7,5	104	12,7	3	-	11,4
06500-0310802	1 kg can	DIN 39	3	80	24	8	-	85,8	49,1	28,5	13	-	104	12,7	2	-	9
06500-0311003	1 kg can	DIN 39	3	80	24	10	-	85,8	49,1	28,5	13	-	104	12,7	3	-	11,4
06500-0321003	1 kg can	DIN 39	3	100	29	10	-	107,1	61,4	35,5	13	-	129	15,7	3	-	11,4
06500-0321204	1 kg can	DIN 39	3	100	29	12	-	107,1	61,4	35,5	13	-	129	15,7	4	-	13,8
06500-0331204	1 kg can	DIN 39	3	125	36	12	-	139,5	82,5	44	18,5	-	161	19,5	4	-	13,8
06500-0331405	1 kg can	DIN 39	3	125	36	14	-	139,5	82,5	44	18,5	-	161	19,5	5	-	16,3
06500-03108026	1 kg can	ChromLine clamping joints	3	80	24	8	M6	85,8	49,1	28,5	13	7,5	104	12,7	2	-	9
06500-03110036	1 kg can	ChromLine clamping joints	3	80	24	10	M6	85,8	49,1	28,5	13	7,5	104	12,7	3	-	11,4
06500-03210036	1 kg can	ChromLine clamping joints	3	100	29	10	M6	107,1	61,4	35,5	13	7,5	129	15,7	3	-	11,4
06500-03212046	1 kg can	ChromLine clamping joints	3	100	29	12	M6	107,1	61,4	35,5	13	7,5	129	15,7	4	-	13,8
06500-03312046	1 kg can	ChromLine clamping joints	3	125	36	12	M6	139,5	82,5	44	18,5	7,5	161	19,5	4	-	13,8
06500-03314056	1 kg can	ChromLine clamping joints	3	125	36	14	M6	139,5	82,5	44	18,5	7,5	161	19,5	5	-	16,3
06500-4108	Clamping claws	DIN 39	0.0029	80	24	-	-	85,8	49,1	28,5	13	-	104	12,7	-	8	-
06500-4110	Clamping claws	DIN 39	0.0029	80	24	-	-	85,8	49,1	28,5	13	-	104	12,7	-	10	-
06500-4210	Clamping claws	DIN 39	0.0029	100	29	-	-	107,1	61,4	35,5	13	-	129	15,7	-	10	-
06500-4212	Clamping claws	DIN 39	0.0029	100	29	-	-	107,1	61,4	35,5	13	-	129	15,7	-	12	-
06500-4312	Clamping claws	DIN 39	0.0068	125	36	-	-	139,5	82,5	44	18,5	-	161	19,5	-	12	-
06500-4314	Clamping claws	DIN 39	0.0068	125	36	-	-	139,5	82,5	44	18,5	-	161	19,5	-	14	-
06500-41086	Clamping claws	ChromLine clamping joints	0.011	80	24	-	M6	85,8	49,1	28,5	13	7,5	104	12,7	-	8	-
06500-41106	Clamping claws	ChromLine clamping joints	0.011	80	24	-	M6	85,8	49,1	28,5	13	7,5	104	12,7	-	10	-
06500-42106	Clamping claws	ChromLine clamping joints	0.011	100	29	-	M6	107,1	61,4	35,5	13	7,5	129	15,7	-	10	-
06500-42126	Clamping claws	ChromLine clamping joints	0.011	100	29	-	M6	107,1	61,4	35,5	13	7,5	129	15,7	-	12	-
06500-43126	Clamping claws	ChromLine clamping joints	0.011	125	36	-	M6	139,5	82,5	44	18,5	7,5	161	19,5	-	12	-
06500-43146	Clamping claws	ChromLine clamping joints	0.011	125	36	-	M6	139,5	82,5	44	18,5	7,5	161	19,5	-	14	-