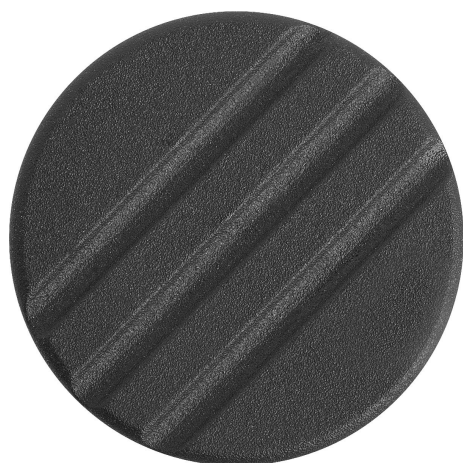


## Item description/product images

INCH  
Parts

## Description

**Material:**

Thermoplastic, black grey.  
Bush and screw stainless steel 1.4305.

**Version:**

Stainless steel bright.

**Note:**

For the inch series, dimension D is in inches, all other dimensions are in mm.

**Drawing reference:**

Form D: tapped bush without cap


Form K: tapped bush with cap

Form L: external thread

Item description/product images



Drawings

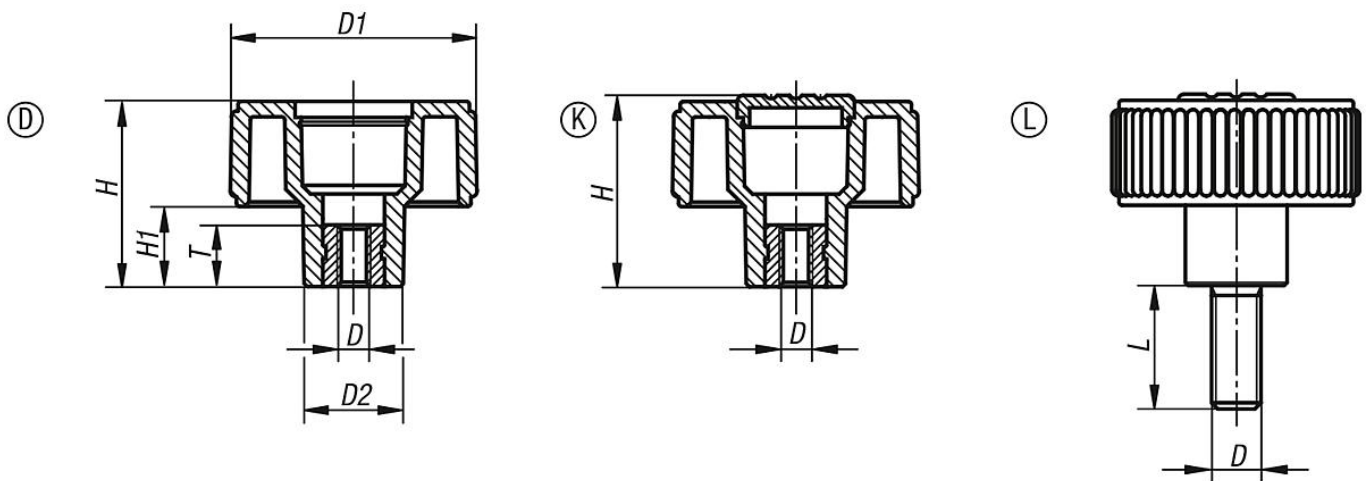

Overview of items

Knurled Wheels, components in stainless steel, internal thread, inch

| Order No.   | Form | Colour Cap            | Size | D       | D1 | D2   | H  | H1 | T  | L |
|-------------|------|-----------------------|------|---------|----|------|----|----|----|---|
| 06267-11A1  | D    | -                     | 1    | 10-32   | 40 | 16,5 | 31 | 13 | 10 | - |
| 06267-11A2  | D    | -                     | 1    | 1/4-20  | 40 | 16,5 | 31 | 13 | 10 | - |
| 06267-11A3  | D    | -                     | 1    | 5/16-18 | 40 | 16,5 | 31 | 13 | 14 | - |
| 06267-12A3  | D    | -                     | 2    | 5/16-18 | 50 | 18   | 36 | 15 | 14 | - |
| 06267-12A4  | D    | -                     | 2    | 3/8-16  | 50 | 18   | 36 | 15 | 14 | - |
| 06267-13A4  | D    | -                     | 3    | 3/8-16  | 63 | 22   | 41 | 17 | 14 | - |
| 06267-13A5  | D    | -                     | 3    | 1/2-13  | 63 | 22   | 41 | 17 | 18 | - |
| 06267-21A1  | K    | black grey RAL 7021   | 1    | 10-32   | 40 | 16,5 | 31 | 13 | 10 | - |
| 06267-21A15 | K    | light grey RAL 7035   | 1    | 10-32   | 40 | 16,5 | 31 | 13 | 10 | - |
| 06267-21A16 | K    | traffic red RAL 3020  | 1    | 10-32   | 40 | 16,5 | 31 | 13 | 10 | - |
| 06267-21A17 | K    | colza yellow RAL 1021 | 1    | 10-32   | 40 | 16,5 | 31 | 13 | 10 | - |
| 06267-21A2  | K    | black grey RAL 7021   | 1    | 1/4-20  | 40 | 16,5 | 31 | 13 | 10 | - |
| 06267-21A25 | K    | light grey RAL 7035   | 1    | 1/4-20  | 40 | 16,5 | 31 | 13 | 10 | - |
| 06267-21A26 | K    | traffic red RAL 3020  | 1    | 1/4-20  | 40 | 16,5 | 31 | 13 | 10 | - |
| 06267-21A27 | K    | colza yellow RAL 1021 | 1    | 1/4-20  | 40 | 16,5 | 31 | 13 | 10 | - |
| 06267-21A3  | K    | black grey RAL 7021   | 1    | 5/16-18 | 40 | 16,5 | 31 | 13 | 14 | - |
| 06267-21A35 | K    | light grey RAL 7035   | 1    | 5/16-18 | 40 | 16,5 | 31 | 13 | 14 | - |
| 06267-21A36 | K    | traffic red RAL 3020  | 1    | 5/16-18 | 40 | 16,5 | 31 | 13 | 14 | - |
| 06267-21A37 | K    | colza yellow RAL 1021 | 1    | 5/16-18 | 40 | 16,5 | 31 | 13 | 14 | - |

## Overview of items

| Order No.      | Form | Colour<br>Cap         | Size | D       | D1 | D2   | H  | H1 | T  | L  |
|----------------|------|-----------------------|------|---------|----|------|----|----|----|----|
| 06267-22A3     | K    | black grey RAL 7021   | 2    | 5/16-18 | 50 | 18   | 36 | 15 | 14 | -  |
| 06267-22A35    | K    | light grey RAL 7035   | 2    | 5/16-18 | 50 | 18   | 36 | 15 | 14 | -  |
| 06267-22A36    | K    | traffic red RAL 3020  | 2    | 5/16-18 | 50 | 18   | 36 | 15 | 14 | -  |
| 06267-22A37    | K    | colza yellow RAL 1021 | 2    | 5/16-18 | 50 | 18   | 36 | 15 | 14 | -  |
| 06267-22A4     | K    | black grey RAL 7021   | 2    | 3/8-16  | 50 | 18   | 36 | 15 | 14 | -  |
| 06267-22A45    | K    | light grey RAL 7035   | 2    | 3/8-16  | 50 | 18   | 36 | 15 | 14 | -  |
| 06267-22A46    | K    | traffic red RAL 3020  | 2    | 3/8-16  | 50 | 18   | 36 | 15 | 14 | -  |
| 06267-22A47    | K    | colza yellow RAL 1021 | 2    | 3/8-16  | 50 | 18   | 36 | 15 | 14 | -  |
| 06267-23A4     | K    | black grey RAL 7021   | 3    | 3/8-16  | 63 | 22   | 41 | 17 | 14 | -  |
| 06267-23A45    | K    | light grey RAL 7035   | 3    | 3/8-16  | 63 | 22   | 41 | 17 | 14 | -  |
| 06267-23A46    | K    | traffic red RAL 3020  | 3    | 3/8-16  | 63 | 22   | 41 | 17 | 14 | -  |
| 06267-23A47    | K    | colza yellow RAL 1021 | 3    | 3/8-16  | 63 | 22   | 41 | 17 | 14 | -  |
| 06267-23A5     | K    | black grey RAL 7021   | 3    | 1/2-13  | 63 | 22   | 41 | 17 | 18 | -  |
| 06267-23A55    | K    | light grey RAL 7035   | 3    | 1/2-13  | 63 | 22   | 41 | 17 | 18 | -  |
| 06267-23A56    | K    | traffic red RAL 3020  | 3    | 1/2-13  | 63 | 22   | 41 | 17 | 18 | -  |
| 06267-23A57    | K    | colza yellow RAL 1021 | 3    | 1/2-13  | 63 | 22   | 41 | 17 | 18 | -  |
| 06267-51A1X10  | L    | black grey RAL 7021   | 1    | 10-32   | 40 | 16,5 | 31 | 13 | -  | 10 |
| 06267-51A15X10 | L    | light grey RAL 7035   | 1    | 10-32   | 40 | 16,5 | 31 | 13 | -  | 10 |
| 06267-51A16X10 | L    | traffic red RAL 3020  | 1    | 10-32   | 40 | 16,5 | 31 | 13 | -  | 10 |
| 06267-51A17X10 | L    | colza yellow RAL 1021 | 1    | 10-32   | 40 | 16,5 | 31 | 13 | -  | 10 |
| 06267-51A1X20  | L    | black grey RAL 7021   | 1    | 10-32   | 40 | 16,5 | 31 | 13 | -  | 20 |
| 06267-51A15X20 | L    | light grey RAL 7035   | 1    | 10-32   | 40 | 16,5 | 31 | 13 | -  | 20 |
| 06267-51A16X20 | L    | traffic red RAL 3020  | 1    | 10-32   | 40 | 16,5 | 31 | 13 | -  | 20 |
| 06267-51A17X20 | L    | colza yellow RAL 1021 | 1    | 10-32   | 40 | 16,5 | 31 | 13 | -  | 20 |
| 06267-51A2X20  | L    | black grey RAL 7021   | 1    | 1/4-20  | 40 | 16,5 | 31 | 13 | -  | 20 |
| 06267-51A25X20 | L    | light grey RAL 7035   | 1    | 1/4-20  | 40 | 16,5 | 31 | 13 | -  | 20 |
| 06267-51A26X20 | L    | traffic red RAL 3020  | 1    | 1/4-20  | 40 | 16,5 | 31 | 13 | -  | 20 |
| 06267-51A27X20 | L    | colza yellow RAL 1021 | 1    | 1/4-20  | 40 | 16,5 | 31 | 13 | -  | 20 |
| 06267-51A2X30  | L    | black grey RAL 7021   | 1    | 1/4-20  | 40 | 16,5 | 31 | 13 | -  | 30 |
| 06267-51A25X30 | L    | light grey RAL 7035   | 1    | 1/4-20  | 40 | 16,5 | 31 | 13 | -  | 30 |
| 06267-51A26X30 | L    | traffic red RAL 3020  | 1    | 1/4-20  | 40 | 16,5 | 31 | 13 | -  | 30 |
| 06267-51A27X30 | L    | colza yellow RAL 1021 | 1    | 1/4-20  | 40 | 16,5 | 31 | 13 | -  | 30 |
| 06267-51A3X20  | L    | black grey RAL 7021   | 1    | 5/16-18 | 40 | 16,5 | 31 | 13 | -  | 20 |
| 06267-51A35X20 | L    | light grey RAL 7035   | 1    | 5/16-18 | 40 | 16,5 | 31 | 13 | -  | 20 |
| 06267-51A36X20 | L    | traffic red RAL 3020  | 1    | 5/16-18 | 40 | 16,5 | 31 | 13 | -  | 20 |
| 06267-51A37X20 | L    | colza yellow RAL 1021 | 1    | 5/16-18 | 40 | 16,5 | 31 | 13 | -  | 20 |
| 06267-51A3X40  | L    | black grey RAL 7021   | 1    | 5/16-18 | 40 | 16,5 | 31 | 13 | -  | 40 |
| 06267-51A35X40 | L    | light grey RAL 7035   | 1    | 5/16-18 | 40 | 16,5 | 31 | 13 | -  | 40 |
| 06267-51A36X40 | L    | traffic red RAL 3020  | 1    | 5/16-18 | 40 | 16,5 | 31 | 13 | -  | 40 |
| 06267-51A37X40 | L    | colza yellow RAL 1021 | 1    | 5/16-18 | 40 | 16,5 | 31 | 13 | -  | 40 |
| 06267-52A3X20  | L    | black grey RAL 7021   | 2    | 5/16-18 | 50 | 18   | 36 | 15 | -  | 20 |
| 06267-52A35X20 | L    | light grey RAL 7035   | 2    | 5/16-18 | 50 | 18   | 36 | 15 | -  | 20 |
| 06267-52A36X20 | L    | traffic red RAL 3020  | 2    | 5/16-18 | 50 | 18   | 36 | 15 | -  | 20 |
| 06267-52A37X20 | L    | colza yellow RAL 1021 | 2    | 5/16-18 | 50 | 18   | 36 | 15 | -  | 20 |
| 06267-52A3X40  | L    | black grey RAL 7021   | 2    | 5/16-18 | 50 | 18   | 36 | 15 | -  | 40 |
| 06267-52A35X40 | L    | light grey RAL 7035   | 2    | 5/16-18 | 50 | 18   | 36 | 15 | -  | 40 |
| 06267-52A36X40 | L    | traffic red RAL 3020  | 2    | 5/16-18 | 50 | 18   | 36 | 15 | -  | 40 |
| 06267-52A37X40 | L    | colza yellow RAL 1021 | 2    | 5/16-18 | 50 | 18   | 36 | 15 | -  | 40 |
| 06267-52A4X20  | L    | black grey RAL 7021   | 2    | 3/8-16  | 50 | 18   | 36 | 15 | -  | 20 |
| 06267-52A45X20 | L    | light grey RAL 7035   | 2    | 3/8-16  | 50 | 18   | 36 | 15 | -  | 20 |
| 06267-52A46X20 | L    | traffic red RAL 3020  | 2    | 3/8-16  | 50 | 18   | 36 | 15 | -  | 20 |
| 06267-52A47X20 | L    | colza yellow RAL 1021 | 2    | 3/8-16  | 50 | 18   | 36 | 15 | -  | 20 |
| 06267-52A4X40  | L    | black grey RAL 7021   | 2    | 3/8-16  | 50 | 18   | 36 | 15 | -  | 40 |
| 06267-52A45X40 | L    | light grey RAL 7035   | 2    | 3/8-16  | 50 | 18   | 36 | 15 | -  | 40 |
| 06267-52A46X40 | L    | traffic red RAL 3020  | 2    | 3/8-16  | 50 | 18   | 36 | 15 | -  | 40 |
| 06267-52A47X40 | L    | colza yellow RAL 1021 | 2    | 3/8-16  | 50 | 18   | 36 | 15 | -  | 40 |
| 06267-53A4X20  | L    | black grey RAL 7021   | 3    | 3/8-16  | 63 | 22   | 41 | 17 | -  | 20 |
| 06267-53A45X20 | L    | light grey RAL 7035   | 3    | 3/8-16  | 63 | 22   | 41 | 17 | -  | 20 |
| 06267-53A46X20 | L    | traffic red RAL 3020  | 3    | 3/8-16  | 63 | 22   | 41 | 17 | -  | 20 |
| 06267-53A47X20 | L    | colza yellow RAL 1021 | 3    | 3/8-16  | 63 | 22   | 41 | 17 | -  | 20 |
| 06267-53A4X40  | L    | black grey RAL 7021   | 3    | 3/8-16  | 63 | 22   | 41 | 17 | -  | 40 |
| 06267-53A45X40 | L    | light grey RAL 7035   | 3    | 3/8-16  | 63 | 22   | 41 | 17 | -  | 40 |
| 06267-53A46X40 | L    | traffic red RAL 3020  | 3    | 3/8-16  | 63 | 22   | 41 | 17 | -  | 40 |
| 06267-53A47X40 | L    | colza yellow RAL 1021 | 3    | 3/8-16  | 63 | 22   | 41 | 17 | -  | 40 |

Overview of items

---