

Item description/product images



Description

Material:

Neoprene with polyester tensile cord.

Note:

Endless V-belt acc. to DIN 2215 (classic V-belt). Electrically conductive acc. to ISO 1813. The V-belts are of equal length (from 1000 mm).

The V-belts have limited oil resistance. Avoid continuous contact with mineral oils and grease as these will reduce the service life.

Temperature range:

-55 °C to +70 °C.


Service life is reduced if the V-belts are exposed to continuous temperatures above +60 °C.

Assembly:

The belts need to be tensioned after installation. Re-tensioning is required after an initial run time of 15 - 20 minutes.

If, by a drive with several belts, one belt requires changing, then the full belt set should be replaced.

Drawings

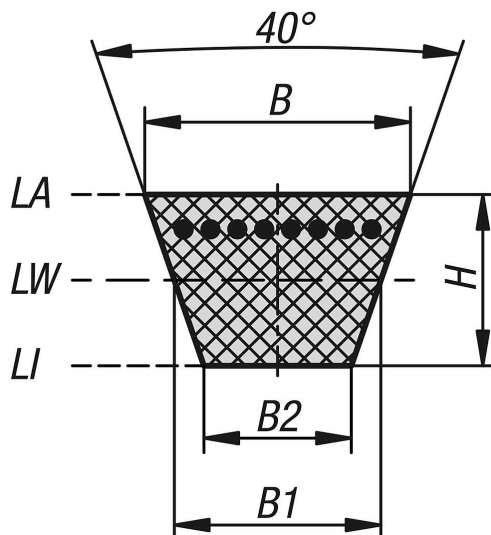

Overview of items

Order No.	Version 1	BW=Belt width	B1	B2	H	External length LA	Internal length LI	Effective length LW
22071-10425	type 10/z	10	8,5	6,1	6	463	425	448
22071-10450	type 10/z	10	8,5	6,1	6	488	450	473
22071-10475	type 10/z	10	8,5	6,1	6	513	475	498
-	Type 10/Z	10	8,5	6,1	6	521	483	506
22071-10500	type 10/z	10	8,5	6,1	6	538	500	523
22071-10508	type 10/z	10	8,5	6,1	6	546	508	531
22071-10520	type 10/z	10	8,5	6,1	6	558	520	543
22071-10530	type 10/z	10	8,5	6,1	6	568	530	553

Overview of items

Order No.	Version 1	BW=Belt width	B1	B2	H	External length LA	Internal length LI	Effective length LW
22071-10560	type 10/z	10	8,5	6,1	6	598	560	583
22071-10575	type 10/z	10	8,5	6,1	6	613	575	598
22071-10584	type 10/z	10	8,5	6,1	6	622	584	607
22071-10600	type 10/z	10	8,5	6,1	6	638	600	623
22071-10610	type 10/z	10	8,5	6,1	6	648	610	633
22071-10630	type 10/z	10	8,5	6,1	6	668	630	653
22071-10650	type 10/z	10	8,5	6,1	6	688	650	673
22071-10670	type 10/z	10	8,5	6,1	6	708	670	693
22071-10686	type 10/z	10	8,5	6,1	6	724	686	709
22071-10700	type 10/z	10	8,5	6,1	6	738	700	723
22071-10710	type 10/z	10	8,5	6,1	6	748	710	733
22071-10725	type 10/z	10	8,5	6,1	6	763	725	748
22071-10730	type 10/z	10	8,5	6,1	6	768	730	753
22071-10750	type 10/z	10	8,5	6,1	6	788	750	773
22071-10765	type 10/z	10	8,5	6,1	6	803	765	788
22071-10775	type 10/z	10	8,5	6,1	6	813	775	798
22071-10800	type 10/z	10	8,5	6,1	6	838	800	823
22071-10813	type 10/z	10	8,5	6,1	6	851	813	836
22071-10820	type 10/z	10	8,5	6,1	6	858	820	843
22071-10825	type 10/z	10	8,5	6,1	6	863	825	848
22071-10838	type 10/z	10	8,5	6,1	6	876	838	861
22071-10850	type 10/z	10	8,5	6,1	6	888	850	873
22071-10865	type 10/z	10	8,5	6,1	6	903	865	888
22071-10875	type 10/z	10	8,5	6,1	6	913	875	898
-	Type 10/Z	10	8,5	6,1	6	927	889	912
22071-10900	type 10/z	10	8,5	6,1	6	938	900	923
22071-10914	type 10/z	10	8,5	6,1	6	952	914	937
22071-10925	type 10/z	10	8,5	6,1	6	963	925	948
22071-10953	type 10/z	10	8,5	6,1	6	991	953	976
22071-10990	type 10/z	10	8,5	6,1	6	1028	990	1013
22071-11000	type 10/z	10	8,5	6,1	6	1038	1000	1023
22071-11016	type 10/z	10	8,5	6,1	6	1054	1016	1039
22071-11030	type 10/z	10	8,5	6,1	6	1068	1030	1053
22071-11041	type 10/z	10	8,5	6,1	6	1079	1041	1064
22071-11060	type 10/z	10	8,5	6,1	6	1098	1060	1083
22071-11080	type 10/z	10	8,5	6,1	6	1118	1080	1103
22071-11105	type 10/z	10	8,5	6,1	6	1143	1105	1128
22071-11120	type 10/z	10	8,5	6,1	6	1158	1120	1143
22071-11150	type 10/z	10	8,5	6,1	6	1188	1150	1173
22071-11170	type 10/z	10	8,5	6,1	6	1208	1170	1193
22071-11180	type 10/z	10	8,5	6,1	6	1218	1180	1203
22071-11194	type 10/z	10	8,5	6,1	6	1232	1194	1217
22071-11215	type 10/z	10	8,5	6,1	6	1253	1215	1238
22071-11230	type 10/z	10	8,5	6,1	6	1268	1230	1253
22071-11250	type 10/z	10	8,5	6,1	6	1288	1250	1273
22071-11270	type 10/z	10	8,5	6,1	6	1308	1270	1293
22071-11295	type 10/z	10	8,5	6,1	6	1333	1295	1318
22071-11320	type 10/z	10	8,5	6,1	6	1358	1320	1343
22071-11346	type 10/z	10	8,5	6,1	6	1384	1346	1369
22071-11371	type 10/z	10	8,5	6,1	6	1409	1371	1394
22071-11400	type 10/z	10	8,5	6,1	6	1438	1400	1423
22071-11450	type 10/z	10	8,5	6,1	6	1488	1450	1473
22071-11475	type 10/z	10	8,5	6,1	6	1513	1475	1498
22071-11500	type 10/z	10	8,5	6,1	6	1538	1500	1523
22071-11550	type 10/z	10	8,5	6,1	6	1588	1550	1573
-	Type 10/Z	10	8,5	6,1	6	1613	1575	1598
22071-11600	type 10/z	10	8,5	6,1	6	1638	1600	1623
22071-11680	type 10/z	10	8,5	6,1	6	1718	1680	1703
-	Type 10/Z	10	8,5	6,1	6	1738	1700	1723
22071-11750	type 10/z	10	8,5	6,1	6	1788	1750	1773
22071-11800	type 10/z	10	8,5	6,1	6	1838	1800	1823
22071-11900	type 10/z	10	8,5	6,1	6	1938	1900	1923
-	Type 10/Z	10	8,5	6,1	6	2013	1975	1998
-	Type 10/Z	10	8,5	6,1	6	2038	2000	2023
22071-12080	type 10/z	10	8,5	6,1	6	2118	2080	2103

Overview of items

Order No.	Version 1	BW=Belt width	B1	B2	H	External length LA	Internal length LI	Effective length LW
-	Type 10/Z	10	8,5	6,1	6	2158	2120	2143
22071-12360	type 10/z	10	8,5	6,1	6	2398	2360	2383
22071-20457	type 13/a	13	11	7,8	8	507	457	487
22071-20483	type 13/a	13	11	7,8	8	533	483	513
22071-20508	type 13/a	13	11	7,8	8	558	508	538
22071-20535	type 13/a	13	11	7,8	8	585	535	565
22071-20560	type 13/a	13	11	7,8	8	610	560	590
22071-20580	type 13/a	13	11	7,8	8	630	580	610
22071-20600	type 13/a	13	11	7,8	8	650	600	630
22071-20630	type 13/a	13	11	7,8	8	680	630	660
-	Type 13/A	13	11	7,8	8	698	660	683
22071-20670	type 13/a	13	11	7,8	8	720	670	700
-	Type 13/A	13	11	7,8	8	728	690	713
22071-20710	type 13/a	13	11	7,8	8	760	710	740
22071-20730	type 13/a	13	11	7,8	8	780	730	760
22071-20750	type 13/a	13	11	7,8	8	800	750	780
22071-20767	type 13/a	13	11	7,8	8	817	767	797
-	Type 13/A	13	11	7,8	8	818	780	803
22071-20787	type 13/a	13	11	7,8	8	837	787	817
22071-20800	type 13/a	13	11	7,8	8	850	800	830
22071-20813	type 13/a	13	11	7,8	8	863	813	843
22071-20825	type 13/a	13	11	7,8	8	875	825	855
22071-20838	type 13/a	13	11	7,8	8	888	838	868
22071-20850	type 13/a	13	11	7,8	8	900	850	880
-	Type 13/A	13	11	7,8	8	893	855	878
22071-20875	type 13/a	13	11	7,8	8	925	875	905
22071-20889	type 13/a	13	11	7,8	8	939	889	919
22071-20900	type 13/a	13	11	7,8	8	950	900	930
22071-20914	type 13/a	13	11	7,8	8	964	914	944
22071-20925	type 13/a	13	11	7,8	8	975	925	955
22071-20939	type 13/a	13	11	7,8	8	989	939	969
22071-20950	type 13/a	13	11	7,8	8	1000	950	980
22071-20965	type 13/a	13	11	7,8	8	1015	965	995
22071-20975	type 13/a	13	11	7,8	8	1025	975	1005
22071-20991	type 13/a	13	11	7,8	8	1041	991	1021
22071-21000	type 13/a	13	11	7,8	8	1050	1000	1030
22071-21016	type 13/a	13	11	7,8	8	1066	1016	1046
22071-21030	type 13/a	13	11	7,8	8	1080	1030	1060
22071-21041	type 13/a	13	11	7,8	8	1091	1041	1071
22071-21060	type 13/a	13	11	7,8	8	1110	1060	1090
22071-21075	type 13/a	13	11	7,8	8	1125	1075	1105
-	Type 13/A	13	11	7,8	8	1128	1090	1113
-	Type 13/A	13	11	7,8	8	1143	1105	1128
22071-21120	type 13/a	13	11	7,8	8	1170	1120	1150
22071-21143	type 13/a	13	11	7,8	8	1193	1143	1173
22071-21168	type 13/a	13	11	7,8	8	1218	1168	1198
22071-21180	type 13/a	13	11	7,8	8	1230	1180	1210
-	Type 13/A	13	11	7,8	8	1238	1200	1223
-	Type 13/A	13	11	7,8	8	1258	1220	1243
-	Type 13/A	13	11	7,8	8	1278	1240	1263
22071-21250	type 13/a	13	11	7,8	8	1300	1250	1280
22071-21270	type 13/a	13	11	7,8	8	1320	1270	1300
22071-21300	type 13/a	13	11	7,8	8	1350	1300	1330
22071-21320	type 13/a	13	11	7,8	8	1370	1320	1350
-	Type 13/A	13	11	7,8	8	1384	1346	1369
-	Type 13/A	13	11	7,8	8	1410	1372	1395
22071-21400	type 13/a	13	11	7,8	8	1450	1400	1430
-	Type 13/A	13	11	7,8	8	1460	1422	1445
22071-21448	type 13/a	13	11	7,8	8	1498	1448	1478
22071-21475	type 13/a	13	11	7,8	8	1525	1475	1505
22071-21500	type 13/a	13	11	7,8	8	1550	1500	1530
-	Type 13/A	13	11	7,8	8	1563	1525	1548
22071-21550	type 13/a	13	11	7,8	8	1600	1550	1580
22071-21575	type 13/a	13	11	7,8	8	1625	1575	1605
22071-21600	type 13/a	13	11	7,8	8	1650	1600	1630

Overview of items

Order No.	Version 1	BW=Belt width	B1	B2	H	External length LA	Internal length LI	Effective length LW
22071-21625	type 13/a	13	11	7,8	8	1675	1625	1655
22071-21651	type 13/a	13	11	7,8	8	1701	1651	1681
-	Type 13/A	13	11	7,8	8	1714	1676	1699
22071-21700	type 13/a	13	11	7,8	8	1750	1700	1730
22071-21725	type 13/a	13	11	7,8	8	1775	1725	1755
22071-21750	type 13/a	13	11	7,8	8	1800	1750	1780
22071-21780	type 13/a	13	11	7,8	8	1830	1780	1810
22071-21800	type 13/a	13	11	7,8	8	1850	1800	1830
22071-21825	type 13/a	13	11	7,8	8	1875	1825	1855
22071-21854	type 13/a	13	11	7,8	8	1904	1854	1884
22071-21880	type 13/a	13	11	7,8	8	1930	1880	1910
-	Type 13/A	13	11	7,8	8	1938	1900	1923
-	Type 13/A	13	11	7,8	8	1968	1930	1953
-	Type 13/A	13	11	7,8	8	1994	1956	1979
-	Type 13/A	13	11	7,8	8	2018	1980	2003
-	Type 13/A	13	11	7,8	8	2038	2000	2023
22071-22010	type 13/a	13	11	7,8	8	2060	2010	2040
22071-22030	type 13/a	13	11	7,8	8	2080	2030	2060
22071-22040	type 13/a	13	11	7,8	8	2090	2040	2070
22071-22057	type 13/a	13	11	7,8	8	2107	2057	2087
22071-22083	type 13/a	13	11	7,8	8	2133	2083	2113
22071-22100	type 13/a	13	11	7,8	8	2150	2100	2130
22071-22120	type 13/a	13	11	7,8	8	2170	2120	2150
22071-22134	type 13/a	13	11	7,8	8	2184	2134	2164
22071-22150	type 13/a	13	11	7,8	8	2200	2150	2180
22071-22184	type 13/a	13	11	7,8	8	2234	2184	2214
22071-22200	type 13/a	13	11	7,8	8	2250	2200	2230
22071-22240	type 13/a	13	11	7,8	8	2290	2240	2270
22071-22261	type 13/a	13	11	7,8	8	2311	2261	2291
22071-22285	type 13/a	13	11	7,8	8	2335	2285	2315
22071-22311	type 13/a	13	11	7,8	8	2361	2311	2341
22071-22337	type 13/a	13	11	7,8	8	2387	2337	2367
22071-22360	type 13/a	13	11	7,8	8	2410	2360	2390
22071-22388	type 13/a	13	11	7,8	8	2438	2388	2418
22071-22413	type 13/a	13	11	7,8	8	2463	2413	2443
22071-22435	type 13/a	13	11	7,8	8	2485	2435	2465
22071-22475	type 13/a	13	11	7,8	8	2525	2475	2505
22071-22500	type 13/a	13	11	7,8	8	2550	2500	2530
22071-22540	type 13/a	13	11	7,8	8	2590	2540	2570
22071-22591	type 13/a	13	11	7,8	8	2641	2591	2621
22071-22616	type 13/a	13	11	7,8	8	2666	2616	2646
22071-22650	type 13/a	13	11	7,8	8	2700	2650	2680
22071-22667	type 13/a	13	11	7,8	8	2717	2667	2697
22071-22730	type 13/a	13	11	7,8	8	2780	2730	2760
22071-22743	type 13/a	13	11	7,8	8	2793	2743	2773
22071-22800	type 13/a	13	11	7,8	8	2850	2800	2830
22071-22840	type 13/a	13	11	7,8	8	2890	2840	2870
22071-22946	type 13/a	13	11	7,8	8	2996	2946	2976
22071-23000	type 13/a	13	11	7,8	8	3050	3000	3030
22071-23050	type 13/a	13	11	7,8	8	3100	3050	3080
22071-23150	type 13/a	13	11	7,8	8	3200	3150	3180
22071-23250	type 13/a	13	11	7,8	8	3300	3250	3280
22071-23350	type 13/a	13	11	7,8	8	3400	3350	3380
22071-23404	type 13/a	13	11	7,8	8	3454	3404	3434
22071-23454	type 13/a	13	11	7,8	8	3504	3454	3484
22071-23550	type 13/a	13	11	7,8	8	3600	3550	3580
22071-23650	type 13/a	13	11	7,8	8	3700	3650	3680
22071-23683	type 13/a	13	11	7,8	8	3733	3683	3713
22071-24000	type 13/a	13	11	7,8	8	4050	4000	4030
22071-24572	type 13/a	13	11	7,8	8	4622	4572	4602
22071-25000	type 13/a	13	11	7,8	8	5050	5000	5030
22071-30615	type 17/b	17	14	9,4	11	684	615	660
22071-30635	type 17/b	17	14	9,4	11	704	635	680
22071-30650	type 17/b	17	14	9,4	11	719	650	695
22071-30670	type 17/b	17	14	9,4	11	739	670	715

Overview of items

Order No.	Version 1	BW=Belt width	B1	B2	H	External length LA	Internal length LI	Effective length LW
22071-30686	type 17/b	17	14	9,4	11	755	686	731
22071-30710	type 17/b	17	14	9,4	11	779	710	755
22071-30725	type 17/b	17	14	9,4	11	794	725	770
22071-30737	type 17/b	17	14	9,4	11	806	737	782
22071-30750	type 17/b	17	14	9,4	11	819	750	795
22071-30762	type 17/b	17	14	9,4	11	831	762	807
22071-30775	type 17/b	17	14	9,4	11	844	775	820
22071-30788	type 17/b	17	14	9,4	11	857	788	833
22071-30800	type 17/b	17	14	9,4	11	869	800	845
22071-30813	type 17/b	17	14	9,4	11	882	813	858
22071-30826	type 17/b	17	14	9,4	11	895	826	871
22071-30838	type 17/b	17	14	9,4	11	907	838	883
22071-30850	type 17/b	17	14	9,4	11	919	850	895
22071-30864	type 17/b	17	14	9,4	11	933	864	909
22071-30875	type 17/b	17	14	9,4	11	944	875	920
22071-30889	type 17/b	17	14	9,4	11	958	889	934
22071-30900	type 17/b	17	14	9,4	11	969	900	945
22071-30915	type 17/b	17	14	9,4	11	984	915	960
22071-30925	type 17/b	17	14	9,4	11	994	925	970
22071-30940	type 17/b	17	14	9,4	11	1009	940	985
22071-30950	type 17/b	17	14	9,4	11	1019	950	995
22071-30965	type 17/b	17	14	9,4	11	1034	965	1010
22071-30975	type 17/b	17	14	9,4	11	1044	975	1020
22071-30991	type 17/b	17	14	9,4	11	1060	991	1036
22071-31000	type 17/b	17	14	9,4	11	1069	1000	1045
22071-31017	type 17/b	17	14	9,4	11	1086	1017	1062
22071-31030	type 17/b	17	14	9,4	11	1099	1030	1075
22071-31040	type 17/b	17	14	9,4	11	1109	1040	1085
22071-31050	type 17/b	17	14	9,4	11	1119	1050	1095
22071-31060	type 17/b	17	14	9,4	11	1129	1060	1105
22071-31075	type 17/b	17	14	9,4	11	1144	1075	1120
22071-31090	type 17/b	17	14	9,4	11	1159	1090	1135
22071-31100	type 17/b	17	14	9,4	11	1169	1100	1145
22071-31120	type 17/b	17	14	9,4	11	1189	1120	1165
22071-31150	type 17/b	17	14	9,4	11	1219	1150	1195
22071-31175	type 17/b	17	14	9,4	11	1244	1175	1220
22071-31180	type 17/b	17	14	9,4	11	1249	1180	1225
22071-31200	type 17/b	17	14	9,4	11	1269	1200	1245
22071-31215	type 17/b	17	14	9,4	11	1284	1215	1260
22071-31225	type 17/b	17	14	9,4	11	1294	1225	1270
22071-31250	type 17/b	17	14	9,4	11	1319	1250	1295
22071-31270	type 17/b	17	14	9,4	11	1339	1270	1315
22071-31300	type 17/b	17	14	9,4	11	1369	1300	1345
22071-31320	type 17/b	17	14	9,4	11	1389	1320	1365
22071-31335	type 17/b	17	14	9,4	11	1404	1335	1380
22071-31350	type 17/b	17	14	9,4	11	1419	1350	1395
22071-31360	type 17/b	17	14	9,4	11	1429	1360	1405
22071-31372	type 17/b	17	14	9,4	11	1441	1372	1417
22071-31400	type 17/b	17	14	9,4	11	1469	1400	1445
22071-31422	type 17/b	17	14	9,4	11	1491	1422	1467
22071-31450	type 17/b	17	14	9,4	11	1519	1450	1495
22071-31470	type 17/b	17	14	9,4	11	1539	1470	1515
22071-31500	type 17/b	17	14	9,4	11	1569	1500	1545
22071-31525	type 17/b	17	14	9,4	11	1594	1525	1570
22071-31550	type 17/b	17	14	9,4	11	1619	1550	1595
22071-31575	type 17/b	17	14	9,4	11	1644	1575	1620
22071-31600	type 17/b	17	14	9,4	11	1669	1600	1645
22071-31625	type 17/b	17	14	9,4	11	1694	1625	1670
22071-31650	type 17/b	17	14	9,4	11	1719	1650	1695
22071-31676	type 17/b	17	14	9,4	11	1745	1676	1721
22071-31700	type 17/b	17	14	9,4	11	1769	1700	1745
22071-31725	type 17/b	17	14	9,4	11	1794	1725	1770
22071-31750	type 17/b	17	14	9,4	11	1819	1750	1795
22071-31761	type 17/b	17	14	9,4	11	1830	1761	1806
22071-31775	type 17/b	17	14	9,4	11	1844	1775	1820

Overview of items

Order No.	Version 1	BW=Belt width	B1	B2	H	External length LA	Internal length LI	Effective length LW
22071-31800	type 17/b	17	14	9,4	11	1869	1800	1845
22071-31829	type 17/b	17	14	9,4	11	1898	1829	1874
22071-31850	type 17/b	17	14	9,4	11	1919	1850	1895
22071-31880	type 17/b	17	14	9,4	11	1949	1880	1925
22071-31900	type 17/b	17	14	9,4	11	1969	1900	1945
22071-31930	type 17/b	17	14	9,4	11	1999	1930	1975
22071-31950	type 17/b	17	14	9,4	11	2019	1950	1995
22071-31981	type 17/b	17	14	9,4	11	2050	1981	2026
22071-32000	type 17/b	17	14	9,4	11	2069	2000	2045
22071-32030	type 17/b	17	14	9,4	11	2099	2030	2075
22071-32060	type 17/b	17	14	9,4	11	2129	2060	2105
22071-32083	type 17/b	17	14	9,4	11	2152	2083	2128
22071-32108	type 17/b	17	14	9,4	11	2177	2108	2153
22071-32120	type 17/b	17	14	9,4	11	2189	2120	2165
22071-32134	type 17/b	17	14	9,4	11	2203	2134	2179
22071-32160	type 17/b	17	14	9,4	11	2229	2160	2205
22071-32184	type 17/b	17	14	9,4	11	2253	2184	2229
22071-32200	type 17/b	17	14	9,4	11	2266	2197	2242
22071-32210	type 17/b	17	14	9,4	11	2279	2210	2255
22071-32240	type 17/b	17	14	9,4	11	2309	2240	2285
22071-32261	type 17/b	17	14	9,4	11	2330	2261	2306
22071-32286	type 17/b	17	14	9,4	11	2355	2286	2331
22071-32300	type 17/b	17	14	9,4	11	2369	2300	2345
22071-32337	type 17/b	17	14	9,4	11	2406	2337	2382
22071-32360	type 17/b	17	14	9,4	11	2429	2360	2405
22071-32388	type 17/b	17	14	9,4	11	2457	2388	2433
22071-32400	type 17/b	17	14	9,4	11	2469	2400	2445
22071-32413	type 17/b	17	14	9,4	11	2482	2413	2458
22071-32438	type 17/b	17	14	9,4	11	2507	2438	2483
22071-32450	type 17/b	17	14	9,4	11	2519	2450	2495
22071-32465	type 17/b	17	14	9,4	11	2534	2465	2510
22071-32500	type 17/b	17	14	9,4	11	2569	2500	2545
22071-32515	type 17/b	17	14	9,4	11	2584	2515	2560
22071-32540	type 17/b	17	14	9,4	11	2609	2540	2585
22071-32565	type 17/b	17	14	9,4	11	2634	2565	2610
22071-32600	type 17/b	17	14	9,4	11	2669	2600	2645
22071-32616	type 17/b	17	14	9,4	11	2685	2616	2661
22071-32650	type 17/b	17	14	9,4	11	2719	2650	2695
22071-32667	type 17/b	17	14	9,4	11	2736	2667	2712
22071-32700	type 17/b	17	14	9,4	11	2769	2700	2745
22071-32718	type 17/b	17	14	9,4	11	2787	2718	2763
22071-32750	type 17/b	17	14	9,4	11	2819	2750	2795
22071-32800	type 17/b	17	14	9,4	11	2869	2800	2845
22071-32840	type 17/b	17	14	9,4	11	2909	2840	2885
22071-32900	type 17/b	17	14	9,4	11	2969	2900	2945
22071-32921	type 17/b	17	14	9,4	11	2990	2921	2966
22071-32950	type 17/b	17	14	9,4	11	3019	2950	2995
22071-33000	type 17/b	17	14	9,4	11	3069	3000	3045
22071-33050	type 17/b	17	14	9,4	11	3119	3050	3095
22071-33100	type 17/b	17	14	9,4	11	3169	3100	3145
22071-33150	type 17/b	17	14	9,4	11	3219	3150	3195
22071-33175	type 17/b	17	14	9,4	11	3244	3175	3220
22071-33200	type 17/b	17	14	9,4	11	3269	3200	3245
22071-33250	type 17/b	17	14	9,4	11	3319	3250	3295
22071-33302	type 17/b	17	14	9,4	11	3371	3302	3347
22071-33350	type 17/b	17	14	9,4	11	3419	3350	3395
22071-33378	type 17/b	17	14	9,4	11	3447	3378	3423
22071-33404	type 17/b	17	14	9,4	11	3473	3404	3449
22071-33450	type 17/b	17	14	9,4	11	3519	3450	3495
22071-33505	type 17/b	17	14	9,4	11	3574	3505	3550
22071-33550	type 17/b	17	14	9,4	11	3619	3550	3595
22071-33581	type 17/b	17	14	9,4	11	3650	3581	3626
22071-33600	type 17/b	17	14	9,4	11	3669	3600	3645
22071-33658	type 17/b	17	14	9,4	11	3727	3658	3703
22071-33700	type 17/b	17	14	9,4	11	3769	3700	3745

Overview of items

Order No.	Version 1	BW=Belt width	B1	B2	H	External length LA	Internal length LI	Effective length LW
22071-33750	type 17/b	17	14	9,4	11	3819	3750	3795
22071-33810	type 17/b	17	14	9,4	11	3879	3810	3855
22071-33895	type 17/b	17	14	9,4	11	3919	3895	3895
22071-33861	type 17/b	17	14	9,4	11	3930	3861	3906
22071-33912	type 17/b	17	14	9,4	11	3981	3912	3957
22071-33950	type 17/b	17	14	9,4	11	4019	3950	3995
22071-34000	type 17/b	17	14	9,4	11	4069	4000	4045
22071-34115	type 17/b	17	14	9,4	11	4184	4115	4160
22071-34200	type 17/b	17	14	9,4	11	4269	4200	4245
22071-34250	type 17/b	17	14	9,4	11	4319	4250	4295
22071-34378	type 17/b	17	14	9,4	11	4438	4378	4414
22071-34394	type 17/b	17	14	9,4	11	4463	4394	4439
22071-34450	type 17/b	17	14	9,4	11	4519	4450	4495
22071-34500	type 17/b	17	14	9,4	11	4569	4500	4545
22071-34572	type 17/b	17	14	9,4	11	4641	4572	4617
22071-34699	type 17/b	17	14	9,4	11	4768	4699	4744
22071-34750	type 17/b	17	14	9,4	11	4819	4750	4795
22071-34826	type 17/b	17	14	9,4	11	4895	4826	4871
22071-34877	type 17/b	17	14	9,4	11	4946	4877	4922
22071-34953	type 17/b	17	14	9,4	11	5022	4953	4998
22071-35000	type 17/b	17	14	9,4	11	5069	5000	5045