

Item description/product images



Description

Material:

Steel.

Version:

Grade 10.

Plastic-coated, red.

Note:

The shortening hook is for incorporating into single or multiple strand chains and is used to shorten the chain.

Shortening hooks are permissible for lifting, but not for lashing since they do not have a latch to prevent unintentional unhooking.

The shortening hooks correspond to the Machinery Directive and are BG certified (H stamp).

Temperature range:

From -40°C to 200°C = 100% permissible load

Up to 300°C = 90% permissible load


Up to 400°C = 75% permissible load

Drawing reference:

Form A: eye hook.

Form B: clevis hook.

Drawings

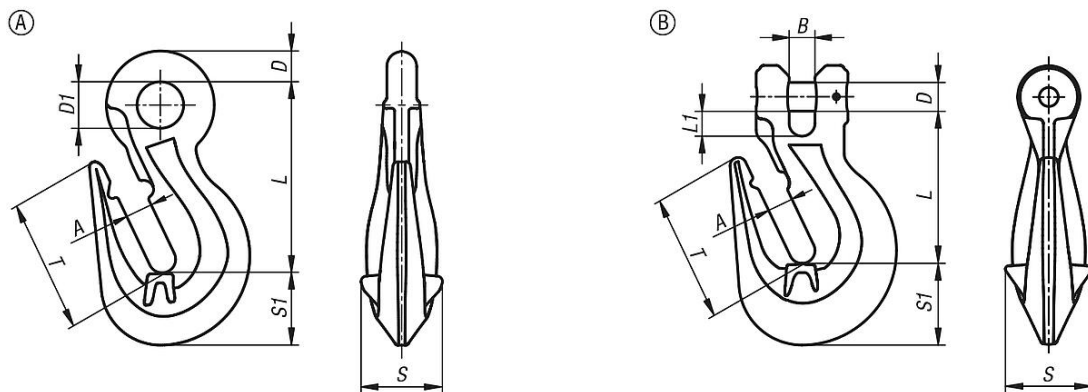

Overview of items

Order No.	Version 1	Form	for chain mm	A	B	D	D1	L	L1	S	S1	T	Permissible load kg
07793-11001400	for interchangeable subplates	A	6	8	-	8,5	12	51,5	-	22	22	35,5	1400
07793-11002500	for interchangeable subplates	A	7-8	10	-	11	17	69	-	30	28	47	2500
07793-11004000	for interchangeable subplates	A	10	13	-	15	22	86,5	-	44	34	55	4000
07793-11006700	for interchangeable subplates	A	13	17	-	18	26	110,5	-	53	47	81	6700
07793-11010000	for interchangeable subplates	A	16	19	-	21	32	129	-	64	60	92	10000
07793-21001400	for latch	B	6	8	8	7,5	-	51	8,8	22	22	36	1400
07793-21001900	for latch	B	7	10	10	9	-	66	11	30	28	47	1900
07793-21002500	for latch	B	8	10	10	10	-	65	11	30	28	47	2500
07793-21004000	for latch	B	10	13	13	13	-	80	15	44	34	55	4000
07793-21006700	for latch	B	13	17	17	16	-	105	18	53	47	81	6700

Overview of items

Order No.	Version 1	Form	for chain mm	A	B	D	D1	L	L1	S	S1	T	Permissible load kg
07793-21010000	for latch	B	16	19	19	21	-	112	18	64	60	92	10000