

Popis zboží/obrázky produktu



Popis


Materiál:

Ocel 1.1192 nebo nerezová ocel 1.4571.


Provedení:

Bez povrchové úpravy.

Příklad využití:

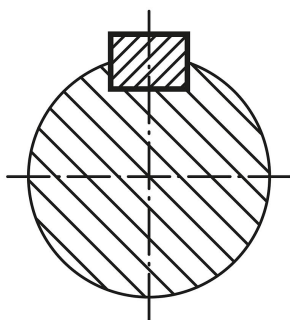

Výkresy

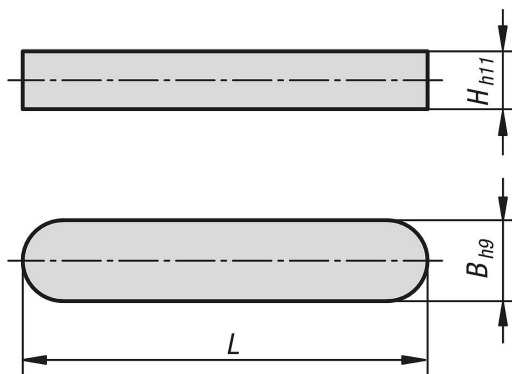

Přehled zboží

Objednací číslo	Materiál základní těleso	B	H	L = délka
03288-03X8	ocel	3	3	8
03288-03X10	ocel	3	3	10
03288-03X12	ocel	3	3	12
03288-03X14	ocel	3	3	14
03288-03X16	ocel	3	3	16
03288-03X18	ocel	3	3	18
03288-03X20	ocel	3	3	20
03288-03X22	ocel	3	3	22
03288-03X25	ocel	3	3	25
03288-03X28	ocel	3	3	28
03288-04X8	ocel	4	4	8
03288-04X10	ocel	4	4	10
03288-04X12	ocel	4	4	12

Přehled zboží

Objednací číslo	Materiál základní těleso	B	H	L = délka
03288-04X14	ocel	4	4	14
03288-04X16	ocel	4	4	16
03288-04X18	ocel	4	4	18
03288-04X20	ocel	4	4	20
03288-04X22	ocel	4	4	22
03288-04X25	ocel	4	4	25
03288-04X28	ocel	4	4	28
03288-05X12	ocel	5	5	12
03288-05X14	ocel	5	5	14
03288-05X16	ocel	5	5	16
03288-05X18	ocel	5	5	18
03288-05X20	ocel	5	5	20
03288-05X22	ocel	5	5	22
03288-05X25	ocel	5	5	25
03288-05X28	ocel	5	5	28
03288-05X32	ocel	5	5	32
03288-05X36	ocel	5	5	36
03288-05X40	ocel	5	5	40
03288-06X12	ocel	6	6	12
03288-06X14	ocel	6	6	14
03288-06X16	ocel	6	6	16
03288-06X18	ocel	6	6	18
03288-06X20	ocel	6	6	20
03288-06X22	ocel	6	6	22
03288-06X25	ocel	6	6	25
03288-06X28	ocel	6	6	28
03288-06X32	ocel	6	6	32
03288-06X36	ocel	6	6	36
03288-06X40	ocel	6	6	40
03288-06X45	ocel	6	6	45
03288-08X14	ocel	8	7	14
03288-08X16	ocel	8	7	16
03288-08X18	ocel	8	7	18
03288-08X20	ocel	8	7	20
03288-08X22	ocel	8	7	22
03288-08X25	ocel	8	7	25
03288-08X28	ocel	8	7	28
03288-08X32	ocel	8	7	32
03288-08X36	ocel	8	7	36
03288-08X40	ocel	8	7	40
03288-08X45	ocel	8	7	45
03288-08X50	ocel	8	7	50
03288-08X70	ocel	8	7	70
03288-10X22	ocel	10	8	22
03288-10X25	ocel	10	8	25
03288-10X28	ocel	10	8	28
03288-10X32	ocel	10	8	32
03288-10X36	ocel	10	8	36
03288-10X40	ocel	10	8	40
03288-10X45	ocel	10	8	45
03288-10X50	ocel	10	8	50
03288-10X56	ocel	10	8	56
03288-10X70	ocel	10	8	70
03288-10X80	ocel	10	8	80
03288-12X25	ocel	12	8	25
03288-12X28	ocel	12	8	28
03288-12X32	ocel	12	8	32
03288-12X36	ocel	12	8	36
03288-12X40	ocel	12	8	40
03288-12X45	ocel	12	8	45
03288-12X50	ocel	12	8	50
03288-12X56	ocel	12	8	56
03288-12X70	ocel	12	8	70
03288-12X80	ocel	12	8	80

Přehled zboží

Objednací číslo	Materiál základní těleso	B	H	L = délka
03288-14X25	ocel	14	9	25
03288-14X28	ocel	14	9	28
03288-14X32	ocel	14	9	32
03288-14X36	ocel	14	9	36
03288-14X40	ocel	14	9	40
03288-14X45	ocel	14	9	45
03288-14X50	ocel	14	9	50
03288-14X56	ocel	14	9	56
03288-14X70	ocel	14	9	70
03288-14X80	ocel	14	9	80
03288-16X50	ocel	16	10	50
03288-16X56	ocel	16	10	56
03288-16X63	ocel	16	10	63
03288-16X70	ocel	16	10	70
03288-16X80	ocel	16	10	80
03288-16X90	ocel	16	10	90
03288-16X100	ocel	16	10	100
03288-103X10	nerezová ocel	3	3	10
03288-103X12	nerezová ocel	3	3	12
03288-103X16	nerezová ocel	3	3	16
03288-103X20	nerezová ocel	3	3	20
03288-104X10	nerezová ocel	4	4	10
03288-104X12	nerezová ocel	4	4	12
03288-104X14	nerezová ocel	4	4	14
03288-104X16	nerezová ocel	4	4	16
03288-104X18	nerezová ocel	4	4	18
03288-104X20	nerezová ocel	4	4	20
03288-104X22	nerezová ocel	4	4	22
03288-105X12	nerezová ocel	5	5	12
03288-105X14	nerezová ocel	5	5	14
03288-105X16	nerezová ocel	5	5	16
03288-105X18	nerezová ocel	5	5	18
03288-105X20	nerezová ocel	5	5	20
03288-105X22	nerezová ocel	5	5	22
03288-105X25	nerezová ocel	5	5	25
03288-105X28	nerezová ocel	5	5	28
03288-105X36	nerezová ocel	5	5	36
03288-105X40	nerezová ocel	5	5	40
03288-106X12	nerezová ocel	6	6	12
03288-106X14	nerezová ocel	6	6	14
03288-106X16	nerezová ocel	6	6	16
03288-106X18	nerezová ocel	6	6	18
03288-106X20	nerezová ocel	6	6	20
03288-106X22	nerezová ocel	6	6	22
03288-106X25	nerezová ocel	6	6	25
03288-106X28	nerezová ocel	6	6	28
03288-106X32	nerezová ocel	6	6	32
03288-106X36	nerezová ocel	6	6	36
03288-106X40	nerezová ocel	6	6	40
03288-108X16	nerezová ocel	8	7	16
03288-108X18	nerezová ocel	8	7	18
03288-108X20	nerezová ocel	8	7	20
03288-108X22	nerezová ocel	8	7	22
03288-108X25	nerezová ocel	8	7	25
03288-108X28	nerezová ocel	8	7	28
03288-108X32	nerezová ocel	8	7	32
03288-108X36	nerezová ocel	8	7	36
03288-108X40	nerezová ocel	8	7	40
03288-108X45	nerezová ocel	8	7	45
03288-108X50	nerezová ocel	8	7	50
03288-108X70	nerezová ocel	8	7	70
03288-110X22	nerezová ocel	10	8	22
03288-110X25	nerezová ocel	10	8	25
03288-110X28	nerezová ocel	10	8	28

Přehled zboží

Objednáací číslo	Materiál základní těleso	B	H	L = délka
03288-110X32	nerezová ocel	10	8	32
03288-110X36	nerezová ocel	10	8	36
03288-110X40	nerezová ocel	10	8	40
03288-110X45	nerezová ocel	10	8	45
03288-110X50	nerezová ocel	10	8	50
03288-110X56	nerezová ocel	10	8	56
03288-110X70	nerezová ocel	10	8	70
03288-110X80	nerezová ocel	10	8	80
03288-112X28	nerezová ocel	12	8	28
03288-112X32	nerezová ocel	12	8	32
03288-112X36	nerezová ocel	12	8	36
03288-112X40	nerezová ocel	12	8	40
03288-112X45	nerezová ocel	12	8	45
03288-112X50	nerezová ocel	12	8	50
03288-112X56	nerezová ocel	12	8	56
03288-112X70	nerezová ocel	12	8	70
03288-112X80	nerezová ocel	12	8	80
03288-114X32	nerezová ocel	14	9	32
03288-114X40	nerezová ocel	14	9	40
03288-114X45	nerezová ocel	14	9	45
03288-114X50	nerezová ocel	14	9	50
03288-114X56	nerezová ocel	14	9	56
03288-114X70	nerezová ocel	14	9	70
03288-114X80	nerezová ocel	14	9	80
03288-116X50	nerezová ocel	16	10	50
03288-116X63	nerezová ocel	16	10	63
03288-116X70	nerezová ocel	16	10	70
03288-116X80	nerezová ocel	16	10	80
03288-116X90	nerezová ocel	16	10	90
03288-116X100	nerezová ocel	16	10	100